


# UL Type 12 hood for ACS580-01, ACH580-01 and ACQ580-01, and for ACH580-31 and ACQ580-31 frames R6 and R8

## Installation instructions


### Frame sizes R1 ... R3:

1. Push the hood plate down on the drive until you can hear a click to make sure the hood plate is secured.

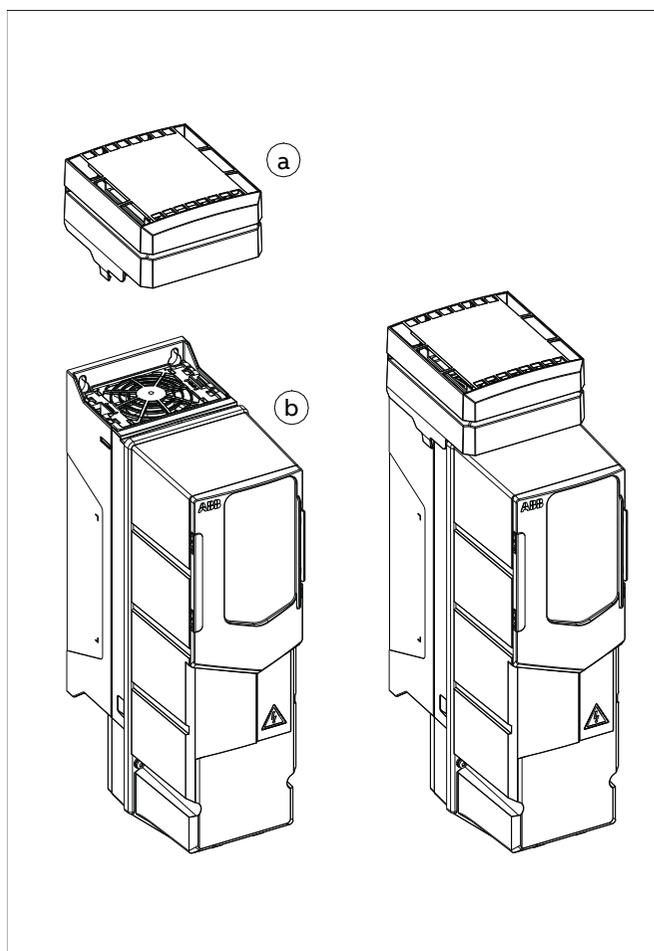

### Frame sizes R6 ... R9:


1. Loosen the mounting screws somewhat if necessary.
2. Put the hood plate on the drive.
3. Tighten the drive mounting screws until the hood is correctly attached.

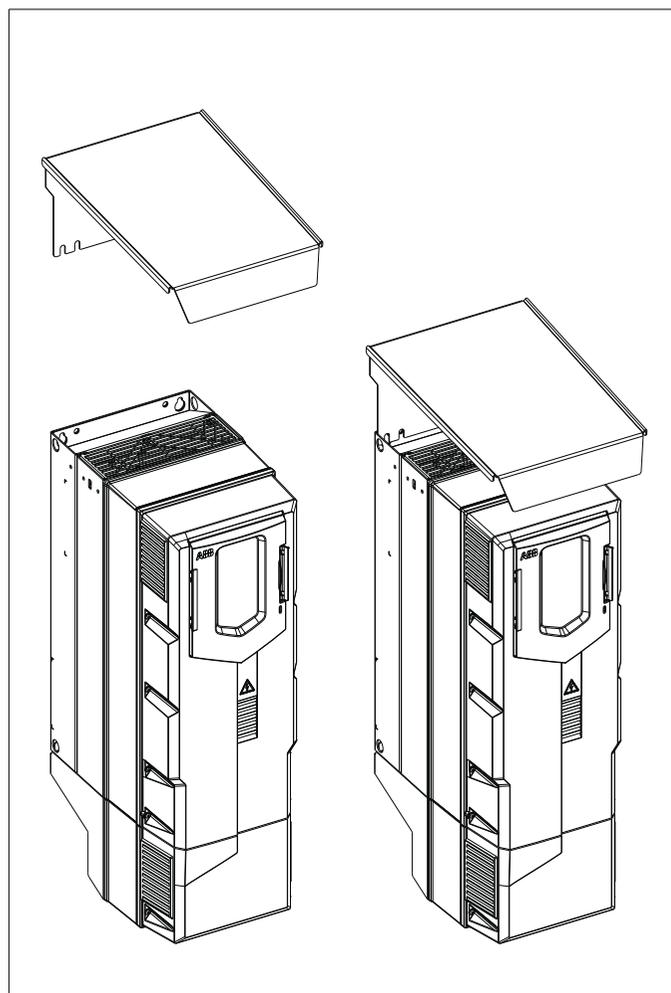

a	Hood plate
b	Drive

**Frame sizes R4 ... R5:**

1. Loosen the mounting screws somewhat if necessary.
2. Put the fastener plate on the drive.
3. Tighten the drive mounting screws until correctly attached.
4. Put the hood plate on the fastener plate.

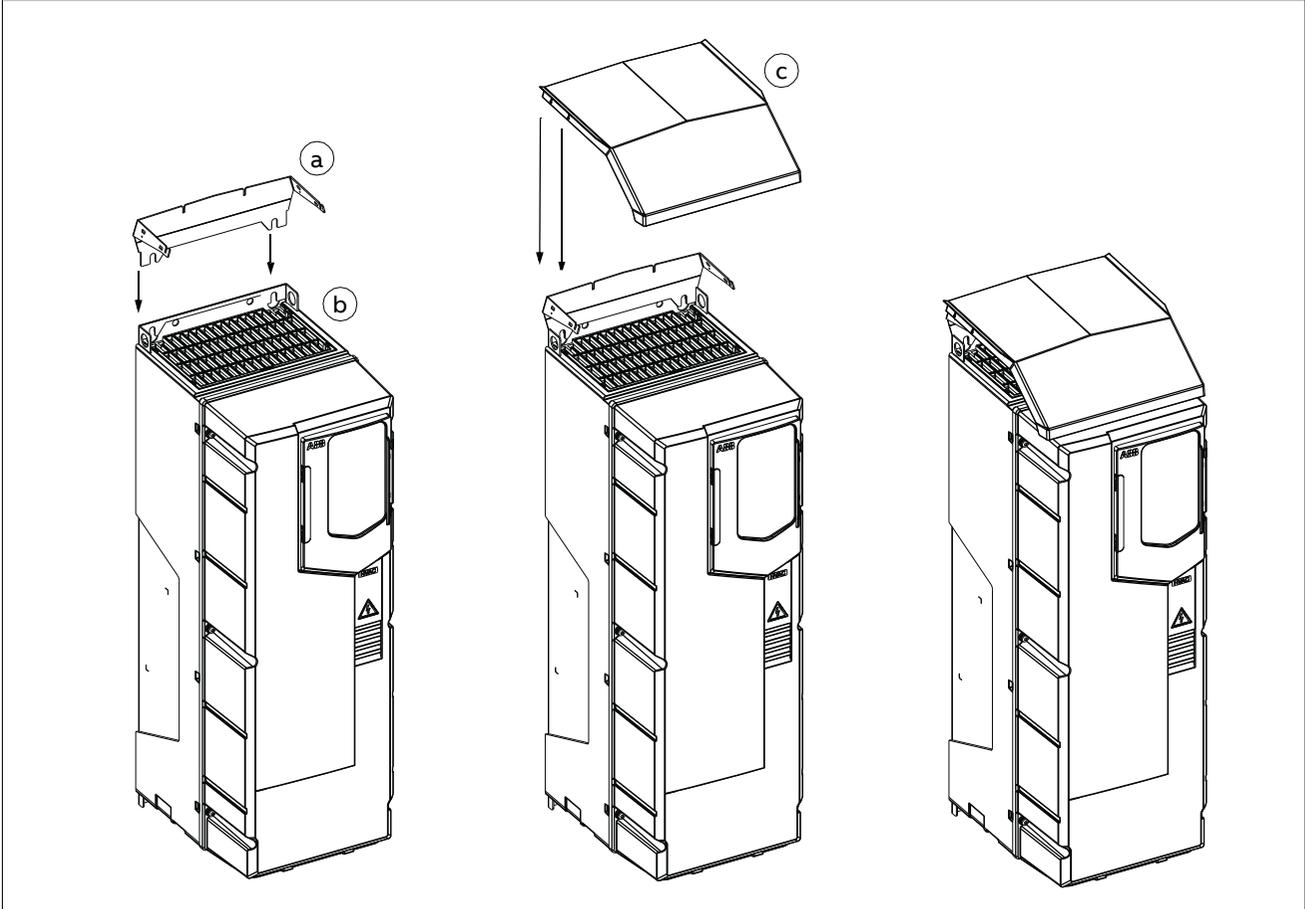

a	Fastener
b	Drive
c	Hood plate

