


Earth bonds & clamps

Accessories

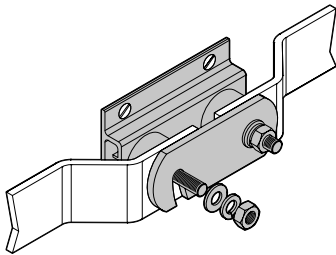

Standards

BS 7430



Earth bar accessories

Part no.	Description	Length (mm)	Width (mm)	Height (mm)	Weight each (kg)
Copper earth bar					
LK004	Swan-neck link	400	50	36	0.42
LK205	Disconnecting link	125	90	77	0.59
Tinned copper earth bar					
LK004-T	Swan-neck link	400	50	36	0.42
LK205-T	Disconnecting link	125	90	77	0.59

– Fix using countersunk wood screws 1½" No. 12 (Part no. SW110) and wall plugs (Part no. PS310) fixings only apply to disconnecting link

Insulator

Part no.	Height (A) (mm)	Top diameter (B) (mm)	Max diameter (C) (mm)	Insert size	For copper bar size (mm)
Insulator					
IN020	20	Ø 14	Ø 18	M6	25 x 3
IN030	30	Ø 25	Ø 33	M6	25 x 6
IN040	40	Ø 31	Ø 39	M8	38 x 6
IN013	50	Ø 27	Ø 35	M10	50 x 6
IN060	60	Ø 38	Ø 52	M10	75 x 6
IN070	70	Ø 51	Ø 55	M12	100 x 6
Insulator with 2 studs and 3 nuts					
IN005	50	Ø 27	Ø 35	M10	50 x 6

– Insulator manufactured from grey GRP material with brass insert

