

TECHNICAL DATA SHEET

Stanilite®

Economy exit LED one box - maintained body

e-Range



Range

Economy range

Product group


Exit LED



Features

- 1 year warranty
- LED technology 75,000 hours lamp life
- Low power consumption and LED light source for reduced operation and maintenance costs
- High temperature NiCad batteries
- Strong, lightweight, UV/FR polycarbonate body and gear tray
- Wall or ceiling mount
- Switched active input available for mains switching
- Large terminal block (16mm²) for easy wiring
- Designed for direct replacement of installed 10W economy exit EE110M and EE210S
- Retrofit capability; gear tray fits into existing 10W economy exit EE110M and EE210S base
- Main body and gear tray only, diffuser not included (can be ordered separately)

Catalogue no.	Description
Standard products	
ECOLED	Economy exit LED - maintained body only
Accessories	
31-PEWM-AU	Diffuser wall mount pictograph
31-PECMS	Diffuser ceiling mount single sided pictograph
31-PECMD	Diffuser ceiling mount double sided pictograph
EEWGWM	Wire guard wall mount
EEWGCM	Wire guard ceiling mount
Spare parts	
03-01219	Battery 3 cell NiCad 3.6V 1.6Ah

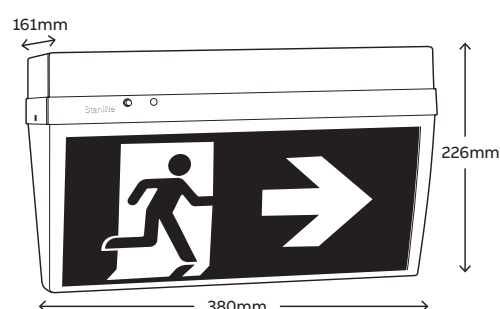

Dimensions				
	Model	Length	Width (incl. diffuser)	Height
	Wall mount	380mm	110mm	161mm
	Ceiling mount	380mm	161mm	226mm
Weight				
	Model	Weight		
	Standard	1.4kg		
Construction				
	Part	Construction		
	Body	Moulded polycarbonate		
	Diffuser	Moulded acrylic		

Light source			
	Model	Light source	
	Standard	Multiple LED 1.2W	
Power consumption			
	Model	Power consumption	
	Standard	6.5W	
Photometrics			
	Model	Class	Classification
	Wall mount	C0	E2
		C90	E1.25
	Ceiling mount	C0	E2.5
		C90	E3.2
Note: Preliminary results			

Note:

- Designed to comply with AS2293 and meet relevant Australian EMC standards