




 


## Pedestals


### EH2 - Column cabinets

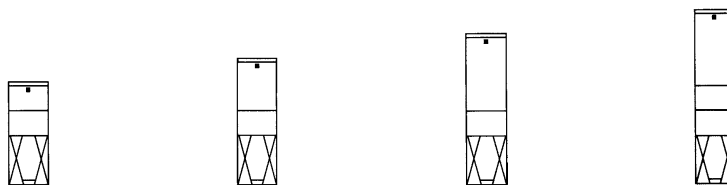



	Type	EH2-NA	EH2-NB	EH2-NC	EH2-ND
	H x W x D	1097x433x240	1347x433x240	1622x433x240	1896x433x240
Standard	Type	EH2C25CH	EH2C35CH	EH2C45CH	EH2C55CH
	Order code	4TBE842072C0100	4TBE842073C0100	4TBE842074C0100	4TBE842075N0100
With UV coating	Type	EH2U25CH	EH2U35CH	EH2U45CH	EH2U55CH
	Order code	4TBE842082N0100	4TBE842083N0100	4TBE842084N0100	4TBE842085N0100
	Mounting plate	H x W x D	200x395x5	450x395x5	700x395x5
	Pertinax with fixing bolts	Type	EH2M25EH	EH2M35EH	EH2M45EH
		Order code	4TBE842002C0100	4TBE842000C0100	4TBE842001C0100

### EH2 - Accessories

Product	Type	Order code	Pack
<b>Locks - profile half cylinder type</b>			
	With 2 keys, V2432-E		
	EH3AEECI	4TBE843001C0100	1
	spare keys for EH3AEECI		
	PS832022	4TBP832022C0100	2
	With 1 square key, 8mm		
	EH3AEEQHN	4TBE843002C0100	1
	With an 8mm triangular key		
	EH3AEETHN	4TBE843003C0100	1
	With 2 keys A434		
	EH3UAECI	4TBE843248C0100	1
	Replacement keys upon request.		

Product	Type	Order code	Pack
<b>Vandal proof nameplate holder</b>			
Can be placed on every flat surface, by drilling two holes Ø 5.5 mm; the identification window is used as a drill template. Steady against vandalism; it keeps its total isolation. Possibility to write on manually and/or to use the standard letteringsystems; the maximal letterheight is 18 mm. Usefull dimensions of letters: 18 x 143. Outside dimensions: 30 x 183 x 5.			
	EH3AEEE4	4TBE843304C0100	1

Inserts			
	M6 x 11 threaded inserts		
	VJ890846	4TBO890846C0100	100
	Punch for inserting M6 threaded barrel		
	Support for cable release clamp (to be ordered separately)		
	APPL	4TBO852004C0100	1