



OT315-400_C

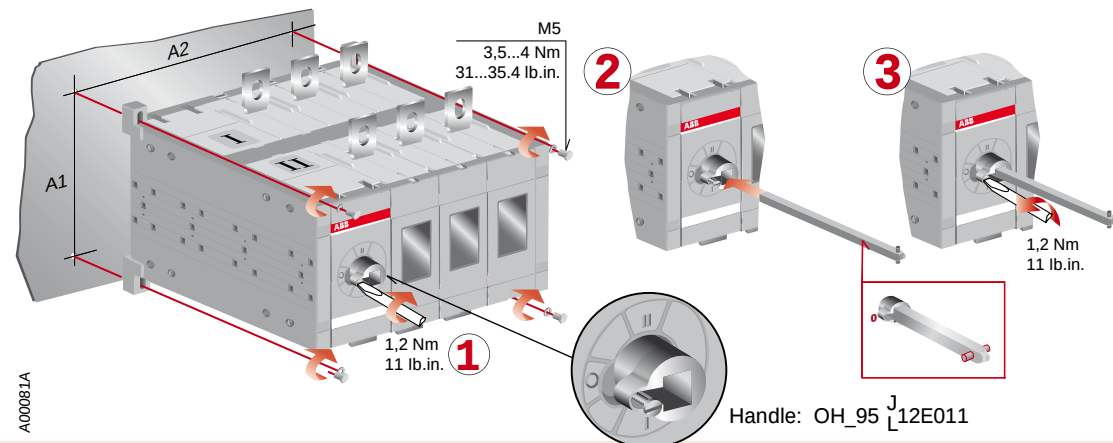

OT315_400_C

[mm]

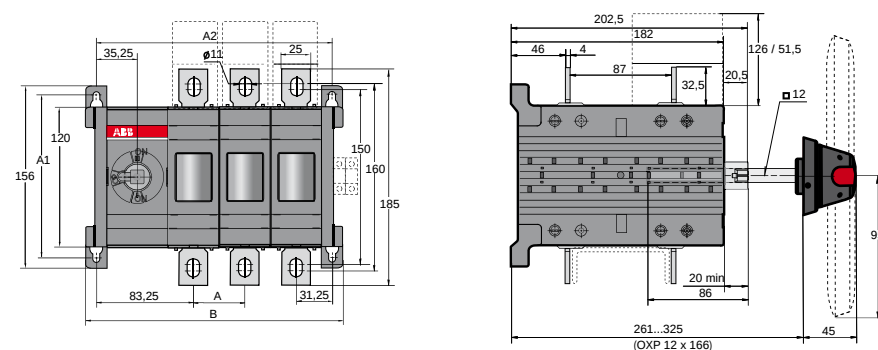


	OT 315...400E C		
	E02	E03	E04
A	44	44	44
A1	142	142	142
A2	158,5	202,5	246,5
B	177	221	265

000000 / 21E 400E C AS A

OT400U_C



[mm] / [in]

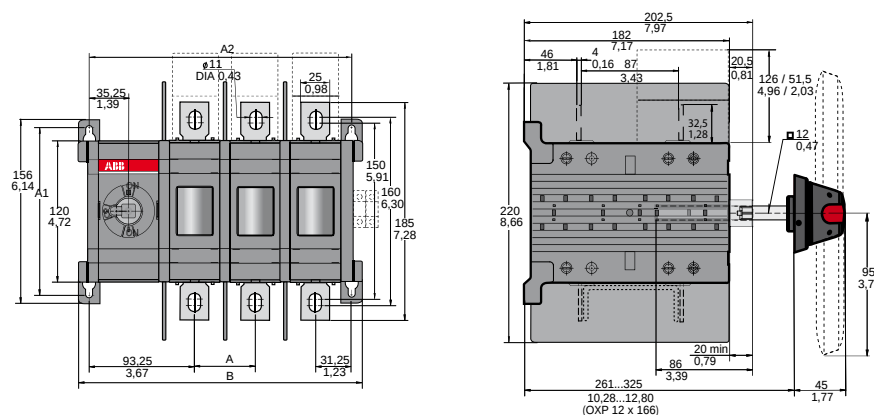


	OT 400U_C		
	U02	U03	U04
A	54 / 2,13	54 / 2,13	54 / 2,13
A1	142 / 5,59	142 / 5,59	142 / 5,59
A2	178,5 / 7,03	232,5 / 9,15	286,5 / 11,28
B	197 / 7,76	251 / 9,88	305 / 12,01

[illegible]



OTS_

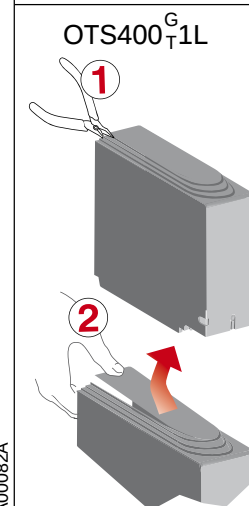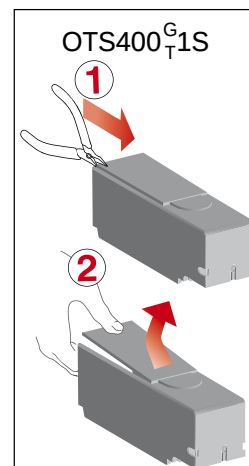

VGGG

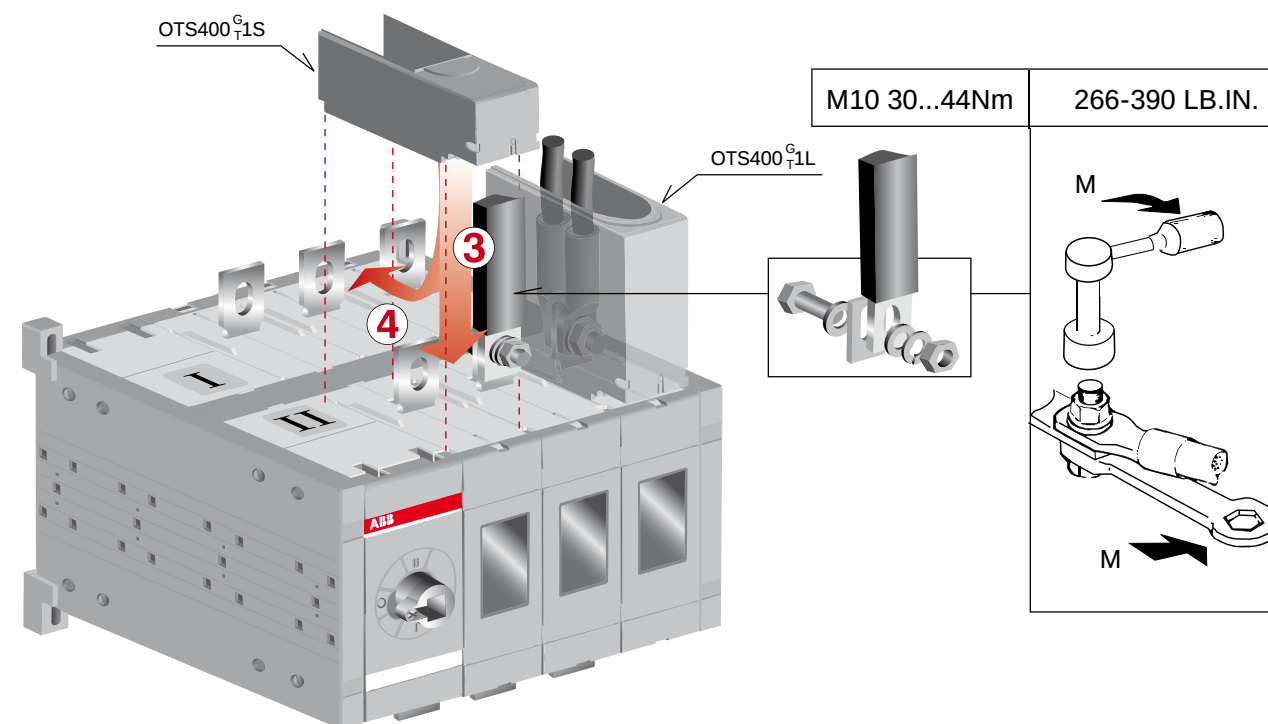

OZX_

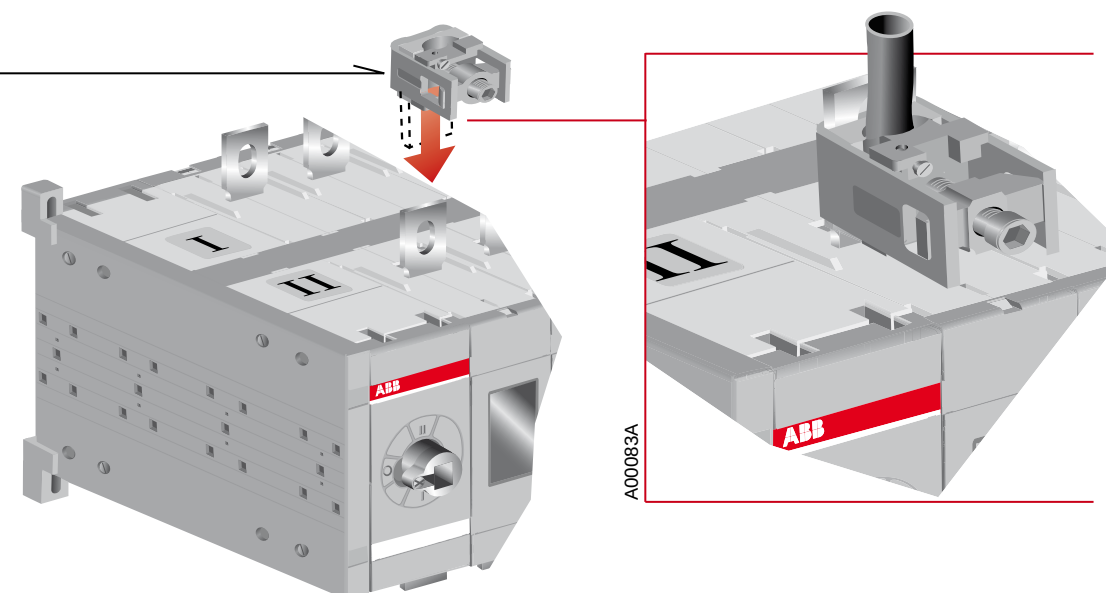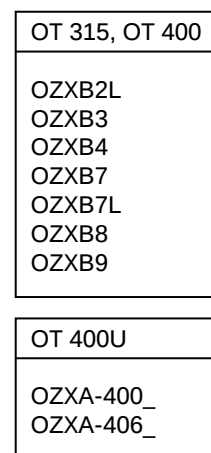

Clearances per UL98

OT400U_

A	0
B	13mm 0,5 in
C	Cable size AWG/MCM
D	13mm 0,5 in

C

A

B

C

D

2

100 mm 4in

1

100 mm 4 in

1/0

150 mm 5 in

2/0

150 mm 6 in

3/0-4/0

175 mm 7 in

250

200 mm 8 in

300

250 mm 10 in

350

300 mm 12 in

Minimum enclosure size or equivalent volume

Heigh	x	Width	x	Depth
610 mm	x	356 mm	x	254 mm
24 in	x	14 in	x	10 in

Label

OTZC_

OTV400ECK

OA_

ABB Oy
Low Voltage Products
P.O. Box 622
FIN-65101 Vaasa, Finland
Telephone +358-10 224 000
Telefax +358-10 224 5708