



OT600-800_C

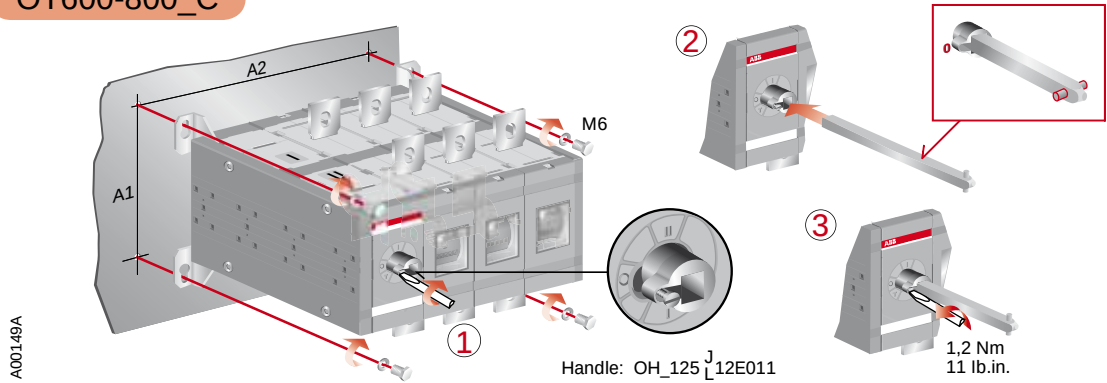


OT630_800E_C

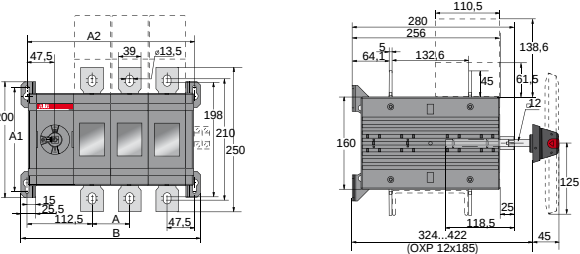


OT630/800E_C			
	E02	E03	E04
A	65	65	65
A1	180	180	180
A2	225	290	355
B	246	311	376

OT630_800E_C

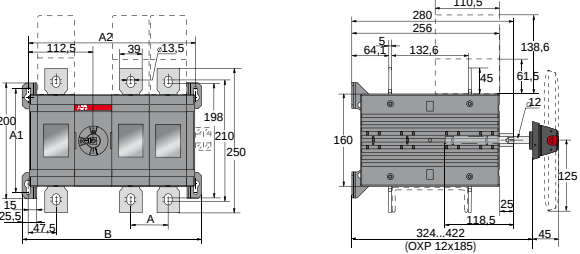


OT630/800E_C			
	E12	E13	E22
A	65	65	65
A1	180	180	180
A2	290	355	355
B	311	376	376

OT600U02_04C

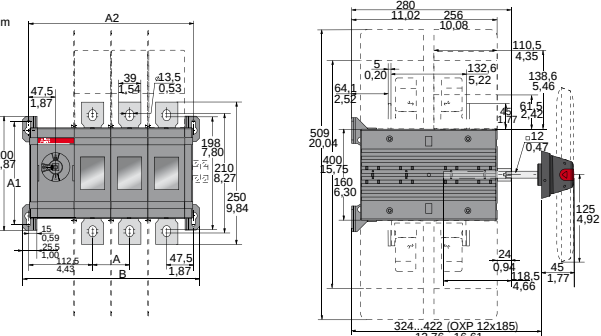


OT600U02-04C			
	U02	U03	U04
A	65/2,56	65/2,56	65/2,56
A1	180/7,09	180/7,09	180/7,09
A2	225/8,86	290/11,42	355/13,98
B	246/9,69	311/12,24	376/14,80

OT600U12_22C


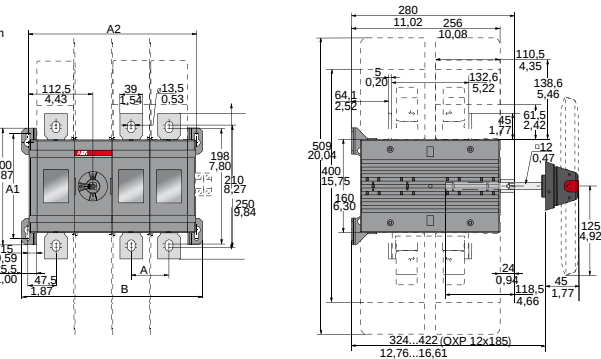


OT600U12-22C			
	U12	U13	U22
A	65/2,56	65/2,56	65/2,56
A1	180/7,09	180/7,09	180/7,09
A2	290/11,42	355/13,98	355/13,98
B	311/12,24	376/14,80	376/14,80


Label

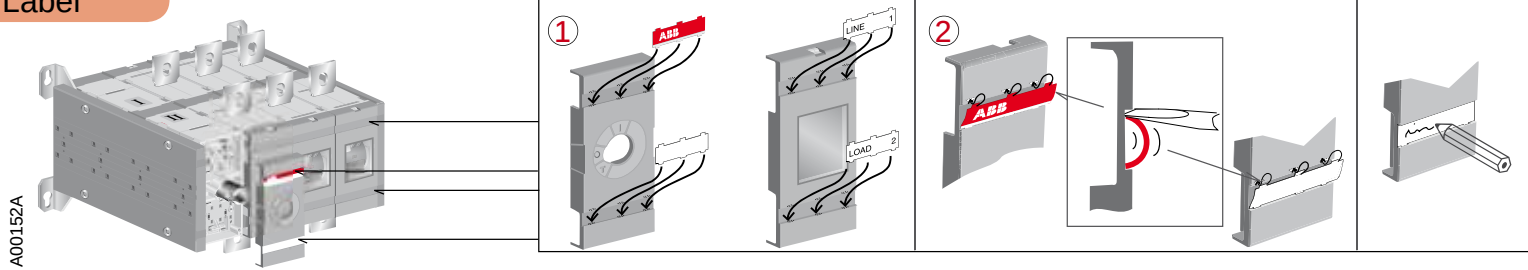

OTS_

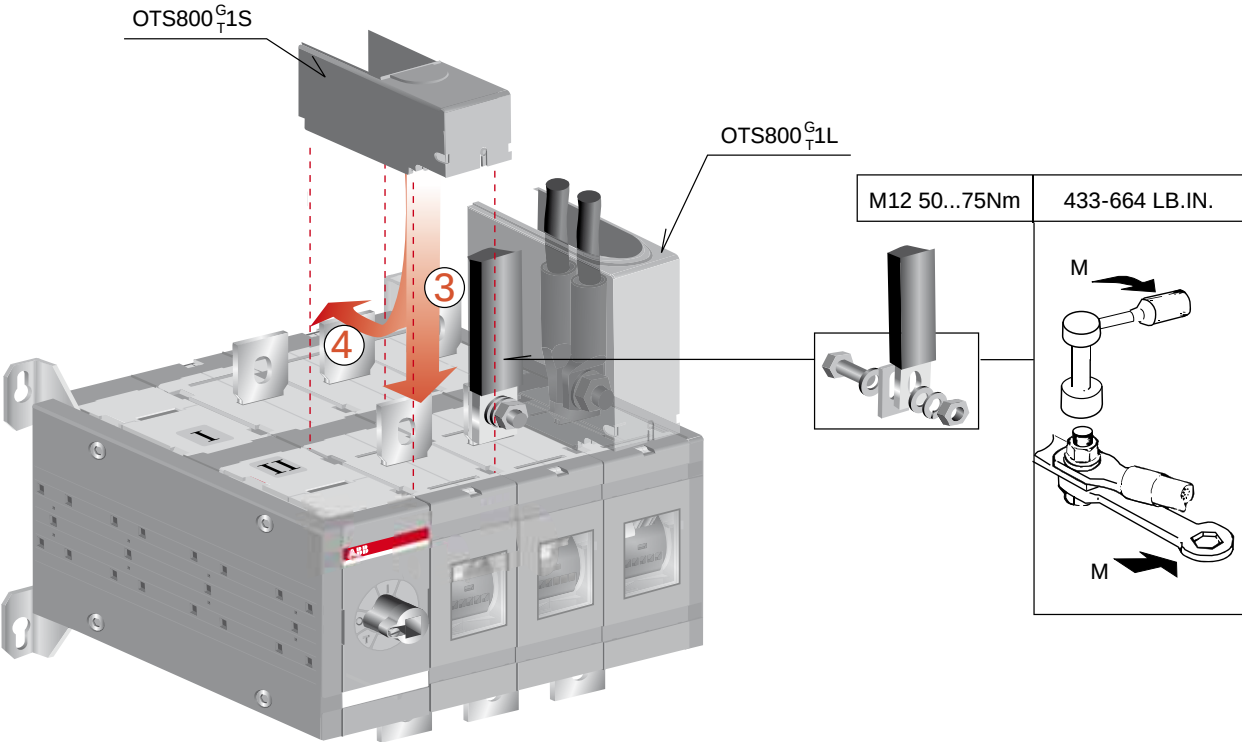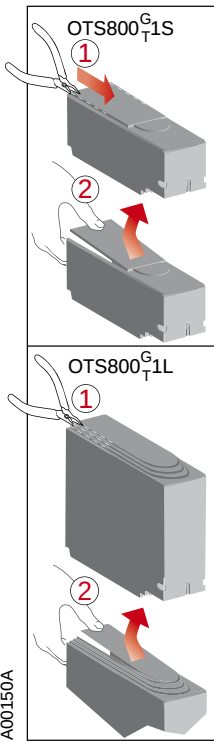


OA_

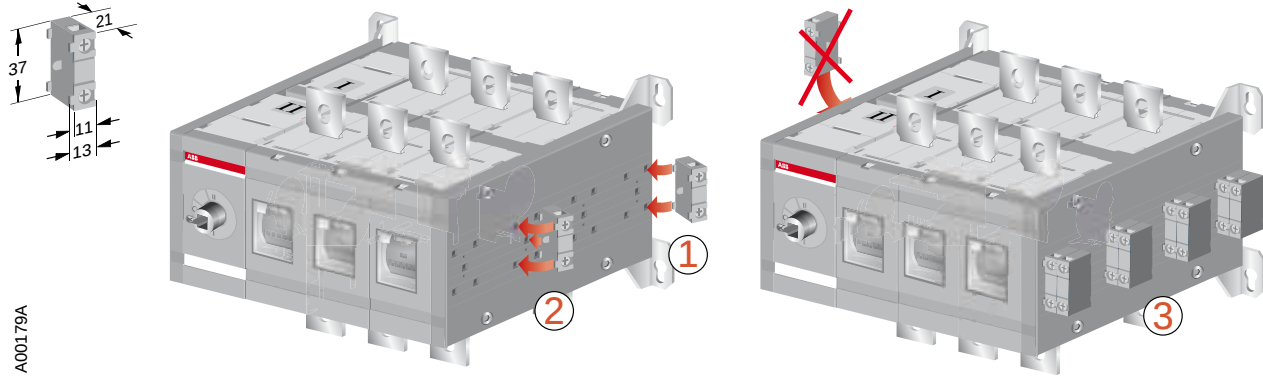


I max 2+2		
	OA 1G10	OA 3G01
I	—	—
O	—	—
II	—	—

II max 2+2		
	OA 1G10	OA 3G01
I	—	—
O	—	—
II	—	—


OZX_

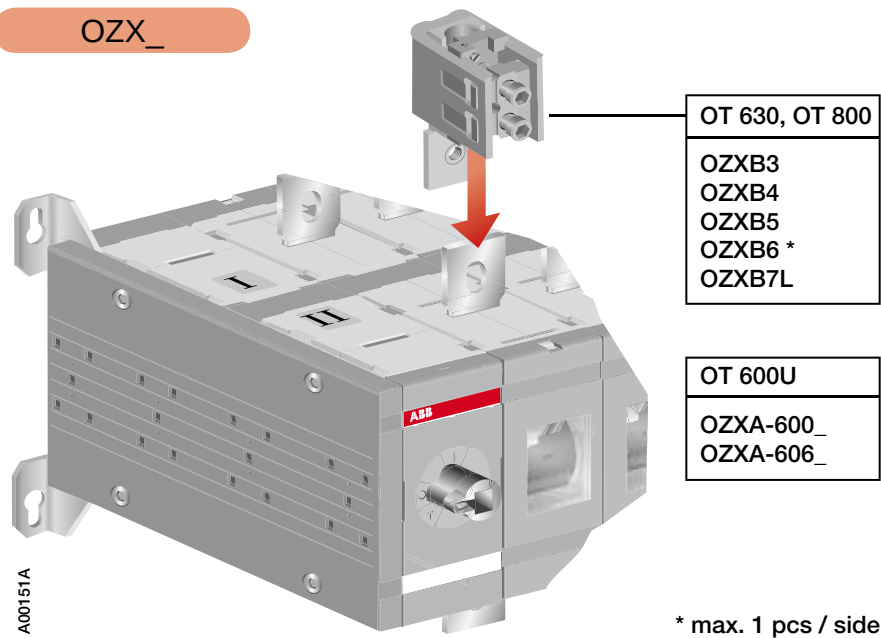


OTV800ECK

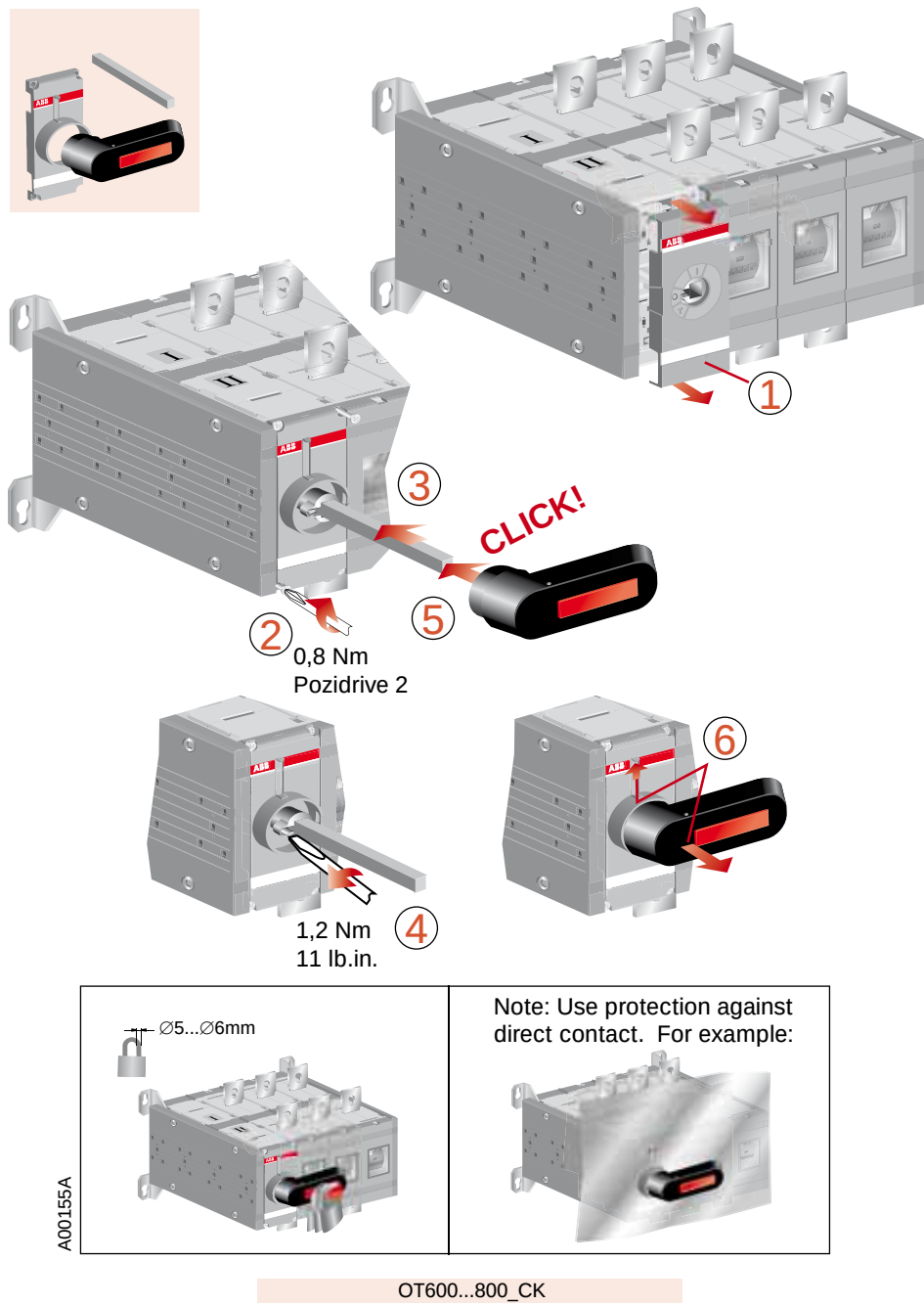

Clearances per UL98

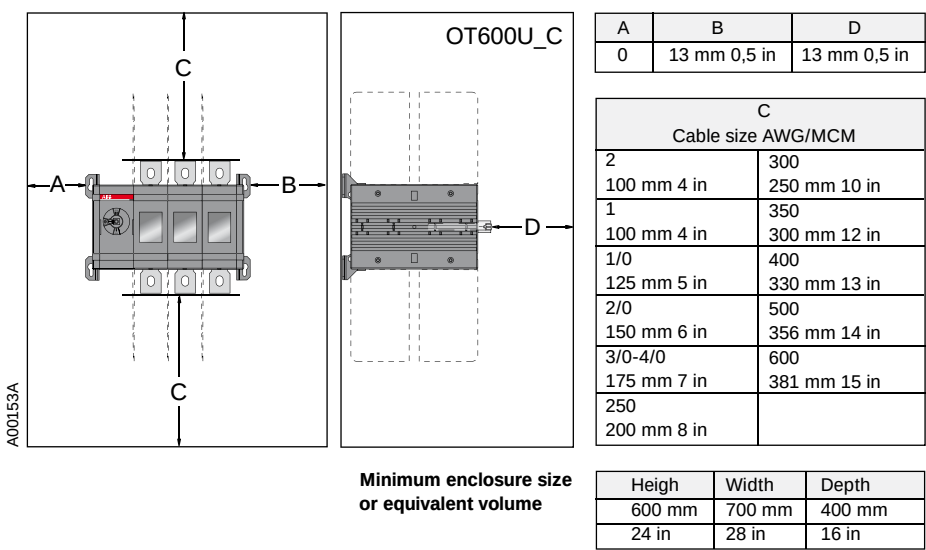

OTZC

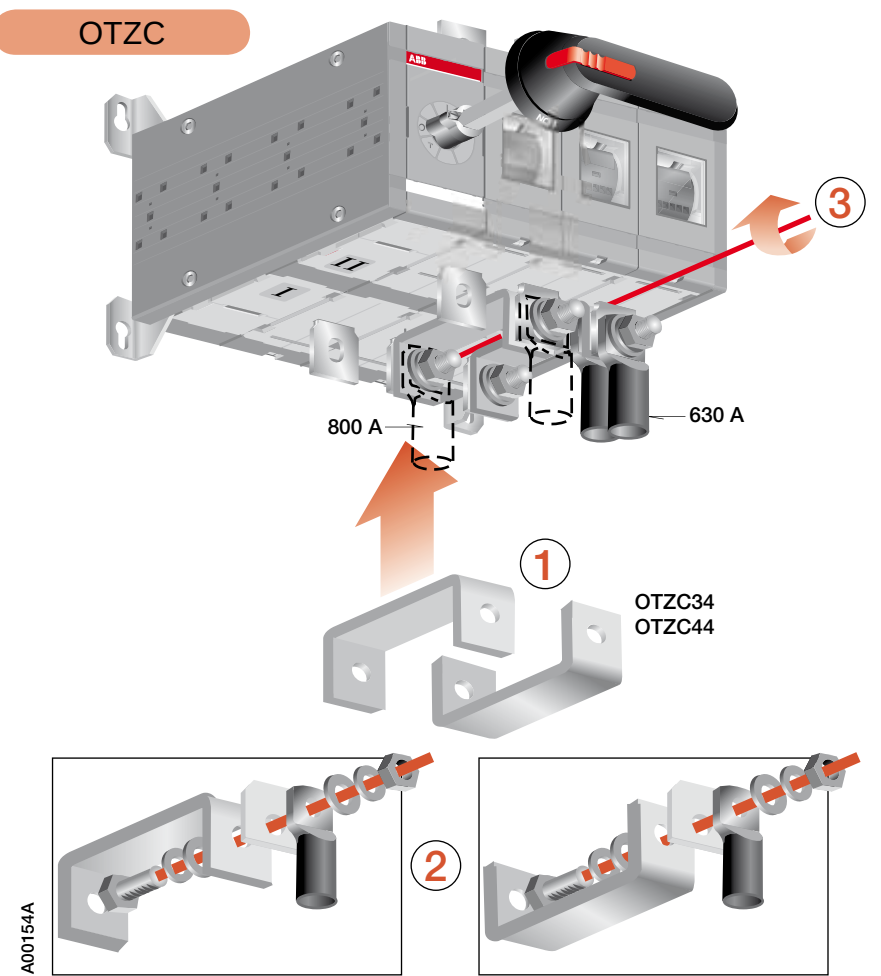

OTB_

