
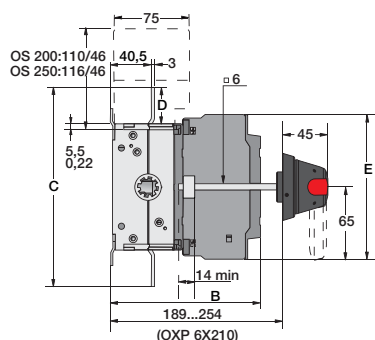
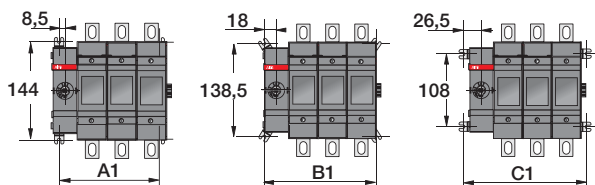
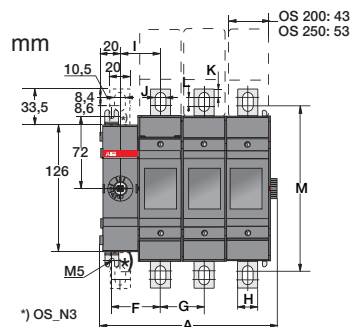


OS200-250




1SCC311012M0008

Document no. 34OS200-250 H

OS200-250_

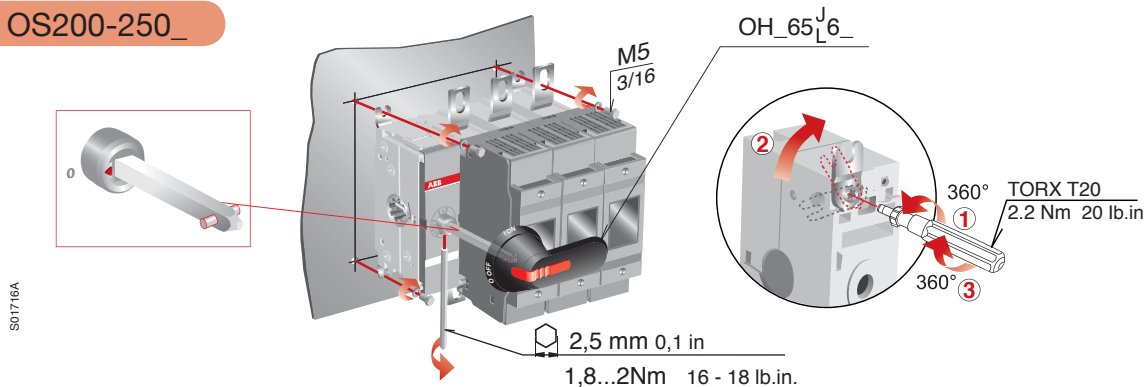


OS200-250_01-04												
OS200								OS250				
D01	B01	D02	B02	D03	B03	D04	B04	D01/B01	D02/B02	D03/B03	D04/B04	
A 89,5	89,5	133	133	176,5	176,5	220	220	99,5	153,5	207,5	261,5	
B 149	130	149	130	149	130	149	149	154	154	154	154	
C 198,5	198,5	198,5	198,5	198,5	198,5	198,5	198,5	193	193	193	193	
D 36,5	36,5	36,5	36,5	36,5	36,5	36,5	36,5	33,5	33,5	33,5	33,5	
E 144,5	144,5	144,5	144,5	144,5	144,5	144,5	144,5	148,5	148,5	148,5	148,5	
F 48,5	48,5	48,5	48,5	48,5	48,5	48,5	48,5	53,5	53,5	53,5	53,5	
G -	-	43,5	43,5	43,5	43,5	43,5	43,5	-	54	54	54	
H 20	20	20	20	20	20	20	20	25	25	25	25	
I 40	40	40	40	40	40	40	40	45	45	45	45	
J 10	10	10	10	10	10	10	10	11	11	11	11	
K 8,4	8,4	8,4	8,4	8,4	8,4	8,4	8,4	11,5	11,5	11,5	11,5	
L 8,6	8,6	8,6	8,6	8,6	8,6	8,6	8,6	4	4	4	4	
M 164,5	164,5	164,5	164,5	164,5	164,5	164,5	164,5	162	162	162	162	
A1 60,5	60,5	104	104	147,5	147,5	191	191	70,5	124,5	178,5	232,5	
B1 79,5	79,5	123	123	166,5	166,5	210	210	89,5	143,5	197,5	251,5	
C1 96,5	96,5	140	140	183,5	183,5	227	227	106,5	160,5	214,5	268,5	

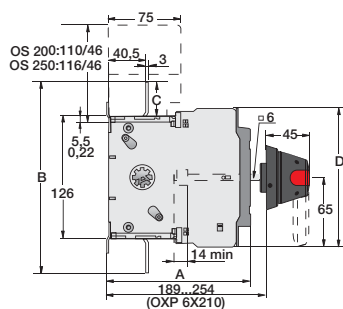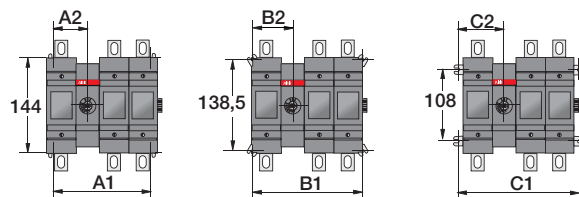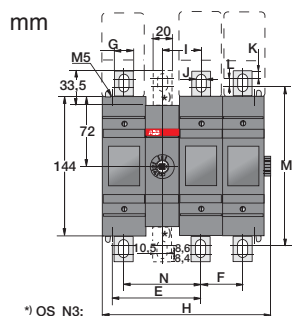

OS200-250_11-22												
OS200								OS250				
D11	B11	D12	B12	D13	B13	D22	B22	D11	D12	D13	D22	
A 149	130	149	130	141	130	149	130	154	154	154	154	
B 199	199	199	199	199	199	199	199	193	193	193	193	
C 36,5	36,5	36,5	36,5	36,5	36,5	36,5	36,5	33,5	33,5	33,5	33,5	
D 144,5	144,5	144,5	144,5	144,5	144,5	144,5	144,5	148,5	148,5	148,5	148,5	
E 92	92	92	92	92	92	92	92	135,5	135,5	112,5	112,5	
F 43,5	43,5	43,5	43,5	43,5	43,5	43,5	43,5	54	54	54	54	
G 20	20	20	20	20	20	20	20	25	25	25	25	
H 132	132	175,5	175,5	219	219	219	219	152	206	260	260	
I 40	40	40	40	40	40	40	40	45	45	45	45	
J 10	10	10	10	10	10	10	10	11	11	11	11	
K 8,4	8,4	8,4	8,4	8,4	8,4	8,4	8,4	11,5	11,5	11,5	11,5	
L 8,6	8,6	8,6	8,6	8,6	8,6	8,6	8,6	4	4	4	4	
M 165	165	165	165	165	165	165	165	162	162	162	162	
N 80	80	80	80	80	80	80	80	90	90	90	90	
A1 104	104	147,5	147,5	191	191	191	191	124	178	232	232	
A2 52	52	52	52	52	52	52	52	95,5	95,5	62	62	
B1 123	123	166,5	166,5	210	210	210	210	143	197	251	251	
B2 61,5	61,5	61,5	61,5	61,5	61,5	61,5	61,5	105	105	71,5	71,5	
C1 140	140	183,5	183,5	227	227	227	227	160	214	268	268	
C2 70	70	70	70	70	70	70	70	113,5	113,5	80	80	



OS200-250

OS200_J_

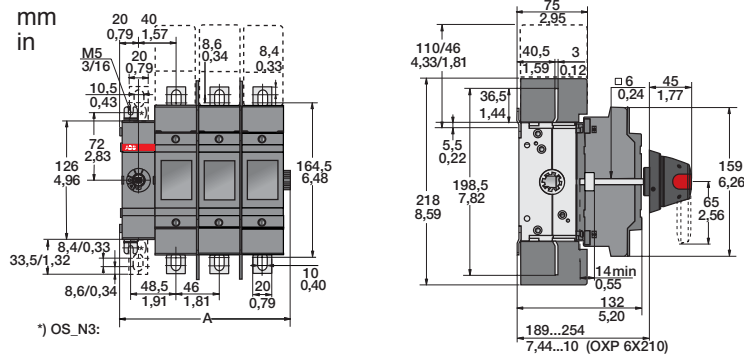


OS200J01-04				
	OS200J01	OS200J02	OS200J03	OS200J04
	mm/ in	mm/ in	mm/ in	mm/ in
A	89,5 / 3,52	135,5 / 5,34	181,5 / 7,15	227,5 / 8,96
A1	60,5 / 2,38	106,5 / 4,19	152,5 / 6,00	198,5 / 7,82
B1	79,5 / 3,13	125,5 / 4,94	171,5 / 6,75	217,5 / 8,56
C1	96,5 / 3,80	142,5 / 5,61	188,5 / 7,42	234,5 / 9,23

M00001/OS200J01_04 H

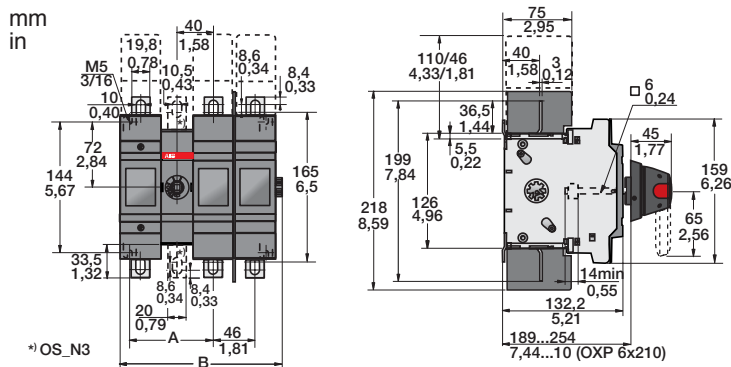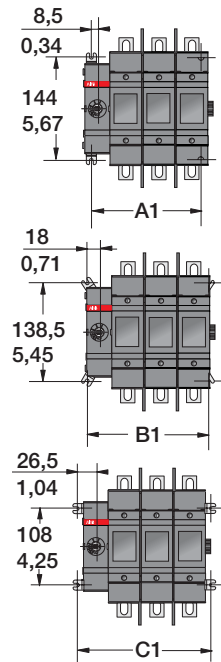


M00015/OS200J11_22 H / A04024

OS200J11-22				
	OS200			
	J11	J12	J13	J22
	mm / in	mm / in	mm / in	mm / in
A	92 / 3,12	92 / 3,62	92 / 3,62	138 / 5,43
B	132 / 5,20	178 / 7,01	224 / 8,82	224 / 8,82
A1	104 / 4,09	150 / 5,91	196 / 7,72	196 / 7,72
A2	52 / 2,05	52 / 2,05	52 / 2,05	98 / 3,86
B1	106 / 4,18	141 / 5,55	141 / 5,55	176 / 6,93
B2	61,5 / 2,42	61,5 / 2,42	61,5 / 2,42	107,5 / 4,23
C1	140 / 5,51	186 / 7,32	232 / 9,13	232 / 9,13
C2	70 / 2,76	70 / 2,76	70 / 2,76	116 / 4,57

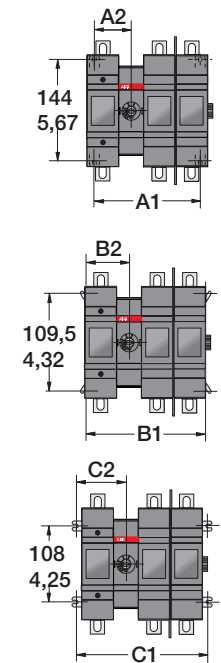

Label



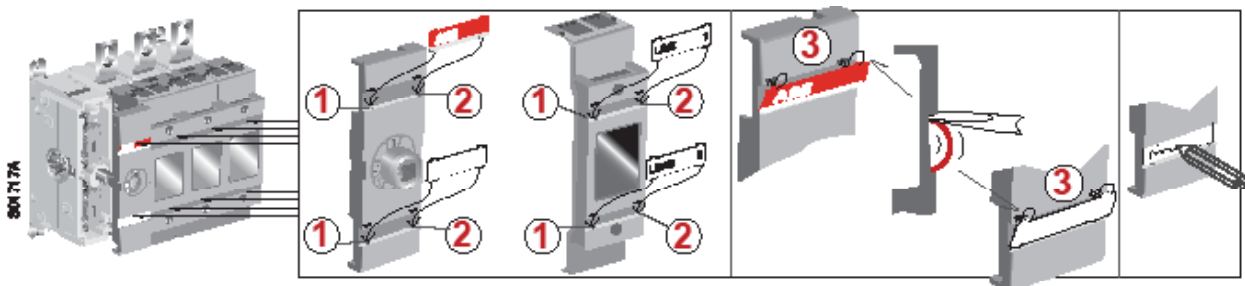


OS200-250


OZX_

OS200	OS250
OZXB1L	OZXB1L
OZXB2	OZXB2L
OZXB2L	OZXB3
OZXB8	OZXB4
	OZXB5
	OZXB7L
	OZXB8

OS200J
OZXA-200_
OZXA-206_

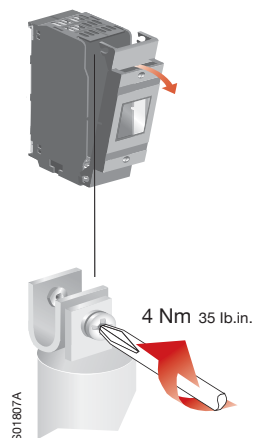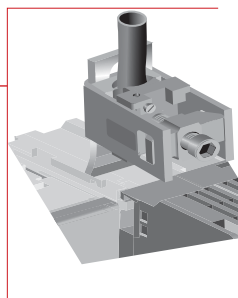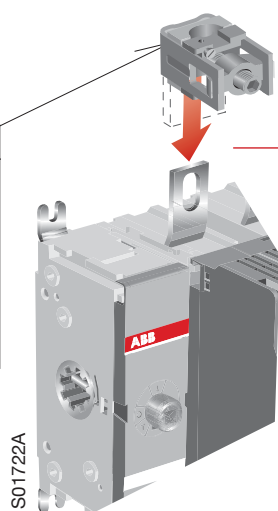

OSP_


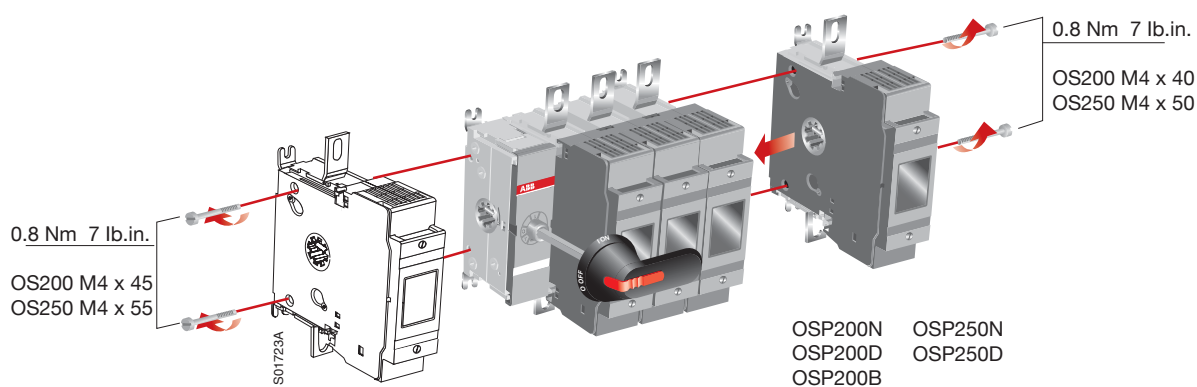


Clearances per UL98

Minimum enclosure size or equivalent volume

Heigh	Width	Depth
600 mm	350 mm	200 mm
23,6 in	13,8 in	7,9 in

A	0
B	13 mm 0,5 in
D	13 mm 0,5 in

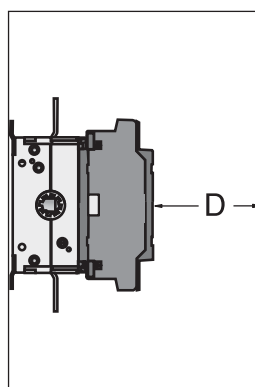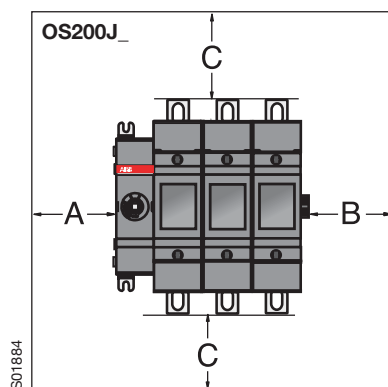


Cable size	
MCM	C
250	200 mm 8 in
300	250 mm 10 in


Cable size	
AWG	C
4-3	100 mm 4 in
2	100 mm 4 in
1	100 mm 4 in
1/0	125 mm 5 in
2/0	150 mm 6 in
3/0-4/0	175 mm 7 in

OS200-250

OS_N3 & OXN 250

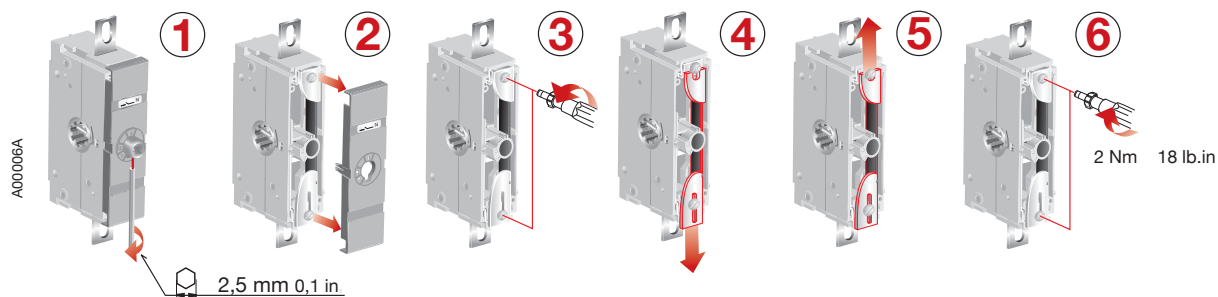



DPMM_

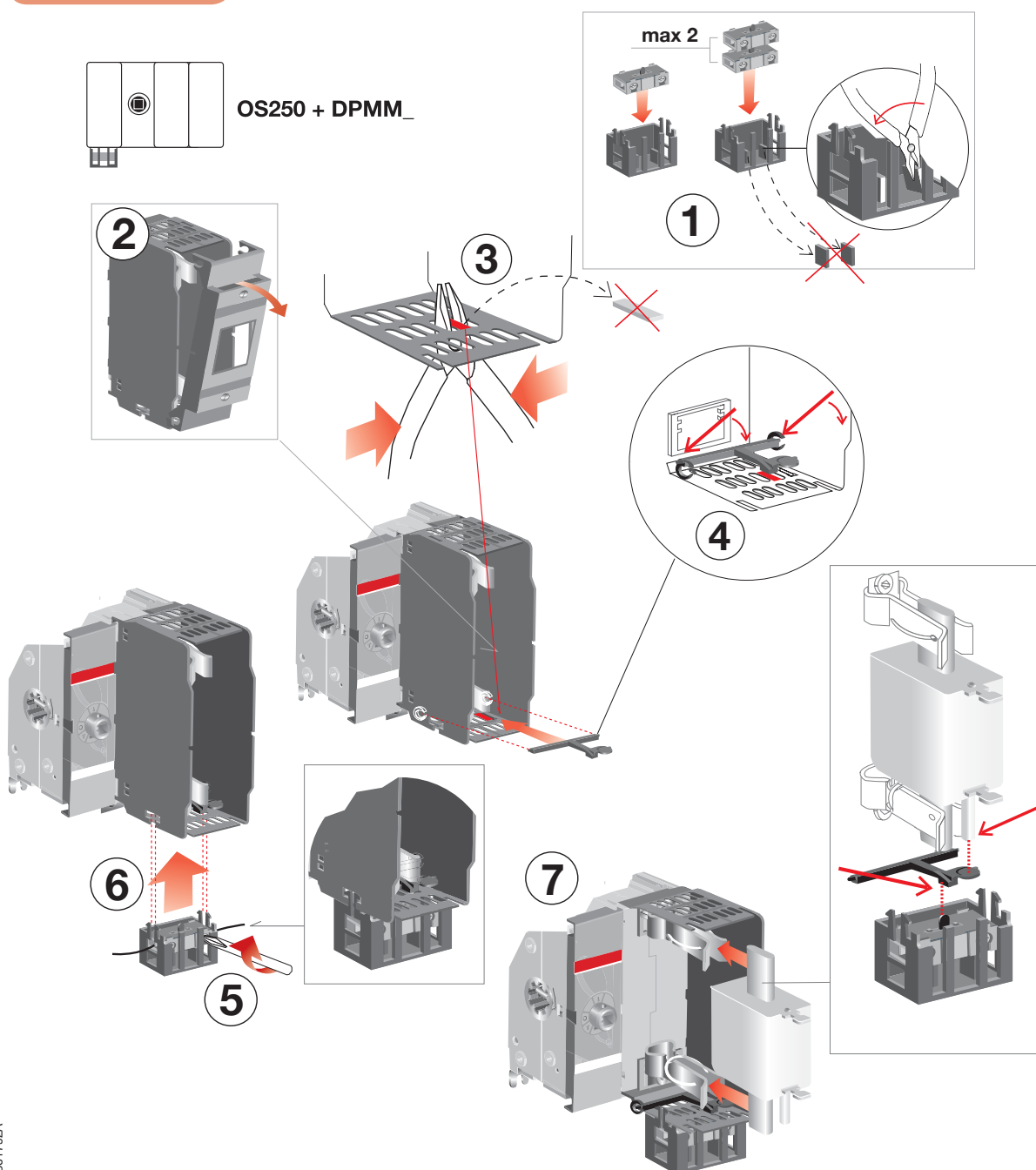



OS200-250

OFS_

 OS200...+OFS_

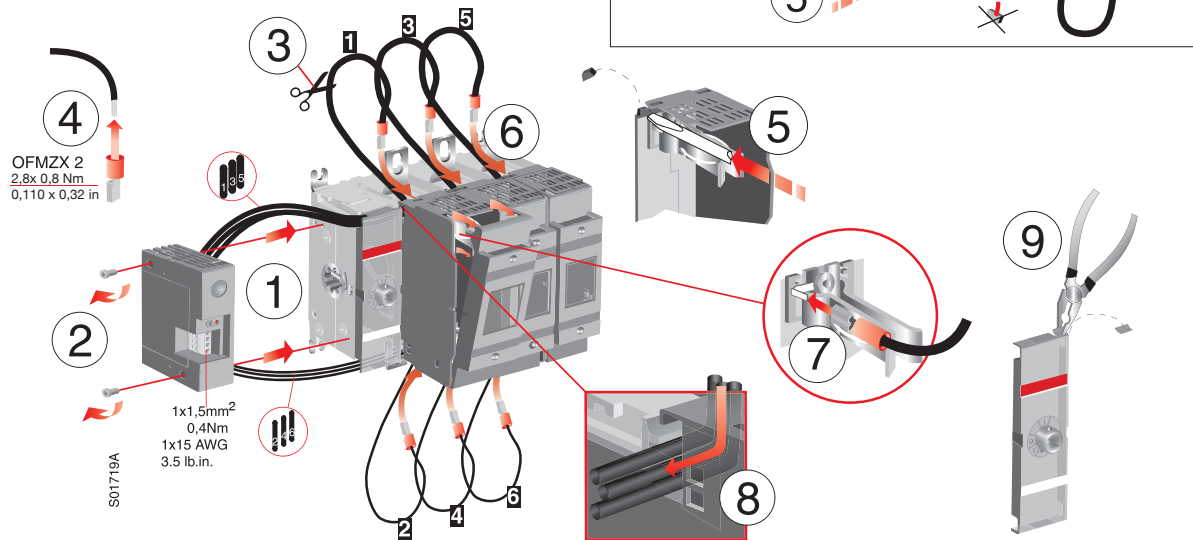


OSS_

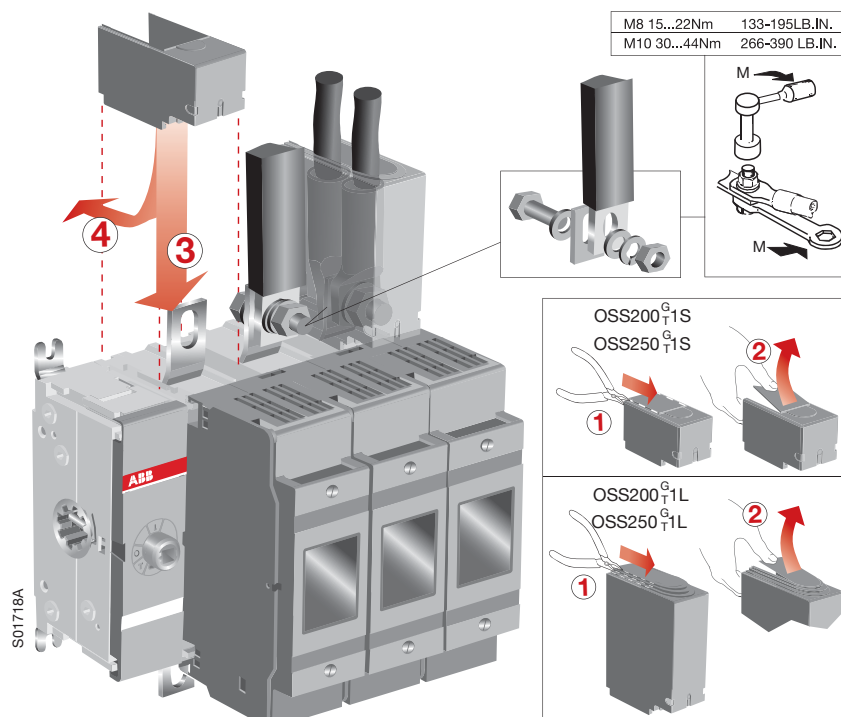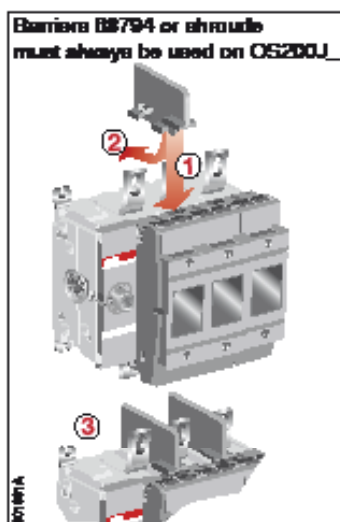


OS200-250

OEA28_

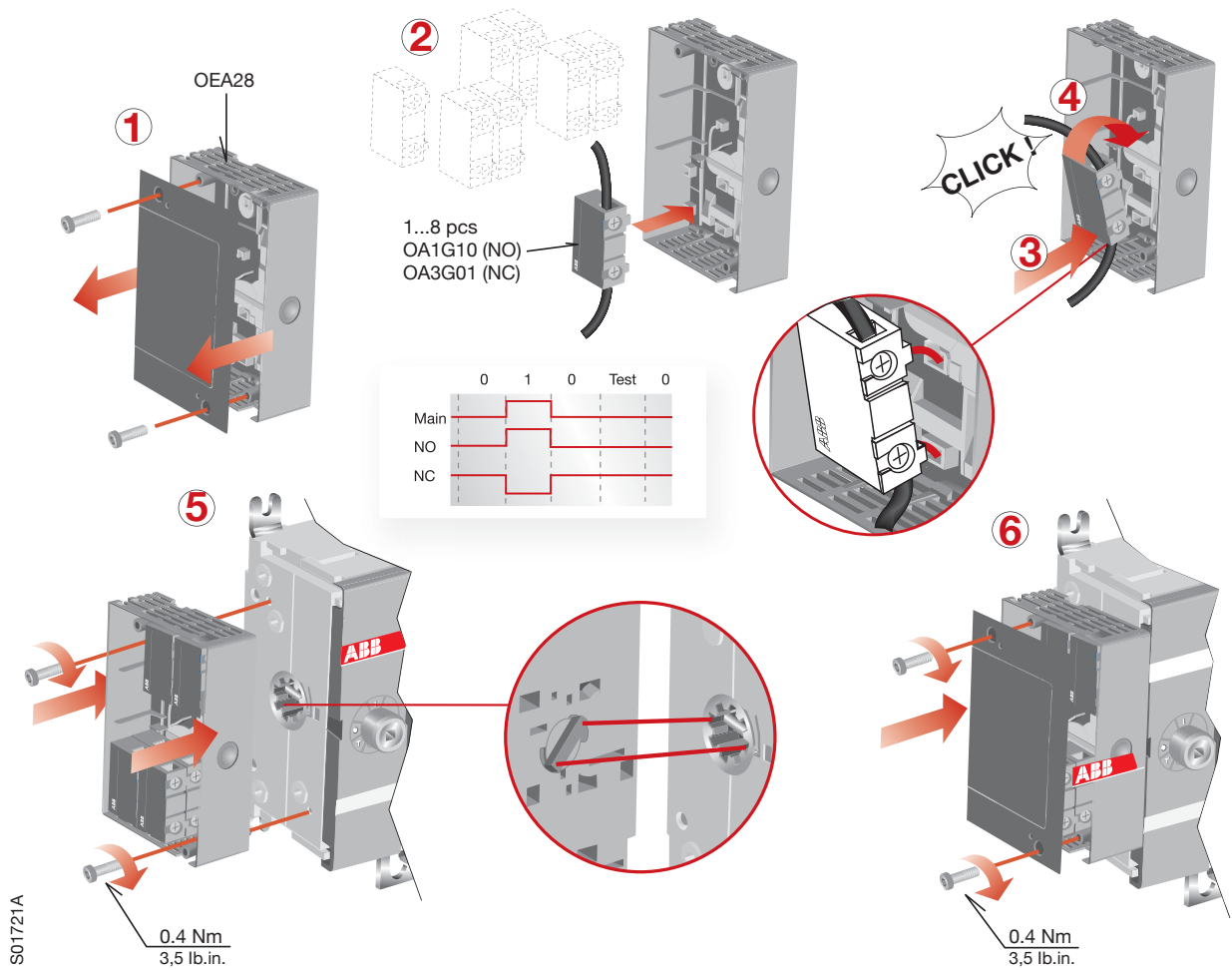




OSZT1_

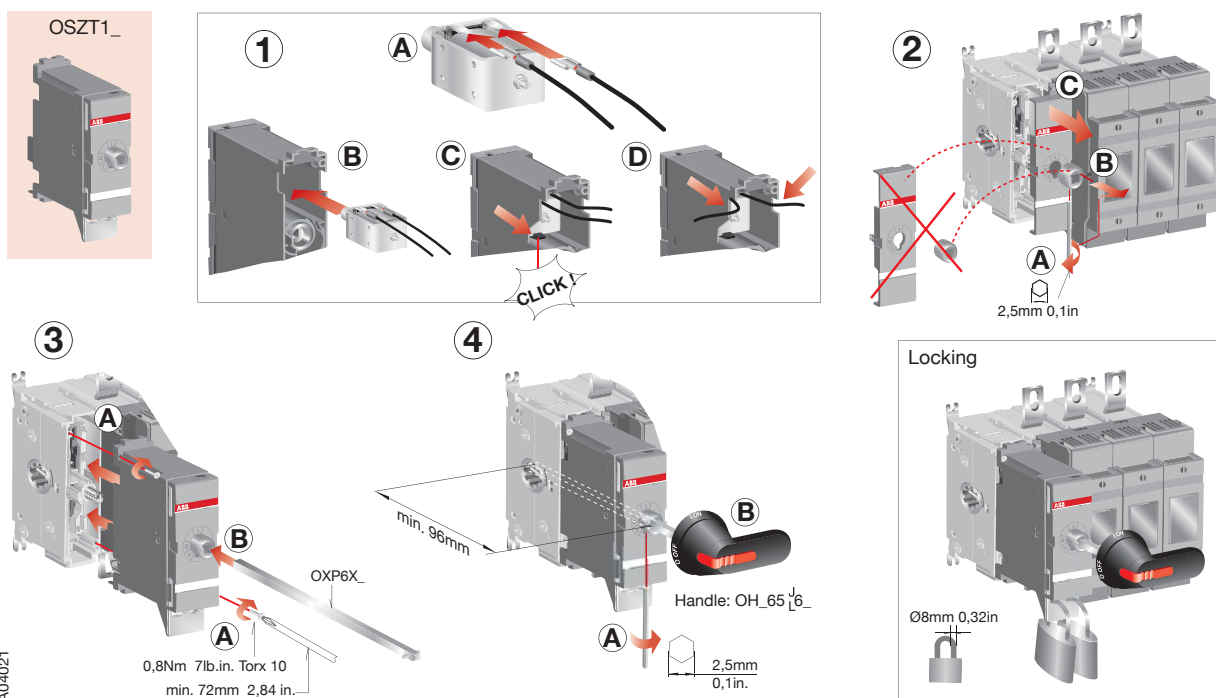


OS200-250

OSV_

OSV250DK
OSV250BK




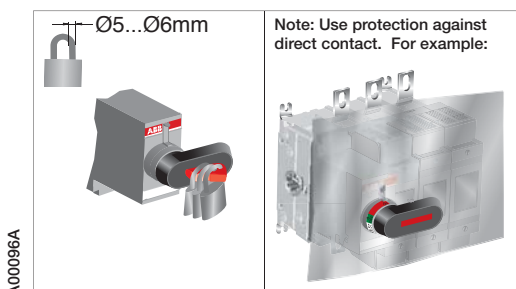
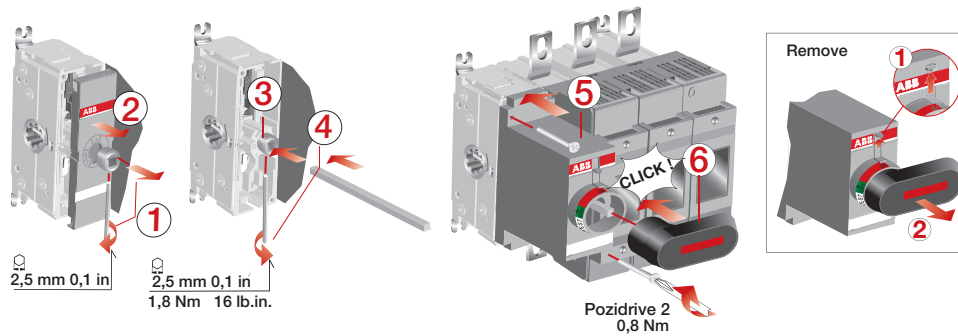
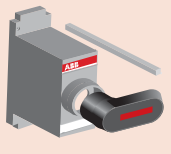


OS200_250D03 OS200-250B03

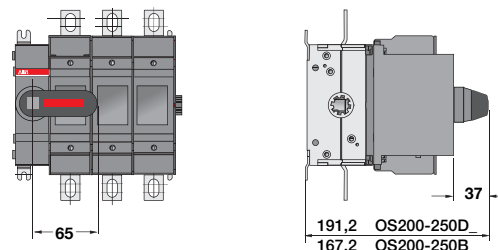

OA_

NO: OA1G10
NC: OA3G01

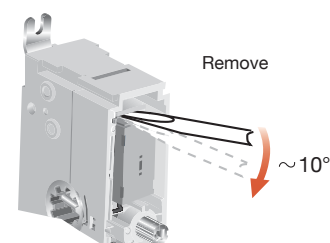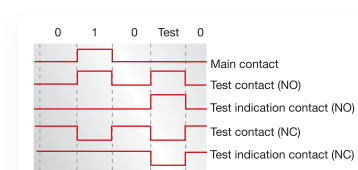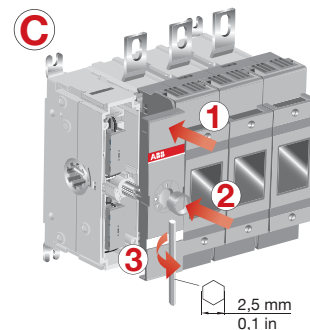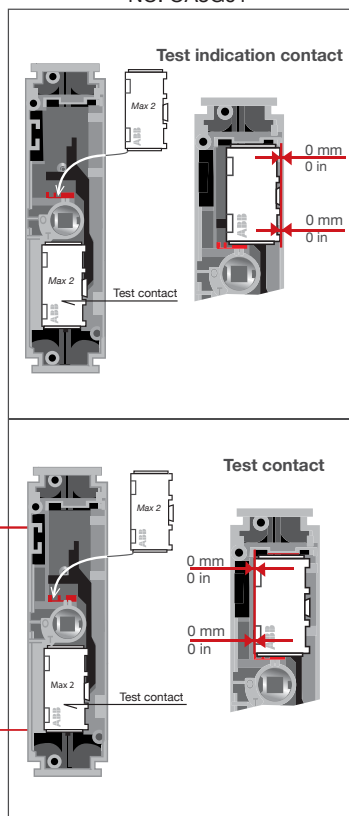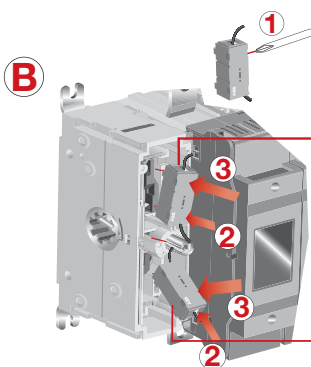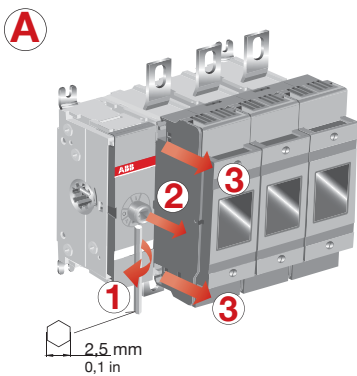

S01720A

ABB Oy
Low Voltage Products
P.O. Box 622 Telephone +358-10 224 000
FIN-65101 Vaasa, Finland Telefax +358-10 224 5708