

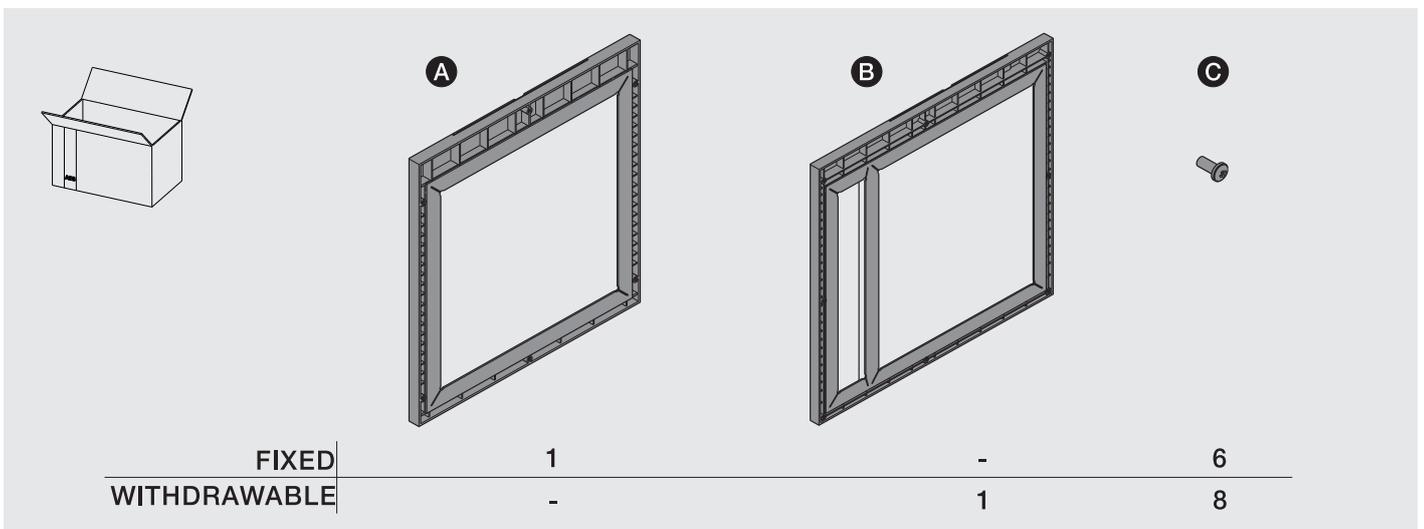
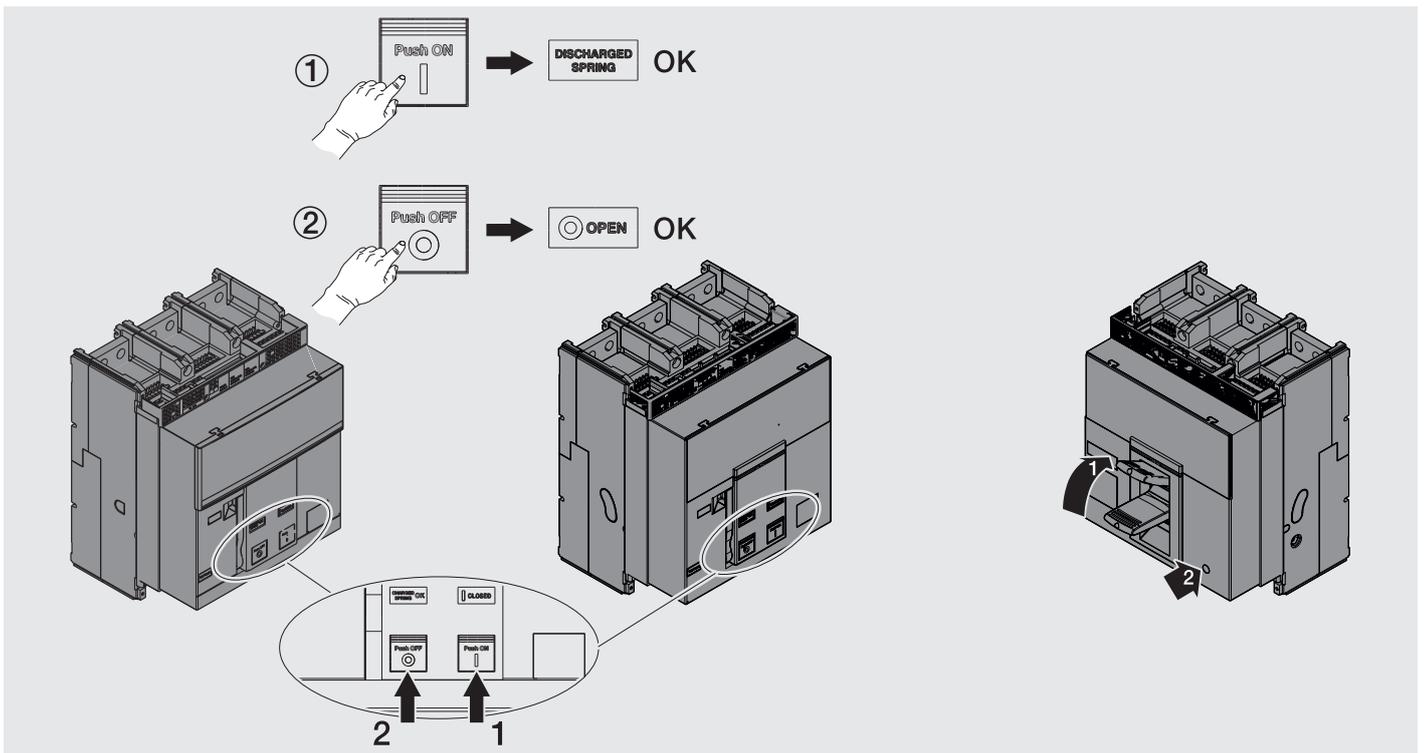
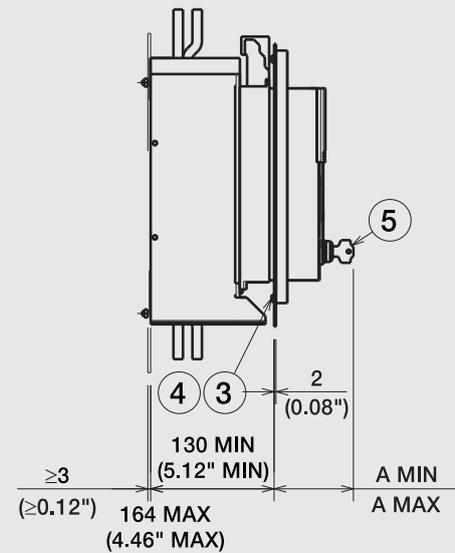
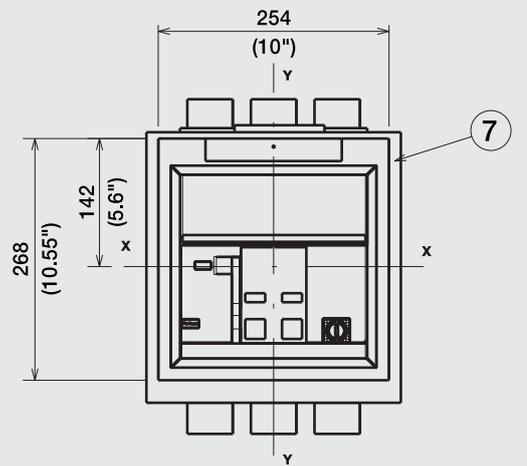


SACE Emax 2 - Tmax XT

Mostrina antipolvere IP30 - E1.2 - XT7M - XT7
 IP30 dust-guard flange - E1.2 - XT7M - XT7
 Staubschutzrahmen IP30 - E1.2 - XT7M - XT7
 Garniture anti-poussière IP30 - E1.2 - XT7M - XT7
 Marco antipolvo IP30 - E1.2 - XT7M - XT7
 IP30 灰尘防护壳 - E1.2 - XT7M - XT7




E1.2 - XT7M - XT7

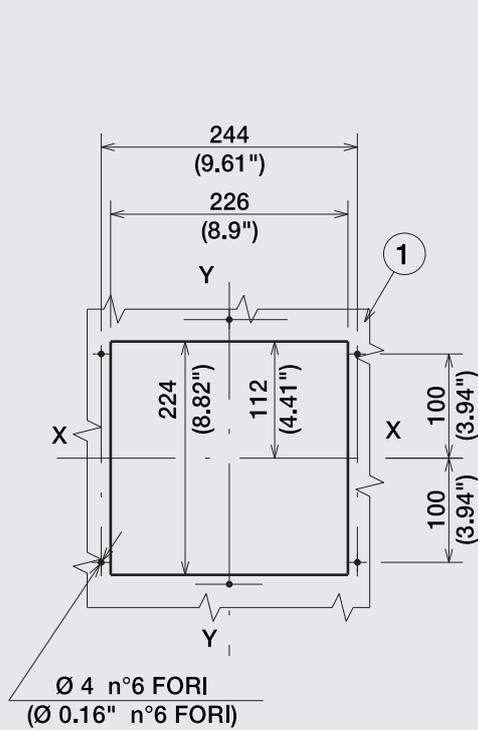



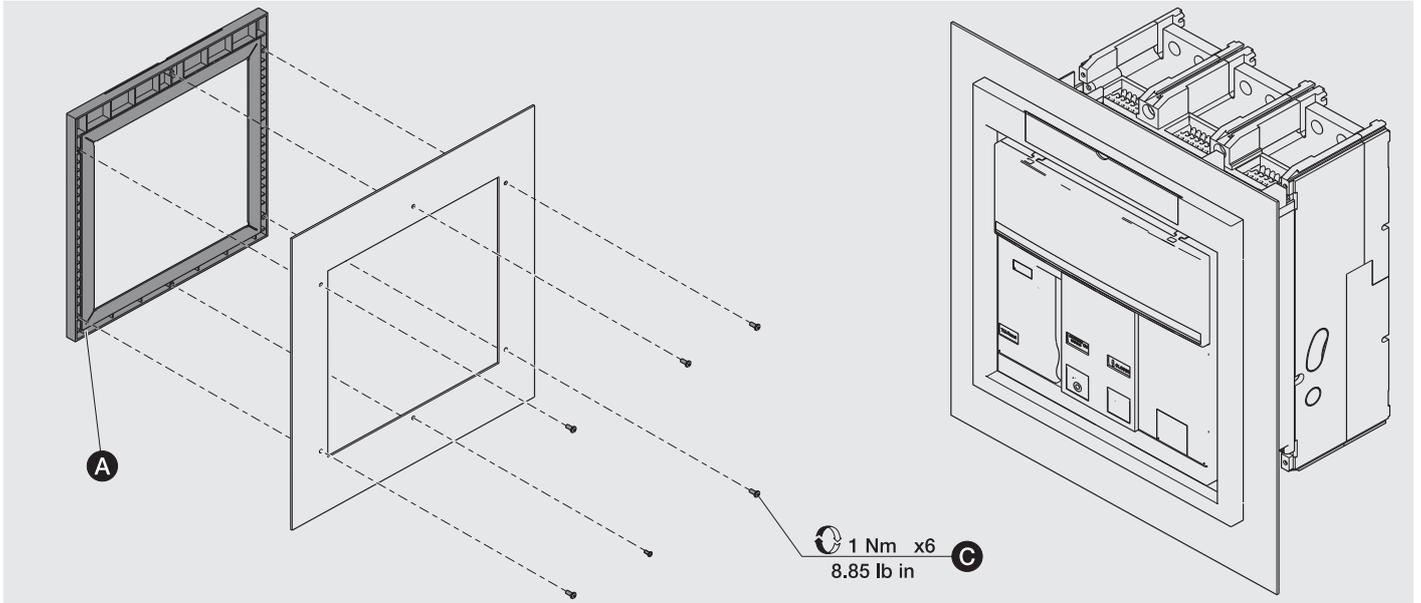


MOSTRINA E1.2 - XT7M INTERRUPTORE FISSO
FLANGE E1.2 - XT7M FIXED CIRCUIT-BREAKER
ABDECKRAHMEN E1.2 - XT7M FESTER LEISTUNGSSCHALTER
GARNITURE E1.2 - XT7M DISJONCTEUR FIXE
MARCO E1.2 - XT7M INTERRUPTOR FIJO
壳体 E1.2 - XT7M 固定式断路器


	Standard	Ronis / Profalux	Kirk	Castell
A MIN	49.5 (1.95")	63.5 (2.5")	63.5 (2.5")	83.5 (3.29")
A MAX	83.5 (3.29")	97.5 (3.84")	97.5 (3.84")	117.5 (4.63")

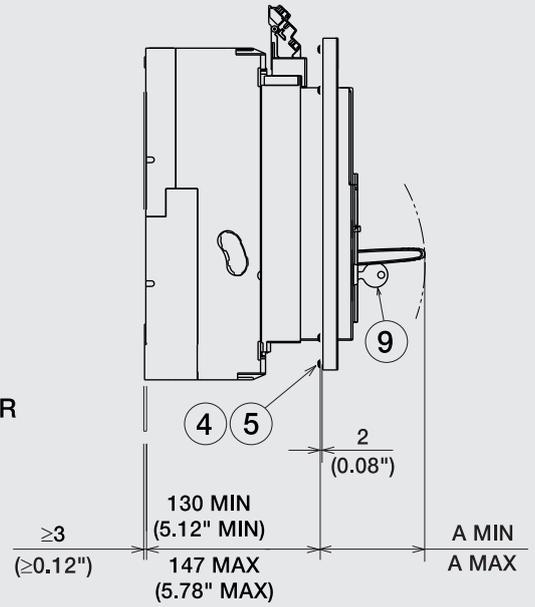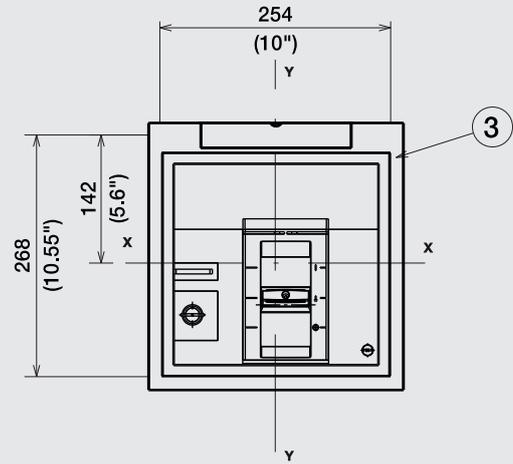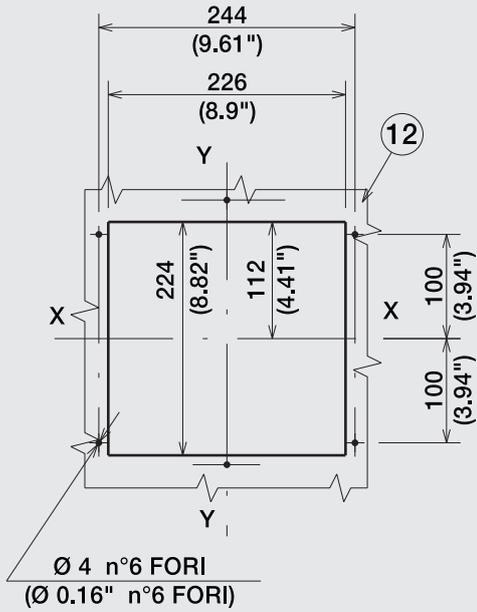



MOSTRINA XT7 - XT7M INTERRUOTORE FISSO
FLANGE XT7 - XT7M FIXED CIRCUIT-BREAKER
ABDECKRAHMEN XT7 - XT7M FESTER LEISTUNGSSCHALTER
GARNITURE XT7 - XT7M DISJONCTEUR FIXE
MARCO XT7 - XT7M INTERRUPTOR FIJO
壳体 XT7 - XT7M 固定式断路器

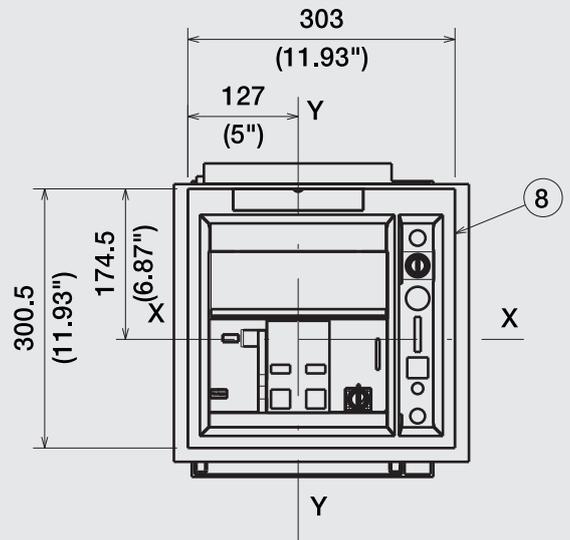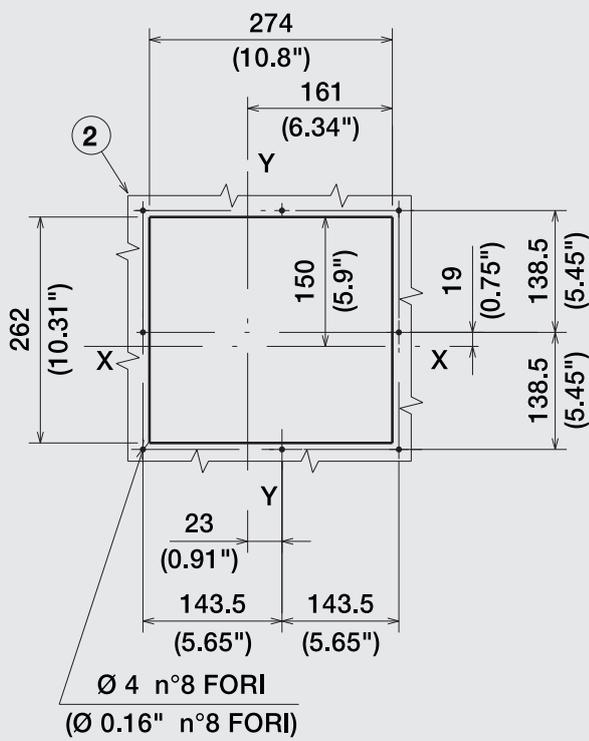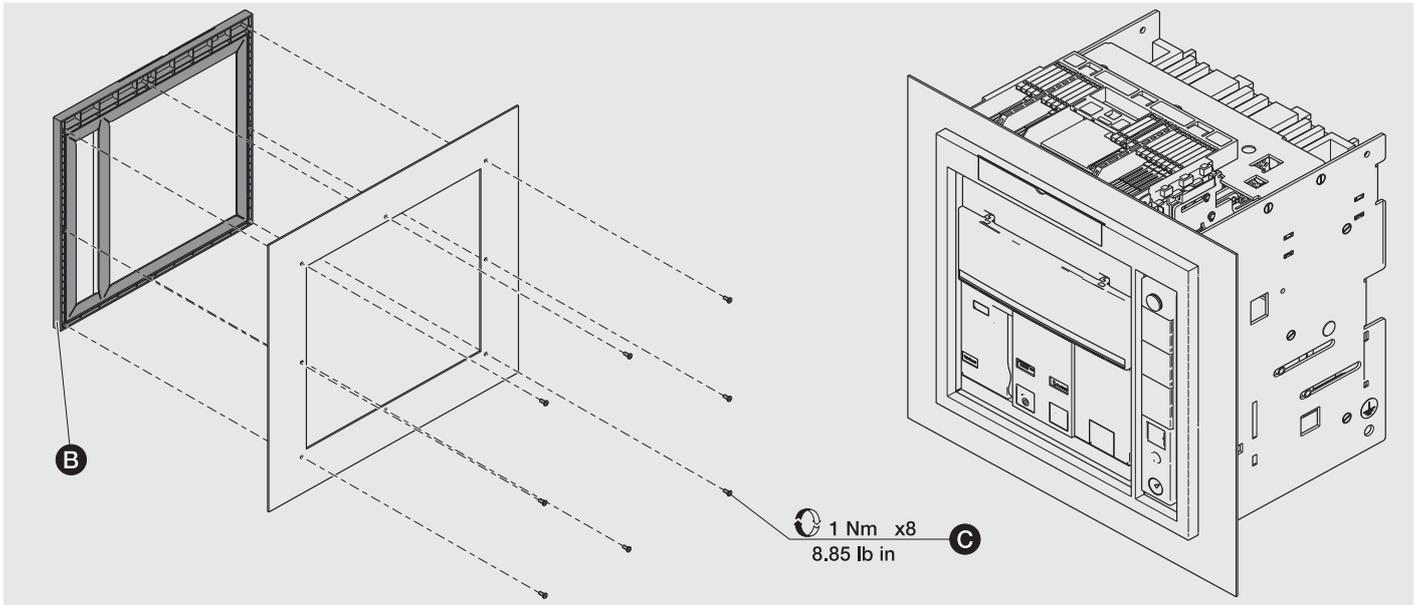

MOSTRINA E1.2 - XT7M INTERRUPTORE ESTRAIBILE
 FLANGE E1.2 - XT7M WITHDRAWABLE CIRCUIT-BREAKER
 ABDECKRAHMEN E1.2 - XT7M AUSFAHRBARER LEISTUNGSSCHALTER
 GARNITURE E1.2 - XT7M DISJONCTEUR DÉBROCHABLE
 MARCO E1.2 - XT7M INTERRUPTOR EXTRAÍBLE

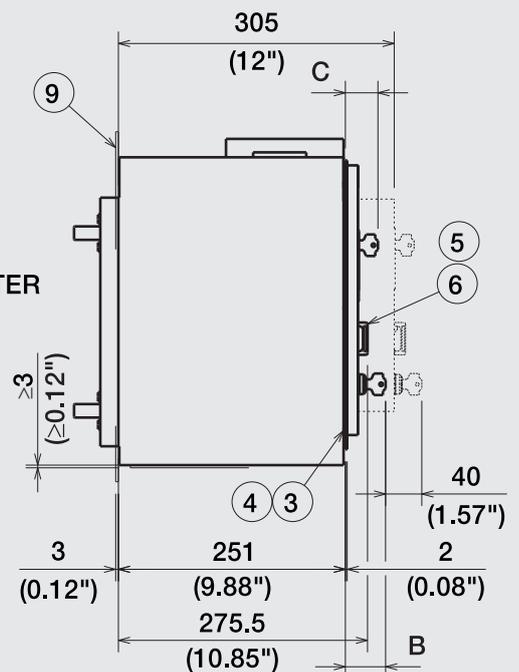

	Standard	Ronis / Profalux	Kirk	Castel
B	44.5 (1.75")	55 (2.16")	55 (2.16")	85 (3.35")
C	36 (1.42")	46.5 (1.83")	46.5 (1.83")	76.5 (3.01")

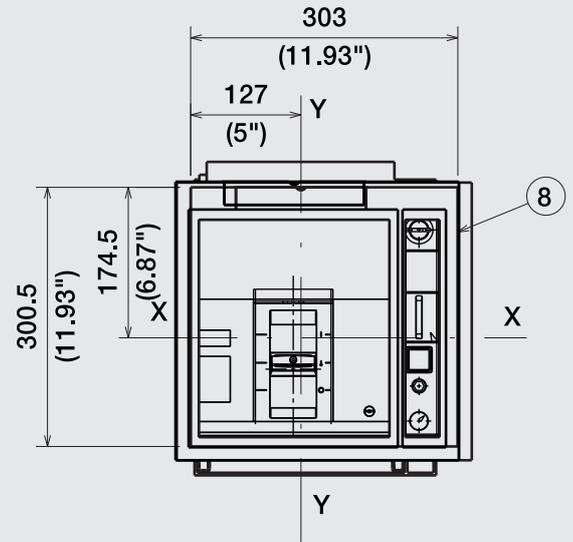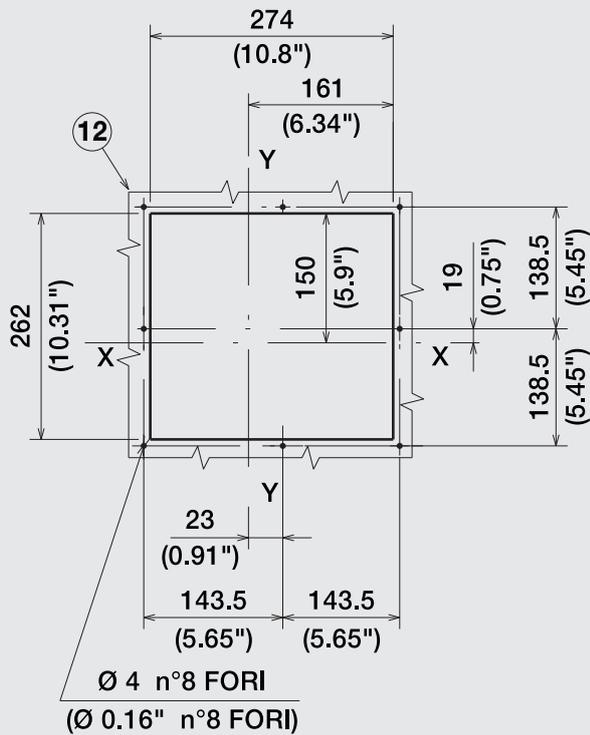

MOSTRINA XT7 - XT7M INTERRUTTORE ESTRAIBILE
FLANGE XT7 - XT7M WITHDRAWABLE CIRCUIT-BREAKER
ABDECKRAHMEN XT7 - XT7M AUSFAHRBARER LEISTUNGSSCHALTER
GARNITURE XT7 - XT7M DISJONCTEUR DÉBROCHABLE
MARCO XT7 - XT7M INTERRUPTOR EXTRAÍBLE
 壳体 XT7 - XT7M 抽出式断路器

