


# SACE Emax 2

Terminali posteriori orientabili HR/VR - E2.2-E4.2-E6.2  
Adjustable rear terminals HR/VR - E2.2-E4.2-E6.2  
Rückseitige drehbare Anschlüsse HR/VR - E2.2-E4.2-E6.2  
Prises arrière orientables HR/VR - E2.2-E4.2-E6.2  
Terminales posteriores orientables HR/VR - E2.2-E4.2-E6.2


E2.2-E4.2-E6.2

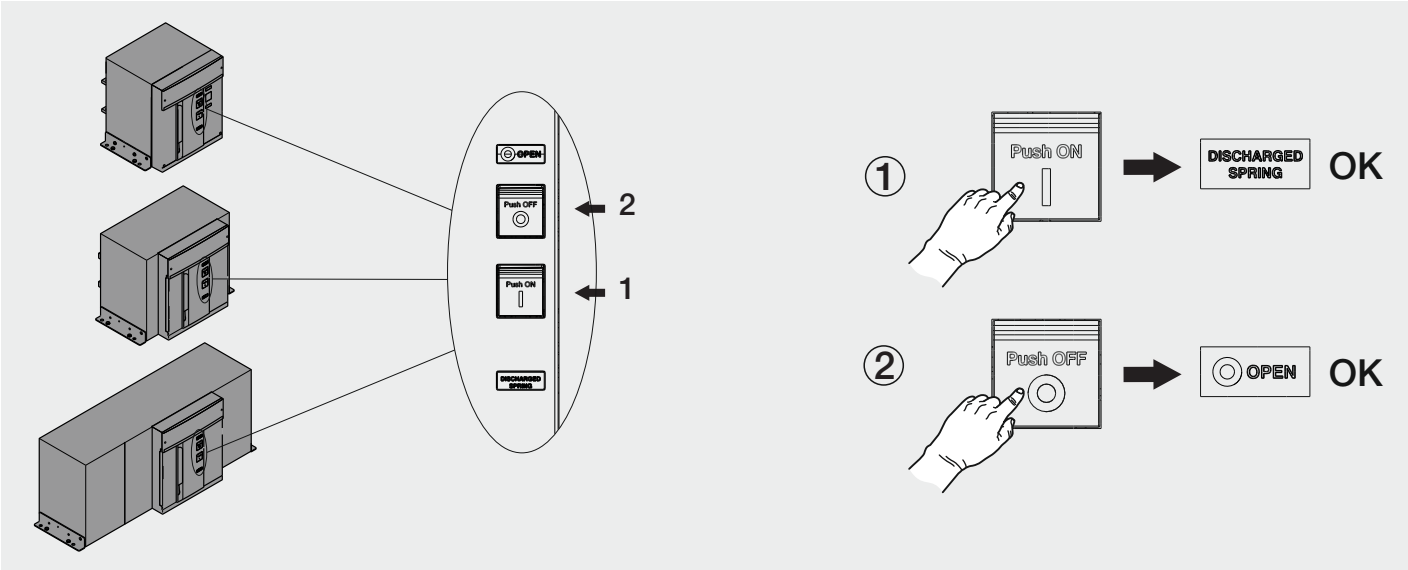

|       |             | A   |        | B   |        | C   |        | D   |        | E   |        |
|-------|-------------|-----|--------|-----|--------|-----|--------|-----|--------|-----|--------|
|       |             | III | IV(FS) | III | IV(FS) | III | IV(FS) | III | IV(FS) | III | IV(FS) |
| F - W | E2.2 2000 A | 3   | 4      |     |        |     |        | 12  | 16     |     |        |
|       | E4.2 3200 A | 3   | 4      |     |        |     |        |     |        | 12  | 16     |
|       | E6.2 5000 A | 6   | 7(8)   |     |        |     |        |     |        | 24  | 28(32) |
| F     | E2.2 2500 A |     |        | 3   | 4      |     |        | 24  | 32     |     |        |
|       | E4.2 4000 A |     |        |     |        | 3   | 4      |     |        | 24  | 32     |
|       | E6.2 6300 A |     |        |     |        | 6   | 7(8)   |     |        | 48  | 56(64) |
| W     | E2.2 2500 A |     |        | 3   | 4      |     |        | 12  | 16     |     |        |
|       | E4.2 4000 A |     |        |     |        | 3   | 4      |     |        | 12  | 16     |
|       | E6.2 5000 A |     |        |     |        | 6   | 7(8)   |     |        | 24  | 28(32) |
|       | E6.2 6300 A |     |        |     |        | 6   | 7(8)   |     |        | 24  | 28(32) |


## Example with E2.2 F 2000A III

-  **D** E2.2 - 8.6 Nm / 76 lb in  
 **E** E4.2-E6.2 - 20 Nm / 177 lb in

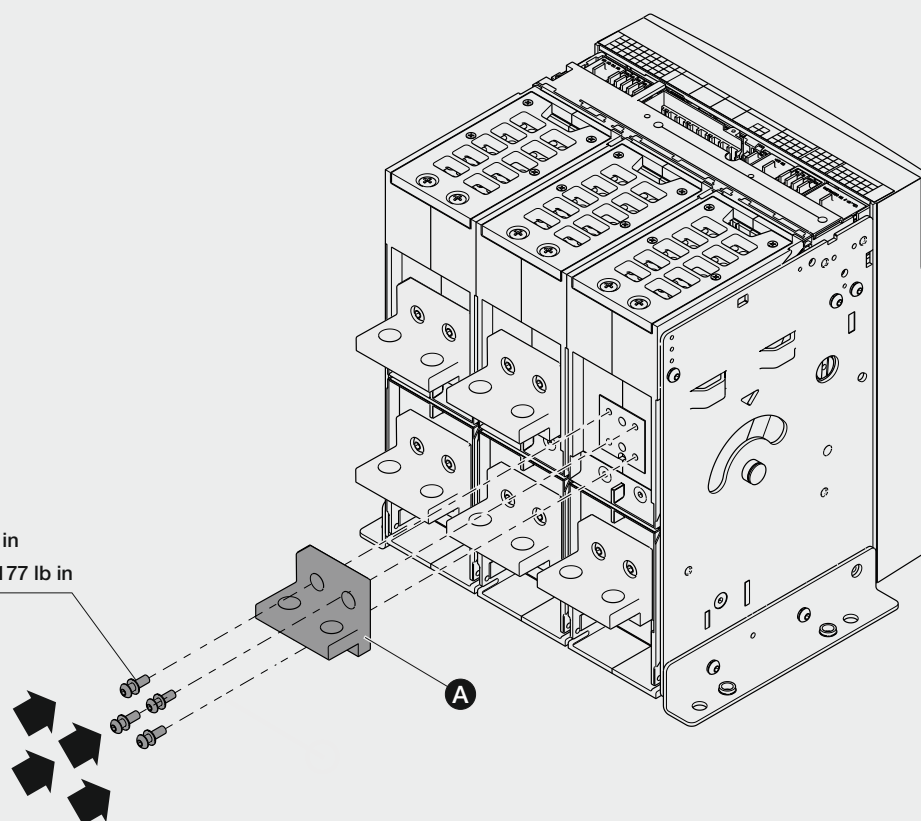


## Example with E2.2 F 2500A III


 8.6 Nm  
 76 lb in

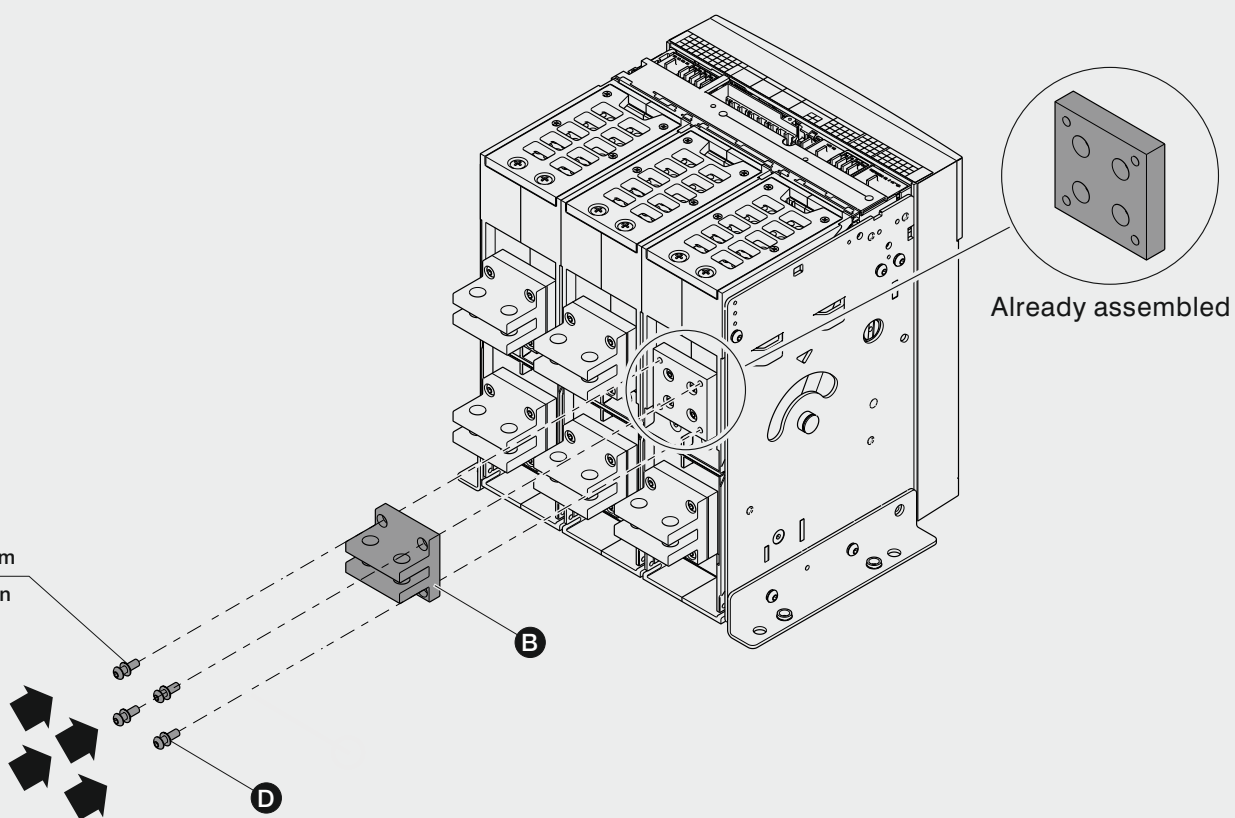


## Example with E4.2 F 4000A III

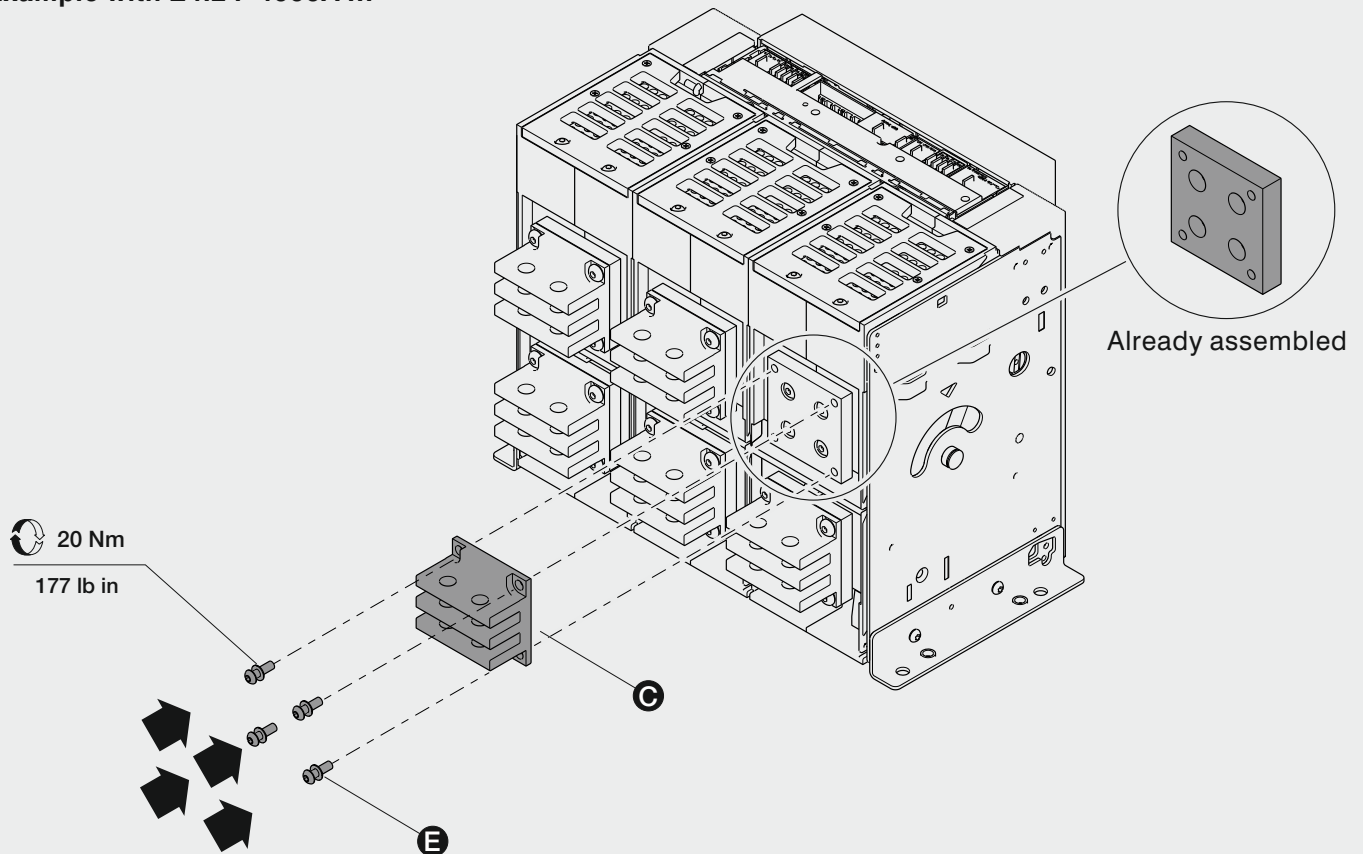

## Example with E2.2 W 2000A III

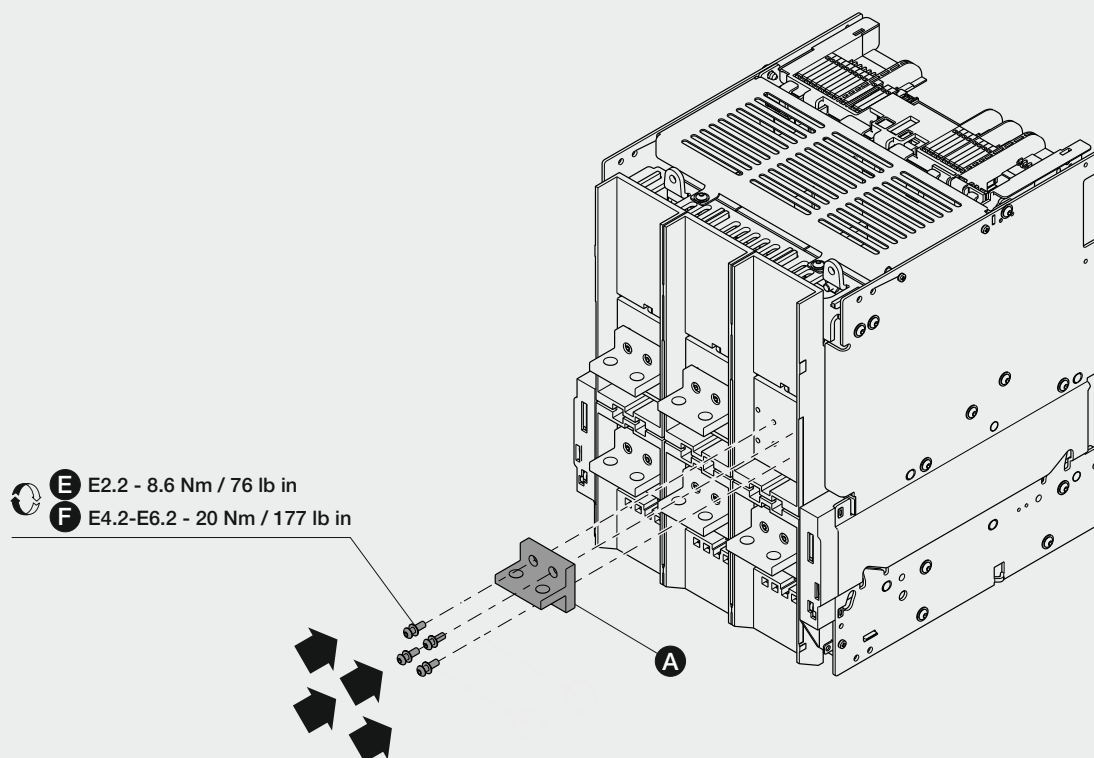

## Example with E2.2 W 2500A III

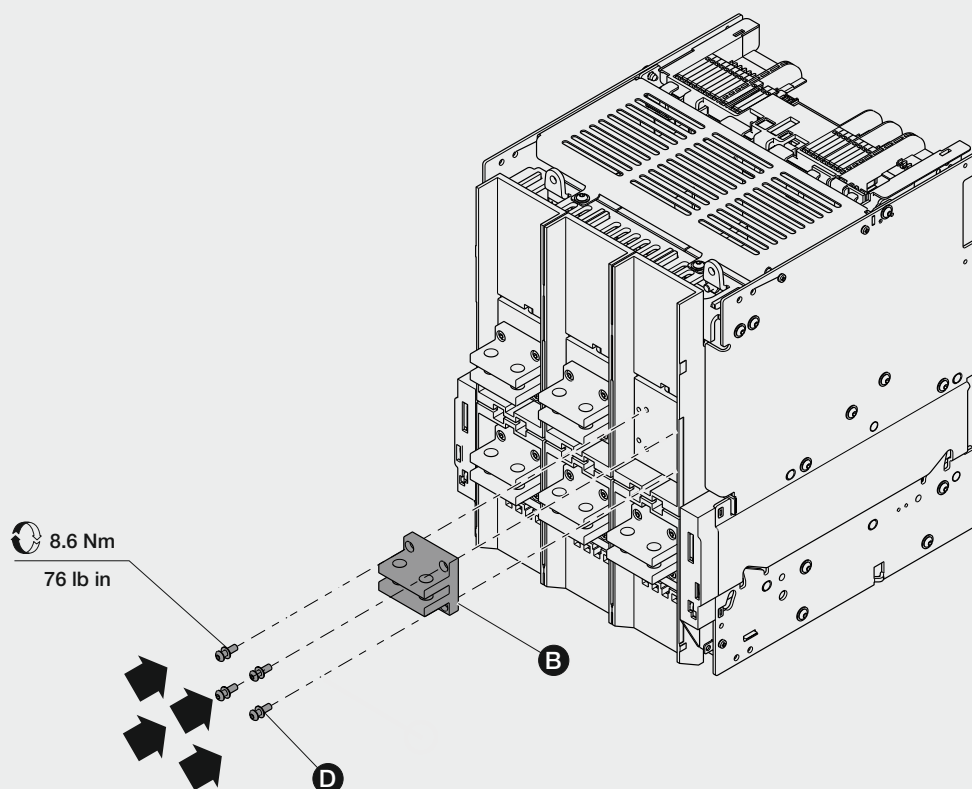

## Example with E4.2 W 4000A III

