

CATALOG 2023

Pilot devices, 30 mm

Heavy duty oil-tight range



The A3 (30 mm) heavy duty oil-tight range includes pilot lights, pushbuttons and selector switches with a variety of accessories and enclosures. It is suitable for many applications such as machine control panel, material handling (conveyors, food and beverage, packaging) and automotive.

Table of contents

004	Overview
005	Non-illuminated flush pushbuttons
006	Non-illuminated extended pushbuttons
007–009	Illuminated extended pushbuttons
010–011	Non-illuminated mushroom pushbuttons–44 mm
012	Non-illuminated mushroom pushbuttons–60 mm
013–014	Illuminated mushroom pushbuttons– 44 mm
015	Illuminated mushroom pushbuttons– 44 mm metal
016	Illuminated mushroom pushbuttons– 60 mm
017	Non-illuminated pushbuttons–no cap
018–019	Pilot lights–LED bulb
020–024	Non-illuminated selector switches
025	Illuminated selector switches
026–027	Non-illuminated key-operated selector switches
028	Contact configuration for pushbuttons and selector switches
029	Cam table
030	Contact blocks
031–033	Accessories
034	NEMA enclosures
035–036	Name plates
037	Technical specifications
038–042	Dimensions
043–052	Index

Heavy duty oil-tight range

The A3 (30 mm) heavy duty oil-tight range includes pilot lights, pushbuttons and selector switches with a variety of accessories and enclosures. It is suitable for many applications such as machine control panel, material handling (conveyors, food and beverage, packaging) and automotive.



Pushbuttons



Mushroom pushbuttons



Pilot lights



Selector switches

- Available ratings:
 - NEMA 1, 3, 3R, 4, 4X, 12, 13
 - IEC IP10, IP11, IP14, IP52, IP54, IP56, IP66
- NEMA 4X rated out of the box solution
- Button, lights and power block nameplate as one catalog number solution
- Flush button accessories may be stocked and octagonal operator ring can be interchanged to achieve either extended or recessed functionality

Maximum number of contacts:
Pushbuttons: Eight in total, four on each side
Selector switches: Six in total, three on each side


Optional double-break silver contacts with more dependable operation

Ease of assembly with one-screw contact block mounting

Easy wiring thanks to 45° angled wire terminals

Multiple synthetic rubber seals prevent oil, water, coolants and dirt from entering unit

Configurable products: wide choice of contact blocks, cap color, LED color

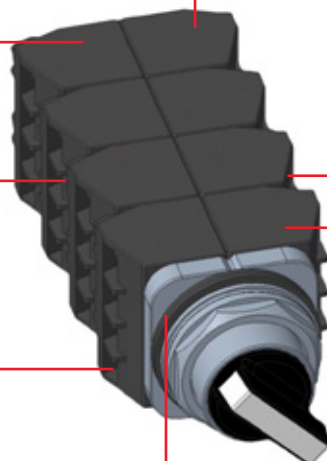

Contacts have screw attachments with see-through inspection covers

Positive make and break with strong contact springs help prevent contact freezing or accidental closure from machine vibration

30 mm heavy duty oil-tight range

Non-illuminated flush pushbuttons



A3PBF1-600B-10

15QC910017V0201



A3PBF1-600G-10

15QC910021V0201



A3PBF1-600L-10

15QC910019V0201




A3PBF1-600R-10

15QC910023V0201

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
Momentary					
Assorted Colors	–	0 0	A3PBF1-6007-00	1SQA009171R0001	1
● ● ● ● ●	–	0 1	A3PBF1-6007-01	1SQA009172R0001	1
–	–	1 0	A3PBF1-6007-10	1SQA009173R0001	1
–	–	1 1	A3PBF1-6007-91	1SQA010758R0001	1
● Black	–	0 0	A3PBF1-600B-00	1SQA009175R0001	1
–	–	0 1	A3PBF1-600B-01	1SQA009176R0001	1
–	–	1 0	A3PBF1-600B-10	1SQA009177R0001	1
–	–	1 1	A3PBF1-600B-91	1SQA010759R0001	1
● Green	–	0 0	A3PBF1-600G-00	1SQA009179R0001	1
–	–	0 1	A3PBF1-600G-01	1SQA009180R0001	1
–	–	1 0	A3PBF1-600G-10	1SQA009181R0001	1
–	–	1 1	A3PBF1-600G-91	1SQA010760R0001	1
● Blue	–	0 0	A3PBF1-600L-00	1SQA009183R0001	1
–	–	1 0	A3PBF1-600L-10	1SQA009184R0001	1
–	–	1 1	A3PBF1-600L-91	1SQA010761R0001	1
● Amber	–	0 0	A3PBF1-600Y-00	1SQA009186R0001	1
● Red	–	0 0	A3PBF1-600R-00	1SQA009187R0001	1
–	–	0 1	A3PBF1-600R-01	1SQA009188R0001	1
–	–	1 0	A3PBF1-600R-10	1SQA009189R0001	1
–	–	1 1	A3PBF1-600R-91	1SQA010762R0001	1
● Yellow	–	0 1	A3PBF1-600Y-01	1SQA009191R0001	1
–	–	1 0	A3PBF1-600Y-10	1SQA009192R0001	1
–	–	1 1	A3PBF1-600Y-91	1SQA010763R0001	1

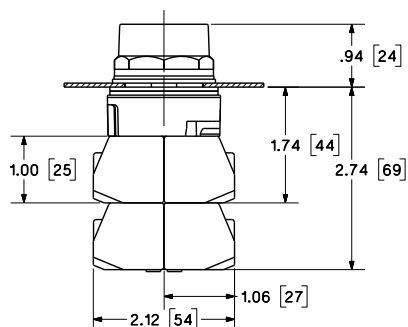

Momentary pushbutton non-illuminated flush cap

Dimensions inches, [mm]



30 mm heavy duty oil-tight range


Non-illuminated extended pushbuttons



Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary					
Assorted Colors	–	0 0	A3PBE1-6007-00	1SQA009152R0001	1
	–	0 1	A3PBE1-6007-01	1SQA009153R0001	1
	–	1 0	A3PBE1-6007-10	1SQA009154R0001	1
	–	1 1	A3PBE1-6007-91	1SQA010753R0001	1
	–	1 1	A3PBE1-600B-91	1SQA010754R0001	1
● Black	–	0 0	A3PBE1-600B-00	1SQA009156R0001	1
	–	0 1	A3PBE1-600B-01	1SQA009157R0001	1
	–	1 0	A3PBE1-600B-10	1SQA009158R0001	1
	–	1 1	A3PBE1-600B-91	1SQA010754R0001	1
● Green	–	0 0	A3PBE1-600G-00	1SQA009160R0001	1
	–	0 1	A3PBE1-600G-01	1SQA009161R0001	1
	–	1 0	A3PBE1-600G-10	1SQA009162R0001	1
	–	1 1	A3PBE1-600G-91	1SQA010755R0001	1
● Red	–	0 0	A3PBE1-600R-00	1SQA009164R0001	1
	–	0 1	A3PBE1-600R-01	1SQA009165R0001	1
	–	1 0	A3PBE1-600R-10	1SQA009166R0001	1
	–	1 1	A3PBE1-600R-91	1SQA010756R0001	1
● Yellow	–	0 0	A3PBE1-600Y-00	1SQA009168R0001	1
	–	1 0	A3PBE1-600Y-10	1SQA009169R0001	1
	–	1 1	A3PBE1-600Y-91	1SQA010757R0001	1

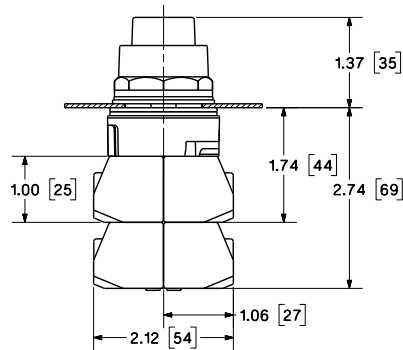

Momentary pushbutton non-illuminated raised cap
Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated extended pushbuttons



A3PLE1-6L2G-91

1SQA010785R0001



A3PLE1-6L2M-91

1SQA010787R0001



A3PLE1-6L2R-91

1SQA010788R0001

 



A3PLE1-6L2W-91

1SQA010789R0001

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary – full voltage					
○ Clear	24 V AC/DC	1 1	A3PLE1-6L2C-91	1SQA010784R0001	1
● Green	24 V AC/DC	1 0	A3PLE1-6L2G-10	1SQA009218R0001	1
	24 V AC/DC	1 1	A3PLE1-6L2G-91	1SQA010785R0001	1
● Blue	24 V AC/DC	1 1	A3PLE1-6L2L-91	1SQA010786R0001	1
● Amber	24 V AC/DC	0 0	A3PLE1-6L2M-00	1SQA009221R0001	1
	24 V AC/DC	1 0	A3PLE1-6L2M-10	1SQA009222R0001	1
	24 V AC/DC	1 1	A3PLE1-6L2M-91	1SQA010787R0001	1
● Red	24 V AC/DC	0 0	A3PLE1-6L2R-00	1SQA009224R0001	1
	24 V AC/DC	1 1	A3PLE1-6L2R-91	1SQA010788R0001	1
○ White	24 V AC/DC	1 0	A3PLE1-6L2W-10	1SQA009226R0001	1
	24 V AC/DC	1 1	A3PLE1-6L2W-91	1SQA010789R0001	1
○ Clear	120 V AC/DC	1 1	A3PLE1-6L4C-91	1SQA010790R0001	1
● Green	120 V AC/DC	0 0	A3PLE1-6L4G-00	1SQA009229R0001	1
	120 V AC/DC	1 0	A3PLE1-6L4G-10	1SQA009230R0001	1
	120 V AC/DC	1 1	A3PLE1-6L4G-91	1SQA010791R0001	1
● Blue	120 V AC/DC	1 1	A3PLE1-6L4L-91	1SQA010792R0001	1
● Amber	120 V AC/DC	0 0	A3PLE1-6L4M-00	1SQA009233R0001	1
	120 V AC/DC	1 1	A3PLE1-6L4M-91	1SQA010793R0001	1
● Red	120 V AC/DC	0 0	A3PLE1-6L4R-00	1SQA009235R0001	1
	120 V AC/DC	1 0	A3PLE1-6L4R-10	1SQA009236R0001	1
	120 V AC/DC	1 1	A3PLE1-6L4R-91	1SQA010794R0001	1
○ White	120 V AC/DC	1 0	A3PLE1-6L4W-10	1SQA009238R0001	1
	120 V AC/DC	1 1	A3PLE1-6L4W-91	1SQA010795R0001	1

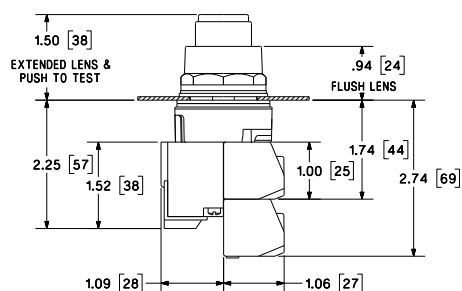

ILLUMINATED PUSHBUTTON FLUSH LENS
ILLUMINATED PUSHBUTTON EXTENDED LENS
ILLUMINATED PUSH TO TEST

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated extended pushbuttons



A3PLE1-6L5G-91

1SQA01079R0001



A3PLE1-6L5M-91

1SQA01079R0001



A3PLE1-6L5R-91

1SQA01080R0001



A3PLE1-6L5W-91

1SQA01080R0001

Description


Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
-------	---------	----------	----------------	------------	---------



Momentary – transformer

○ Clear	120 V AC	1 1	A3PLE1-6L5C-91	1SQA010796R0001	1
● Green	120 V AC	0 0	A3PLE1-6L5G-00	1SQA009241R0001	1
	120 V AC	1 0	A3PLE1-6L5G-10	1SQA009242R0001	1
	120 V AC	1 1	A3PLE1-6L5G-91	1SQA010797R0001	1
● Blue	120 V AC	1 1	A3PLE1-6L5L-91	1SQA010798R0001	1
● Amber	120 V AC	1 0	A3PLE1-6L5M-10	1SQA009245R0001	1
	120 V AC	1 1	A3PLE1-6L5M-91	1SQA010799R0001	1
● Red	120 V AC	1 0	A3PLE1-6L5R-10	1SQA009247R0001	1
	120 V AC	1 1	A3PLE1-6L5R-91	1SQA010800R0001	1
○ White	120 V AC	1 1	A3PLE1-6L5W-91	1SQA010801R0001	1
○ Clear	240 V AC	1 1	A3PLE1-6L6C-91	1SQA010839R0001	1
● Green	240 V AC	1 1	A3PLE1-6L6G-91	1SQA010802R0001	1
● Blue	240 V AC	1 1	A3PLE1-6L6L-91	1SQA010803R0001	1
● Amber	240 V AC	1 1	A3PLE1-6L6M-91	1SQA010804R0001	1
● Red	240 V AC	1 1	A3PLE1-6L6R-91	1SQA010805R0001	1
○ White	240 V AC	1 1	A3PLE1-6L6W-91	1SQA010806R0001	1
○ Clear	277 V AC	1 1	A3PLE1-6L7C-91	1SQA010825R0001	1
● Green	277 V AC	1 1	A3PLE1-6L7G-91	1SQA010820R0001	1
● Blue	277 V AC	1 1	A3PLE1-6L7L-91	1SQA010824R0001	1
● Amber	277 V AC	1 1	A3PLE1-6L7M-91	1SQA010822R0001	1
● Red	277 V AC	1 1	A3PLE1-6L7R-91	1SQA010821R0001	1
○ White	277 V AC	1 1	A3PLE1-6L7W-91	1SQA010823R0001	1
○ Clear	480 V AC	1 1	A3PLE1-6L8C-91	1SQA010840R0001	1
● Green	480 V AC	1 1	A3PLE1-6L8G-91	1SQA010807R0001	1
● Blue	480 V AC	1 1	A3PLE1-6L8L-91	1SQA010837R0001	1
● Amber	480 V AC	1 1	A3PLE1-6L8M-91	1SQA010808R0001	1
● Red	480 V AC	1 1	A3PLE1-6L8R-91	1SQA010809R0001	1
○ White	480 V AC	1 1	A3PLE1-6L8W-91	1SQA010835R0001	1
○ Clear	600 V AC	1 1	A3PLE1-6L9C-91	1SQA010841R0001	1
● Green	600 V AC	1 1	A3PLE1-6L9G-91	1SQA010810R0001	1
● Blue	600 V AC	1 1	A3PLE1-6L9L-91	1SQA010838R0001	1
● Amber	600 V AC	1 1	A3PLE1-6L9M-91	1SQA010834R0001	1
● Red	600 V AC	1 1	A3PLE1-6L9R-91	1SQA010811R0001	1
○ White	600 V AC	1 1	A3PLE1-6L9W-91	1SQA010836R0001	1

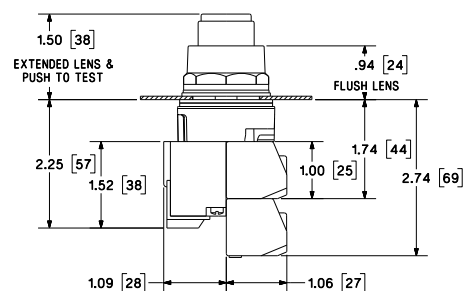

Illuminated pushbutton flush lens
 Illuminated pushbutton extended lens
 Illuminated push to test

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated extended pushbuttons



A3PLE1-6LBG-91

1SQA009260R0001



A3PLE1-6LBM-91

1SQA009262R0001



A3PLE1-6LBR-91

1SQA009263R0001



A3PLE1-6LLW-91

1SQA009269R0001

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
-------	---------	----------	----------------	------------	------------




Momentary – full voltage

Green	6-8 V AC/DC	1 1	A3PLE1-6LBG-91	1SQA010812R0001	1
Blue	6-8 V AC/DC	1 1	A3PLE1-6LBL-91	1SQA010813R0001	1
Amber	6-8 V AC/DC	1 1	A3PLE1-6LBM-91	1SQA010814R0001	1
Red	6-8 V AC/DC	1 1	A3PLE1-6LBR-91	1SQA010815R0001	1

Momentary – integrated LED module

Clear	6-24V AC/DC	1 1	A3PLE1-6LLC-91	1SQA010833R0001	1
Green	6-24 V AC/DC	1 1	A3PLE1-6LLG-91	1SQA010816R0001	1
Blue	6-24V AC/DC	1 1	A3PLE1-6LLL-91	1SQA010832R0001	1
Amber	6-24 V AC/DC	1 0	A3PLE1-6LLM-10	1SQA009265R0001	1
	6-24 V AC/DC	1 1	A3PLE1-6LLM-91	1SQA010817R0001	1
Red	6-24 V AC/DC	1 0	A3PLE1-6LLR-10	1SQA009267R0001	1
	6-24 V AC/DC	1 1	A3PLE1-6LLR-91	1SQA010818R0001	1
White	6-24 V AC/DC	1 1	A3PLE1-6LLW-91	1SQA010819R0001	1
Clear	24-240V AC/DC	1 1	A3PLE1-6LUC-91	1SQA010831R0001	1
Green	24-240V AC/DC	1 1	A3PLE1-6LUG-91	1SQA010826R0001	1
Blue	24-240V AC/DC	1 1	A3PLE1-6LUL-91	1SQA010830R0001	1
Amber	24-240V AC/DC	1 1	A3PLE1-6LUM-91	1SQA010827R0001	1
Red	24-240V AC/DC	1 1	A3PLE1-6LUR-91	1SQA010828R0001	1
White	24-240V AC/DC	1 1	A3PLE1-6LUW-91	1SQA010829R0001	1

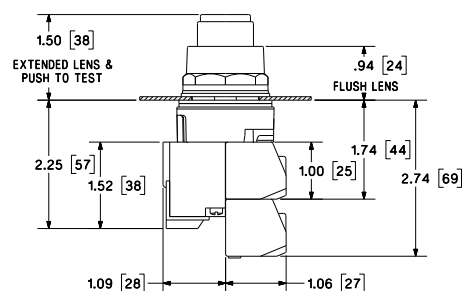

Illuminated pushbutton flush lens
Illuminated pushbutton extended lens
Illuminated push to test

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated mushroom pushbuttons – 44 mm



A3PB41-600B-10

15QC910047V0201



A3PB41-600G-10

15QC910049V0201



A3PB41-600R-10

15QC910051V0201

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
-------	---------	----------	----------------	------------	---------



Momentary

● Black	–	0 0	A3PB41-600B-00	1SQA009121R0001	1
	–	0 1	A3PB41-600B-01	1SQA009122R0001	1
	–	1 0	A3PB41-600B-10	1SQA009123R0001	1
	–	1 1	A3PB41-600B-91	1SQA010745R0001	1
● Green	–	0 0	A3PB41-600G-00	1SQA009125R0001	1
	–	0 1	A3PB41-600G-01	1SQA009126R0001	1
	–	1 0	A3PB41-600G-10	1SQA009127R0001	1
	–	1 1	A3PB41-600G-91	1SQA010746R0001	1
● Red	–	0 0	A3PB41-600R-00	1SQA009129R0001	1
	–	0 1	A3PB41-600R-01	1SQA009130R0001	1
	–	1 0	A3PB41-600R-10	1SQA009131R0001	1
	–	1 1	A3PB41-600R-91	1SQA010747R0001	1
● Yellow	–	0 0	A3PB41-600Y-00	1SQA009133R0001	1
	–	0 1	A3PB41-600Y-01	1SQA009134R0001	1
	–	1 0	A3PB41-600Y-10	1SQA009135R0001	1
	–	1 1	A3PB41-600Y-91	1SQA010748R0001	1

Maintained push-pull


● Black	–	0 1	A3PP42-600B-01	1SQA009270R0001	1
	–	1 1	A3PP42-600B-91	1SQA010842R0001	1
● Green	–	0 1	A3PP42-600G-01	1SQA009272R0001	1
	–	0 0	A3PP42-600R-00	1SQA009273R0001	1
● Red	–	0 1	A3PP42-600R-01	1SQA009274R0001	1
	–	1 1	A3PP42-600R-91	1SQA010843R0001	1
	–	1 1	A3PP43-600R-1N	1SQA010844R0001	1
	–	Extra late break			
● Yellow	–	0 1	A3PP42-600Y-01	1SQA009276R0001	1

Maintained push – momentary pull

● Red	–	1 1	A3PP44-600R-1N	1SQA010845R0001	1
		Extra late break			

Maintained twist – release

● Red	–	0 0	A3PT4R-600R-00	1SQA009333R0001	1
	–	0 1	A3PT4R-600R-01	1SQA009334R0001	1
	–	1 0	A3PT4R-600R-10	1SQA009335R0001	1
	–	1 1	A3PT4R-600R-91	1SQA010881R0001	1

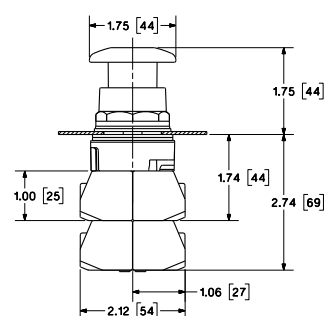

Momentary pushbutton small plastic mushroom head

Dimensions inches, [mm]

Continued on next page

30 mm heavy duty oil-tight range

Non-illuminated mushroom pushbuttons – 44 mm metal




A3PBM1-600R-01

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
Maintained push-pull – full voltage					
● Red	6-8 V AC/DC	0 1	A3PPM2-6LBR-01	1SQA009320R0001	1
Momentary					
● Red	–	1 0	A3PBM1-600R-01	1SQA010177R0001	1
Maintained push-pull					
No Cap	–	0 0	A3PPM2-600N-00	1SQA009308R0001	1
● Red	–	0 0	A3PPM2-600R-00	1SQA009309R0001	1
	–	0 1	A3PPM2-600R-01	1SQA009310R0001	1
	–	1 0	A3PPM2-600R-10	1SQA009311R0001	1
	–	1 1	A3PPM2-600R-91	1SQA010847R0001	1
Maintained push – momentary pull					
● Red	–	1 1	A3PPM4-600R-1N	1SQA010849R0001	1
Extra late break					

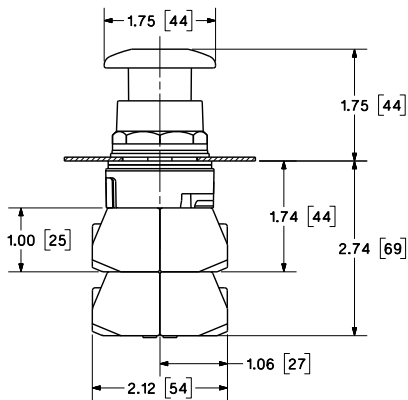


Momentary pushbutton small plastic mushroom head
Dimensions inches, [mm]


30 mm heavy duty oil-tight range

Non-illuminated mushroom pushbuttons – 60 mm

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary					
● Black	–	0 0	A3PB61-600B-00	1SQA009137R0001	1
	–	0 1	A3PB61-600B-01	1SQA009138R0001	1
	–	1 0	A3PB61-600B-10	1SQA009139R0001	1
	–	1 1	A3PB61-600B-91	1SQA010749R0001	1
● Green	–	0 0	A3PB61-600G-00	1SQA009141R0001	1
	–	0 1	A3PB61-600G-01	1SQA009142R0001	1
	–	1 0	A3PB61-600G-10	1SQA009143R0001	1
	–	1 1	A3PB61-600G-91	1SQA010750R0001	1
● Red	–	0 0	A3PB61-600R-00	1SQA009145R0001	1
	–	0 1	A3PB61-600R-01	1SQA009146R0001	1
	–	1 0	A3PB61-600R-10	1SQA009147R0001	1
	–	1 1	A3PB61-600R-91	1SQA010751R0001	1
● Yellow	–	0 0	A3PB61-600Y-00	1SQA009149R0001	1
	–	0 1	A3PB61-600Y-01	1SQA009150R0001	1
	–	1 1	A3PB61-600Y-91	1SQA010752R0001	1
Maintained push-pull					
● Red	–	0 0	A3PP62-600R-00	1SQA009304R0001	1
	–	0 1	A3PP62-600R-01	1SQA009305R0001	1
	–	1 1	A3PP62-600R-91	1SQA010846R0001	1

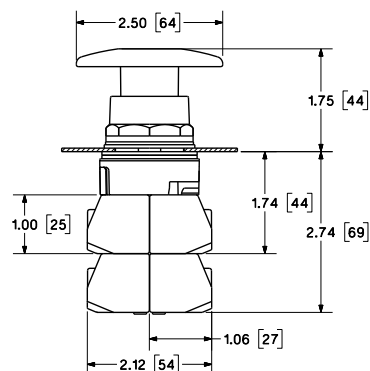

Momentary pushbutton large plastic mushroom head

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated mushroom pushbuttons – 44 mm



 
A3PL41-6L2G-91




A3PL41-6L2R-91

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary – full voltage					
Green	24 V AC/DC	1 1	A3PL41-6L2G-91	1SQA010764R0001	1
Amber	24 V AC/DC	1 1	A3PL41-6L2M-91	1SQA010765R0001	1
Red	24 V AC/DC	1 1	A3PL41-6L2R-91	1SQA010766R0001	1
Green	120 V AC/DC	1 1	A3PL41-6L4G-91	1SQA010767R0001	1
Amber	120 V AC/DC	1 1	A3PL41-6L4M-91	1SQA010768R0001	1
Red	120 V AC/DC	1 1	A3PL41-6L4R-91	1SQA010769R0001	1
Momentary – transformer					
Green	120 V AC	1 1	A3PL41-6L5G-91	1SQA010770R0001	1
Red	120 V AC	0 0	A3PL41-6L5R-00	1SQA009202R0001	1
	120 V AC	1 1	A3PL41-6L5R-91	1SQA010771R0001	1
	240 V AC	1 1	A3PL41-6L6R-91	1SQA010772R0001	1
	600 V AC	1 1	A3PL41-6L9R-91	1SQA010773R0001	1
Momentary – full voltage					
Green	6-8 V AC/DC	1 1	A3PL41-6L2G-91	1SQA010774R0001	1
Amber	6-8 V AC/DC	1 1	A3PL41-6L2M-91	1SQA010775R0001	1
Red	6-8 V AC/DC	1 0	A3PL41-6L2R-10	1SQA009208R0001	1
Momentary – integrated LED module					
Red	6-24 V AC/DC	1 1	A3PL41-6LLR-91	1SQA010776R0001	1
Maintained push-pull – full voltage					
Green	24 V AC/DC	1 1	A3PP42-6L2G-91	1SQA010850R0001	1
Amber	24 V AC/DC	1 1	A3PP42-6L2M-91	1SQA010851R0001	1
Red	24 V AC/DC	0 1	A3PP42-6L2R-01	1SQA009279R0001	1
	24 V AC/DC	1 0	A3PP42-6L2R-10	1SQA009280R0001	1
	24 V AC/DC	1 1	A3PP42-6L2R-91	1SQA010852R0001	1
Green	120 V AC/DC	1 1	A3PP42-6L4G-91	1SQA010853R0001	1
Amber	120 V AC/DC	1 1	A3PP42-6L4M-91	1SQA010854R0001	1
Red	120 V AC/DC	1 0	A3PP42-6L4R-10	1SQA009284R0001	1
	120 V AC/DC	1 1	A3PP42-6L4R-91	1SQA010855R0001	1

Continued on next page

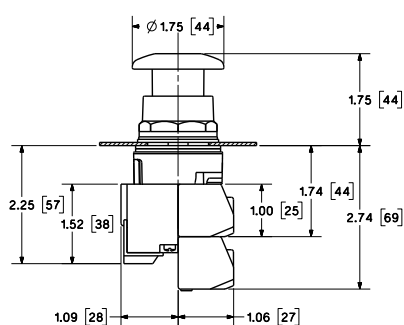

Illuminated momentary pushbutton small plastic mushroom head

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated mushroom pushbuttons – 44 mm




A3PP42-6LLG-91




A3PP42-6L5R-91

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Maintained push-pull – transformer					
● Green	120 V AC	1 1	A3PP42-6L5G-91	1SQA010856R0001	1
● Amber	120 V AC	1 1	A3PP42-6L5M-91	1SQA010857R0001	1
● Red	120 V AC	0 0	A3PP42-6L5R-00	1SQA009288R0001	1
	120 V AC	0 1	A3PP42-6L5R-01	1SQA009289R0001	1
	120 V AC	1 1	A3PP42-6L5R-91	1SQA010858R0001	1
● Green	480 V AC	1 1	A3PP42-6L8G-91	1SQA010859R0001	1
● Red	600 V AC	1 1	A3PP42-6L9R-91	1SQA010860R0001	1
Maintained push-pull – integrated LED module					
● Green	6-24 V AC/DC	1 1	A3PP42-6LLG-91	1SQA010861R0001	1
● Red	6-24 V AC/DC	1 1	A3PP42-6LLR-91	1SQA010862R0001	1
Maintained push-pull – full voltage					
● Green	120 V AC/DC	1 1 Extra late break	A3PP43-6L4G-1N	1SQA010863R0001	1
● Red	120 V AC/DC	1 1 Extra late break	A3PP43-6L4R-1N	1SQA010864R0001	1
Maintained push-pull – transformer					
● Red	120 V AC	1 1 Extra late break	A3PP43-6L5R-1N	1SQA010865R0001	1
● Green	480 V AC	1 1 Extra late break	A3PP43-6L8G-1N	1SQA010866R0001	1
Maintained push-momentary pull – full voltage					
● Red	24 V AC/DC	1 1 Extra late break	A3PP44-6L2R-1N	1SQA010867R0001	1
	120 V AC/DC	1 1 Extra late break	A3PP44-6L4R-1N	1SQA010868R0001	1
Maintained push-momentary pull – transformer					
● Red	120 V AC	1 1 Extra late break	A3PP44-6L5R-1N	1SQA010869R0001	1

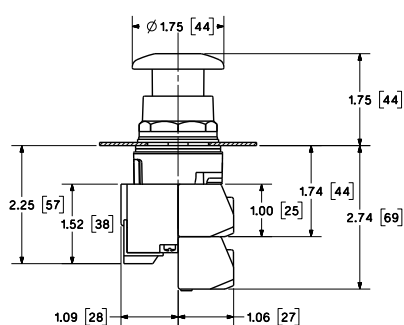

Illuminated momentary pushbutton small plastic mushroom head

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated mushroom pushbuttons – 44 mm metal




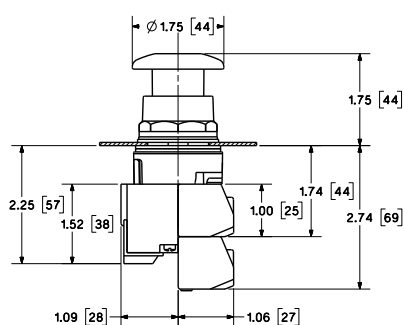
A3XLMLR*

* A3XLMLR is only the accessory head.
All illuminated A3PPM... devices will
come with this head installed.

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary					
● Red	–	1 1 Extra late break	A3PPM3-600R-1N	1SQA010848R0001	1
Momentary – full voltage					
● Red	24 V AC/DC	1 1 Extra late break	A3PPM3-6L2R-1N	1SQA010875R0001	1
● Green	120 V AC/DC	1 1 Extra late break	A3PPM3-6L4G-1N	1SQA010876R0001	1
● Amber	120 V AC/DC	1 1 Extra late break	A3PPM3-6L4M-1N	1SQA010877R0001	1
● Red	120 V AC/DC	0 0	A3PPM3-6L4R-00	1SQA009325R0001	1
	120 V AC/DC	1 1 Extra late break	A3PPM3-6L4R-1N	1SQA010878R0001	1
Maintained push-pull – full voltage					
● Red	24 V AC/DC	1 1	A3PPM2-6L2R-91	1SQA010871R0001	1
● Green	120 V AC/DC	0 1	A3PPM2-6L4G-01	1SQA009314R0001	1
	120 V AC/DC	1 1	A3PPM2-6L4G-91	1SQA010872R0001	1
● Red	120 V AC/DC	0 0	A3PPM2-6L4R-00	1SQA009316R0001	1
	120 V AC/DC	0 1	A3PPM2-6L4R-01	1SQA009317R0001	1
	120 V AC/DC	1 1	A3PPM2-6L4R-91	1SQA010873R0001	1
	120 V AC/DC	1 1	A3PPM2-6L4W-91	1SQA010874R0001	1
○ White	120 V AC/DC	1 1	A3PPM2-6L4W-91	1SQA010874R0001	1
Maintained push-momentary pull – full voltage					
● Red	24 V AC/DC	0 0	A3PPM4-6L2R-00	1SQA009328R0001	1
	24 V AC/DC	1 1 Extra late break	A3PPM4-6L2R-1N	1SQA010879R0001	1
	120 V AC/DC	1 1	A3PPM4-6L4R-1N	1SQA010880R0001	1
		Extra late break			



Illuminated momentary pushbutton small plastic mushroom head


Dimensions inches, [mm]


30 mm heavy duty oil-tight range

Illuminated mushroom pushbuttons – 60 mm

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary – full voltage					
● Green	24 V AC/DC	1 1	A3PL61-6L2G-91	1SQA010777R0001	1
● Red	24 V AC/DC	1 1	A3PL61-6L2R-91	1SQA010778R0001	1
● Green	120 V AC/DC	1 1	A3PL61-6L4G-91	1SQA010779R0001	1
● Red	120 V AC/DC	1 1	A3PL61-6L4R-91	1SQA010780R0001	1
Momentary – transformer					
● Red	120 V AC	1 1	A3PL61-6L5R-91	1SQA010781R0001	1
Momentary – integrated LED module					
● Amber	6-24 V AC/DC	1 1	A3PL61-6LLM-91	1SQA010782R0001	1
● Red	6-24 V AC/DC	1 1	A3PL61-6LLR-91	1SQA010783R0001	1
Maintained push-pull – full voltage					
● Red	24 V AC/DC	1 1	A3PP62-6L2R-91	1SQA010870R0001	1

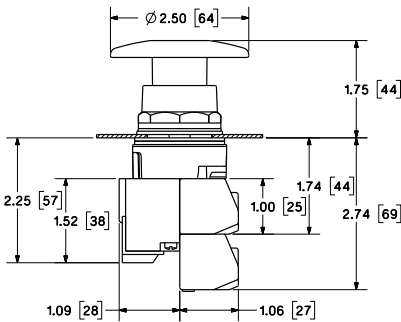


Illuminated momentary pushbutton large plastic mushroom head
Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated pushbuttons – no cap

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Contacts	Catalog number	Order code	Pkg qty
					
Momentary					
No cap	–	0 0	A3PBN1-600N-00	1SQA010178R0001	1
Maintained push-pull					
No cap	–	0 0	A3PPN2-600N-00	1SQA010200R0001	1
Maintained twist-release					
No cap	–	0 0	A3PT4R-600N-00	1SQA009332R0001	1

30 mm heavy duty oil-tight range

Pilot lights – LED bulb



A3L4AA-6L4G

15QA009084R0001



A3L4AA-6L4M

15QA009086R0001



A3L4AA-6L4R

15QA009087R0001



A3L4AA-6L4W


15QA009088R0001

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Catalog number	Order code	Pkg qty
Momentary – full voltage				
○ Clear	24 V AC/DC	A3L4AA-6L2C	15QA009077R0001	1
	120 V AC/DC	A3L4AA-6L4C	15QA009083R0001	1
	24-240 V AC/DC	A3L4AA-6LUC	15QA010465R0001	1
● Green	24 V AC/DC	A3L4AA-6L2G	15QA009078R0001	1
	120 V AC/DC	A3L4AA-6L4G	15QA009084R0001	1
	6-8 V AC/DC	A3L4AA-6LBG	15QA009112R0001	1
● Blue	24-240 V AC/DC	A3L4AA-6LUG	15QA010460R0001	1
	24 V AC/DC	A3L4AA-6L2L	15QA009079R0001	1
	120 V AC/DC	A3L4AA-6L4L	15QA009085R0001	1
● Amber	24-240 V AC/DC	A3L4AA-6LUL	15QA010464R0001	1
	24 V AC/DC	A3L4AA-6L2M	15QA009080R0001	1
	120 V AC/DC	A3L4AA-6L4M	15QA009086R0001	1
● Red	6-8 V AC/DC	A3L4AA-6LBM	15QA009113R0001	1
	24-240 V AC/DC	A3L4AA-6LUM	15QA010461R0001	1
No Lens	120 V AC/DC	A3L4AA-6N4N	15QA009120R0001	1
	24 V AC/DC	A3L4AA-6L2R	15QA009081R0001	1
	120 V AC/DC	A3L4AA-6L4R	15QA009087R0001	1
● Red	6-8 V AC/DC	A3L4AA-6LBR	15QA009114R0001	1
	24-240 V AC/DC	A3L4AA-6LUR	15QA010462R0001	1
○ White	24 V AC/DC	A3L4AA-6L2W	15QA009082R0001	1
	120 V AC/DC	A3L4AA-6L4W	15QA009088R0001	1
	6-8 V AC/DC	A3L4AA-6LBW	15QA009115R0001	1
○ White	24-240 V AC/DC	A3L4AA-6LUW	15QA010463R0001	1

Continued on next page

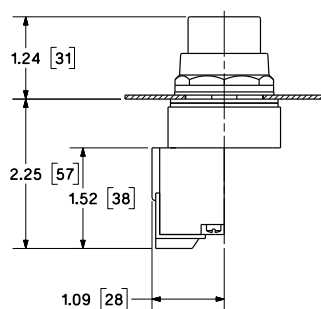

Indicator light plastic lens

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Pilot lights – LED bulb



A3L4AA-6L5G

15QA009090R0001



A3L4AA-6L5M

15QA009092R0001



A3L4AA-6L5R

15QA009093R0001




A3L4AA-6L5W

15QA009094R0001

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Color	Voltage	Catalog number	Order code	Pkg qty
Momentary – transformer				
○ Clear	120 V AC	A3L4AA-6L5C	15QA009089R0001	1
	240 V AC	A3L4AA-6L6C	15QA009095R0001	1
	480 V AC	A3L4AA-6L8C	15QA009103R0001	1
	600 V AC	A3L4AA-6L9C	15QA010492R0001	1
● Green	120 V AC	A3L4AA-6L5G	15QA009090R0001	1
	240 V AC	A3L4AA-6L6G	15QA009096R0001	1
	277 V SC	A3L4AA-6L7G	15QA009101R0001	1
	480 V AC	A3L4AA-6L8G	15QA009104R0001	1
● Blue	120 V AC	A3L4AA-6L5L	15QA009091R0001	1
	240 V AC	A3L4AA-6L6L	15QA009097R0001	1
	480 V AC	A3L4AA-6L8L	15QA009105R0001	1
	600 V AC	A3L4AA-6L9L	15QA010494R0001	1
● Amber	120 V AC	A3L4AA-6L5M	15QA009092R0001	1
	240 V AC	A3L4AA-6L6M	15QA009098R0001	1
	480 V AC	A3L4AA-6L8M	15QA009106R0001	1
	600 V AC	A3L4AA-6L9M	15QA010493R0001	1
● Red	120 V AC	A3L4AA-6L5R	15QA009093R0001	1
	240 V AC	A3L4AA-6L6R	15QA009099R0001	1
	277 V SC	A3L4AA-6L7R	15QA009102R0001	1
	480 V AC	A3L4AA-6L8R	15QA009107R0001	1
○ White	120 V AC	A3L4AA-6L5W	15QA009094R0001	1
	240 V AC	A3L4AA-6L6W	15QA009100R0001	1
	480 V AC	A3L4AA-6L8W	15QA009108R0001	1
	600 V AC	A3L4AA-6L9W	15QA009111R0001	1
Momentary – integrated LED module				
● Green	6-24 V AC/DC	A3L4AA-6LLG	15QA009116R0001	1
● Amber	6-24 V AC/DC	A3L4AA-6LLM	15QA009117R0001	1
● Red	6-24 V AC/DC	A3L4AA-6LLR	15QA009118R0001	1
○ White	6-24 V AC/DC	A3L4AA-6LLW	15QA009119R0001	1
Momentary – no lamp block				
No lens	No lamp block	A3L4AA-6N0N	15QA010199R0001	1

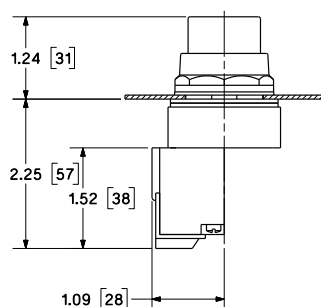

Indicator light plastic lens

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated selector switches




A3SSAA-6AAB-91


1SQC310095V0201


Description


Each reference includes the satin chrome metal body and nut together with the holder.


Operating principle	Color	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
---------------------	-------	--------------	---------	----------	----------------	------------	---------

 


2-position, short handle							
	● Green	Operator only	–	0 0	A3SSAA-6AAG-00	1SQA010204R0001	1
	● Red	Operator only	–	0 0	A3SSAA-6AAR-00	1SQA010205R0001	1
	○ White	A	–	1 1	A3SSAA-6AAB-91	1SQA010926R0001	1
		A	–	1 0	A3SSAA-6AAB-10	1SQA010925R0001	1
		A	–	0 1	A3SSAA-6AAB-01	1SQA010924R0001	1
		A	–	0 0	A3SSAA-6AAB-00	1SQA010161R0001	1
		A	–	2 0	A3SSAA-6AAB-20	1SQA010984R0001	1
		A	–	2 1	A3SSAA-6AAB-21	1SQA010985R0001	1

 
2-position, long handle							
	○ White	A	–	1 1	A3SLAA-6AAB-91	1SQA010903R0001	1
		A	–	0 0	A3SLAA-6AAB-00	1SQA010202R0001	1

2-position, short handle							
	○ White	A	–	1 1	A3SSAC-6AAB-91	1SQA010927R0001	1
		A	–	0 0	A3SSAC-6AAB-00	1SQA010203R0001	1

 2-position, long handle							
	○ White	A	–	1 1	A3SLAC-6AAB-91	1SQA010904R0001	1

 3-position, short handle							
	○ White	B	–	2 2	A3SSBA-6AAB-92	1SQA011107R0001	1
		B	–	1 0	A3SSBA-6AAB-10	1SQA010928R0001	1
		B	–	2 0	A3SSBA-6AAB-20	1SQA011106R0001	1
		B	–	0 0	A3SSBA-6AAB-00	1SQA010172R0001	1
		B	–	1 1	A3SSBA-6AAB-91	1SQA010929R0001	1
		B	–	2 1	A3SSBA-6AAB-21	1SQA010993R0001	1
		C	–	1 1	A3SSCA-6AAB-91	1SQA010935R0001	1
		C	–	0 0	A3SSCA-6AAB-00	1SQA010162R0001	1
		C	–	1 0	A3SSCA-6AAB-10	1SQA010934R0001	1
		C	–	1 2	A3SSCA-6AAB-12	1SQA010989R0001	1
		D	–	1 1	A3SSDA-6AAB-91	1SQA010940R0001	1
		D	–	0 0	A3SSDA-6AAB-00	1SQA010209R0001	1

Continued on next page

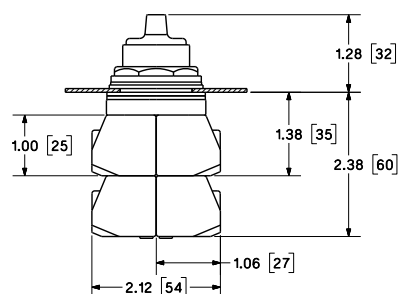

Selector switch non-illuminated

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated selector switches



A3SSBB-6AAB-91


1SQC310035V0201

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Operating principle	Color	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
3-position, short handle							
	○ White	E	–	1 1	A3SSEA-6AAB-91	1SQA010944R0001	1
		E	–	0 0	A3SSEA-6AAB-00	1SQA010175R0001	1
		G	–	0 0	A3SSGA-6AAB-00	1SQA010165R0001	1
		G	–	1 2	A3SSGA-6AAB-12	1SQA010991R0001	1
		G	–	1 1	A3SSGA-6AAB-91	1SQA010947R0001	1
	○ White	B	–	0 0	A3SSBB-6AAB-00	1SQA010206R0001	1
		B	–	2 2	A3SSBB-6AAB-92	1SQA011108R0001	1
		B	–	1 1	A3SSBB-6AAB-91	1SQA010930R0001	1
		C	–	0 0	A3SSCB-6AAB-00	1SQA010163R0001	1
		C	–	1 1	A3SSCB-6AAB-91	1SQA010936R0001	1
		D	–	0 0	A3SSDB-6AAB-00	1SQA010440R0001	1
		D	–	1 1	A3SSDB-6AAB-91	1SQA010941R0001	1
		E	–	0 0	A3SSEB-6AAB-00	1SQA009480R0001	1
		G	–	0 0	A3SSGB-6AAB-00	1SQA010441R0001	1
		G	–	1 1	A3SSGB-6AAB-91	1SQA010948R0001	1
		G	–	2 2	A3SSGB-6AAB-92	1SQA011117R0001	1
	○ White	B	–	0 0	A3SSBC-6AAB-00	1SQA010207R0001	1
		B	–	1 1	A3SSBC-6AAB-91	1SQA010931R0001	1
		B	–	2 2	A3SSBC-6AAB-92	1SQA011109R0001	1
		C	–	0 0	A3SSCC-6AAB-00	1SQA010208R0001	1
		C	–	1 1	A3SSCC-6AAB-91	1SQA010937R0001	1
		C	–	2 2	A3SSCC-6AAB-92	1SQA011111R0001	1
		D	–	0 0	A3SSDC-6AAB-00	1SQA009474R0001	1
		D	–	1 1	A3SSDC-6AAB-91	1SQA010942R0001	1
		D	–	2 2	A3SSDC-6AAB-92	1SQA011113R0001	1
		E	–	0 0	A3SSEC-6AAB-00	1SQA009481R0001	1
		E	–	1 1	A3SSEC-6AAB-91	1SQA010945R0001	1
		G	–	0 0	A3SSGC-6AAB-00	1SQA009488R0001	1
		G	–	1 1	A3SSGC-6AAB-91	1SQA010949R0001	1
		G	–	2 2	A3SSGC-6AAB-92	1SQA011118R0001	1

Continued on next page

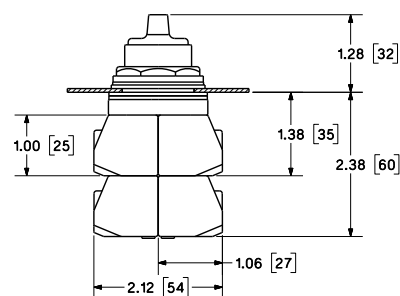

Selector switch non-illuminated

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated selector switches



A3SSBD-6AAB-91

1SQA01108R0001

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Operating principle	Color	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
---------------------	-------	--------------	---------	----------	----------------	------------	---------



3-position, short handle

	○ White	B	–	0 0	A3SSBD-6AAB-00	1SQA010173R0001	1
		B	–	1 1	A3SSBD-6AAB-91	1SQA010932R0001	1
		B	–	2 2	A3SSBD-6AAB-92	1SQA010933R0001	1
		C	–	0 0	A3SSCD-6AAB-00	1SQA010164R0001	1
		C	–	1 0	A3SSCD-6AAB-10	1SQA010938R0001	1
		C	–	1 1	A3SSCD-6AAB-91	1SQA010939R0001	1
		D	–	0 0	A3SSDD-6AAB-00	1SQA009476R0001	1
		D	–	1 1	A3SSDD-6AAB-91	1SQA010943R0001	1
		E	–	0 0	A3SSED-6AAB-00	1SQA009483R0001	1
		E	–	1 1	A3SSED-6AAB-91	1SQA010946R0001	1
		G	–	0 0	A3SSGD-6AAB-00	1SQA009490R0001	1
		G	–	1 1	A3SSGD-6AAB-91	1SQA010950R0001	1
		G	–	2 2	A3SSGD-6AAB-92	1SQA011119R0001	1


4-position, short handle

	○ White	H	–	0 0	A3SSHA-6AAB-00	1SQA010174R0001	1
		H	–	2 2	A3SSHA-6AAB-92	1SQA010951R0001	1

2-position, long handle

	○ White	A	–	0 0	A3SLAC-6AAB-00	1SQA010442R0001	1
--	---------	---	---	-----	----------------	-----------------	---

Continued on next page

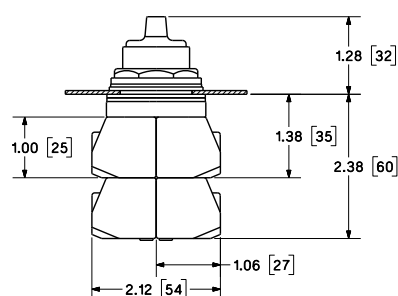

Selector switch non-illuminated

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated selector switches




A3SLBA-6AAB-91

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Operating principle	Color	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
3-position, long handle							
	○ White	B	–	0 0	A3SLBA-6AAB-00	1SQA010443R0001	1
		B	–	1 1	A3SLBA-6AAB-91	1SQA010905R0001	1
		B	–	2 2	A3SLBA-6AAB-92	1SQA011095R0001	1
		C	–	0 0	A3SLCA-6AAB-00	1SQA009393R0001	1
		C	–	1 1	A3SLCA-6AAB-91	1SQA010909R0001	1
		D	–	0 0	A3SLDA-6AAB-00	1SQA010446R0001	1
		D	–	1 1	A3SLDA-6AAB-91	1SQA010913R0001	1
		E	–	0 0	A3SLEA-6AAB-00	1SQA010449R0001	1
		E	–	1 1	A3SLEA-6AAB-91	1SQA010916R0001	1
		E	–	2 2	A3SLEA-6AAB-92	1SQA011100R0001	1
		G	–	0 0	A3SLGA-6AAB-00	1SQA009406R0001	1
		G	–	1 1	A3SLGA-6AAB-91	1SQA010919R0001	1
		G	–	2 2	A3SLGA-6AAB-92	1SQA011102R0001	1
	○ White	B	–	0 0	A3SLBB-6AAB-00	1SQA010444R0001	1
		B	–	1 1	A3SLBB-6AAB-91	1SQA010906R0001	1
		B	–	2 2	A3SLBB-6AAB-92	1SQA011096R0001	1
		C	–	0 0	A3SLCB-6AAB-00	1SQA009395R0001	1
		C	–	1 1	A3SLCB-6AAB-91	1SQA010910R0001	1
		G	–	0 0	A3SLGB-6AAB-00	1SQA010452R0001	1
		G	–	1 1	A3SLGB-6AAB-91	1SQA010920R0001	1
		G	–	2 2	A3SLGB-6AAB-92	1SQA011103R0001	1
	○ White	B	–	0 0	A3SLBC-6AAB-00	1SQA009389R0001	1
		B	–	1 1	A3SLBC-6AAB-91	1SQA010907R0001	1
		B	–	2 2	A3SLBC-6AAB-92	1SQA011097R0001	1
		C	–	0 0	A3SLCC-6AAB-00	1SQA010445R0001	1
		C	–	1 1	A3SLCC-6AAB-91	1SQA010911R0001	1
		D	–	0 0	A3SLDC-6AAB-00	1SQA010447R0001	1
		D	–	1 1	A3SLDC-6AAB-91	1SQA010914R0001	1
		E	–	0 0	A3SLEC-6AAB-00	1SQA010450R0001	1
		E	–	1 1	A3SLEC-6AAB-91	1SQA010917R0001	1
		G	–	0 0	A3SLGC-6AAB-00	1SQA010453R0001	1
		G	–	1 1	A3SLGC-6AAB-91	1SQA010921R0001	1
		G	–	2 2	A3SLGC-6AAB-92	1SQA011104R0001	1

Continued on next page

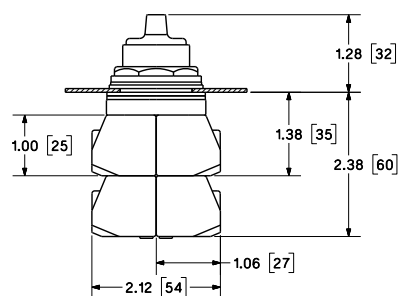

Selector switch non-illuminated

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Non-illuminated selector switches



Description


Each reference includes the satin chrome metal body and nut together with the holder.

3-position, long handle

	White	B	–	0 0	A3SLBD-6AAB-00	1SQA009391R0001	1
		B	–	1 1	A3SLBD-6AAB-91	1SQA010908R0001	1
		B	–	2 2	A3SLBD-6AAB-92	1SQA011098R0001	1
		C	–	0 0	A3SLCD-6AAB-00	1SQA009398R0001	1
		C	–	1 1	A3SLCD-6AAB-91	1SQA010912R0001	1
		D	–	0 0	A3SLDD-6AAB-00	1SQA010448R0001	1
		D	–	1 1	A3SLDD-6AAB-91	1SQA010915R0001	1
		D	–	2 2	A3SLDD-6AAB-92	1SQA011099R0001	1
		E	–	0 0	A3SLED-6AAB-00	1SQA010451R0001	1
		E	–	1 1	A3SLED-6AAB-91	1SQA010918R0001	1
		E	–	2 2	A3SLED-6AAB-92	1SQA011101R0001	1
		G	–	0 0	A3SLGD-6AAB-00	1SQA009410R0001	1
		G	–	1 1	A3SLGD-6AAB-91	1SQA010922R0001	1
		G	–	2 2	A3SLGD-6AAB-92	1SQA011105R0001	1

4-position, long handle

	White	H	–	0 0	A3SLHA-6AAB-00	1SQA010454R0001	1
		H	–	2 2	A3SLHA-6AAB-92	1SQA010923R0001	1

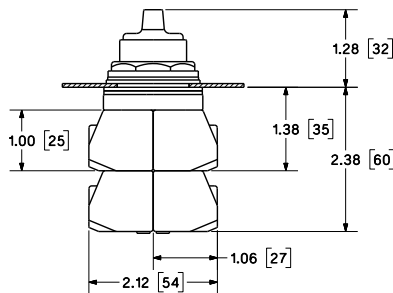

Selector switch non-illuminated

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Illuminated selector switches



A3SSAA-6L2G-91

15QC910095V0201



A3SSAA-6L2L-91

15QC910097V0201



A3SSAA-6L2R-91

15QC910093V0201

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Operating principle	Color	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
---------------------	-------	--------------	---------	----------	----------------	------------	---------



2-position, short handle

	● Green	A	FV 24 V	0 0	A3SSAA-6L2G-00	1SQA009417R0001	1
		A	FV 24 V	1 0	A3SSAA-6L2G-10	1SQA010882R0001	1
		A	FV 24 V	1 1	A3SSAA-6L2G-91	1SQA010883R0001	1
	● Blue	A	FV 24 V	0 0	A3SSAA-6L2L-00	1SQA010421R0001	1
		A	FV 24 V	1 0	A3SSAA-6L2L-10	1SQA010884R0001	1
		A	FV 24 V	1 1	A3SSAA-6L2L-91	1SQA010885R0001	1
	● Red	A	FV 24 V	0 0	A3SSAA-6L2R-00	1SQA009422R0001	1
		A	FV 24 V	1 1	A3SSAA-6L2R-91	1SQA010886R0001	1
	● Amber	A	FV 120V	0 0	A3SSAA-6L4M-00	1SQA010425R0001	1
		A	FV 120 V	1 1	A3SSAA-6L4M-91	1SQA010889R0001	1
	● Blue	A	FV 120 V	0 0	A3SSAA-6L4L-00	1SQA010424R0001	1
		A	FV 120 V	1 1	A3SSAA-6L4L-91	1SQA010888R0001	1
	● Green	A	FV 120 V	0 0	A3SSAA-6L4G-00	1SQA009424R0001	1
		A	FV 120 V	1 1	A3SSAA-6L4G-91	1SQA010887R0001	1
	● Red	A	FV 120 V	1 1	A3SSAA-6L4R-91	1SQA010890R0001	1
		A	FV 120 V	0 0	A3SSAA-6L4R-00	1SQA009428R0001	1
	● Amber	A	Trans. 120 V	0 0	A3SSAA-6L5M-00	1SQA010428R0001	1
		A	Trans. 120 V	1 1	A3SSAA-6L5M-91	1SQA010892R0001	1
	● Green	A	Trans. 120 V	1 1	A3SSAA-6L5G-91	1SQA010891R0001	1
		A	Trans. 240 V	0 0	A3SSAA-6L6G-00	1SQA010430R0001	1
		A	Trans. 240 V	1 1	A3SSAA-6L6G-91	1SQA010894R0001	1
		A	Trans. 120 V	0 0	A3SSAA-6L5G-00	1SQA009430R0001	1
	● Red	A	Trans. 120 V	0 0	A3SSAA-6L5R-00	1SQA009433R0001	1
		A	Trans. 120 V	1 1	A3SSAA-6L5R-91	1SQA010893R0001	1

3-position, short handle





	● Green	B	FV 24 V	1 1	A3SSBA-6L2G-91	1SQA010999R0001	1
		B	FV 24 V	0 0	A3SSBA-6L2G-00	1SQA009441R0001	1
	● Amber	C	FV 24 V	0 0	A3SSCA-6L2M-00	1SQA010434R0001	1
		C	FV 24 V	1 1	A3SSCA-6L2M-91	1SQA010897R0001	1
	● Green	C	FV 24 V	1 1	A3SSCA-6L2G-91	1SQA010896R0001	1
		C	FV 24 V	0 0	A3SSCA-6L2G-00	1SQA009453R0001	1
	● Red	B	FV 24 V	0 0	A3SSBA-6L2R-00	1SQA010432R0001	1
		B	FV 24 V	1 1	A3SSBA-6L2R-91	1SQA010895R0001	1
	● Green	C	FV 120 V	1 1	A3SSCA-6L4G-91	1SQA010898R0001	1
	● Blue	C	FV 120 V	0 0	A3SSCA-6L4L-00	1SQA010436R0001	1
		C	FV 120 V	1 1	A3SSCA-6L4L-91	1SQA010899R0001	1
	● Green	C	FV 120 V	0 0	A3SSCA-6L4G-00	1SQA009456R0001	1
	● Red	C	FV 120 V	1 1	A3SSCA-6L4R-91	1SQA010900R0001	1
		C	FV 120 V	0 0	A3SSCA-6L4R-00	1SQA009459R0001	1
	● Green	C	Trans. 120 V	0 0	A3SSCA-6L5G-00	1SQA010438R0001	1
		C	Trans. 120 V	1 1	A3SSCA-6L5G-91	1SQA010901R0001	1
	● Red	C	Trans. 120 V	1 1	A3SSCA-6L5R-91	1SQA010902R0001	1
		C	Trans. 120 V	0 0	A3SSCA-6L5R-00	1SQA009462R0001	1

30 mm heavy duty oil-tight range


Non-illuminated key-operated selector switches

Description

    Each reference includes the satin chrome metal body and nut together with the holder.

Operating principle	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
						
2-position						
	A	–	1 0	A3SKAE-6AA1-10	1SQA010952R0001	1
	A	–	1 1	A3SKAE-6AA1-91	1SQA010953R0001	1
	A	–	1 1	A3SKAF-6AA1-91	1SQA010955R0001	1
	A	–	1 1	A3SKAG-6AA1-91	1SQA010956R0001	1
	A	–	1 0	A3SKAE-6AA1-20	1SQA011084R0001	1
	A	–	1 0	A3SKAF-6AA1-10	1SQA010954R0001	1
	A	–	0 0	A3SKAE-6AA1-00	1SQA010170R0001	1
	A	–	0 0	A3SKAF-6AA1-00	1SQA010171R0001	1
	A	–	0 0	A3SKAG-6AA1-00	1SQA010210R0001	1
	A	–	0 0	A3SKAX-6AA1-00	1SQA009345R0001	1
3-position						
	B	–	0 0	A3SKBF-6AA1-00	1SQA010412R0001	1
	B	–	1 1	A3SKBE-6AA1-91	1SQA010958R0001	1
	B	–	1 1	A3SKBF-6AA1-91	1SQA010959R0001	1
	B	–	1 1	A3SKBH-6AA1-91	1SQA010960R0001	1
	B	–	2 2	A3SKBH-6AA1-92	1SQA011087R0001	1
	C	–	0 0	A3SKCF-6AA1-00	1SQA010413R0001	1
	D	–	1 1	A3SKDE-6AA1-91	1SQA010969R0001	1
	D	–	0 0	A3SKDF-6AA1-00	1SQA010415R0001	1
	D	–	0 0	A3SKDH-6AA1-00	1SQA010416R0001	1
	D	–	2 2	A3SKDY-6AA1-92	1SQA011091R0001	1
	E	–	0 0	A3SKEE-6AA1-00	1SQA010418R0001	1
	E	–	0 0	A3SKEV-6AA1-00	1SQA009376R0001	1
	E	–	1 1	A3SKEE-6AA1-91	1SQA010973R0001	1
	E	–	2 2	A3SKEE-6AA1-92	1SQA011092R0001	1
	E	–	2 2	A3SKET-6AA1-92	1SQA011093R0001	1
	E	–	2 2	A3SKEV-6AA1-92	1SQA011094R0001	1
	G	–	0 0	A3SKGE-6AA1-00	1SQA009378R0001	1
	G	–	0 0	A3SKGG-6AA1-00	1SQA009380R0001	1
	G	–	0 0	A3SKGH-6AA1-00	1SQA009381R0001	1
	G	–	2 2	A3SKGH-6AA1-92	1SQA010977R0001	1
	G	–	2 2	A3SKGE-6AA1-92	1SQA010976R0001	1
	A	–	1 1	A3SKAX-6AA1-91	1SQA010957R0001	1
	C	–	0 0	A3SKCU-6AA1-00	1SQA010414R0001	1

Continued on next page

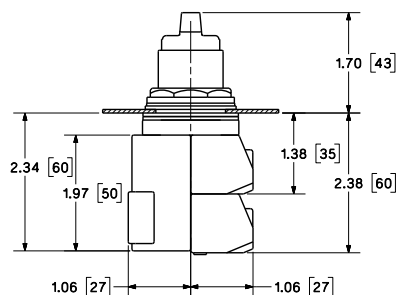

Selector switch illuminated


 

 
 
 
Dimensions inches, [mm]


30 mm heavy duty oil-tight range

Non-illuminated key-operated selector switches

Description

Each reference includes the satin chrome metal body and nut together with the holder.

Operating principle	Cam function	Voltage	Contacts	Catalog number	Order code	Pkg qty
						
3-position						
	C	–	1 1	A3SKCY-6AA1-91	1SQA010968R0001	1
	D	–	0 0	A3SKDY-6AA1-00	1SQA010417R0001	1
	D	–	1 1	A3SKDY-6AA1-91	1SQA010972R0001	1
	E	–	0 0	A3SKET-6AA1-00	1SQA010419R0001	1
	E	–	1 1	A3SKET-6AA1-91	1SQA010974R0001	1
	B	–	1 1	A3SKBV-6AA1-91	1SQA010961R0001	1
	E	–	1 1	A3SKEV-6AA1-91	1SQA010975R0001	1
	B	–	0 0	A3SKBY-6AA1-00	1SQA009354R0001	1
	C	–	1 1	A3SKCE-6AA1-91	1SQA010962R0001	1
	C	–	1 1	A3SKCF-6AA1-91	1SQA010963R0001	1
	C	–	1 1	A3SKCG-6AA1-91	1SQA010964R0001	1
	C	–	1 1	A3SKCH-6AA1-91	1SQA010965R0001	1
	C	–	1 1	A3SKCU-6AA1-91	1SQA010966R0001	1
	C	–	1 1	A3SKCV-6AA1-91	1SQA010967R0001	1
	C	–	0 0	A3SKCE-6AA1-00	1SQA009355R0001	1
	C	–	0 0	A3SKCG-6AA1-00	1SQA009358R0001	1
	C	–	0 0	A3SKCH-6AA1-00	1SQA009360R0001	1
	C	–	0 0	A3SKCT-6AA1-00	1SQA009362R0001	1
	C	–	0 0	A3SKCV-6AA1-00	1SQA009364R0001	1
	C	–	0 0	A3SKCY-6AA1-00	1SQA009366R0001	1
	B	–	2 2	A3SKBE-6AA1-92	1SQA011085R0001	1
	B	–	2 2	A3SKBF-6AA1-92	1SQA011086R0001	1
	B	–	2 2	A3SKBV-6AA1-92	1SQA011088R0001	1
	B	–	0 0	A3SKBE-6AA1-00	1SQA009347R0001	1
	B	–	0 0	A3SKBH-6AA1-00	1SQA009350R0001	1
	B	–	0 0	A3SKBV-6AA1-00	1SQA009352R0001	1
	C	–	2 2	A3SKCY-6AA1-92	1SQA011089R0001	1
	D	–	2 2	A3SKDE-6AA1-92	1SQA011090R0001	1
	D	–	1 1	A3SKDF-6AA1-91	1SQA010970R0001	1
	D	–	1 1	A3SKDH-6AA1-91	1SQA010971R0001	1
	D	–	0 0	A3SKDE-6AA1-00	1SQA009368R0001	1
	D	–	0 0	A3SKDV-6AA1-00	1SQA009372R0001	1

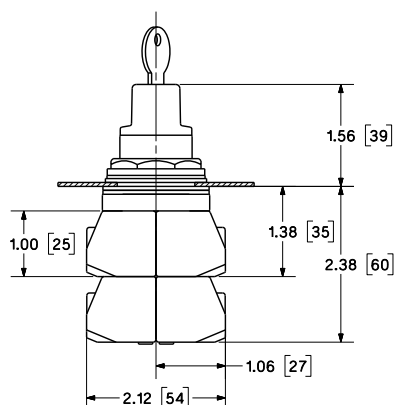


Selector switch keyed

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Contact configuration for pushbuttons and selector switches

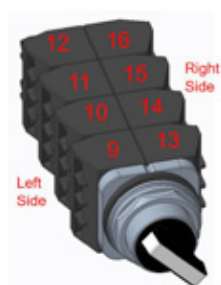

Maximum number of contacts is:

- (8) four on each side for non-illuminated pushbuttons
- (4) four on right side for illuminated/push-to-test pushbuttons
- (8) four on each side for non-illuminated selector switches
- (4) four on left side for illuminated selector switches (CAM A and C)
- (4) four on right side for illuminated selector switches (CAM B)

NC: Normally closed contact [X] — single contact block

NO: Normally opened contact [0] — single contact block

NO-NC: normally closed and normally opened contact — double contact block

Position

Contact no.	9	10	11	12	13	14	15	16
01*	NC							
02	NC				NC			
03	NC	NC			NC			
04	NC	NC			NC	NC		
05	NC	NC	NC		NC	NC		
06	NC	NC	NC		NC	NC	NC	
07	NC	NC	NC	NC	NC	NC	NC	
08	NC	NC	NC	NC	NC	NC	NC	NC
10	NO							
11	NC				NO			
12	NC	NO			NC			
13	NC	NO			NC	NC		
14	NC	NO	NC		NC	NC		
15	NC	NO	NC		NC	NC	NC	
16	NC	NO	NC	NC	NC	NC	NC	
17	NC	NO	NC	NC	NC	NC	NC	NC
20	NO				NO			
21	NC	NO			NO			
22	NC	NO			NC	NO		
23	NC	NO	NC		NC	NO		
24	NC	NO	NC		NC	NO	NC	
25	NC	NO	NC	NC	NC	NO	NC	
26	NC	NO	NC	NC	NC	NO	NC	NC
30	NO	NO			NO			
31	NC	NO			NO	NO		
32	NC	NO	NO		NC	NO		
33	NC	NO	NO		NC	NO	NC	
34	NC	NO	NC	NO	NC	NO	NC	
35	NC	NO	NC	NO	NC	NO	NC	NC
40	NO	NO			NO	NO		
41	NC	NO	NO		NO	NO		
42	NC	NO	NO		NC	NO	NO	
43	NC	NO	NO	NO	NC	NO	NO	
44	NC	NO	NO	NO	NC	NO	NO	NO
50	NO	NO	NO		NO	NO		
51	NC	NO	NO		NO	NO	NO	
52	NC	NO	NO	NO	NC	NO	NO	
53	NC	NO	NC	NO	NC	NO	NO	NO
60	NO	NO	NO		NO	NO	NO	
61	NC	NO	NO	NO	NO	NO	NO	
62	NC	NO	NO	NO	NC	NO	NO	NO
70	NO	NO	NO	NO	NO	NO	NO	
71	NC	NO	NO	NO	NO	NO	NO	NO
80	NO	NO	NO	NO	NO	NO	NO	NO
91	NO-NC							
92	NO-NC				NO-NC			
93	NO-NC	NO-NC			NO-NC			
94	NO-NC	NO-NC			NO-NC	NO-NC		

* Use for pushbuttons only. Selector switches with one contact block will have a special catalog number.

30 mm heavy duty oil-tight range

Cam table

Cam table

Cam type	Contact block	2 Position			Mounting location	
A3 series		Left	Right			
A	A3XC10	O	X		Left/right	
	A3XC01	X	O		Left/right	
Cam type	Contact block	3 Position			Mounting location	
A3 series		Left	Center	Right		
B	A3XC10	X			Right	
	A3XC10		X		Left	
	A3XC01	X	X		Left	
	A3XC01		X	X	Right	
C	A3XC01	X			Left/right	
	A3XC10		X		Left/right	
D	A3XC01		X		Left/right	
	A3XC10		X		Left/right	
E	A3XC10	X			Left/right	
	A3XC01		X		Left/right	
G	A3XC01	X			Left	
	A3XC01		X		Right	
	A3XC10		X		Left/right	
Cam type	Contact block	4 Position			Mounting location	
A3 series		Left	Left center	Right center	Right	
H	A3XC10	X			Right	
	A3XC01		X			Left
	A3XC01		X		Right	
	A3XC10				X	Left

30 mm heavy duty oil-tight range

Contact blocks





A3XC01

Description

Contact blocks

Contacts	Catalog number	Order code	Pkg qty
0 1	A3XC01	1SQA009494R0001	1
0 1 Late break	A3XC0B	1SQA010979R0001	1
1 0	A3XC10	1SQA009496R0001	1
1 0 Early break	A3XC0M	1SQA010981R0001	1
1 1	A3XC91	1SQA010978R0001	1
1 0 Extra late break	A3XC0N	1SQA010980R0001	1

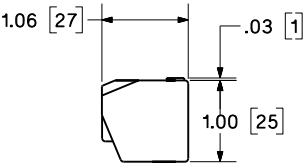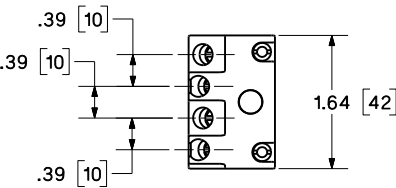

Contact block

Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Accessories



A3XGLP

15QC910114V0201



A3XGPM

15QC91011P V0201



A3XGGP

15QC910113V0201



A3XL4NG

15QC910115V0201



A3XL4LG

15QC910116V0201



A3XL4LR

15QC910117V0201



A3XL6NR

15QC910118V0201


Description

Locks, guards, keys, caps and lenses.


Description	Color	Catalog number	Order code	Pkg qty
Locks and guards				
Pad lock ext cap		A3XGCE	1SQA009500R0001	1
Pad lock flush cap		A3XGCF	1SQA009501R0001	1
Lock nut mushroom		A3XGLM	1SQA009502R0001	1
Lock nut push-pull and twist release		A3XGLN	1SQA009503R0001	1
Lock nut pushbutton		A3XGLP	1SQA009504R0001	1
Guards mushroom		A3XGPM	1SQA009506R0001	1
Locking cover		A3XGCC	1SQA010211R0001	1
Guard PTT		A3XGGL	1SQA010180R0001	1
Guard pushbutton		A3XGGP	1SQA010181R0001	1
Keys				
501H key code		A3XK501	1SQA009581R0001	1
Caps and lenses				
Caps for 44 mm non-illuminated mushrooms	Orange	A3XL4N8	1SQA009511R0001	1
	Assorted*	A3XL4NA	1SQA009512R0001	1
	Black	A3XL4NB	1SQA009513R0001	1
	Green	A3XL4NG	1SQA009514R0001	1
	Blue	A3XL4NL	1SQA009515R0001	1
	Red	A3XL4NR	1SQA009516R0001	1
Caps for 44 mm illuminated mushrooms	Yellow	A3XL4NY	1SQA009517R0001	1
	Green	A3XL4LG	1SQA010212R0001	1
	Amber	A3XL4LM	1SQA010215R0001	1
	Red	A3XL4LR	1SQA009510R0001	1
Caps for 60 mm non-illuminated mushrooms	Orange	A3XL6N8	1SQA009518R0001	1
	Assorted*	A3XL6NA	1SQA009519R0001	1
	Black	A3XL6NB	1SQA009520R0001	1
	Green	A3XL6NG	1SQA009521R0001	1
	Blue	A3XL6NL	1SQA009522R0001	1
	Red	A3XL6NR	1SQA009523R0001	1
Caps for 60 mm illuminated mushrooms	Yellow	A3XL6NY	1SQA009524R0001	1
	Green	A3XL6LG	1SQA010409R0001	1
	Amber	A3XL6LM	1SQA010411R0001	1
	Red	A3XL6LR	1SQA010410R0001	1
Caps for illuminated pushbutton / push to test	Clear	A3XLELC	1SQA009525R0001	1
	Green	A3XLELG	1SQA009526R0001	1
	Blue	A3XLELL	1SQA009527R0001	1
	Amber	A3XLELM	1SQA009528R0001	1
	Red	A3XLELR	1SQA009529R0001	1
	White	A3XLELW	1SQA009530R0001	1
Caps for non-illuminated extended pushbuttons	Grey	A3XLEN6	1SQA009531R0001	1
	Orange	A3XLEN8	1SQA009532R0001	1
	Assorted*	A3XLENA	1SQA009533R0001	1
	Green	A3XLENG	1SQA009534R0001	1
	Blue	A3XLENL	1SQA009535R0001	1
	Red	A3XLENR	1SQA009536R0001	1
	Yellow	A3XLENY	1SQA009537R0001	1

* Assorted includes one of each available color.

Continued on next page

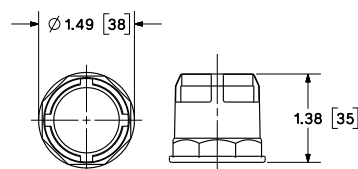

Momentary pushbutton guard, illuminated push to test guard
Dimensions inches, [mm]

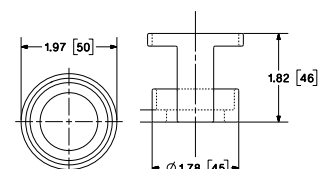

Mushroom head Guard
Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Accessories



A3XLFNG

15QC910119V0201



A3XLFNL

15QC910120V0201



A3XLFNR

15QC910121V0201



A3XLLLC

15QC910122V0201



A3XLLLG

15QC910123V0201



A3XLLLR

15QC910124V0201



A3XLMLR

15QC910125V0201



A3XLSSG

15QC910126V0201



A3XLSSR

15QC910127V0201


Description

Caps and lenses, selectors and twist releases.


Description	Color	Catalog number	Order code	Pkg qty
Caps and lenses				
Caps for non-illuminated flush pushbuttons	● Grey	A3XLFN6	1SQA009538R0001	1
	● Orange	A3XLFN8	1SQA009539R0001	1
	Assorted*	A3XLFNA	1SQA009540R0001	1
	● Black	A3XLFNB	1SQA009541R0001	1
	● Green	A3XLFNG	1SQA009542R0001	1
	● Blue	A3XLFNL	1SQA009543R0001	1
	● Red	A3XLFNR	1SQA009544R0001	1
	● Yellow	A3XLFNY	1SQA009545R0001	1
Caps for illuminated extended pushbuttons	Assorted*	A3XLLLA	1SQA009546R0001	1
	○ Clear	A3XLLLC	1SQA009547R0001	1
	● Green	A3XLLLG	1SQA009548R0001	1
	● Blue	A3XLLLL	1SQA009549R0001	1
	● Amber	A3XLLLM	1SQA009550R0001	1
	● Red	A3XLLLR	1SQA009551R0001	1
	○ White	A3XLLLW	1SQA009552R0001	1
Caps for 44 mm non-illuminated mushrooms – metal	Chrome	A3XLMN1	1SQA009557R0001	1
	● Green	A3XLMNG	1SQA009558R0001	1
	● Red	A3XLMNR	1SQA009559R0001	1
Caps for 44 mm illuminated mushrooms – metal	● Green	A3XMLG	1SQA009553R0001	1
	● Amber	A3XMLM	1SQA009554R0001	1
	● Red	A3XMLR	1SQA009555R0001	1
	○ White	A3XMLW	1SQA009556R0001	1
Caps for selector switches long handle	● Grey	A3XLSG6	1SQA009560R0001	1
	● Orange	A3XLSG8	1SQA009561R0001	1
	● Green	A3XLSGG	1SQA009562R0001	1
	● Blue	A3XLSGL	1SQA009563R0001	1
	● Red	A3XLSGR	1SQA009564R0001	1
	○ White	A3XLSGW	1SQA009565R0001	1
	● Yellow	A3XLSGY	1SQA009566R0001	1
Caps for selector switches short handle	● Grey	A3XLSS6	1SQA009567R0001	1
	● Orange	A3XLSS8	1SQA009568R0001	1
	● Green	A3XLSSG	1SQA009569R0001	1
	● Blue	A3XLSSL	1SQA009570R0001	1
	● Red	A3XLSSR	1SQA009571R0001	1
	○ White	A3XLSSW	1SQA009572R0001	1
	● Yellow	A3XLSSY	1SQA009573R0001	1
Caps for 44 mm non-illuminated mushroom – Twist release	● Green	A3XLTNG	1SQA009577R0001	1
	● Red	A3XLTNR	1SQA009578R0001	1
	● Yellow	A3XLTNY	1SQA009579R0001	1

* Assorted includes one of each available color.

Continued on next page

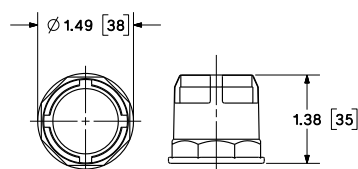

Momentary pushbutton guard, illuminated push to test guard
Dimensions inches, [mm]

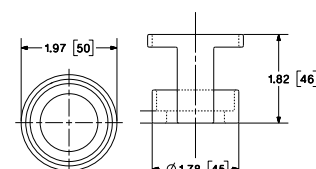

Mushroom head Guard
Dimensions inches, [mm]

30 mm heavy duty oil-tight range

Accessories



9PAA00000143801

A3XBL2G



9PAA00000143791

A3XBL2R



9PAA00000143722

A3XBL4L



9PAA00000143787

A3XBL6W

Description

Lock out kit, LED bulbs, tools, caps and lenses, boots and LED modules.

Description	Color	Catalog number	Order code	Pkg qty
Tools				
Lock out kit		A3XXGC	1SQA009583R0001	1
LED bulb				
Green 24 V	● Green	A3XBL2G	1SQA010193R0001	1
Blue 24V	● Blue	A3XBL2L	1SQA010401R0001	1
Red 24 V	● Red	A3XBL2R	1SQA010192R0001	1
White 24 V	○ White	A3XBL2W	1SQA010194R0001	1
Yellow 24V	● Yellow	A3XBL2Y	1SQA010402R0001	1
Green 120V	● Green	A3XBL4G	1SQA010403R0001	1
Blue 120 V	● Blue	A3XBL4L	1SQA010197R0001	1
Red 120 V	● Red	A3XBL4R	1SQA010195R0001	1
White 120 V	○ White	A3XBL4W	1SQA010198R0001	1
Yellow 120 V	● Yellow	A3XBL4Y	1SQA010196R0001	1
Green 6 V	● Green	A3XBL6G	1SQA010190R0001	1
Blue 6V	● Blue	A3XBL6L	1SQA010405R0001	1
Red 6 V	● Red	A3XBL6R	1SQA010189R0001	1
White 6 V	○ White	A3XBL6W	1SQA010191R0001	1
Yellow 6V	● Yellow	A3XBL6Y	1SQA010406R0001	1
Tools				
Lock nut wrench		A3XGLW	1SQA010221R0001	1
Caps and lenses				
Cap extended black 5 pieces	● Black	A3XLENB	1SQA010201R0001	5
Clear knob and lens	○ Clear	A3XLKLC	1SQA010218R0001	1
Green knob and lens	● Green	A3XLKLG	1SQA010213R0001	1
Blue knob and lens	● Blue	A3XLKLL	1SQA010216R0001	1
Amber knob and lens	● Amber	A3XLKLM	1SQA010217R0001	1
Red knob and lens	● Red	A3XLKLR	1SQA010214R0001	1
White knob and lens	○ White	A3XLKLW	1SQA010219R0001	1
Boots				
Black boot	● Black	A3XLP0B	1SQA010223R0001	1
Clear boot	○ Clear	A3XLP0C	1SQA010222R0001	1
LED module				
Green 24 V	● Green	A3XMLLG	1SQA010183R0001	1
Blue 24 V	● Blue	A3XMLLL	1SQA010480R0001	1
Red 24 V	● Red	A3XMLLR	1SQA010182R0001	1
White 24 V	○ White	A3XMLLW	1SQA010408R0001	1
Yellow 24 V	● Yellow	A3XMLLY	1SQA010184R0001	1
Green 24-240 V	● Green	A3XMLUG	1SQA010185R0001	1
Blue 24-240 V	● Blue	A3XMLUL	1SQA010458R0001	1
Red 24-240 V	● Red	A3XMLUR	1SQA010456R0001	1
White 24-240 V	○ White	A3XMLUW	1SQA010455R0001	1
Yellow 24-240 V	● Yellow	A3XMLUY	1SQA010459R0001	1
Lamp module no bulb 120 V max		A3XMN4N	1SQA010179R0001	1
Transformer 120 V AC no bulb		A3XMN5N	1SQA010404R0001	1
Transformer 240 V AC no bulb		A3XMN6N	1SQA010186R0001	1
Transformer 277 V AC no bulb		A3XMN7N	1SQA010188R0001	1
Transformer 480 V AC no bulb		A3XMN8N	1SQA010187R0001	1
Transformer 600 V AC no bulb		A3XMN9N	1SQA010407R0001	1

30 mm heavy duty oil-tight range

NEMA enclosures



9PAA00000142298

104PEG11E



9PAA00000142569

104PEG12G



9PAA00000142225

104PEG11S



9PAA00000142303

104PEG12



9PAA00000142131

104PEG13



9PAA00000142160

104PES11



9PAA00000142372

104PES14

Description

Painted sheet steel or stainless steel.

Material type	Text	Number of holes	Catalog number	Pkg qty
NEMA 1, 3, 3R, 12, 13				
Painted sheet steel	Start	1	104PEG11C	1
	Stop	1	104PEG11D	1
	Hand-Off-Auto	1	104PEG11E	1
	Start-Stop	2	104PEG12G	1
	Open-Close	2	104PEG12K	1
	Open-Close-Stop	3	104PEG13P	1
	Estop	1	104PEG11S	1
	Hand-Auto	1	104PEG11T	1
	No text	1	104PEG11	1
	No text	2	104PEG12	1
	No text	3	104PEG13	1
	No text	4	104PEG14	1
	No text	6	104PEG23	1
NEMA 3, 3R, 4, 4X, 12, 13				
Stainless steel	Start	1	104PES11C	1
NEMA 4X stainless steel				
Stainless steel	Hand-Off-Auto	1	104PES11E	1
	Start-Stop	2	104PES12G	1
	Open-Close	2	104PES12K	1
	Open-Close-Stop	3	104PES13P	1
	Estop	1	104PES11S	1
	Hand-Auto	1	104PES11T	1
	No text	1	104PES11	1
	No text	2	104PES12	1
	No text	3	104PES13	1
	No text	4	104PES14	1
	No text	6	104PES23	1

30 mm heavy duty oil-tight range

Name plates



CR104PXN1BP006

9PAA00000142302



CR104PXN2RP009

9PAA00000142452



CR104PXN1BP024

9PAA00000142505



CR104PXN1BP037

9PAA00000142364



CR104PXN2RP040

9PAA00000142504

Sizes table

Sizes	Dimensions (H x W, Inches)
-------	-------------------------------

Nameplate

Standard (Replace * with 1)	1.98 x 1.93
Large (Replace * with 2)	1.98 x 2.63
Extra-large, automotive (Replace * with 3)	2.40 x 2.44

Description

To select size, replace asterisk (*) in product number with appropriate digit from sizes table.

Text	Catalog number	Pkg qty
Blank	CR104PXN*B	1
Blank (Red)	CR104PXN*R	1
Blank (with round)	CR104PXN6E	1
CLOSE	CR104PXN*BP006	1
DECREASE	CR104PXN*BP007	1
DOWN	CR104PXN*BP008	1
EMERGENCY STOP (Red)	CR104PXN*RP009	1
FAST	CR104PXN*BP010	1
FORWARD	CR104PXN*BP011	1
HIGH	CR104PXN*BP012	1
IN	CR104PXN*BP013	1
INCH	CR104PXN*BP014	1
INCREASE	CR104PXN*BP017	1
JOG	CR104PXN*BP018	1
JOG FORWARD	CR104PXN*BP019	1
JOG REVERSE	CR104PXN*BP020	1
LEFT	CR104PXN*BP021	1
LOW	CR104PXN*BP022	1
LOWER	CR104PXN*BP023	1
OFF	CR104PXN*BP024	1
ON	CR104PXN*BP025	1
OPEN	CR104PXN*BP026	1
OUT	CR104PXN*BP027	1
POWER ON	CR104PXN*BP084	1
RAISE	CR104PXN*BP028	1
RESET	CR104PXN*BP030	1
RETURN	CR104PXN*BP031	1
REVERSE	CR104PXN*BP032	1
RIGHT	CR104PXN*BP033	1
RUN	CR104PXN*BP034	1
SLOW	CR104PXN*BP036	1
START	CR104PXN*BP037	1
START CYCLE	CR104PXN*BP038	1
STOP (Red)	CR104PXN*RP040	1
STOP CYCLE (Red)	CR104PXN*RP041	1
TEST	CR104PXN*BP043	1
UP	CR104PXN*BP047	1
EMERGENCY STOP PULL TO TEST (Red)	CR104PXN*RP048	1
PUSH TO STOP–PULL TO START	CR104PXN*BP085	1

Continued on next page

30 mm heavy duty oil-tight range

Name plates



9PAA00000142621

CR104PXN1BP050



9PAA000000142795

CR104PXN1BP057



9PAA00000142515

CR104PXN1BP066



9PAA00000142273

CR104PXN1BP070



9PAA00000142520

CR104PXN2BP070

Sizes table

Sizes	Dimensions (H x W, Inches)
Nameplate	
Standard (Replace * with 1)	1.98 x 1.93
Large (Replace * with 2)	1.98 x 2.63
Extra-large, automotive (Replace * with 3)	2.40 x 2.44

Description

To select size, replace asterisk (*) in product number with appropriate digit from sizes table.

Text	Catalog number	Pkg qty
FOR-REV	CR104PXN*BP050	1
HAND-AUTO	CR104PXN*BP051	1
HIGH-LOW	CR104PXN*BP052	1
JOG-RUN	CR104PXN*BP053	1
LEFT-RIGHT	CR104PXN*BP054	1
LOW-HIGH	CR104PXN*BP055	1
LOWER-RAISE	CR104PXN*BP056	1
OFF-ON	CR104PXN*BP057	1
OPEN-CLOSE	CR104PXN*BP058	1
RAISE-LOWER	CR104PXN*BP059	1
REV-FOR	CR104PXN*BP060	1
RUN-JOG	CR104PXN*BP061	1
SAFE-RUN	CR104PXN*BP062	1
SAFE-STOP-RUN	CR104PXN*BP063	1
SLOW-FAST	CR104PXN*BP064	1
START-JOG	CR104PXN*BP087	1
START-STOP	CR104PXN*BP086	1
STOP-START	CR104PXN*BP065	1
UP-DOWN	CR104PXN*BP066	1
OFF-COOLANT-ON	CR104PXN*BP067	1
AUTO-OFF-HAND	CR104PXN*BP083	1
FOR-OFF-REV	CR104PXN*BP068	1
FOR-STOP-REV	CR104PXN*BP069	1
HAND-OFF-AUTO	CR104PXN*BP070	1
JOG-OFF-RUN	CR104PXN*BP071	1
JOG-SAFE-RUN	CR104PXN*BP072	1
LOW-OFF-HIGH	CR104PXN*BP073	1
LOWER-OFF-RAISE	CR104PXN*BP074	1
MAN-OFF-AUTO	CR104PXN*BP076	1
OPEN-OFF-CLOSE	CR104PXN*BP077	1
REV-OFF-FOR	CR104PXN*BP079	1
SLOW-OFF-FAST	CR104PXN*BP080	1
SLOW-STOP-FAST	CR104PXN*BP081	1
POTENTIOMETER MARKINGS	CR104PXN*BP082	1
OFF-AUTO	CR104PXN1BP090	1
ON-OFF-AUTO	CR104PXN1BP091	1
PUSH TO STOP-TURN TO RESET (Round w/Yellow Background)	CR104PXN6EP092	1
Yellow Background Emergency Stop	CR104PXN6EP009	1


30 mm heavy duty oil-tight range

Technical specifications

Standards	UL Listed File # E2403	
Utilization	Category NEMA	A600/P600
Degree of protection	Operators	NEMA: 1, 3, 3R, 4, 4X, 12 and 13 IEC 529; IP10, IP11, IP14, IP52, IP54, IP56 and IP66

Rated operational current

NEMA A600 — 10 continuous amps			NEMA P600 — Rating codes for DC control	
Voltage AC	Make amps	Break amps	Circuit application	
120 V	60	6	Thermal continuous test current amps	
240 V	30	3	5.0	
480 V	15	1.5	Maximum make or break; current / amps	
600 V	12	1.2	125 V	1.10
Total VA	7200	720	250 V	0.55
			301–600 V	0.20
			Maximum make or break	
			Volt amperes at 300 V or Less	
			138	

Contact blocks	A3X	600 V AC maximum, heavy duty 200 V AC 0.25 amp, 10 watt maximum 200 V DC 0.50 amp, 10 watt maximum		
a  Positively driven contacts.	Contact blocks are suitable for applications down to 5V/1mA low voltage applications as found in PLCs.			
Pilot light	Full voltage LED module Transformer type	A3L	-B (6-8 V), -1 (12 V), -2 (24 V), -4 (120 V) -L (6-24 V), U (24-240 V) -5 (120 V), -6 (240 V), -7 (277 V), -8 (480 V), -9 (600 V)	120 V AC/DC max. 240 V AC/DC max. 600 V AC max., 50/60 Hz
Push-to-test	Full voltage LED module Transformer type	A3PL	-B (6-8 V), -1 (12 V), -2 (24 V), -4 (120 V) -L (6-24 V), U (24-240 V) -5 (120 V), -6 (240 V), -7 (277 V), -8 (480 V), -9 (600 V)	120 V AC/DC max. 240 V AC/DC max. 600 V AC max., 50/60 Hz
Illuminated push-pull	Full voltage LED module Transformer	A3PP	-B (6-8 V), -1 (12 V), -2 (24 V), -4 (120 V) -L (6-24 V), U (24-240 V) -5 (120 V), -6 (240 V), -7 (277 V), -8 (480 V), -9 (600 V)	120 V AC/DC max. 240 V AC/DC max. 600 V AC max., 50/60 Hz
Twist-to-release	Full voltage LED module Transformer	A3PT	-B (6-8 V), -1 (12 V), -2 (24 V), -4 (120 V) -L (6-24 V), U (24-240 V) -5 (120 V), -6 (240 V), -7 (277 V), -8 (480 V), -9 (600 V)	120 V AC/DC max. 240 V AC/DC max. 600 V AC max., 50/60 Hz
Illuminated selector switch	Full voltage Transformer	A3S	-B (6-8 V), -1 (12 V), -2 (24 V), -4 (120 V) -L (6-24 V), U (24-240 V) -5 (120 V), -6 (240 V), -7 (277 V), -8 (480 V), -9 (600 V)	120 V AC/DC max. 240 V AC/DC max. 600 V AC max., 50/60 Hz
Dielectric strength	2200 V for one minute			

Mechanical design life cycles

Vibration	Frequency 5–60 Hz.; Disp. .030 inches, sweep 5 minutes for a duration of 30 minutes on each axis. Not to exceed 5.5 G's for maximum of 1 minute.	
Pushbuttons	Momentary, non-illuminated Momentary, illuminated	5,000,000 Operating cycles 300,000 Operating cycles
Push-pull	Maintained Momentary	300,000 Operating cycles 2,000,000 Operating cycles
Twist-to-release		300,000 Operating cycles
Selector Switches	Non-illuminated Illuminated, key-operated	2,000,000 Operating cycles 2,000,000 Operating cycles
Contact operation	Standard contact black Logic reed	
Wire gauge	#18-12 AWG	
Terminal screw torque	2-10 lb-in / 20 lb-in max; 8 lb-in recommended	
Locknut torque	15 ft. lbs. max	
Temperature range	Operating storage	31 °F to +158 °F (-35 °C to +70 °C) 40 °F to +185 °F (-40 °C to +85 °C)

All parts are designed and manufactured of corrosion-resistant material or are plated or painted as corrosion protection. All contact block contacts are gold flashed as a standard offering. Internal return spring mechanisms of operators and contact blocks of stainless steel. RoHS Compliant.

Declaration of Conformity — The products listed below, to which this declaration relates, are in conformity with the following standards, following the provisions of the Low Voltage Directive (LVD) (73/23/EEC), and the Electromagnetic Compatibility Directive (89/336/EEC.)

Products: Contact Blocks: Cat Nos. A3XC0B, A3XC0M, A3XC01, A3XC10, A3XC0N and A3XC91, with suffixes. Pilot Lights: Cat Nos 52P, with suffixes. Operators: Cat Nos 52S or 52P, with suffixes.


Applicable Standards: EN 60947-5-1 Low-Voltage Switchgear and control gear. Enclosed devices meet the requirements of environmental ratings of IP10, IP11, IP14, IP52, IP54, and IP56. Open devices, when mounted as instructed, in environmental type IP10, IP11, IP14, IP52, IP54 or IP56 enclosures, maintain the environmental requirements for those enclosure types. 2 Position, Twist-To-Release and 2 Position, Push Pull Maintained operators provided with red operating heads and A3XC91 contact blocks meet the requirements of EN 60947-5-5 for Electrical Emergency Stop Device With Mechanical Latching Function (e-stop).

30 mm heavy duty oil-tight range


Dimensions

30 mm water, oil-tight and corrosion-resistant — A3


Non-illuminated push-pull
metal mushroom head

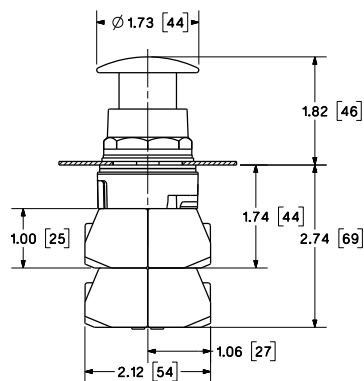


Non-illuminated push-pull
small plastic mushroom head

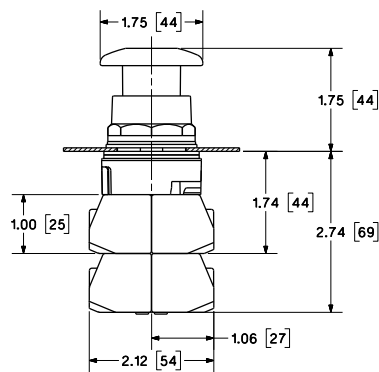


Non-illuminated push-pull
large plastic mushroom head

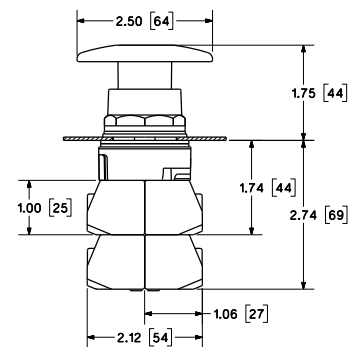


Illuminated push-pull
metal mushroom head

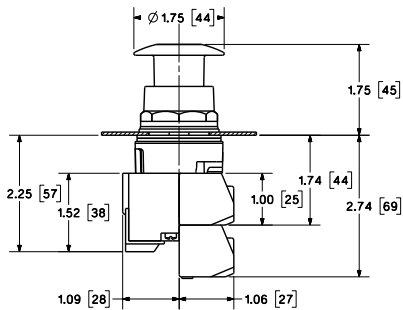


Fully illuminated push-pull
small plastic mushroom head

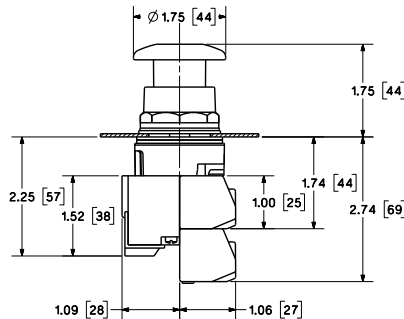


Illuminated push-pull
large plastic mushroom head

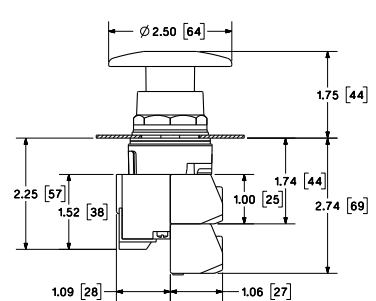


Non-illuminated twist release
plastic mushroom head

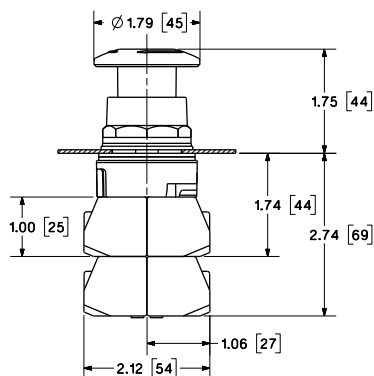

Illuminated twist release
plastic mushroom head

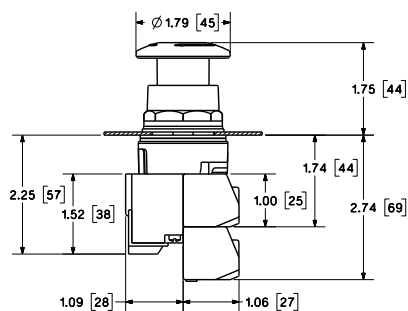

Illuminated pushbutton flush lens
illuminated pushbutton extended lens
illuminated push to test

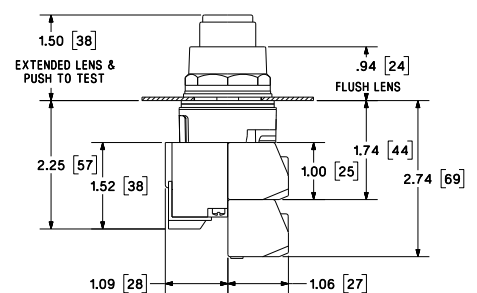


30 mm heavy duty oil-tight range


Dimensions

30 mm water, oil-tight and corrosion-resistant — A3


Selector switch
Non-illuminated

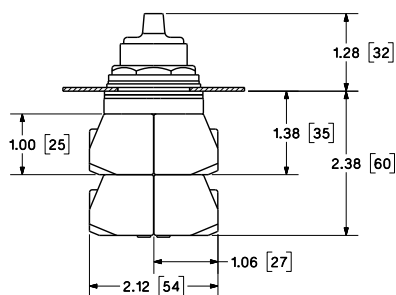


Selector switch
illuminated

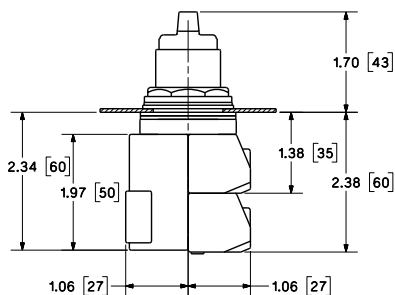


Indicator light
plastic lens

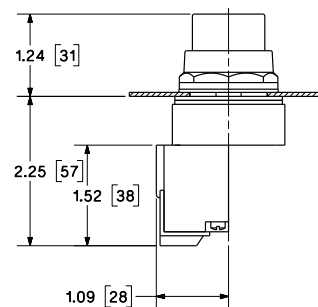


Momentary pushbutton
non-illuminated flush cap

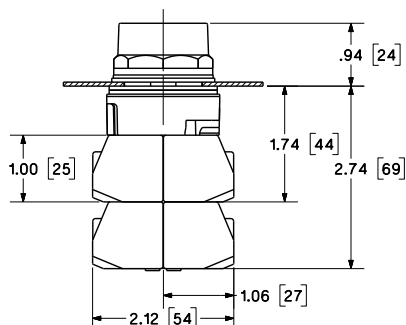


Momentary pushbutton
non-illuminated raised cap

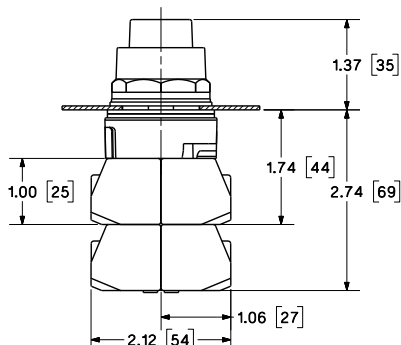


Indicator light
glass lens

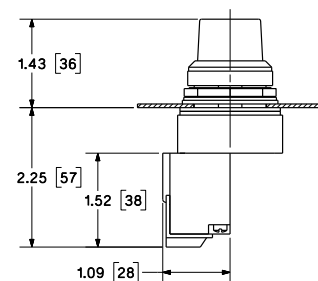


Momentary pushbutton
metal mushroom head

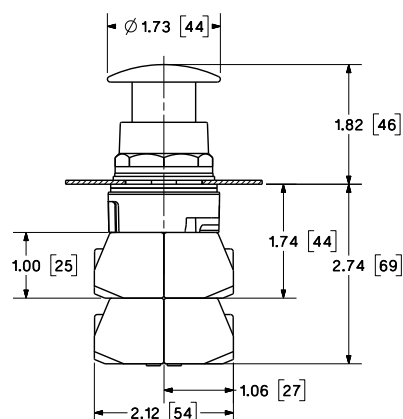

Momentary pushbutton
small plastic mushroom head

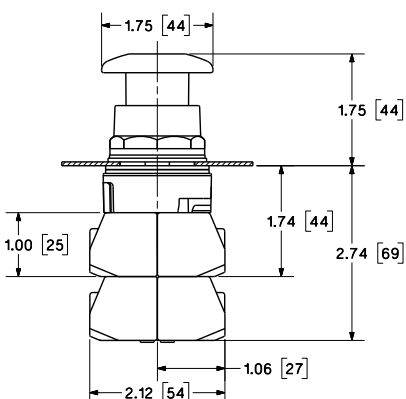

Momentary pushbutton
large plastic mushroom head

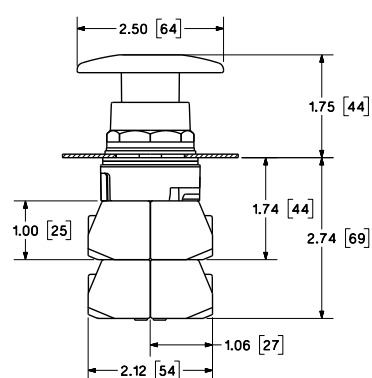


30 mm heavy duty oil-tight range


Dimensions

30 mm water, oil-tight and corrosion-resistant — A3


Illuminated momentary pushbutton
metal mushroom head

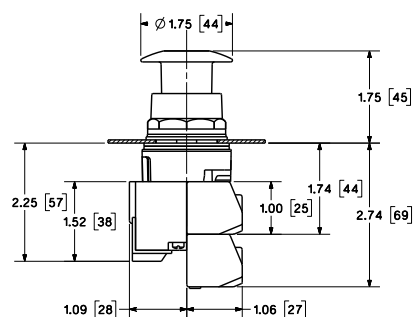


Illuminated momentary pushbutton
small plastic mushroom head

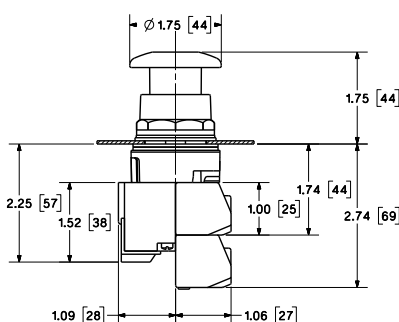


Illuminated momentary pushbutton
large plastic mushroom head

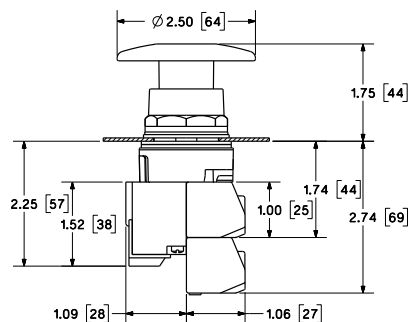


Selector switch
keyed

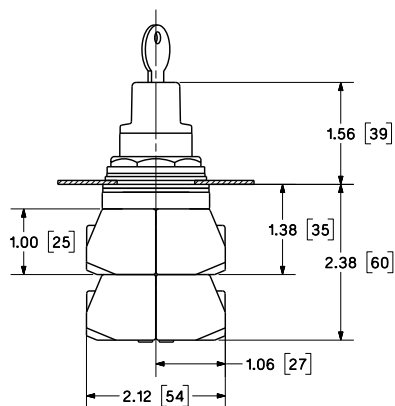


Wobble switch

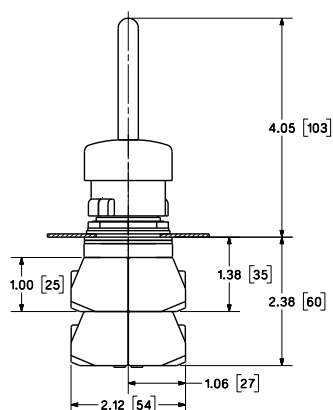


Potentiometer switch

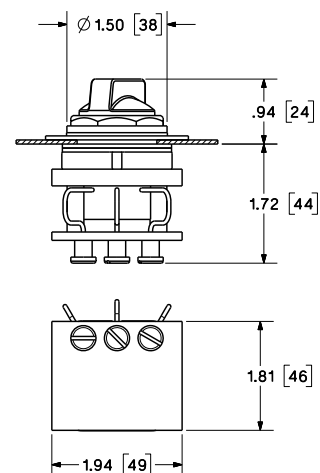


Toggle switch

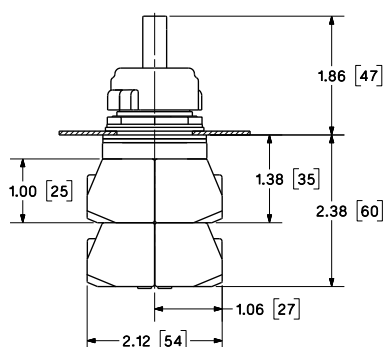

Selector pushbutton switch
flush cap

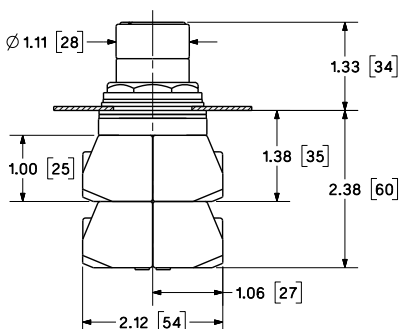

Selector pushbutton switch
raised cap

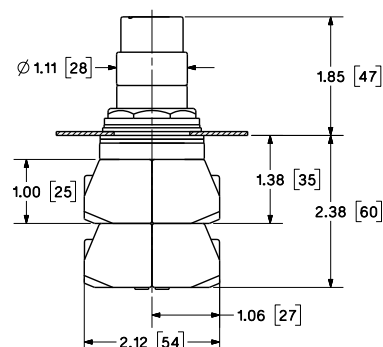


30 mm heavy duty oil-tight range


Dimensions

30 mm water, oil-tight and corrosion-resistant — A3


Momentary pushbutton guard
illuminated push to test guard

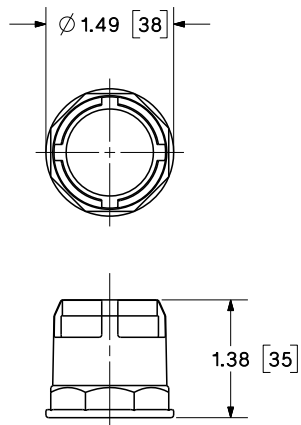

Mushroom head guard

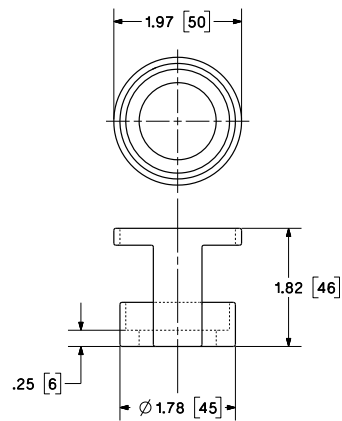

Contact block

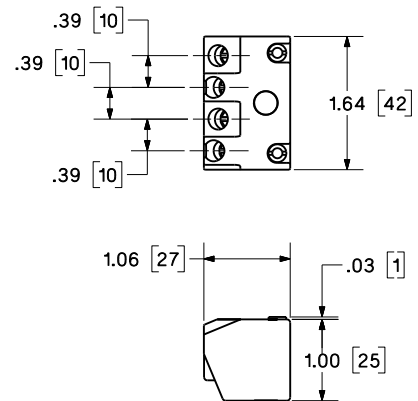

30 mm heavy duty oil-tight range

Dimensions

NEMA enclosures


Part	No. of holes per unit ²	A		B		C		D		E		F		Hub sizes inches ³
		In.	mm	In.	mm	In.	mm	In.	mm	In.	mm	In.	mm	
1	1	5.50	139.70	3.50	88.90	4.25	108.00	5.00	127.00	2.38	60.40	.31	7.90	$\frac{3}{4}$
2	2	7.75	196.80	3.50	88.90	4.25	108.00	7.25	184.20	2.38	60.40	.31	7.90	$\frac{3}{4}$
3	3	10.00	254.00	3.50	88.90	4.25	108.00	9.50	241.30	2.38	60.40	.31	7.90	$\frac{3}{4}$
4 ¹	4	13.38	339.80	3.50	88.90	4.25	108.00	12.88	327.20	2.38	60.40	.31	7.90	1
5	4	8.25	209.60	6.50	165.10	4.25	108.00	7.75	196.80	5.38	136.60	.31	7.90	1
6	6	10.50	266.70	7.00	177.80	4.25	108.00	10.00	254.00	5.88	149.40	.31	7.90	1 $\frac{1}{4}$
7	9	10.50	266.70	9.25	235.00	4.25	108.00	10.00	254.00	8.19	208.00	.34	7.90	1 $\frac{1}{2}$
8	12	12.75	323.80	9.25	235.00	4.25	108.00	12.25	311.20	8.19	208.00	.31	7.90	1 $\frac{1}{2}$
9	16	12.75	323.80	11.50	292.10	4.25	108.00	12.25	311.20	10.38	263.60	.31	7.90	1 $\frac{1}{2}$
10	20	15.00	381.00	11.50	292.10	4.25	108.00	14.50	368.30	10.38	263.60	.38	9.60	1 $\frac{1}{2}$ ⁴
11	25	15.00	381.00	13.75	349.20	4.25	108.00	14.50	368.30	12.63	320.80	.38	9.60	1 $\frac{1}{2}$ ⁴
12	5	15.00	381.00	3.50	88.90	4.25	108.00	5.00	127.00	2.38	60.40	.31	7.90	1 $\frac{1}{4}$

¹ Four vertical openings.


² Vertical and horizontal spacing of holes is suitable for use with standard (size 1) and large (size 3) CR104P nameplates.

³ Stainless steel enclosure only.

⁴ Two 1 $\frac{1}{2}$ " hubs (top and bottom).

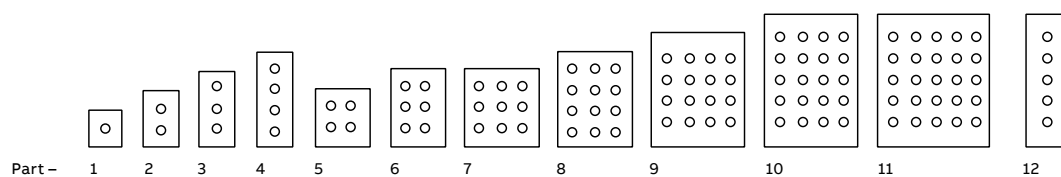

Part –

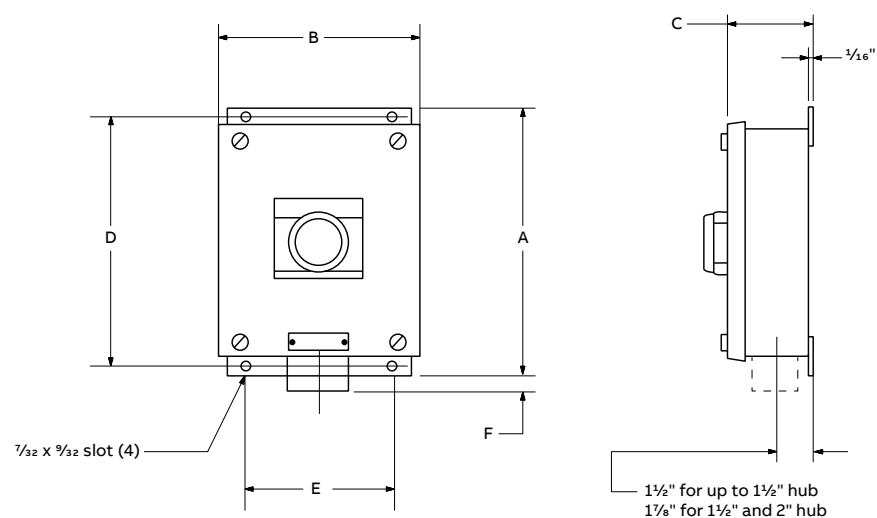

Index

Order code classification

Order code	Type	Page	Order code	Type	Page	Order code	Type	Page
1SQA009077R0001	A3L4AA-6L2C	18	1SQA009135R0001	A3PB41-600Y-10	10	1SQA009238R0001	A3PLE1-6L4W-10	7
1SQA009078R0001	A3L4AA-6L2G	18	1SQA009137R0001	A3PB61-600B-00	12	1SQA009241R0001	A3PLE1-6L5G-00	8
1SQA009079R0001	A3L4AA-6L2L	18	1SQA009138R0001	A3PB61-600B-01	12	1SQA009242R0001	A3PLE1-6L5G-10	8
1SQA009080R0001	A3L4AA-6L2M	18	1SQA009139R0001	A3PB61-600B-10	12	1SQA009245R0001	A3PLE1-6L5M-10	8
1SQA009081R0001	A3L4AA-6L2R	18	1SQA009141R0001	A3PB61-600G-00	12	1SQA009247R0001	A3PLE1-6L5R-10	8
1SQA009082R0001	A3L4AA-6L2W	18	1SQA009142R0001	A3PB61-600G-01	12	1SQA009265R0001	A3PLE1-6LLM-10	9
1SQA009083R0001	A3L4AA-6L4C	18	1SQA009143R0001	A3PB61-600G-10	12	1SQA009267R0001	A3PLE1-6LLR-10	9
1SQA009084R0001	A3L4AA-6L4G	18	1SQA009145R0001	A3PB61-600R-00	12	1SQA009270R0001	A3PP42-600B-01	10
1SQA009085R0001	A3L4AA-6L4L	18	1SQA009146R0001	A3PB61-600R-01	12	1SQA009272R0001	A3PP42-600G-01	10
1SQA009086R0001	A3L4AA-6L4M	18	1SQA009147R0001	A3PB61-600R-10	12	1SQA009273R0001	A3PP42-600R-00	10
1SQA009087R0001	A3L4AA-6L4R	18	1SQA009149R0001	A3PB61-600Y-00	12	1SQA009274R0001	A3PP42-600R-01	10
1SQA009088R0001	A3L4AA-6L4W	18	1SQA009150R0001	A3PB61-600Y-01	12	1SQA009276R0001	A3PP42-600Y-01	10
1SQA009089R0001	A3L4AA-6L5C	19	1SQA009152R0001	A3PBE1-6007-00	6	1SQA009279R0001	A3PP42-6L2R-01	13
1SQA009090R0001	A3L4AA-6L5G	19	1SQA009153R0001	A3PBE1-6007-01	6	1SQA009280R0001	A3PP42-6L2R-10	13
1SQA009091R0001	A3L4AA-6L5L	19	1SQA009154R0001	A3PBE1-6007-10	6	1SQA009284R0001	A3PP42-6L4R-10	13
1SQA009092R0001	A3L4AA-6L5M	19	1SQA009156R0001	A3PBE1-600B-00	6	1SQA009288R0001	A3PP42-6L5R-00	14
1SQA009093R0001	A3L4AA-6L5R	19	1SQA009157R0001	A3PBE1-600B-01	6	1SQA009289R0001	A3PP42-6L5R-01	14
1SQA009094R0001	A3L4AA-6L5W	19	1SQA009158R0001	A3PBE1-600B-10	6	1SQA009304R0001	A3PP62-600R-00	12
1SQA009095R0001	A3L4AA-6L6C	19	1SQA009160R0001	A3PBE1-600G-00	6	1SQA009305R0001	A3PP62-600R-01	12
1SQA009096R0001	A3L4AA-6L6G	19	1SQA009161R0001	A3PBE1-600G-01	6	1SQA009308R0001	A3PPM2-600N-00	11
1SQA009097R0001	A3L4AA-6L6L	19	1SQA009162R0001	A3PBE1-600G-10	6	1SQA009309R0001	A3PPM2-600R-00	11
1SQA009098R0001	A3L4AA-6L6M	19	1SQA009164R0001	A3PBE1-600R-00	6	1SQA009310R0001	A3PPM2-600R-01	11
1SQA009099R0001	A3L4AA-6L6R	19	1SQA009165R0001	A3PBE1-600R-01	6	1SQA009311R0001	A3PPM2-600R-10	11
1SQA009100R0001	A3L4AA-6L6W	19	1SQA009166R0001	A3PBE1-600R-10	6	1SQA009314R0001	A3PPM2-6L4G-01	15
1SQA009101R0001	A3L4AA-6L7G	19	1SQA009168R0001	A3PBE1-600Y-00	6	1SQA009316R0001	A3PPM2-6L4R-00	15
1SQA009102R0001	A3L4AA-6L7R	19	1SQA009169R0001	A3PBE1-600Y-10	6	1SQA009317R0001	A3PPM2-6L4R-01	15
1SQA009103R0001	A3L4AA-6L8C	19	1SQA009171R0001	A3PBF1-6007-00	5	1SQA009320R0001	A3PPM2-6LBR-01	11
1SQA009104R0001	A3L4AA-6L8G	19	1SQA009172R0001	A3PBF1-6007-01	5	1SQA009325R0001	A3PPM3-6L4R-00	15
1SQA009105R0001	A3L4AA-6L8L	19	1SQA009173R0001	A3PBF1-6007-10	5	1SQA009328R0001	A3PPM4-6L2R-00	15
1SQA009106R0001	A3L4AA-6L8M	19	1SQA009175R0001	A3PBF1-600B-00	5	1SQA009332R0001	A3PT4R-600N-00	17
1SQA009107R0001	A3L4AA-6L8R	19	1SQA009176R0001	A3PBF1-600B-01	5	1SQA009333R0001	A3PT4R-600R-00	10
1SQA009108R0001	A3L4AA-6L8W	19	1SQA009177R0001	A3PBF1-600B-10	5	1SQA009334R0001	A3PT4R-600R-01	10
1SQA009109R0001	A3L4AA-6L9G	19	1SQA009179R0001	A3PBF1-600G-00	5	1SQA009335R0001	A3PT4R-600R-10	10
1SQA009110R0001	A3L4AA-6L9R	19	1SQA009180R0001	A3PBF1-600G-01	5	1SQA009345R0001	A3SKAX-6AA1-00	26
1SQA009111R0001	A3L4AA-6L9W	19	1SQA009181R0001	A3PBF1-600G-10	5	1SQA009347R0001	A3SKBE-6AA1-00	27
1SQA009112R0001	A3L4AA-6LBG	18	1SQA009183R0001	A3PBF1-600L-00	5	1SQA009350R0001	A3SKBH-6AA1-00	27
1SQA009113R0001	A3L4AA-6LBM	18	1SQA009184R0001	A3PBF1-600L-10	5	1SQA009352R0001	A3SKBV-6AA1-00	27
1SQA009114R0001	A3L4AA-6LBR	18	1SQA009186R0001	A3PBF1-600Y-00	5	1SQA009354R0001	A3SKBY-6AA1-00	27
1SQA009115R0001	A3L4AA-6LBW	18	1SQA009187R0001	A3PBF1-600R-00	5	1SQA009355R0001	A3SKCE-6AA1-00	27
1SQA009116R0001	A3L4AA-6LLG	19	1SQA009188R0001	A3PBF1-600R-01	5	1SQA009358R0001	A3SKCG-6AA1-00	27
1SQA009117R0001	A3L4AA-6LLM	19	1SQA009189R0001	A3PBF1-600R-10	5	1SQA009360R0001	A3SKCH-6AA1-00	27
1SQA009118R0001	A3L4AA-6LLR	19	1SQA009191R0001	A3PBF1-600Y-01	5	1SQA009362R0001	A3SKCT-6AA1-00	27
1SQA009119R0001	A3L4AA-6LLW	19	1SQA009192R0001	A3PBF1-600Y-10	5	1SQA009364R0001	A3SKCV-6AA1-00	27
1SQA009120R0001	A3L4AA-6N4N	18	1SQA009202R0001	A3PL41-6L5R-00	13	1SQA009366R0001	A3SKCY-6AA1-00	27
1SQA009121R0001	A3PB41-600B-00	10	1SQA009208R0001	A3PL41-6LBR-10	13	1SQA009368R0001	A3SKDE-6AA1-00	27
1SQA009122R0001	A3PB41-600B-01	10	1SQA009218R0001	A3PLE1-6L2G-10	7	1SQA009372R0001	A3SKDV-6AA1-00	27
1SQA009123R0001	A3PB41-600B-10	10	1SQA009221R0001	A3PLE1-6L2M-00	7	1SQA009376R0001	A3SKEV-6AA1-00	26
1SQA009125R0001	A3PB41-600G-00	10	1SQA009222R0001	A3PLE1-6L2M-10	7	1SQA009378R0001	A3SKGE-6AA1-00	26
1SQA009126R0001	A3PB41-600G-01	10	1SQA009224R0001	A3PLE1-6L2R-00	7	1SQA009380R0001	A3SKGG-6AA1-00	26
1SQA009127R0001	A3PB41-600G-10	10	1SQA009226R0001	A3PLE1-6L2W-10	7	1SQA009381R0001	A3SKGH-6AA1-00	26
1SQA009129R0001	A3PB41-600R-00	10	1SQA009229R0001	A3PLE1-6L4G-00	7	1SQA009389R0001	A3SLBC-6AAB-00	23
1SQA009130R0001	A3PB41-600R-01	10	1SQA009230R0001	A3PLE1-6L4G-10	7	1SQA009391R0001	A3SLBD-6AAB-00	24
1SQA009131R0001	A3PB41-600R-10	10	1SQA009233R0001	A3PLE1-6L4M-00	7	1SQA009393R0001	A3SLCA-6AAB-00	23
1SQA009133R0001	A3PB41-600Y-00	10	1SQA009235R0001	A3PLE1-6L4R-00	7	1SQA009395R0001	A3SLCB-6AAB-00	23
1SQA009134R0001	A3PB41-600Y-01	10	1SQA009236R0001	A3PLE1-6L4R-10	7	1SQA009398R0001	A3SLCD-6AAB-00	24

Index

Order code classification

Order code	Type	Page	Order code	Type	Page	Order code	Type	Page
1SQA009406R0001	A3SLGA-6AAB-00	23	1SQA009537R0001	A3XLENY	31	1SQA010179R0001	A3XMN4N	33
1SQA009410R0001	A3SLGD-6AAB-00	24	1SQA009538R0001	A3XLFN6	32	1SQA010180R0001	A3XGGL	31
1SQA009417R0001	A3SSAA-6L2G-00	25	1SQA009539R0001	A3XLFN8	32	1SQA010181R0001	A3XGGP	31
1SQA009422R0001	A3SSAA-6L2R-00	25	1SQA009540R0001	A3XLFNA	32	1SQA010182R0001	A3XMLLR	33
1SQA009424R0001	A3SSAA-6L4G-00	25	1SQA009541R0001	A3XLFN6	32	1SQA010183R0001	A3XMLLG	33
1SQA009428R0001	A3SSAA-6L4R-00	25	1SQA009542R0001	A3XLFNG	32	1SQA010184R0001	A3XMLLY	33
1SQA009430R0001	A3SSAA-6L5G-00	25	1SQA009543R0001	A3XLFNL	32	1SQA010185R0001	A3XMLUG	33
1SQA009433R0001	A3SSAA-6L5R-00	25	1SQA009544R0001	A3XLFNR	32	1SQA010186R0001	A3XMN6N	33
1SQA009441R0001	A3SSBA-6L2G-00	25	1SQA009545R0001	A3XLFNY	32	1SQA010187R0001	A3XMN8N	33
1SQA009453R0001	A3SSCA-6L2G-00	25	1SQA009546R0001	A3XLLLA	32	1SQA010188R0001	A3XMN7N	33
1SQA009456R0001	A3SSCA-6L4G-00	25	1SQA009547R0001	A3XLLLC	32	1SQA010189R0001	A3XBL6R	33
1SQA009459R0001	A3SSCA-6L4R-00	25	1SQA009548R0001	A3XLLLG	32	1SQA010190R0001	A3XBL6G	33
1SQA009462R0001	A3SSCA-6L5R-00	25	1SQA009549R0001	A3XLLLL	32	1SQA010191R0001	A3XBL6W	33
1SQA009474R0001	A3SSDC-6AAB-00	21	1SQA009550R0001	A3XLLLM	32	1SQA010192R0001	A3XBL2R	33
1SQA009476R0001	A3SSDD-6AAB-00	22	1SQA009551R0001	A3XLLLR	32	1SQA010193R0001	A3XBL2G	33
1SQA009480R0001	A3SSEB-6AAB-00	21	1SQA009552R0001	A3XLLLW	32	1SQA010194R0001	A3XBL2W	33
1SQA009481R0001	A3SSEC-6AAB-00	21	1SQA009553R0001	A3XLMLG	32	1SQA010195R0001	A3XBL4R	33
1SQA009483R0001	A3SSED-6AAB-00	22	1SQA009554R0001	A3XLMLM	32	1SQA010196R0001	A3XBL4Y	33
1SQA009488R0001	A3SSGC-6AAB-00	21	1SQA009555R0001	A3XLMLR	32	1SQA010197R0001	A3XBL4L	33
1SQA009490R0001	A3SSGD-6AAB-00	22	1SQA009556R0001	A3XLMLW	32	1SQA010198R0001	A3XBL4W	33
1SQA009494R0001	A3XC01	30	1SQA009557R0001	A3XLMN1	32	1SQA010199R0001	A3L4AA-6N0N	19
1SQA009496R0001	A3XC10	30	1SQA009558R0001	A3XLMNG	32	1SQA010200R0001	A3PPN2-600N-00	17
1SQA009500R0001	A3XGCE	31	1SQA009559R0001	A3XLMNR	32	1SQA010201R0001	A3XLENB	33
1SQA009501R0001	A3XGCF	31	1SQA009560R0001	A3XLSG6	32	1SQA010202R0001	A3SLAA-6AAB-00	20
1SQA009502R0001	A3XGLM	31	1SQA009561R0001	A3XLSG8	32	1SQA010203R0001	A3SSAC-6AAB-00	20
1SQA009503R0001	A3XGLN	31	1SQA009562R0001	A3XLSGG	32	1SQA010204R0001	A3SSAA-6AAG-00	20
1SQA009504R0001	A3XGLP	31	1SQA009563R0001	A3XLSSL	32	1SQA010205R0001	A3SSAA-6AAR-00	20
1SQA009506R0001	A3XGPM	31	1SQA009564R0001	A3XLSGR	32	1SQA010206R0001	A3SSBB-6AAB-00	21
1SQA009510R0001	A3XL4LR	31	1SQA009565R0001	A3XLSGW	32	1SQA010207R0001	A3SSBC-6AAB-00	21
1SQA009511R0001	A3XL4N8	31	1SQA009566R0001	A3XLSGY	32	1SQA010208R0001	A3SSCC-6AAB-00	21
1SQA009512R0001	A3XL4NA	31	1SQA009567R0001	A3XLSS6	32	1SQA010209R0001	A3SSDA-6AAB-00	20
1SQA009513R0001	A3XL4NB	31	1SQA009568R0001	A3XLSS8	32	1SQA010210R0001	A3SKAG-6AA1-00	26
1SQA009514R0001	A3XL4NG	31	1SQA009569R0001	A3XLSSG	32	1SQA010211R0001	A3XGCC	31
1SQA009515R0001	A3XL4NL	31	1SQA009570R0001	A3XLSSL	32	1SQA010212R0001	A3XL4LG	31
1SQA009516R0001	A3XL4NR	31	1SQA009571R0001	A3XLSSR	32	1SQA010213R0001	A3XLKLG	33
1SQA009517R0001	A3XL4NY	31	1SQA009572R0001	A3XLSSW	32	1SQA010214R0001	A3XLKLR	33
1SQA009518R0001	A3XL6N8	31	1SQA009573R0001	A3XLSSY	32	1SQA010215R0001	A3XL4LM	31
1SQA009519R0001	A3XL6NA	31	1SQA009577R0001	A3XLTN6	32	1SQA010216R0001	A3XLKLL	33
1SQA009520R0001	A3XL6NB	31	1SQA009578R0001	A3XLTNR	32	1SQA010217R0001	A3XLKLM	33
1SQA009521R0001	A3XL6NG	31	1SQA009579R0001	A3XLTN6	32	1SQA010218R0001	A3XLKLC	33
1SQA009522R0001	A3XL6NL	31	1SQA009581R0001	A3XK501	31	1SQA010219R0001	A3XLKLW	33
1SQA009523R0001	A3XL6NR	31	1SQA009583R0001	A3XXGC	33	1SQA010221R0001	A3XGLW	33
1SQA009524R0001	A3XL6NY	31	1SQA010161R0001	A3SSAA-6AAB-00	20	1SQA010222R0001	A3XLP0C	33
1SQA009525R0001	A3XLELC	31	1SQA010162R0001	A3SSCA-6AAB-00	20	1SQA010223R0001	A3XLP0B	33
1SQA009526R0001	A3XLELG	31	1SQA010163R0001	A3SSCB-6AAB-00	21	1SQA010401R0001	A3XBL2L	33
1SQA009527R0001	A3XLELL	31	1SQA010164R0001	A3SSCD-6AAB-00	22	1SQA010402R0001	A3XBL2Y	33
1SQA009528R0001	A3XLELM	31	1SQA010165R0001	A3SSGA-6AAB-00	21	1SQA010403R0001	A3XBL4G	33
1SQA009529R0001	A3XLELR	31	1SQA010170R0001	A3SKAE-6AA1-00	26	1SQA010404R0001	A3XMN5N	33
1SQA009530R0001	A3XLELW	31	1SQA010171R0001	A3SKAF-6AA1-00	26	1SQA010405R0001	A3XBL6L	33
1SQA009531R0001	A3XLEN6	31	1SQA010172R0001	A3SSBA-6AAB-00	20	1SQA010406R0001	A3XBL6Y	33
1SQA009532R0001	A3XLEN8	31	1SQA010173R0001	A3SSBD-6AAB-00	22	1SQA010407R0001	A3XMN9N	33
1SQA009533R0001	A3XLENA	31	1SQA010174R0001	A3SSHA-6AAB-00	22	1SQA010408R0001	A3XMLLW	33
1SQA009534R0001	A3XLENG	31	1SQA010175R0001	A3SSEA-6AAB-00	21	1SQA010409R0001	A3XL6LG	31
1SQA009535R0001	A3XLENL	31	1SQA010177R0001	A3PBM1-600R-01	11	1SQA010410R0001	A3XL6LR	31
1SQA009536R0001	A3XLENR	31	1SQA010178R0001	A3PBN1-600N-00	17	1SQA010411R0001	A3XL6LM	31

Index

Order code classification

Order code	Type	Page	Order code	Type	Page	Order code	Type	Page
1SQA010412R0001	A3SKBF-6AA1-00	26	1SQA010754R0001	A3PBE1-600B-91	6	1SQA010809R0001	A3PLE1-6L8R-91	8
1SQA010413R0001	A3SKCF-6AA1-00	26	1SQA010755R0001	A3PBE1-600G-91	6	1SQA010810R0001	A3PLE1-6L9G-91	8
1SQA010414R0001	A3SKCU-6AA1-00	26	1SQA010756R0001	A3PBE1-600R-91	6	1SQA010811R0001	A3PLE1-6L9R-91	8
1SQA010415R0001	A3SKDF-6AA1-00	26	1SQA010757R0001	A3PBE1-600Y-91	6	1SQA010812R0001	A3PLE1-6LBG-91	9
1SQA010416R0001	A3SKDH-6AA1-00	26	1SQA010758R0001	A3PBF1-6007-91	5	1SQA010813R0001	A3PLE1-6LBL-91	9
1SQA010417R0001	A3SKDY-6AA1-00	27	1SQA010759R0001	A3PBF1-600B-91	5	1SQA010814R0001	A3PLE1-6LBM-91	9
1SQA010418R0001	A3SKEE-6AA1-00	26	1SQA010760R0001	A3PBF1-600G-91	5	1SQA010815R0001	A3PLE1-6LBR-91	9
1SQA010419R0001	A3SKET-6AA1-00	27	1SQA010761R0001	A3PBF1-600L-91	5	1SQA010816R0001	A3PLE1-6LLG-91	9
1SQA010421R0001	A3SSAA-6L2L-00	25	1SQA010762R0001	A3PBF1-600R-91	5	1SQA010817R0001	A3PLE1-6LLM-91	9
1SQA010424R0001	A3SSAA-6L4L-00	25	1SQA010763R0001	A3PBF1-600Y-91	5	1SQA010818R0001	A3PLE1-6LLR-91	9
1SQA010425R0001	A3SSAA-6L4M-00	25	1SQA010764R0001	A3PL41-6L2G-91	13	1SQA010819R0001	A3PLE1-6LLW-91	9
1SQA010428R0001	A3SSAA-6L5M-00	25	1SQA010765R0001	A3PL41-6L2M-91	13	1SQA010820R0001	A3PLE1-6L7G-91	8
1SQA010430R0001	A3SSAA-6L6G-00	25	1SQA010766R0001	A3PL41-6L2R-91	13	1SQA010821R0001	A3PLE1-6L7R-91	8
1SQA010432R0001	A3SSBA-6L2R-00	25	1SQA010767R0001	A3PL41-6L4G-91	13	1SQA010822R0001	A3PLE1-6L7M-91	8
1SQA010434R0001	A3SSCA-6L2M-00	25	1SQA010768R0001	A3PL41-6L4M-91	13	1SQA010823R0001	A3PLE1-6L7W-91	8
1SQA010436R0001	A3SSCA-6L4L-00	25	1SQA010769R0001	A3PL41-6L4R-91	13	1SQA010824R0001	A3PLE1-6L7L-91	8
1SQA010438R0001	A3SSCA-6L5G-00	25	1SQA010770R0001	A3PL41-6L5G-91	13	1SQA010825R0001	A3PLE1-6L7C-91	8
1SQA010440R0001	A3SSDB-6AAB-00	21	1SQA010771R0001	A3PL41-6L5R-91	13	1SQA010826R0001	A3PLE1-6LUG-91	9
1SQA010441R0001	A3SSGB-6AAB-00	21	1SQA010772R0001	A3PL41-6L6R-91	13	1SQA010827R0001	A3PLE1-6LUM-91	9
1SQA010442R0001	A3SLAC-6AAB-00	22	1SQA010773R0001	A3PL41-6L9R-91	13	1SQA010828R0001	A3PLE1-6LUR-91	9
1SQA010443R0001	A3SLBA-6AAB-00	23	1SQA010774R0001	A3PL41-6LBG-91	13	1SQA010829R0001	A3PLE1-6LUW-91	9
1SQA010444R0001	A3SLBB-6AAB-00	23	1SQA010775R0001	A3PL41-6LBM-91	13	1SQA010830R0001	A3PLE1-6LUL-91	9
1SQA010445R0001	A3SLCC-6AAB-00	23	1SQA010776R0001	A3PL41-6LLR-91	13	1SQA010831R0001	A3PLE1-6LUC-91	9
1SQA010446R0001	A3SLDA-6AAB-00	23	1SQA010777R0001	A3PL61-6L2G-91	16	1SQA010832R0001	A3PLE1-6LLL-91	9
1SQA010447R0001	A3SLDC-6AAB-00	23	1SQA010778R0001	A3PL61-6L2R-91	16	1SQA010833R0001	A3PLE1-6LLC-91	9
1SQA010448R0001	A3SLDD-6AAB-00	24	1SQA010779R0001	A3PL61-6L4G-91	16	1SQA010834R0001	A3PLE1-6L9M-91	8
1SQA010449R0001	A3SLEA-6AAB-00	23	1SQA010780R0001	A3PL61-6L4R-91	16	1SQA010835R0001	A3PLE1-6L8W-91	8
1SQA010450R0001	A3SLEC-6AAB-00	23	1SQA010781R0001	A3PL61-6L5R-91	16	1SQA010836R0001	A3PLE1-6L9W-91	8
1SQA010451R0001	A3SLED-6AAB-00	24	1SQA010782R0001	A3PL61-6LLM-91	16	1SQA010837R0001	A3PLE1-6L8L-91	8
1SQA010452R0001	A3SLGB-6AAB-00	23	1SQA010783R0001	A3PL61-6LLR-91	16	1SQA010838R0001	A3PLE1-6L9L-91	8
1SQA010453R0001	A3SLGC-6AAB-00	23	1SQA010784R0001	A3PLE1-6L2C-91	7	1SQA010839R0001	A3PLE1-6L6C-91	8
1SQA010454R0001	A3SLHA-6AAB-00	24	1SQA010785R0001	A3PLE1-6L2G-91	7	1SQA010840R0001	A3PLE1-6L8C-91	8
1SQA010455R0001	A3XMLUW	33	1SQA010786R0001	A3PLE1-6L2L-91	7	1SQA010841R0001	A3PLE1-6L9C-91	8
1SQA010456R0001	A3XMLUR	33	1SQA010787R0001	A3PLE1-6L2M-91	7	1SQA010842R0001	A3PP42-600B-91	10
1SQA010458R0001	A3XMLUL	33	1SQA010788R0001	A3PLE1-6L2R-91	7	1SQA010843R0001	A3PP42-600R-91	10
1SQA010459R0001	A3XMLUY	33	1SQA010789R0001	A3PLE1-6L2W-91	7	1SQA010844R0001	A3PP43-600R-1N	10
1SQA010460R0001	A3L4AA-6LUG	18	1SQA010790R0001	A3PLE1-6L4C-91	7	1SQA010845R0001	A3PP44-600R-1N	10
1SQA010461R0001	A3L4AA-6LUM	18	1SQA010791R0001	A3PLE1-6L4G-91	7	1SQA010846R0001	A3PP62-600R-91	12
1SQA010462R0001	A3L4AA-6LUR	18	1SQA010792R0001	A3PLE1-6L4L-91	7	1SQA010847R0001	A3PPM2-600R-91	11
1SQA010463R0001	A3L4AA-6LUW	18	1SQA010793R0001	A3PLE1-6L4M-91	7	1SQA010848R0001	A3PPM3-600R-1N	15
1SQA010464R0001	A3L4AA-6LUL	18	1SQA010794R0001	A3PLE1-6L4R-91	7	1SQA010849R0001	A3PPM4-600R-1N	11
1SQA010465R0001	A3L4AA-6LUC	18	1SQA010795R0001	A3PLE1-6L4W-91	7	1SQA010850R0001	A3PP42-6L2G-91	13
1SQA010480R0001	A3XMLLL	33	1SQA010796R0001	A3PLE1-6L5C-91	8	1SQA010851R0001	A3PP42-6L2M-91	13
1SQA010492R0001	A3L4AA-6L9C	19	1SQA010797R0001	A3PLE1-6L5G-91	8	1SQA010852R0001	A3PP42-6L2R-91	13
1SQA010493R0001	A3L4AA-6L9M	19	1SQA010798R0001	A3PLE1-6L5L-91	8	1SQA010853R0001	A3PP42-6L4G-91	13
1SQA010494R0001	A3L4AA-6L9L	19	1SQA010799R0001	A3PLE1-6L5M-91	8	1SQA010854R0001	A3PP42-6L4M-91	13
1SQA010745R0001	A3PB41-600B-91	10	1SQA010800R0001	A3PLE1-6L5R-91	8	1SQA010855R0001	A3PP42-6L4R-91	13
1SQA010746R0001	A3PB41-600G-91	10	1SQA010801R0001	A3PLE1-6L5W-91	8	1SQA010856R0001	A3PP42-6L5G-91	14
1SQA010747R0001	A3PB41-600R-91	10	1SQA010802R0001	A3PLE1-6L6G-91	8	1SQA010857R0001	A3PP42-6L5M-91	14
1SQA010748R0001	A3PB41-600Y-91	10	1SQA010803R0001	A3PLE1-6L6L-91	8	1SQA010858R0001	A3PP42-6L5R-91	14
1SQA010749R0001	A3PB61-600B-91	12	1SQA010804R0001	A3PLE1-6L6M-91	8	1SQA010859R0001	A3PP42-6L8G-91	14
1SQA010750R0001	A3PB61-600G-91	12	1SQA010805R0001	A3PLE1-6L6R-91	8	1SQA010860R0001	A3PP42-6L9R-91	14
1SQA010751R0001	A3PB61-600R-91	12	1SQA010806R0001	A3PLE1-6L6W-91	8	1SQA010861R0001	A3PP42-6LLG-91	14
1SQA010752R0001	A3PB61-600Y-91	12	1SQA010807R0001	A3PLE1-6L8G-91	8	1SQA010862R0001	A3PP42-6LLR-91	14
1SQA010753R0001	A3PBE1-6007-91	6	1SQA010808R0001	A3PLE1-6L8M-91	8	1SQA010863R0001	A3PP43-6L4G-1N	14

Index

Order code classification

Order code	Type	Page
1SQA010864R0001	A3PP43-6L4R-1N	14
1SQA010865R0001	A3PP43-6L5R-1N	14
1SQA010866R0001	A3PP43-6L8G-1N	14
1SQA010867R0001	A3PP44-6L2R-1N	14
1SQA010868R0001	A3PP44-6L4R-1N	14
1SQA010869R0001	A3PP44-6L5R-1N	14
1SQA010870R0001	A3PP62-6L2R-91	16
1SQA010871R0001	A3PPM2-6L2R-91	15
1SQA010872R0001	A3PPM2-6L4G-91	15
1SQA010873R0001	A3PPM2-6L4R-91	15
1SQA010874R0001	A3PPM2-6L4W-91	15
1SQA010875R0001	A3PPM3-6L2R-1N	15
1SQA010876R0001	A3PPM3-6L4G-1N	15
1SQA010877R0001	A3PPM3-6L4M-1N	15
1SQA010878R0001	A3PPM3-6L4R-1N	15
1SQA010879R0001	A3PPM4-6L2R-1N	15
1SQA010880R0001	A3PPM4-6L4R-1N	15
1SQA010881R0001	A3PT4R-600R-91	10
1SQA010882R0001	A3SSAA-6L2G-10	25
1SQA010883R0001	A3SSAA-6L2G-91	25
1SQA010884R0001	A3SSAA-6L2L-10	25
1SQA010885R0001	A3SSAA-6L2L-91	25
1SQA010886R0001	A3SSAA-6L2R-91	25
1SQA010887R0001	A3SSAA-6L4G-91	25
1SQA010888R0001	A3SSAA-6L4L-91	25
1SQA010889R0001	A3SSAA-6L4M-91	25
1SQA010890R0001	A3SSAA-6L4R-91	25
1SQA010891R0001	A3SSAA-6L5G-91	25
1SQA010892R0001	A3SSAA-6L5M-91	25
1SQA010893R0001	A3SSAA-6L5R-91	25
1SQA010894R0001	A3SSAA-6L6G-91	25
1SQA010895R0001	A3SSBA-6L2R-91	25
1SQA010896R0001	A3SSCA-6L2G-91	25
1SQA010897R0001	A3SSCA-6L2M-91	25
1SQA010898R0001	A3SSCA-6L4G-91	25
1SQA010899R0001	A3SSCA-6L4L-91	25
1SQA010900R0001	A3SSCA-6L4R-91	25
1SQA010901R0001	A3SSCA-6L5G-91	25
1SQA010902R0001	A3SSCA-6L5R-91	25
1SQA010903R0001	A3SLAA-6AAB-91	20
1SQA010904R0001	A3SLAC-6AAB-91	20
1SQA010905R0001	A3SLBA-6AAB-91	23
1SQA010906R0001	A3SLBB-6AAB-91	23
1SQA010907R0001	A3SLBC-6AAB-91	23
1SQA010908R0001	A3SLBD-6AAB-91	24
1SQA010909R0001	A3SLCA-6AAB-91	23
1SQA010910R0001	A3SLCB-6AAB-91	23
1SQA010911R0001	A3SLCC-6AAB-91	23
1SQA010912R0001	A3SLCD-6AAB-91	24
1SQA010913R0001	A3SLDA-6AAB-91	23
1SQA010914R0001	A3SLDC-6AAB-91	23
1SQA010915R0001	A3SLDD-6AAB-91	24
1SQA010916R0001	A3SLEA-6AAB-91	23
1SQA010917R0001	A3SLEC-6AAB-91	23
1SQA010918R0001	A3SLED-6AAB-91	24

Order code	Type	Page
1SQA010919R0001	A3SLGA-6AAB-91	23
1SQA010920R0001	A3SLGB-6AAB-91	23
1SQA010921R0001	A3SLGC-6AAB-91	23
1SQA010922R0001	A3SLGD-6AAB-91	24
1SQA010923R0001	A3SLHA-6AAB-92	24
1SQA010924R0001	A3SSAA-6AAB-01	20
1SQA010925R0001	A3SSAA-6AAB-10	20
1SQA010926R0001	A3SSAA-6AAB-91	20
1SQA010927R0001	A3SSAC-6AAB-91	20
1SQA010928R0001	A3SSBA-6AAB-10	20
1SQA010929R0001	A3SSBA-6AAB-91	20
1SQA010930R0001	A3SSBB-6AAB-91	21
1SQA010931R0001	A3SSBC-6AAB-91	21
1SQA010932R0001	A3SSBD-6AAB-91	22
1SQA010933R0001	A3SSBD-6AAB-92	22
1SQA010934R0001	A3SSCA-6AAB-10	20
1SQA010935R0001	A3SSCA-6AAB-91	20
1SQA010936R0001	A3SSCB-6AAB-91	21
1SQA010937R0001	A3SSCC-6AAB-91	21
1SQA010938R0001	A3SSCD-6AAB-10	22
1SQA010939R0001	A3SSCD-6AAB-91	22
1SQA010940R0001	A3SSDA-6AAB-91	20
1SQA010941R0001	A3SSDB-6AAB-91	21
1SQA010942R0001	A3SSDC-6AAB-91	21
1SQA010943R0001	A3SSDD-6AAB-91	22
1SQA010944R0001	A3SSEA-6AAB-91	21
1SQA010945R0001	A3SSEC-6AAB-91	21
1SQA010946R0001	A3SSED-6AAB-91	22
1SQA010947R0001	A3SSGA-6AAB-91	21
1SQA010948R0001	A3SSGB-6AAB-91	21
1SQA010949R0001	A3SSGC-6AAB-91	21
1SQA010950R0001	A3SSGD-6AAB-91	22
1SQA010951R0001	A3SSHA-6AAB-92	22
1SQA010952R0001	A3SKAE-6AA1-10	26
1SQA010953R0001	A3SKAE-6AA1-91	26
1SQA010954R0001	A3SKAF-6AA1-10	26
1SQA010955R0001	A3SKAF-6AA1-91	26
1SQA010956R0001	A3SKAG-6AA1-91	26
1SQA010957R0001	A3SKAX-6AA1-91	26
1SQA010958R0001	A3SKBE-6AA1-91	26
1SQA010959R0001	A3SKBF-6AA1-91	26
1SQA010960R0001	A3SKBH-6AA1-91	26
1SQA010961R0001	A3SKBV-6AA1-91	27
1SQA010962R0001	A3SKCE-6AA1-91	27
1SQA010963R0001	A3SKCF-6AA1-91	27
1SQA010964R0001	A3SKCG-6AA1-91	27
1SQA010965R0001	A3SKCH-6AA1-91	27
1SQA010966R0001	A3SKCU-6AA1-91	27
1SQA010967R0001	A3SKCV-6AA1-91	27
1SQA010968R0001	A3SKCY-6AA1-91	27
1SQA010969R0001	A3SKDE-6AA1-91	26
1SQA010970R0001	A3SKDF-6AA1-91	27
1SQA010971R0001	A3SKDH-6AA1-91	27
1SQA010972R0001	A3SKDY-6AA1-91	27
1SQA010973R0001	A3SKEE-6AA1-91	26

Order code	Type	Page
1SQA010974R0001	A3SKET-6AA1-91	27
1SQA010975R0001	A3SKEV-6AA1-91	27
1SQA010976R0001	A3SKGE-6AA1-92	26
1SQA010977R0001	A3SKGH-6AA1-92	26
1SQA010978R0001	A3XC91	30
1SQA010979R0001	A3XC0B	30
1SQA010980R0001	A3XC0N	30
1SQA010981R0001	A3XC0M	30
1SQA010984R0001	A3SSAA-6AAB-20	20
1SQA010985R0001	A3SSAA-6AAB-21	20
1SQA010989R0001	A3SSCA-6AAB-12	20
1SQA010991R0001	A3SSGA-6AAB-12	21
1SQA010993R0001	A3SSBA-6AAB-21	20
1SQA010999R0001	A3SSBA-6L2G-91	25
1SQA011084R0001	A3SKAE-6AA1-20	26
1SQA011085R0001	A3SKBE-6AA1-92	27
1SQA011086R0001	A3SKBF-6AA1-92	27
1SQA011087R0001	A3SKBH-6AA1-92	26
1SQA011088R0001	A3SKBV-6AA1-92	27
1SQA011089R0001	A3SKCY-6AA1-92	27
1SQA011090R0001	A3SKDE-6AA1-92	27
1SQA011091R0001	A3SKDY-6AA1-92	26
1SQA011092R0001	A3SKEE-6AA1-92	26
1SQA011093R0001	A3SKET-6AA1-92	26
1SQA011094R0001	A3SKEV-6AA1-92	26
1SQA011095R0001	A3SLBA-6AAB-92	23
1SQA011096R0001	A3SLBB-6AAB-92	23
1SQA011097R0001	A3SLBC-6AAB-92	23
1SQA011098R0001	A3SLBD-6AAB-92	24
1SQA011099R0001	A3SLDD-6AAB-92	24
1SQA011100R0001	A3SLEA-6AAB-92	23
1SQA011101R0001	A3SLED-6AAB-92	24
1SQA011102R0001	A3SLGA-6AAB-92	23
1SQA011103R0001	A3SLGB-6AAB-92	23
1SQA011104R0001	A3SLGC-6AAB-92	23
1SQA011105R0001	A3SLGD-6AAB-92	24
1SQA011106R0001	A3SSBA-6AAB-20	20
1SQA011107R0001	A3SSBA-6AAB-92	20
1SQA011108R0001	A3SSBB-6AAB-92	21
1SQA011109R0001	A3SSBC-6AAB-92	21
1SQA011111R0001	A3SSCC-6AAB-92	21
1SQA011113R0001	A3SSDC-6AAB-92	21
1SQA011117R0001	A3SSGB-6AAB-92	21
1SQA011118R0001	A3SSGC-6AAB-92	21
1SQA011119R0001	A3SSGD-6AAB-92	22
	104PEG11C	34
	104PEG11D	34
	104PEG11E	34
	104PEG12G	34
	104PEG12K	34
	104PEG13P	34
	104PEG11S	34
	104PEG11T	34
	104PEG11	34
	104PEG12	34

Index

Order code classification

Order code	Type	Page
	104PEG13	34
	104PEG14	34
	104PEG23	34
	104PES11C	34
	104PES11E	34
	104PES12G	34
	104PES12K	34
	104PES13P	34
	104PES11S	34
	104PES11T	34
	104PES11	34
	104PES12	34
	104PES13	34
	104PES14	34
	104PES23	34
	CR104PXN*B	35
	CR104PXN*R	35
	CR104PXN6E	35
	CR104PXN*BP006	35
	CR104PXN*BP007	35
	CR104PXN*BP008	35
	CR104PXN*RP009	35
	CR104PXN*BP010	35
	CR104PXN*BP011	35
	CR104PXN*BP012	35
	CR104PXN*BP013	35
	CR104PXN*BP014	35
	CR104PXN*BP017	35
	CR104PXN*BP018	35
	CR104PXN*BP019	35
	CR104PXN*BP020	35
	CR104PXN*BP021	35
	CR104PXN*BP022	35
	CR104PXN*BP023	35
	CR104PXN*BP024	35
	CR104PXN*BP025	35
	CR104PXN*BP026	35
	CR104PXN*BP027	35
	CR104PXN*BP084	35
	CR104PXN*BP028	35
	CR104PXN*BP030	35
	CR104PXN*BP031	35
	CR104PXN*BP032	35
	CR104PXN*BP033	35
	CR104PXN*BP034	35
	CR104PXN*BP036	35
	CR104PXN*BP037	35
	CR104PXN*BP038	35
	CR104PXN*RP040	35
	CR104PXN*RP041	35
	CR104PXN*BP043	35
	CR104PXN*BP047	35
	CR104PXN*RP048	35
	CR104PXN*BP085	35
	CR104PXN*BP050	36

Order code	Type	Page
	CR104PXN*BP051	36
	CR104PXN*BP052	36
	CR104PXN*BP053	36
	CR104PXN*BP054	36
	CR104PXN*BP055	36
	CR104PXN*BP056	36
	CR104PXN*BP057	36
	CR104PXN*BP058	36
	CR104PXN*BP059	36
	CR104PXN*BP060	36
	CR104PXN*BP061	36
	CR104PXN*BP062	36
	CR104PXN*BP063	36
	CR104PXN*BP064	36
	CR104PXN*BP087	36
	CR104PXN*BP086	36
	CR104PXN*BP065	36
	CR104PXN*BP066	36
	CR104PXN*BP067	36
	CR104PXN*BP083	36
	CR104PXN*BP068	36
	CR104PXN*BP069	36
	CR104PXN*BP070	36
	CR104PXN*BP071	36
	CR104PXN*BP072	36
	CR104PXN*BP073	36
	CR104PXN*BP074	36
	CR104PXN*BP076	36
	CR104PXN*BP077	36
	CR104PXN*BP079	36
	CR104PXN*BP080	36
	CR104PXN*BP081	36
	CR104PXN*BP082	36
	CR104PXN1BP090	36
	CR104PXN1BP091	36
	CR104PXN6EP092	36
	CR104PXN6EP009	36

Index

Type classification

Type	Order code	Page	Type	Order code	Page	Type	Order code	Page
104PEG11		34	A3L4AA-6L8R	1SQA009107R0001	19	A3PBE1-6007-00	1SQA009152R0001	6
104PEG11C		34	A3L4AA-6L8W	1SQA009108R0001	19	A3PBE1-6007-01	1SQA009153R0001	6
104PEG11D		34	A3L4AA-6L9C	1SQA010492R0001	19	A3PBE1-6007-10	1SQA009154R0001	6
104PEG11E		34	A3L4AA-6L9G	1SQA009109R0001	19	A3PBE1-6007-91	1SQA010753R0001	6
104PEG11S		34	A3L4AA-6L9L	1SQA010494R0001	19	A3PBE1-600B-00	1SQA009156R0001	6
104PEG11T		34	A3L4AA-6L9M	1SQA010493R0001	19	A3PBE1-600B-01	1SQA009157R0001	6
104PEG12		34	A3L4AA-6L9R	1SQA009110R0001	19	A3PBE1-600B-10	1SQA009158R0001	6
104PEG12G		34	A3L4AA-6L9W	1SQA009111R0001	19	A3PBE1-600B-91	1SQA010754R0001	6
104PEG12K		34	A3L4AA-6LBG	1SQA009112R0001	18	A3PBE1-600G-00	1SQA009160R0001	6
104PEG13		34	A3L4AA-6LBM	1SQA009113R0001	18	A3PBE1-600G-01	1SQA009161R0001	6
104PEG13P		34	A3L4AA-6LBR	1SQA009114R0001	18	A3PBE1-600G-10	1SQA009162R0001	6
104PEG14		34	A3L4AA-6LBW	1SQA009115R0001	18	A3PBE1-600G-91	1SQA010755R0001	6
104PEG23		34	A3L4AA-6LLG	1SQA009116R0001	19	A3PBE1-600R-00	1SQA009164R0001	6
104PES11		34	A3L4AA-6LLM	1SQA009117R0001	19	A3PBE1-600R-01	1SQA009165R0001	6
104PES11C		34	A3L4AA-6LLR	1SQA009118R0001	19	A3PBE1-600R-10	1SQA009166R0001	6
104PES11E		34	A3L4AA-6LLW	1SQA009119R0001	19	A3PBE1-600R-91	1SQA010756R0001	6
104PES11S		34	A3L4AA-6LUC	1SQA010465R0001	18	A3PBE1-600Y-00	1SQA009168R0001	6
104PES11T		34	A3L4AA-6LUG	1SQA010460R0001	18	A3PBE1-600Y-10	1SQA009169R0001	6
104PES12		34	A3L4AA-6LUL	1SQA010464R0001	18	A3PBE1-600Y-91	1SQA010757R0001	6
104PES12G		34	A3L4AA-6LUM	1SQA010461R0001	18	A3PBF1-6007-00	1SQA009171R0001	5
104PES12K		34	A3L4AA-6LUR	1SQA010462R0001	18	A3PBF1-6007-01	1SQA009172R0001	5
104PES13		34	A3L4AA-6LUW	1SQA010463R0001	18	A3PBF1-6007-10	1SQA009173R0001	5
104PES13P		34	A3L4AA-6N0N	1SQA010199R0001	19	A3PBF1-6007-91	1SQA010758R0001	5
104PES14		34	A3L4AA-6N4N	1SQA009120R0001	18	A3PBF1-600B-00	1SQA009175R0001	5
104PES23		34	A3PB41-600B-00	1SQA009121R0001	10	A3PBF1-600B-01	1SQA009176R0001	5
A3L4AA-6L2C	1SQA009077R0001	18	A3PB41-600B-01	1SQA009122R0001	10	A3PBF1-600B-10	1SQA009177R0001	5
A3L4AA-6L2G	1SQA009078R0001	18	A3PB41-600B-10	1SQA009123R0001	10	A3PBF1-600B-91	1SQA010759R0001	5
A3L4AA-6L2L	1SQA009079R0001	18	A3PB41-600B-91	1SQA010745R0001	10	A3PBF1-600G-00	1SQA009179R0001	5
A3L4AA-6L2M	1SQA009080R0001	18	A3PB41-600G-00	1SQA009125R0001	10	A3PBF1-600G-01	1SQA009180R0001	5
A3L4AA-6L2R	1SQA009081R0001	18	A3PB41-600G-01	1SQA009126R0001	10	A3PBF1-600G-10	1SQA009181R0001	5
A3L4AA-6L2W	1SQA009082R0001	18	A3PB41-600G-10	1SQA009127R0001	10	A3PBF1-600G-91	1SQA010760R0001	5
A3L4AA-6L4C	1SQA009083R0001	18	A3PB41-600G-91	1SQA010746R0001	10	A3PBF1-600L-00	1SQA009183R0001	5
A3L4AA-6L4G	1SQA009084R0001	18	A3PB41-600R-00	1SQA009129R0001	10	A3PBF1-600L-10	1SQA009184R0001	5
A3L4AA-6L4L	1SQA009085R0001	18	A3PB41-600R-01	1SQA009130R0001	10	A3PBF1-600L-91	1SQA010761R0001	5
A3L4AA-6L4M	1SQA009086R0001	18	A3PB41-600R-10	1SQA009131R0001	10	A3PBF1-600R-00	1SQA009187R0001	5
A3L4AA-6L4R	1SQA009087R0001	18	A3PB41-600R-91	1SQA010747R0001	10	A3PBF1-600R-01	1SQA009188R0001	5
A3L4AA-6L4W	1SQA009088R0001	18	A3PB41-600Y-00	1SQA009133R0001	10	A3PBF1-600R-10	1SQA009189R0001	5
A3L4AA-6L5C	1SQA009089R0001	19	A3PB41-600Y-01	1SQA009134R0001	10	A3PBF1-600R-91	1SQA010762R0001	5
A3L4AA-6L5G	1SQA009090R0001	19	A3PB41-600Y-10	1SQA009135R0001	10	A3PBF1-600Y-00	1SQA009186R0001	5
A3L4AA-6L5L	1SQA009091R0001	19	A3PB41-600Y-91	1SQA010748R0001	10	A3PBF1-600Y-01	1SQA009191R0001	5
A3L4AA-6L5M	1SQA009092R0001	19	A3PB61-600B-00	1SQA009137R0001	12	A3PBF1-600Y-10	1SQA009192R0001	5
A3L4AA-6L5R	1SQA009093R0001	19	A3PB61-600B-01	1SQA009138R0001	12	A3PBF1-600Y-91	1SQA010763R0001	5
A3L4AA-6L5W	1SQA009094R0001	19	A3PB61-600B-10	1SQA009139R0001	12	A3PBM1-600R-01	1SQA010177R0001	11
A3L4AA-6L6C	1SQA009095R0001	19	A3PB61-600B-91	1SQA010749R0001	12	A3PBN1-600N-00	1SQA010178R0001	17
A3L4AA-6L6G	1SQA009096R0001	19	A3PB61-600G-00	1SQA009141R0001	12	A3PL41-6L2G-91	1SQA010764R0001	13
A3L4AA-6L6L	1SQA009097R0001	19	A3PB61-600G-01	1SQA009142R0001	12	A3PL41-6L2M-91	1SQA010765R0001	13
A3L4AA-6L6M	1SQA009098R0001	19	A3PB61-600G-10	1SQA009143R0001	12	A3PL41-6L2R-91	1SQA010766R0001	13
A3L4AA-6L6R	1SQA009099R0001	19	A3PB61-600G-91	1SQA010750R0001	12	A3PL41-6L4G-91	1SQA010767R0001	13
A3L4AA-6L6W	1SQA009100R0001	19	A3PB61-600R-00	1SQA009145R0001	12	A3PL41-6L4M-91	1SQA010768R0001	13
A3L4AA-6L7G	1SQA009101R0001	19	A3PB61-600R-01	1SQA009146R0001	12	A3PL41-6L4R-91	1SQA010769R0001	13
A3L4AA-6L7R	1SQA009102R0001	19	A3PB61-600R-10	1SQA009147R0001	12	A3PL41-6L5G-91	1SQA010770R0001	13
A3L4AA-6L8C	1SQA009103R0001	19	A3PB61-600R-91	1SQA010751R0001	12	A3PL41-6L5R-00	1SQA009202R0001	13
A3L4AA-6L8G	1SQA009104R0001	19	A3PB61-600Y-00	1SQA009149R0001	12	A3PL41-6L5R-91	1SQA010771R0001	13
A3L4AA-6L8L	1SQA009105R0001	19	A3PB61-600Y-01	1SQA009150R0001	12	A3PL41-6L6R-91	1SQA010772R0001	13
A3L4AA-6L8M	1SQA009106R0001	19	A3PB61-600Y-91	1SQA010752R0001	12	A3PL41-6L9R-91	1SQA010773R0001	13

Index

Type classification

Type	Order code	Page
A3PL41-6LBG-91	1SQA010774R0001	13
A3PL41-6LBM-91	1SQA010775R0001	13
A3PL41-6LBR-10	1SQA009208R0001	13
A3PL41-6LLR-91	1SQA010776R0001	13
A3PL61-6L2G-91	1SQA010777R0001	16
A3PL61-6L2R-91	1SQA010778R0001	16
A3PL61-6L4G-91	1SQA010779R0001	16
A3PL61-6L4R-91	1SQA010780R0001	16
A3PL61-6L5R-91	1SQA010781R0001	16
A3PL61-6LLM-91	1SQA010782R0001	16
A3PL61-6LLR-91	1SQA010783R0001	16
A3PLE1-6L2C-91	1SQA010784R0001	7
A3PLE1-6L2G-10	1SQA009218R0001	7
A3PLE1-6L2G-91	1SQA010785R0001	7
A3PLE1-6L2L-91	1SQA010786R0001	7
A3PLE1-6L2M-00	1SQA009221R0001	7
A3PLE1-6L2M-10	1SQA009222R0001	7
A3PLE1-6L2M-91	1SQA010787R0001	7
A3PLE1-6L2R-00	1SQA009224R0001	7
A3PLE1-6L2R-91	1SQA010788R0001	7
A3PLE1-6L2W-10	1SQA009226R0001	7
A3PLE1-6L2W-91	1SQA010789R0001	7
A3PLE1-6L4C-91	1SQA010790R0001	7
A3PLE1-6L4G-00	1SQA009229R0001	7
A3PLE1-6L4G-10	1SQA009230R0001	7
A3PLE1-6L4G-91	1SQA010791R0001	7
A3PLE1-6L4L-91	1SQA010792R0001	7
A3PLE1-6L4M-00	1SQA009233R0001	7
A3PLE1-6L4M-91	1SQA010793R0001	7
A3PLE1-6L4R-00	1SQA009235R0001	7
A3PLE1-6L4R-10	1SQA009236R0001	7
A3PLE1-6L4R-91	1SQA010794R0001	7
A3PLE1-6L4W-10	1SQA009238R0001	7
A3PLE1-6L4W-91	1SQA010795R0001	7
A3PLE1-6L5C-91	1SQA010796R0001	8
A3PLE1-6L5G-00	1SQA009241R0001	8
A3PLE1-6L5G-10	1SQA009242R0001	8
A3PLE1-6L5G-91	1SQA010797R0001	8
A3PLE1-6L5L-91	1SQA010798R0001	8
A3PLE1-6L5M-10	1SQA009245R0001	8
A3PLE1-6L5M-91	1SQA010799R0001	8
A3PLE1-6L5R-10	1SQA009247R0001	8
A3PLE1-6L5R-91	1SQA010800R0001	8
A3PLE1-6L5W-91	1SQA010801R0001	8
A3PLE1-6L6C-91	1SQA010839R0001	8
A3PLE1-6L6G-91	1SQA010802R0001	8
A3PLE1-6L6L-91	1SQA010803R0001	8
A3PLE1-6L6M-91	1SQA010804R0001	8
A3PLE1-6L6R-91	1SQA010805R0001	8
A3PLE1-6L6W-91	1SQA010806R0001	8
A3PLE1-6L7C-91	1SQA010825R0001	8
A3PLE1-6L7G-91	1SQA010820R0001	8
A3PLE1-6L7L-91	1SQA010824R0001	8
A3PLE1-6L7M-91	1SQA010822R0001	8
A3PLE1-6L7R-91	1SQA010821R0001	8

Type	Order code	Page
A3PLE1-6L7W-91	1SQA010823R0001	8
A3PLE1-6L8C-91	1SQA010840R0001	8
A3PLE1-6L8G-91	1SQA010807R0001	8
A3PLE1-6L8L-91	1SQA010837R0001	8
A3PLE1-6L8M-91	1SQA010808R0001	8
A3PLE1-6L8R-91	1SQA010809R0001	8
A3PLE1-6L8W-91	1SQA010835R0001	8
A3PLE1-6L9C-91	1SQA010841R0001	8
A3PLE1-6L9G-91	1SQA010810R0001	8
A3PLE1-6L9L-91	1SQA010838R0001	8
A3PLE1-6L9M-91	1SQA010834R0001	8
A3PLE1-6L9R-91	1SQA010811R0001	8
A3PLE1-6L9W-91	1SQA010836R0001	8
A3PLE1-6LBG-91	1SQA010812R0001	9
A3PLE1-6LBL-91	1SQA010813R0001	9
A3PLE1-6LBM-91	1SQA010814R0001	9
A3PLE1-6LBR-91	1SQA010815R0001	9
A3PLE1-6LLC-91	1SQA010833R0001	9
A3PLE1-6LLG-91	1SQA010816R0001	9
A3PLE1-6LLL-91	1SQA010832R0001	9
A3PLE1-6LLM-10	1SQA009265R0001	9
A3PLE1-6LLM-91	1SQA010817R0001	9
A3PLE1-6LLR-10	1SQA009267R0001	9
A3PLE1-6LLR-91	1SQA010818R0001	9
A3PLE1-6LLW-91	1SQA010819R0001	9
A3PLE1-6LUC-91	1SQA010831R0001	9
A3PLE1-6LUG-91	1SQA010826R0001	9
A3PLE1-6LUL-91	1SQA010830R0001	9
A3PLE1-6LUM-91	1SQA010827R0001	9
A3PLE1-6LUR-91	1SQA010828R0001	9
A3PLE1-6LUW-91	1SQA010829R0001	9
A3PP42-600B-01	1SQA009270R0001	10
A3PP42-600B-91	1SQA010842R0001	10
A3PP42-600G-01	1SQA009272R0001	10
A3PP42-600R-00	1SQA009273R0001	10
A3PP42-600R-01	1SQA009274R0001	10
A3PP42-600R-91	1SQA010843R0001	10
A3PP42-600Y-01	1SQA009276R0001	10
A3PP42-6L2G-91	1SQA010850R0001	13
A3PP42-6L2M-91	1SQA010851R0001	13
A3PP42-6L2R-01	1SQA009279R0001	13
A3PP42-6L2R-10	1SQA009280R0001	13
A3PP42-6L2R-91	1SQA010852R0001	13
A3PP42-6L4G-91	1SQA010853R0001	13
A3PP42-6L4M-91	1SQA010854R0001	13
A3PP42-6L4R-10	1SQA009284R0001	13
A3PP42-6L4R-91	1SQA010855R0001	13
A3PP42-6L5G-91	1SQA010856R0001	14
A3PP42-6L5M-91	1SQA010857R0001	14
A3PP42-6L5R-00	1SQA009288R0001	14
A3PP42-6L5R-01	1SQA009289R0001	14
A3PP42-6L5R-91	1SQA010858R0001	14
A3PP42-6L8G-91	1SQA010859R0001	14
A3PP42-6L9R-91	1SQA010860R0001	14
A3PP42-6LLG-91	1SQA010861R0001	14

Type	Order code	Page
A3PP42-6LLR-91	1SQA010862R0001	14
A3PP43-600R-1N	1SQA010844R0001	10
A3PP43-6L4G-1N	1SQA010863R0001	14
A3PP43-6L4R-1N	1SQA010864R0001	14
A3PP43-6L5R-1N	1SQA010865R0001	14
A3PP43-6L8G-1N	1SQA010866R0001	14
A3PP44-600R-1N	1SQA010845R0001	10
A3PP44-6L2R-1N	1SQA010867R0001	14
A3PP44-6L4R-1N	1SQA010868R0001	14
A3PP44-6L5R-1N	1SQA010869R0001	14
A3PP62-600R-00	1SQA009304R0001	12
A3PP62-600R-01	1SQA009305R0001	12
A3PP62-600R-91	1SQA010846R0001	12
A3PP62-6L2R-91	1SQA010870R0001	16
A3PPM2-600N-00	1SQA009308R0001	11
A3PPM2-600R-00	1SQA009309R0001	11
A3PPM2-600R-01	1SQA009310R0001	11
A3PPM2-600R-10	1SQA009311R0001	11
A3PPM2-600R-91	1SQA010847R0001	11
A3PPM2-6L2R-91	1SQA010871R0001	15
A3PPM2-6L4G-01	1SQA009314R0001	15
A3PPM2-6L4G-91	1SQA010872R0001	15
A3PPM2-6L4R-00	1SQA009316R0001	15
A3PPM2-6L4R-01	1SQA009317R0001	15
A3PPM2-6L4R-91	1SQA010873R0001	15
A3PPM2-6L4W-91	1SQA010874R0001	15
A3PPM2-6LBR-01	1SQA009320R0001	11
A3PPM3-600R-1N	1SQA010848R0001	15
A3PPM3-6L2R-1N	1SQA010875R0001	15
A3PPM3-6L4G-1N	1SQA010876R0001	15
A3PPM3-6L4M-1N	1SQA010877R0001	15
A3PPM3-6L4R-00	1SQA009325R0001	15
A3PPM3-6L4R-1N	1SQA010878R0001	15
A3PPM4-600R-1N	1SQA010849R0001	11
A3PPM4-6L2R-00	1SQA009328R0001	15
A3PPM4-6L2R-1N	1SQA010879R0001	15
A3PPM4-6L4R-1N	1SQA010880R0001	15
A3PPN2-600N-00	1SQA010200R0001	17
A3PT4R-600N-00	1SQA009332R0001	17
A3PT4R-600R-00	1SQA009333R0001	10
A3PT4R-600R-01	1SQA009334R0001	10
A3PT4R-600R-10	1SQA009335R0001	10
A3PT4R-600R-91	1SQA010881R0001	10
A3SKAE-6AA1-00	1SQA010170R0001	26
A3SKAE-6AA1-10	1SQA010952R0001	26
A3SKAE-6AA1-20	1SQA011084R0001	26
A3SKAE-6AA1-91	1SQA010953R0001	26
A3SKAF-6AA1-00	1SQA010171R0001	26
A3SKAF-6AA1-10	1SQA010954R0001	26
A3SKAF-6AA1-91	1SQA010955R0001	26
A3SKAG-6AA1-00	1SQA010210R0001	26
A3SKAG-6AA1-91	1SQA010956R0001	26
A3SKAX-6AA1-00	1SQA009345R0001	26
A3SKAX-6AA1-91	1SQA010957R0001	26
A3SKBE-6AA1-00	1SQA009347R0001	27

Index

Type classification

Type	Order code	Page
A3SKBE-6AA1-91	1SQA010958R0001	26
A3SKBE-6AA1-92	1SQA011085R0001	27
A3SKBF-6AA1-00	1SQA010412R0001	26
A3SKBF-6AA1-91	1SQA010959R0001	26
A3SKBF-6AA1-92	1SQA011086R0001	27
A3SKBH-6AA1-00	1SQA009350R0001	27
A3SKBH-6AA1-91	1SQA010960R0001	26
A3SKBH-6AA1-92	1SQA011087R0001	26
A3SKBV-6AA1-00	1SQA009352R0001	27
A3SKBV-6AA1-91	1SQA010961R0001	27
A3SKBV-6AA1-92	1SQA011088R0001	27
A3SKBY-6AA1-00	1SQA009354R0001	27
A3SKCE-6AA1-00	1SQA009355R0001	27
A3SKCE-6AA1-91	1SQA010962R0001	27
A3SKCF-6AA1-00	1SQA010413R0001	26
A3SKCF-6AA1-91	1SQA010963R0001	27
A3SKCG-6AA1-00	1SQA009358R0001	27
A3SKCG-6AA1-91	1SQA010964R0001	27
A3SKCH-6AA1-00	1SQA009360R0001	27
A3SKCH-6AA1-91	1SQA010965R0001	27
A3SKCT-6AA1-00	1SQA009362R0001	27
A3SKCU-6AA1-00	1SQA010414R0001	26
A3SKCU-6AA1-91	1SQA010966R0001	27
A3SKCV-6AA1-00	1SQA009364R0001	27
A3SKCV-6AA1-91	1SQA010967R0001	27
A3SKCY-6AA1-00	1SQA009366R0001	27
A3SKCY-6AA1-91	1SQA010968R0001	27
A3SKCY-6AA1-92	1SQA011089R0001	27
A3SKDE-6AA1-00	1SQA009368R0001	27
A3SKDE-6AA1-91	1SQA010969R0001	26
A3SKDE-6AA1-92	1SQA011090R0001	27
A3SKDF-6AA1-00	1SQA010415R0001	26
A3SKDF-6AA1-91	1SQA010970R0001	27
A3SKDH-6AA1-00	1SQA010416R0001	26
A3SKDH-6AA1-91	1SQA010971R0001	27
A3SKDV-6AA1-00	1SQA009372R0001	27
A3SKDY-6AA1-00	1SQA010417R0001	27
A3SKDY-6AA1-91	1SQA010972R0001	27
A3SKDY-6AA1-92	1SQA011091R0001	26
A3SKEE-6AA1-00	1SQA010418R0001	26
A3SKEE-6AA1-91	1SQA010973R0001	26
A3SKEE-6AA1-92	1SQA011092R0001	26
A3SKET-6AA1-00	1SQA010419R0001	27
A3SKET-6AA1-91	1SQA010974R0001	27
A3SKET-6AA1-92	1SQA011093R0001	26
A3SKEV-6AA1-00	1SQA009376R0001	26
A3SKEV-6AA1-91	1SQA010975R0001	27
A3SKEV-6AA1-92	1SQA011094R0001	26
A3SKGE-6AA1-00	1SQA009378R0001	26
A3SKGE-6AA1-92	1SQA010976R0001	26
A3SKGG-6AA1-00	1SQA009380R0001	26
A3SKGH-6AA1-00	1SQA009381R0001	26
A3SKGH-6AA1-92	1SQA010977R0001	26
A3SLAA-6AAB-00	1SQA010202R0001	20
A3SLAA-6AAB-91	1SQA010903R0001	20

Type	Order code	Page
A3SLAC-6AAB-00	1SQA010442R0001	22
A3SLAC-6AAB-91	1SQA010904R0001	20
A3SLBA-6AAB-00	1SQA010443R0001	23
A3SLBA-6AAB-91	1SQA010905R0001	23
A3SLBA-6AAB-92	1SQA011095R0001	23
A3SLBB-6AAB-00	1SQA010444R0001	23
A3SLBB-6AAB-91	1SQA010906R0001	23
A3SLBB-6AAB-92	1SQA011096R0001	23
A3SLBC-6AAB-00	1SQA009389R0001	23
A3SLBC-6AAB-91	1SQA010907R0001	23
A3SLBC-6AAB-92	1SQA011097R0001	23
A3SLBD-6AAB-00	1SQA009391R0001	24
A3SLBD-6AAB-91	1SQA010908R0001	24
A3SLBD-6AAB-92	1SQA011098R0001	24
A3SLCA-6AAB-00	1SQA009393R0001	23
A3SLCA-6AAB-91	1SQA010909R0001	23
A3SLCB-6AAB-00	1SQA009395R0001	23
A3SLCB-6AAB-91	1SQA010910R0001	23
A3SLCC-6AAB-00	1SQA010445R0001	23
A3SLCC-6AAB-91	1SQA010911R0001	23
A3SLCD-6AAB-00	1SQA009398R0001	24
A3SLCD-6AAB-91	1SQA010912R0001	24
A3SLDA-6AAB-00	1SQA010446R0001	23
A3SLDA-6AAB-91	1SQA010913R0001	23
A3SLDC-6AAB-00	1SQA010447R0001	23
A3SLDC-6AAB-91	1SQA010914R0001	23
A3SLDD-6AAB-00	1SQA010448R0001	24
A3SLDD-6AAB-91	1SQA010915R0001	24
A3SLDD-6AAB-92	1SQA011099R0001	24
A3SLEA-6AAB-00	1SQA010449R0001	23
A3SLEA-6AAB-91	1SQA010916R0001	23
A3SLEA-6AAB-92	1SQA011100R0001	23
A3SLEC-6AAB-00	1SQA010450R0001	23
A3SLEC-6AAB-91	1SQA010917R0001	23
A3SLED-6AAB-00	1SQA010451R0001	24
A3SLED-6AAB-91	1SQA010918R0001	24
A3SLED-6AAB-92	1SQA011101R0001	24
A3SLGA-6AAB-00	1SQA009406R0001	23
A3SLGA-6AAB-91	1SQA010919R0001	23
A3SLGA-6AAB-92	1SQA011102R0001	23
A3SLGB-6AAB-00	1SQA010452R0001	23
A3SLGB-6AAB-91	1SQA010920R0001	23
A3SLGB-6AAB-92	1SQA011103R0001	23
A3SLGC-6AAB-00	1SQA010453R0001	23
A3SLGC-6AAB-91	1SQA010921R0001	23
A3SLGC-6AAB-92	1SQA011104R0001	23
A3SLGD-6AAB-00	1SQA009410R0001	24
A3SLGD-6AAB-91	1SQA010922R0001	24
A3SLGD-6AAB-92	1SQA011105R0001	24
A3SLHA-6AAB-00	1SQA010454R0001	24
A3SLHA-6AAB-92	1SQA010923R0001	24
A3SSAA-6AAB-00	1SQA010161R0001	20
A3SSAA-6AAB-01	1SQA010924R0001	20
A3SSAA-6AAB-10	1SQA010925R0001	20
A3SSAA-6AAB-20	1SQA010984R0001	20

Type	Order code	Page
A3SSAA-6AAB-21	1SQA010985R0001	20
A3SSAA-6AAB-91	1SQA010926R0001	20
A3SSAA-6AAG-00	1SQA010204R0001	20
A3SSAA-6AAR-00	1SQA010205R0001	20
A3SSAA-6L2G-00	1SQA009417R0001	25
A3SSAA-6L2G-10	1SQA010882R0001	25
A3SSAA-6L2G-91	1SQA010883R0001	25
A3SSAA-6L2L-00	1SQA010421R0001	25
A3SSAA-6L2L-10	1SQA010884R0001	25
A3SSAA-6L2L-91	1SQA010885R0001	25
A3SSAA-6L2R-00	1SQA009422R0001	25
A3SSAA-6L2R-91	1SQA010886R0001	25
A3SSAA-6L4G-00	1SQA009424R0001	25
A3SSAA-6L4G-91	1SQA010887R0001	25
A3SSAA-6L4L-00	1SQA010424R0001	25
A3SSAA-6L4L-91	1SQA010888R0001	25
A3SSAA-6L4M-00	1SQA010425R0001	25
A3SSAA-6L4M-91	1SQA010889R0001	25
A3SSAA-6L4R-00	1SQA009428R0001	25
A3SSAA-6L4R-91	1SQA010890R0001	25
A3SSAA-6L5G-00	1SQA009430R0001	25
A3SSAA-6L5G-91	1SQA010891R0001	25
A3SSAA-6L5M-00	1SQA010428R0001	25
A3SSAA-6L5M-91	1SQA010892R0001	25
A3SSAA-6L5R-00	1SQA009433R0001	25
A3SSAA-6L5R-91	1SQA010893R0001	25
A3SSAA-6L6G-00	1SQA010430R0001	25
A3SSAA-6L6G-91	1SQA010894R0001	25
A3SSAC-6AAB-00	1SQA010203R0001	20
A3SSAC-6AAB-91	1SQA010927R0001	20
A3SSBA-6AAB-00	1SQA010172R0001	20
A3SSBA-6AAB-10	1SQA010928R0001	20
A3SSBA-6AAB-20	1SQA011106R0001	20
A3SSBA-6AAB-21	1SQA010993R0001	20
A3SSBA-6AAB-91	1SQA010929R0001	20
A3SSBA-6AAB-92	1SQA011107R0001	20
A3SSBA-6L2G-00	1SQA009441R0001	25
A3SSBA-6L2G-91	1SQA010999R0001	25
A3SSBA-6L2R-00	1SQA010432R0001	25
A3SSBA-6L2R-91	1SQA010895R0001	25
A3SSBB-6AAB-00	1SQA010206R0001	21
A3SSBB-6AAB-91	1SQA010930R0001	21
A3SSBB-6AAB-92	1SQA011108R0001	21
A3SSBC-6AAB-00	1SQA010207R0001	21
A3SSBC-6AAB-91	1SQA010931R0001	21
A3SSBC-6AAB-92	1SQA011109R0001	21
A3SSBD-6AAB-00	1SQA010173R0001	22
A3SSBD-6AAB-91	1SQA010932R0001	22
A3SSBD-6AAB-92	1SQA010933R0001	22
A3SSCA-6AAB-00	1SQA010162R0001	20
A3SSCA-6AAB-10	1SQA010934R0001	20
A3SSCA-6AAB-12	1SQA010989R0001	20
A3SSCA-6AAB-91	1SQA010935R0001	20
A3SSCA-6L2G-00	1SQA009453R0001	25
A3SSCA-6L2G-91	1SQA010896R0001	25

Index

Type classification

Type	Order code	Page	Type	Order code	Page	Type	Order code	Page
A3SSCA-6L2M-00	1SQA010434R0001	25	A3XBL4G	1SQA010403R0001	33	A3XLENA	1SQA009533R0001	31
A3SSCA-6L2M-91	1SQA010897R0001	25	A3XBL4L	1SQA010197R0001	33	A3XLENB	1SQA010201R0001	33
A3SSCA-6L4G-00	1SQA009456R0001	25	A3XBL4R	1SQA010195R0001	33	A3XLENG	1SQA009534R0001	31
A3SSCA-6L4G-91	1SQA010898R0001	25	A3XBL4W	1SQA010198R0001	33	A3XLENL	1SQA009535R0001	31
A3SSCA-6L4L-00	1SQA010436R0001	25	A3XBL4Y	1SQA010196R0001	33	A3XLENR	1SQA009536R0001	31
A3SSCA-6L4L-91	1SQA010899R0001	25	A3XBL6G	1SQA010190R0001	33	A3XLENY	1SQA009537R0001	31
A3SSCA-6L4R-00	1SQA009459R0001	25	A3XBL6L	1SQA010405R0001	33	A3XLFN6	1SQA009538R0001	32
A3SSCA-6L4R-91	1SQA010900R0001	25	A3XBL6R	1SQA010189R0001	33	A3XLFN8	1SQA009539R0001	32
A3SSCA-6L5G-00	1SQA010438R0001	25	A3XBL6W	1SQA010191R0001	33	A3XLFNA	1SQA009540R0001	32
A3SSCA-6L5G-91	1SQA010901R0001	25	A3XBL6Y	1SQA010406R0001	33	A3XLFNB	1SQA009541R0001	32
A3SSCA-6L5R-00	1SQA009462R0001	25	A3XC01	1SQA009494R0001	30	A3XLFNG	1SQA009542R0001	32
A3SSCA-6L5R-91	1SQA010902R0001	25	A3XC0B	1SQA010979R0001	30	A3XLFNL	1SQA009543R0001	32
A3SSCB-6AAB-00	1SQA010163R0001	21	A3XC0M	1SQA010981R0001	30	A3XLFNR	1SQA009544R0001	32
A3SSCB-6AAB-91	1SQA010936R0001	21	A3XC0N	1SQA010980R0001	30	A3XLFNY	1SQA009545R0001	32
A3SSCC-6AAB-00	1SQA010208R0001	21	A3XC10	1SQA009496R0001	30	A3XLKLC	1SQA010218R0001	33
A3SSCC-6AAB-91	1SQA010937R0001	21	A3XC91	1SQA010978R0001	30	A3XLKLG	1SQA010213R0001	33
A3SSCC-6AAB-92	1SQA011111R0001	21	A3XGCC	1SQA010211R0001	31	A3XLKLL	1SQA010216R0001	33
A3SSCD-6AAB-00	1SQA010164R0001	22	A3XGCE	1SQA009500R0001	31	A3XLKLM	1SQA010217R0001	33
A3SSCD-6AAB-10	1SQA010938R0001	22	A3XGCF	1SQA009501R0001	31	A3XLKLR	1SQA010214R0001	33
A3SSCD-6AAB-91	1SQA010939R0001	22	A3XGGL	1SQA010180R0001	31	A3XLKLW	1SQA010219R0001	33
A3SSDA-6AAB-00	1SQA010209R0001	20	A3XGGP	1SQA010181R0001	31	A3XLLLA	1SQA009546R0001	32
A3SSDA-6AAB-91	1SQA010940R0001	20	A3XGLM	1SQA009502R0001	31	A3XLLLC	1SQA009547R0001	32
A3SSDB-6AAB-00	1SQA010440R0001	21	A3XGLN	1SQA009503R0001	31	A3XLLLG	1SQA009548R0001	32
A3SSDB-6AAB-91	1SQA010941R0001	21	A3XGLP	1SQA009504R0001	31	A3XLLLL	1SQA009549R0001	32
A3SSDC-6AAB-00	1SQA009474R0001	21	A3XGLW	1SQA010221R0001	33	A3XLLLM	1SQA009550R0001	32
A3SSDC-6AAB-91	1SQA010942R0001	21	A3XGPM	1SQA009506R0001	31	A3XLLLR	1SQA009551R0001	32
A3SSDC-6AAB-92	1SQA011113R0001	21	A3XK501	1SQA009581R0001	31	A3XLLLW	1SQA009552R0001	32
A3SSDD-6AAB-00	1SQA009476R0001	22	A3XL4LG	1SQA010212R0001	31	A3XLMLG	1SQA009553R0001	32
A3SSDD-6AAB-91	1SQA010943R0001	22	A3XL4LM	1SQA010215R0001	31	A3XLMLM	1SQA009554R0001	32
A3SSEA-6AAB-00	1SQA010175R0001	21	A3XL4LR	1SQA009510R0001	31	A3XLMLR	1SQA009555R0001	32
A3SSEA-6AAB-91	1SQA010944R0001	21	A3XL4N8	1SQA009511R0001	31	A3XLMLW	1SQA009556R0001	32
A3SEEB-6AAB-00	1SQA009480R0001	21	A3XL4NA	1SQA009512R0001	31	A3XLMN1	1SQA009557R0001	32
A3SEEC-6AAB-00	1SQA009481R0001	21	A3XL4NB	1SQA009513R0001	31	A3XLMNG	1SQA009558R0001	32
A3SEEC-6AAB-91	1SQA010945R0001	21	A3XL4NG	1SQA009514R0001	31	A3XLMNR	1SQA009559R0001	32
A3SEED-6AAB-00	1SQA009483R0001	22	A3XL4NL	1SQA009515R0001	31	A3XLP0B	1SQA010223R0001	33
A3SEED-6AAB-91	1SQA010946R0001	22	A3XL4NR	1SQA009516R0001	31	A3XLP0C	1SQA010222R0001	33
A3SSGA-6AAB-00	1SQA010165R0001	21	A3XL4NY	1SQA009517R0001	31	A3XLSG6	1SQA009560R0001	32
A3SSGA-6AAB-12	1SQA010991R0001	21	A3XL6LG	1SQA010409R0001	31	A3XLSG8	1SQA009561R0001	32
A3SSGA-6AAB-91	1SQA010947R0001	21	A3XL6LM	1SQA010411R0001	31	A3XLSGG	1SQA009562R0001	32
A3SSGB-6AAB-00	1SQA010441R0001	21	A3XL6LR	1SQA010410R0001	31	A3XLSGL	1SQA009563R0001	32
A3SSGB-6AAB-91	1SQA010948R0001	21	A3XL6N8	1SQA009518R0001	31	A3XLSGR	1SQA009564R0001	32
A3SSGB-6AAB-92	1SQA011117R0001	21	A3XL6NA	1SQA009519R0001	31	A3XLSGW	1SQA009565R0001	32
A3SSGC-6AAB-00	1SQA009488R0001	21	A3XL6NB	1SQA009520R0001	31	A3XLSGY	1SQA009566R0001	32
A3SSGC-6AAB-91	1SQA010949R0001	21	A3XL6NG	1SQA009521R0001	31	A3XLSS6	1SQA009567R0001	32
A3SSGC-6AAB-92	1SQA011118R0001	21	A3XL6NL	1SQA009522R0001	31	A3XLSS8	1SQA009568R0001	32
A3SSGD-6AAB-00	1SQA009490R0001	22	A3XL6NR	1SQA009523R0001	31	A3XLSSG	1SQA009569R0001	32
A3SSGD-6AAB-91	1SQA010950R0001	22	A3XL6NY	1SQA009524R0001	31	A3XLSSL	1SQA009570R0001	32
A3SSGD-6AAB-92	1SQA011119R0001	22	A3XLELC	1SQA009525R0001	31	A3XLSSR	1SQA009571R0001	32
A3SSHA-6AAB-00	1SQA010174R0001	22	A3XLELG	1SQA009526R0001	31	A3XLSSW	1SQA009572R0001	32
A3SSHA-6AAB-92	1SQA010951R0001	22	A3XLELL	1SQA009527R0001	31	A3XLSSY	1SQA009573R0001	32
A3XBL2G	1SQA010193R0001	33	A3XLELM	1SQA009528R0001	31	A3XLTNG	1SQA009577R0001	32
A3XBL2L	1SQA010401R0001	33	A3XLELR	1SQA009529R0001	31	A3XLTNR	1SQA009578R0001	32
A3XBL2R	1SQA010192R0001	33	A3XLELW	1SQA009530R0001	31	A3XLTNV	1SQA009579R0001	32
A3XBL2W	1SQA010194R0001	33	A3XLEN6	1SQA009531R0001	31	A3XMLLG	1SQA010183R0001	33
A3XBL2Y	1SQA010402R0001	33	A3XLEN8	1SQA009532R0001	31	A3XMLLL	1SQA010480R0001	33

Index

Type classification

Type	Order code	Page	Type	Order code	Page
A3XMLLR	1SQA010182R0001	33	CR104PXN*BP059		36
A3XMLLW	1SQA010408R0001	33	CR104PXN*BP060		36
A3XMLLY	1SQA010184R0001	33	CR104PXN*BP061		36
A3XMLUG	1SQA010185R0001	33	CR104PXN*BP062		36
A3XMLUL	1SQA010458R0001	33	CR104PXN*BP063		36
A3XMLUR	1SQA010456R0001	33	CR104PXN*BP064		36
A3XMLUW	1SQA010455R0001	33	CR104PXN*BP065		36
A3XMLUY	1SQA010459R0001	33	CR104PXN*BP066		36
A3XMN4N	1SQA010179R0001	33	CR104PXN*BP067		36
A3XMN5N	1SQA010404R0001	33	CR104PXN*BP068		36
A3XMN6N	1SQA010186R0001	33	CR104PXN*BP069		36
A3XMN7N	1SQA010188R0001	33	CR104PXN*BP070		36
A3XMN8N	1SQA010187R0001	33	CR104PXN*BP071		36
A3XMN9N	1SQA010407R0001	33	CR104PXN*BP072		36
A3XXGC	1SQA009583R0001	33	CR104PXN*BP073		36
CR104PXN*B		35	CR104PXN*BP074		36
CR104PXN*BP006		35	CR104PXN*BP076		36
CR104PXN*BP007		35	CR104PXN*BP077		36
CR104PXN*BP008		35	CR104PXN*BP079		36
CR104PXN*BP010		35	CR104PXN*BP080		36
CR104PXN*BP011		35	CR104PXN*BP081		36
CR104PXN*BP012		35	CR104PXN*BP082		36
CR104PXN*BP013		35	CR104PXN*BP083		36
CR104PXN*BP014		35	CR104PXN*BP084		35
CR104PXN*BP017		35	CR104PXN*BP085		35
CR104PXN*BP018		35	CR104PXN*BP086		36
CR104PXN*BP019		35	CR104PXN*BP087		36
CR104PXN*BP020		35	CR104PXN*R		35
CR104PXN*BP021		35	CR104PXN*RP009		35
CR104PXN*BP022		35	CR104PXN*RP040		35
CR104PXN*BP023		35	CR104PXN*RP041		35
CR104PXN*BP024		35	CR104PXN*RP048		35
CR104PXN*BP025		35	CR104PXN1BP090		36
CR104PXN*BP026		35	CR104PXN1BP091		36
CR104PXN*BP027		35	CR104PXN6E		35
CR104PXN*BP028		35	CR104PXN6EP009		36
CR104PXN*BP030		35	CR104PXN6EP092		36
CR104PXN*BP031		35			
CR104PXN*BP032		35			
CR104PXN*BP033		35			
CR104PXN*BP034		35			
CR104PXN*BP036		35			
CR104PXN*BP037		35			
CR104PXN*BP038		35			
CR104PXN*BP043		35			
CR104PXN*BP047		35			
CR104PXN*BP050		36			
CR104PXN*BP051		36			
CR104PXN*BP052		36			
CR104PXN*BP053		36			
CR104PXN*BP054		36			
CR104PXN*BP055		36			
CR104PXN*BP056		36			
CR104PXN*BP057		36			
CR104PXN*BP058		36			



ABB Inc.
305 Gregson Drive
Cary, NC 27511
USA
electrification.us.abb.com

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB Inc. does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction, disclosure to third parties or utilization of its contents – in whole or in parts – is forbidden without prior written consent of ABB Inc. Copyright© 2023 ABB
All rights reserved