


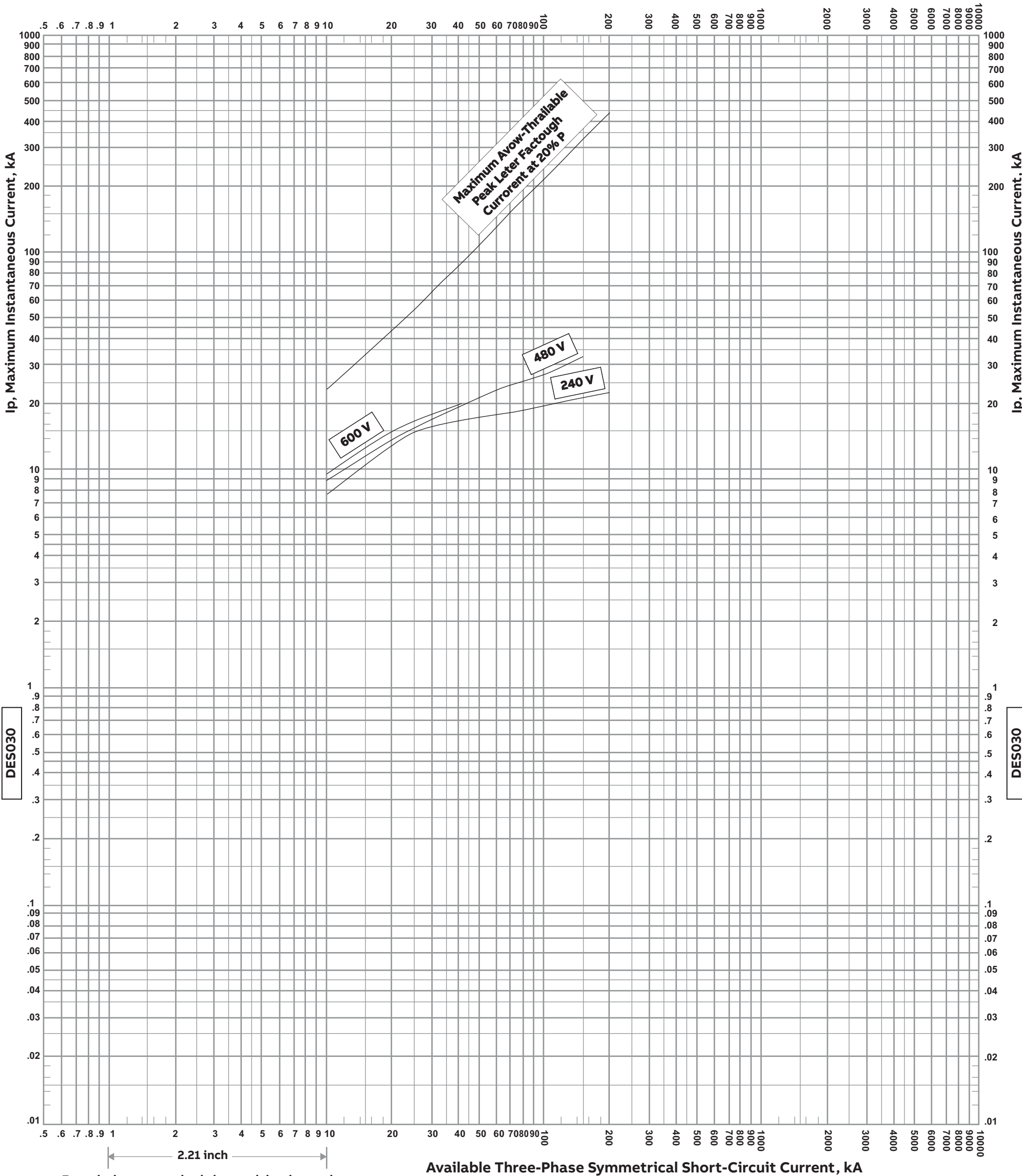

FC Voltage Ratings

2- and 3-pole – 600/347 Vac, 500 Vdc

FB Voltage Ratings

2- and 3-pole – 600/347
Vac 1-pole – 347 Vac

Frequency Rating

50/60 Hertz

**Molded Case Circuit Breaker with
Thermal-Magnetic Trip Unit**

Record Plus™ Types FC & FB
Peak Let-Through Current Curves

DES030

Current Ratings

15, 20, 25, 30, 40, 45, 50, 60, 70,
80, 90, 100 Amperes