


Shaver socket outlet
2332 UJBS-8xx

ENG **Installation and operating instructions**
Read carefully and keep in a safe place

Safety instructions

 Work on the 230 V supply system may only be performed by specialist staff! De-energize mains power supply prior to installation and/or disassembly! Failure to observe installation and operating instructions may result in fire and other hazards!

Technical data

Operating voltage:	115/230 V ~ 50/60 Hz
Rated power:	20 VA
Type of protection :	IP 21
Temperature range :	-25 - + 70°

Function

The shaver socket outlet has been tested and complies to the relevant national and/or International standards. (Euro-, China-, Australian-, New-Zealand-, American- plug)

Installation

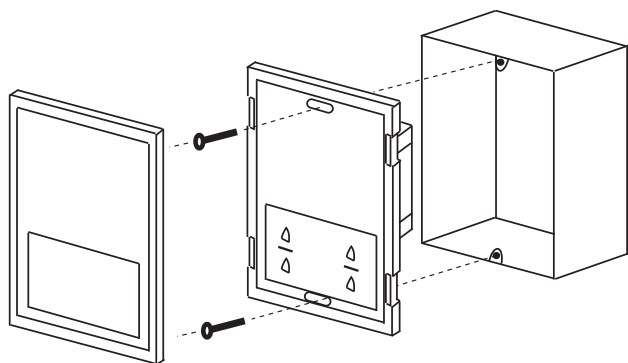


Abb. 1

Product to be wired in accordance with wiring diagram. In case of inductance load, take inductance power loss into account.

Connection

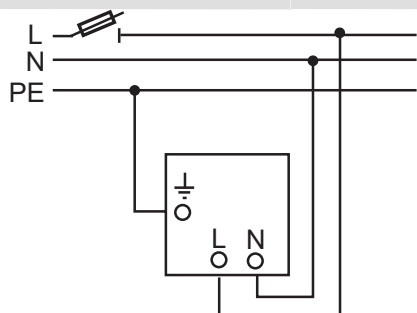


Abb. 2