



TZG 105-605
TZ(L/W) 105-305

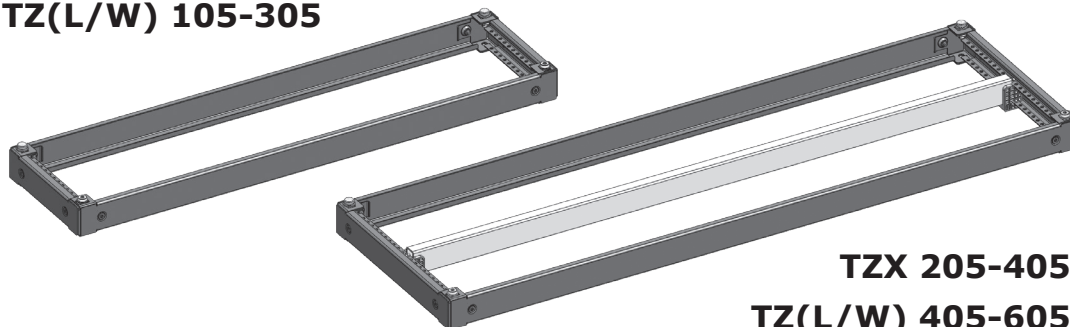


TZX 205-405
TZ(L/W) 405-605


TZG 110-610
TZ(L/W) 110-310

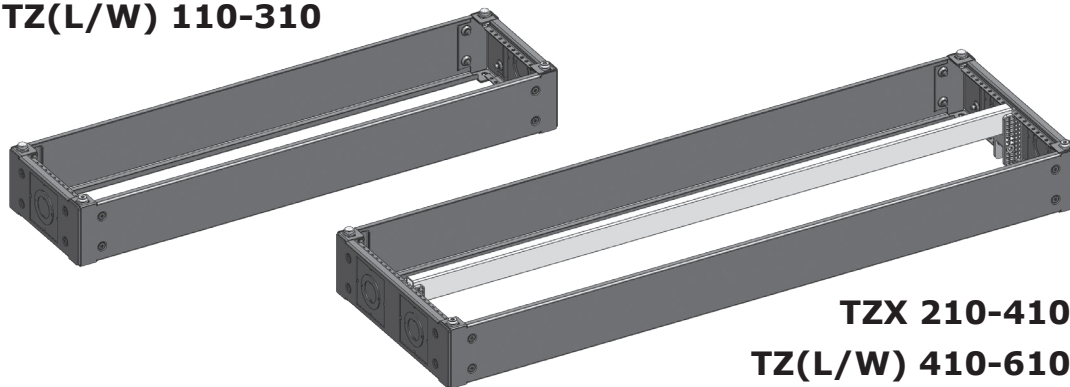



TZX 210-410
TZ(L/W) 410-610

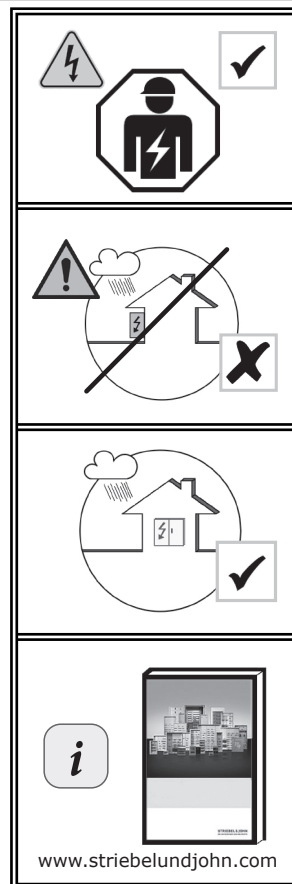




TZG 105-605
TZG 110-610
TZ(L/W) 105-305
TZ(L/W) 110-310

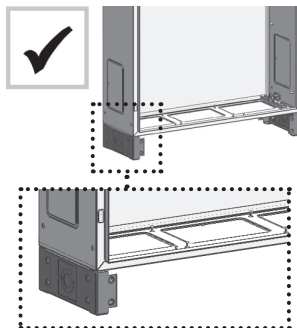


TZX 205-405
TZ(L/W) 405-605
TZX 210-410
TZ(L/W) 410-610

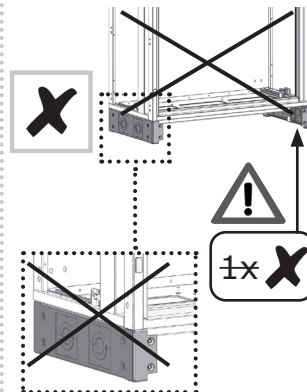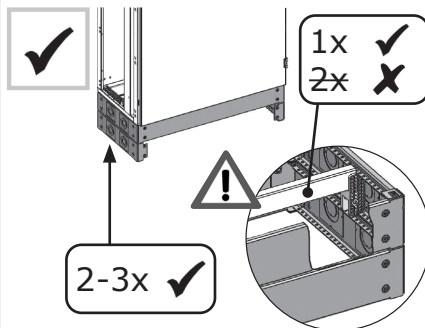



TZW../TZX..
TZG../TZL..

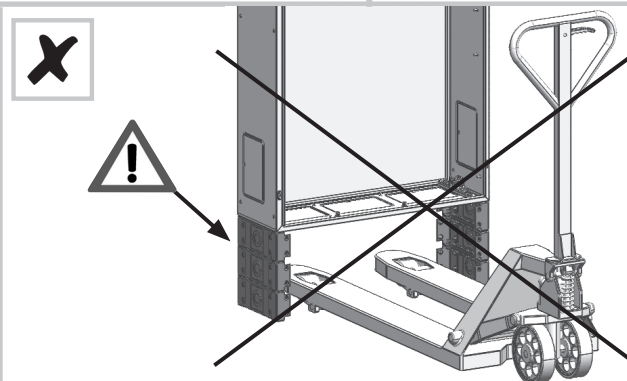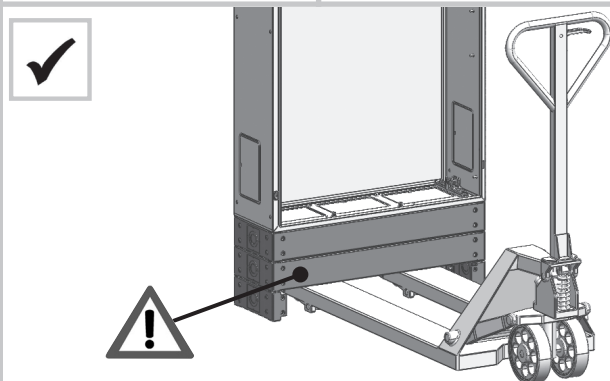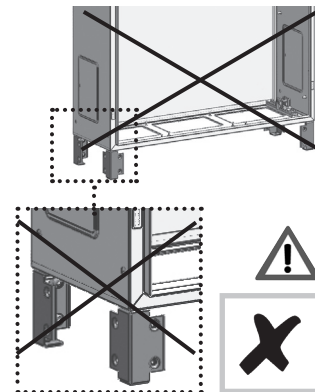



1

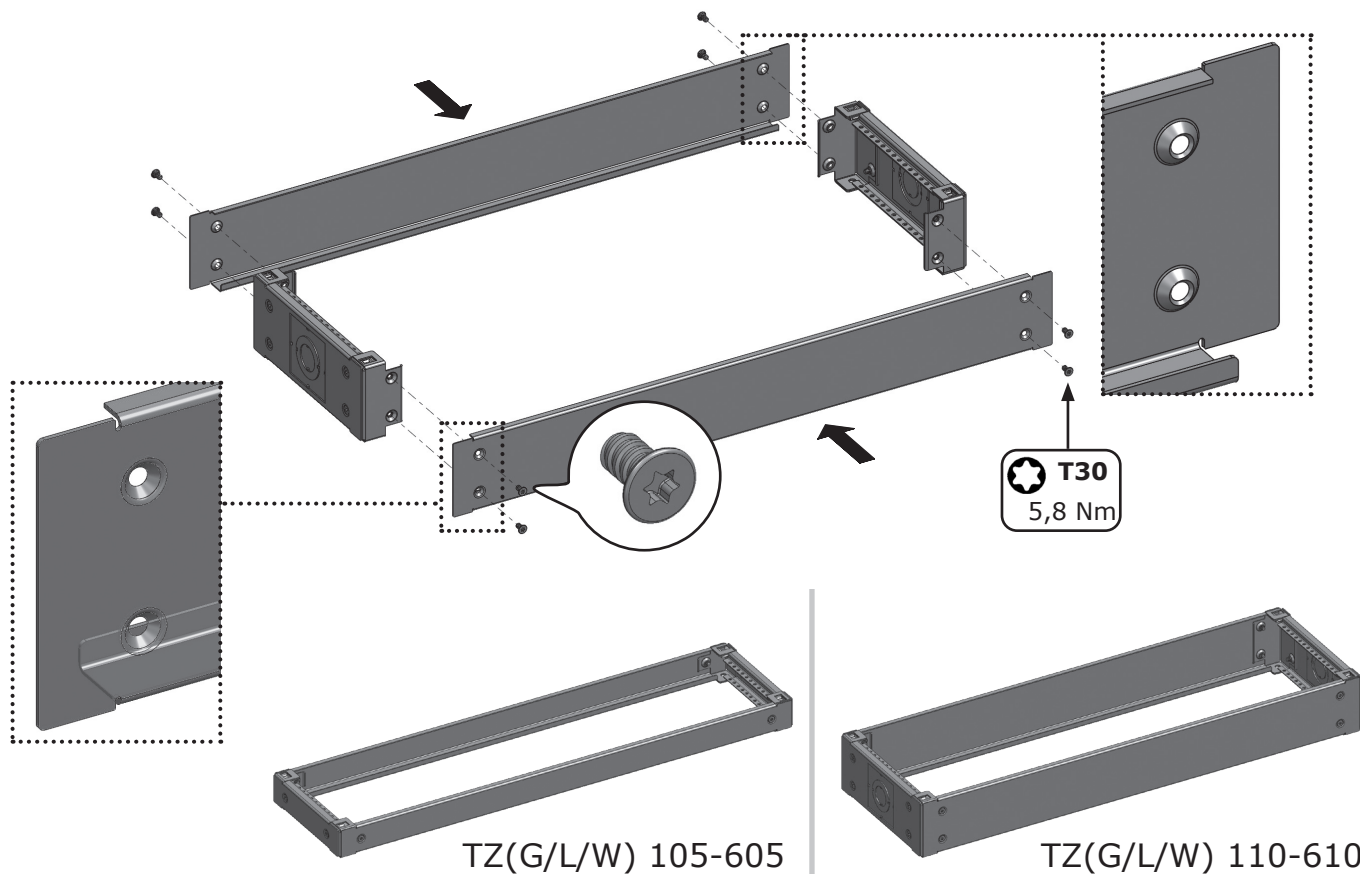

2

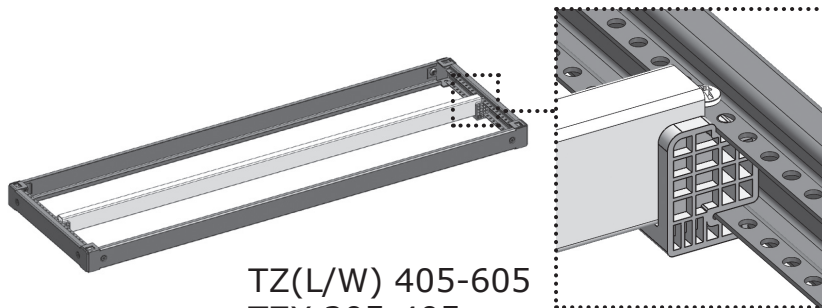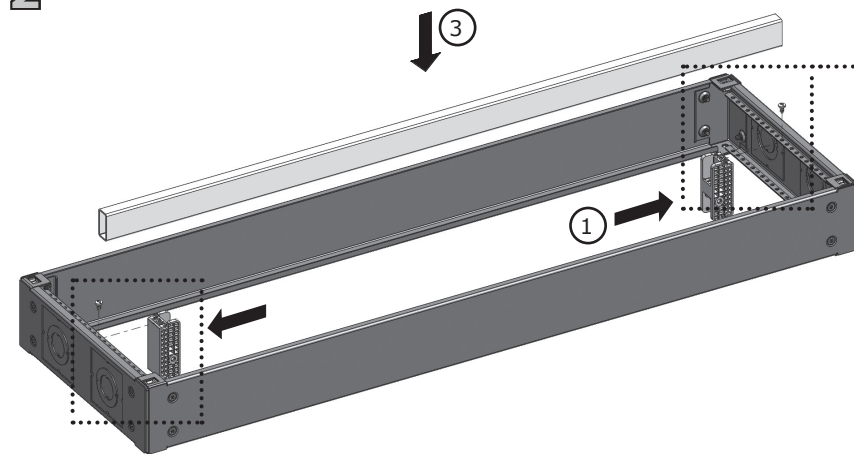


TZ(L/W) 405-605
TZX 205-405


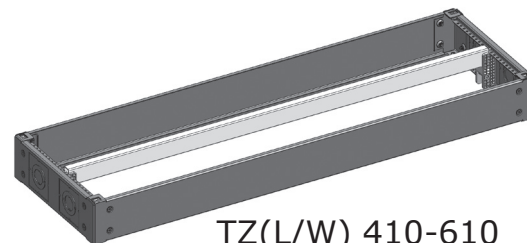
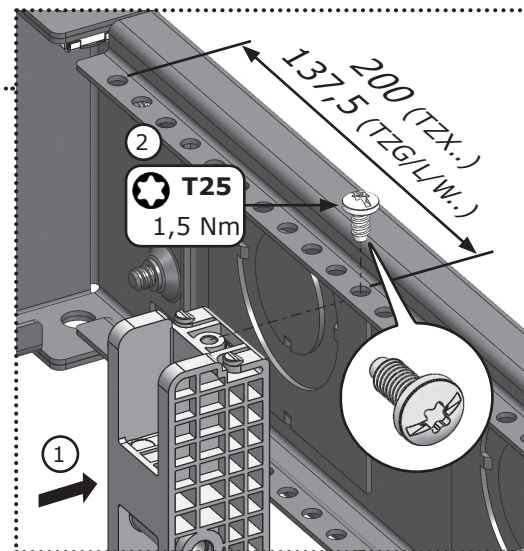


TZ(L/W) 410-610
TZX 210-410


3

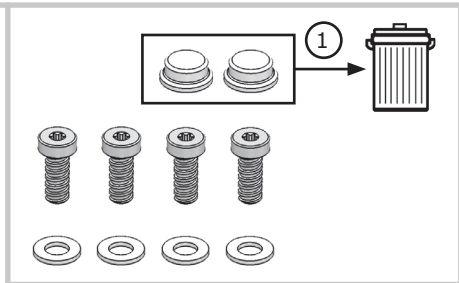

2

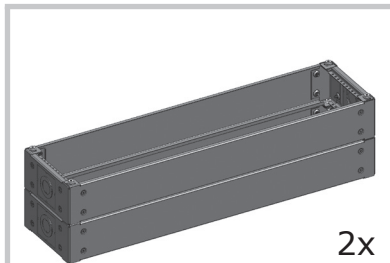
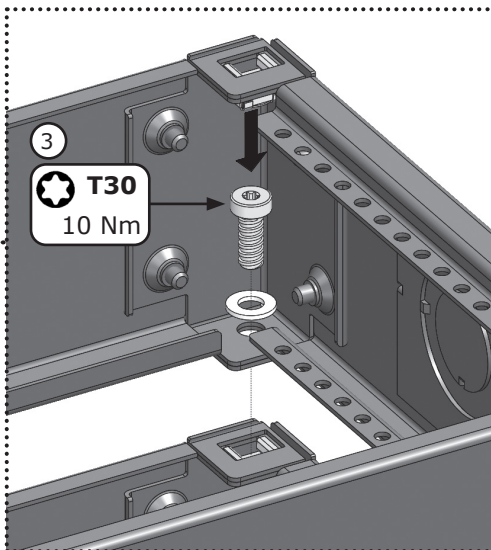
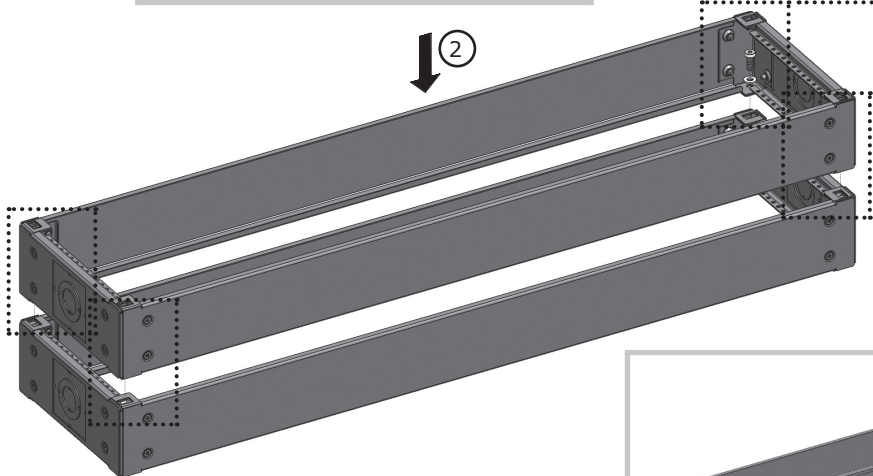


2x


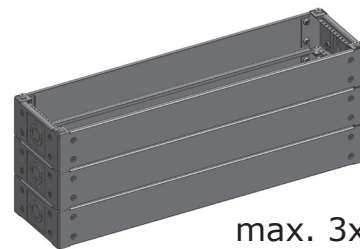



max. 3x


4a

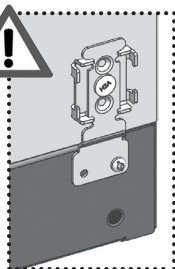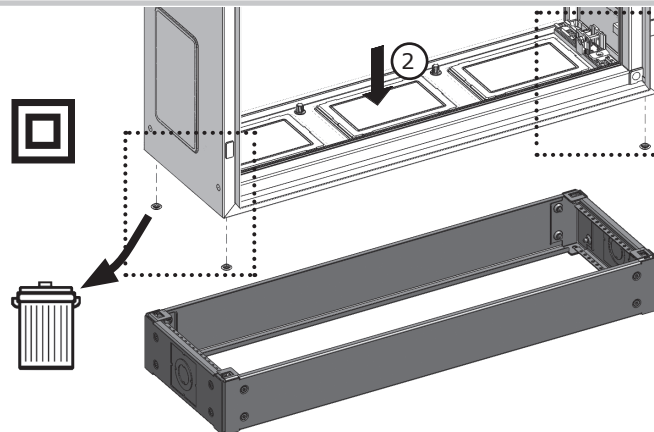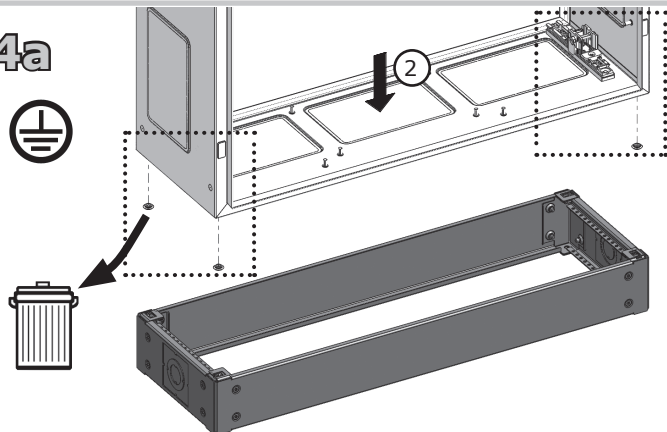



TZ627

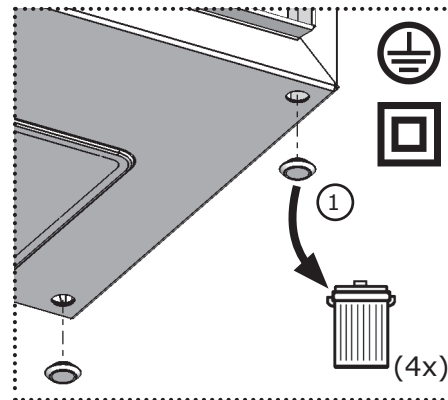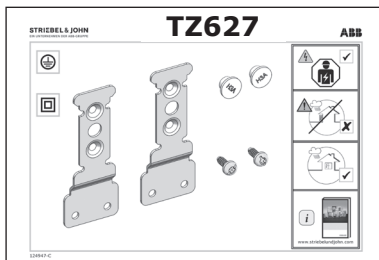

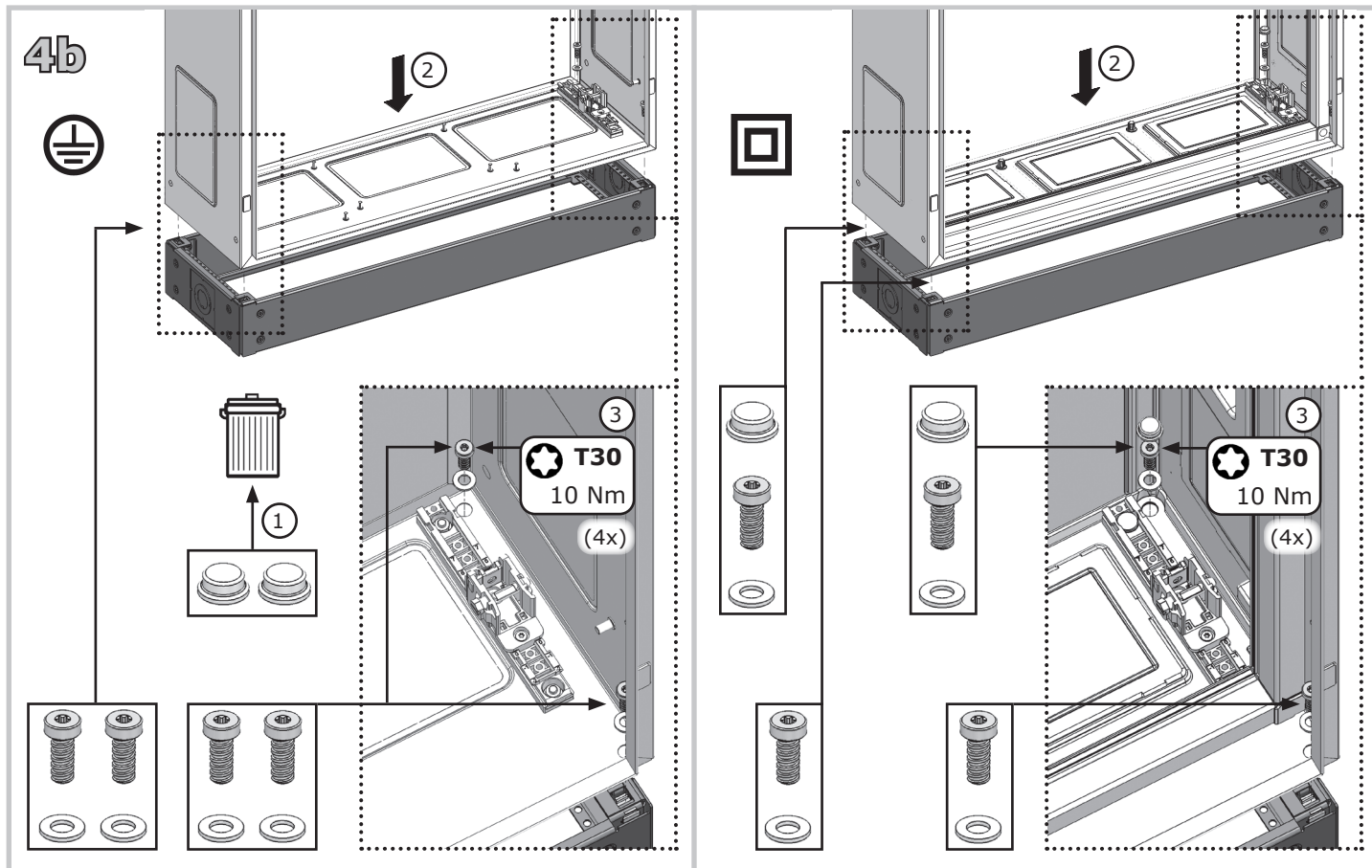

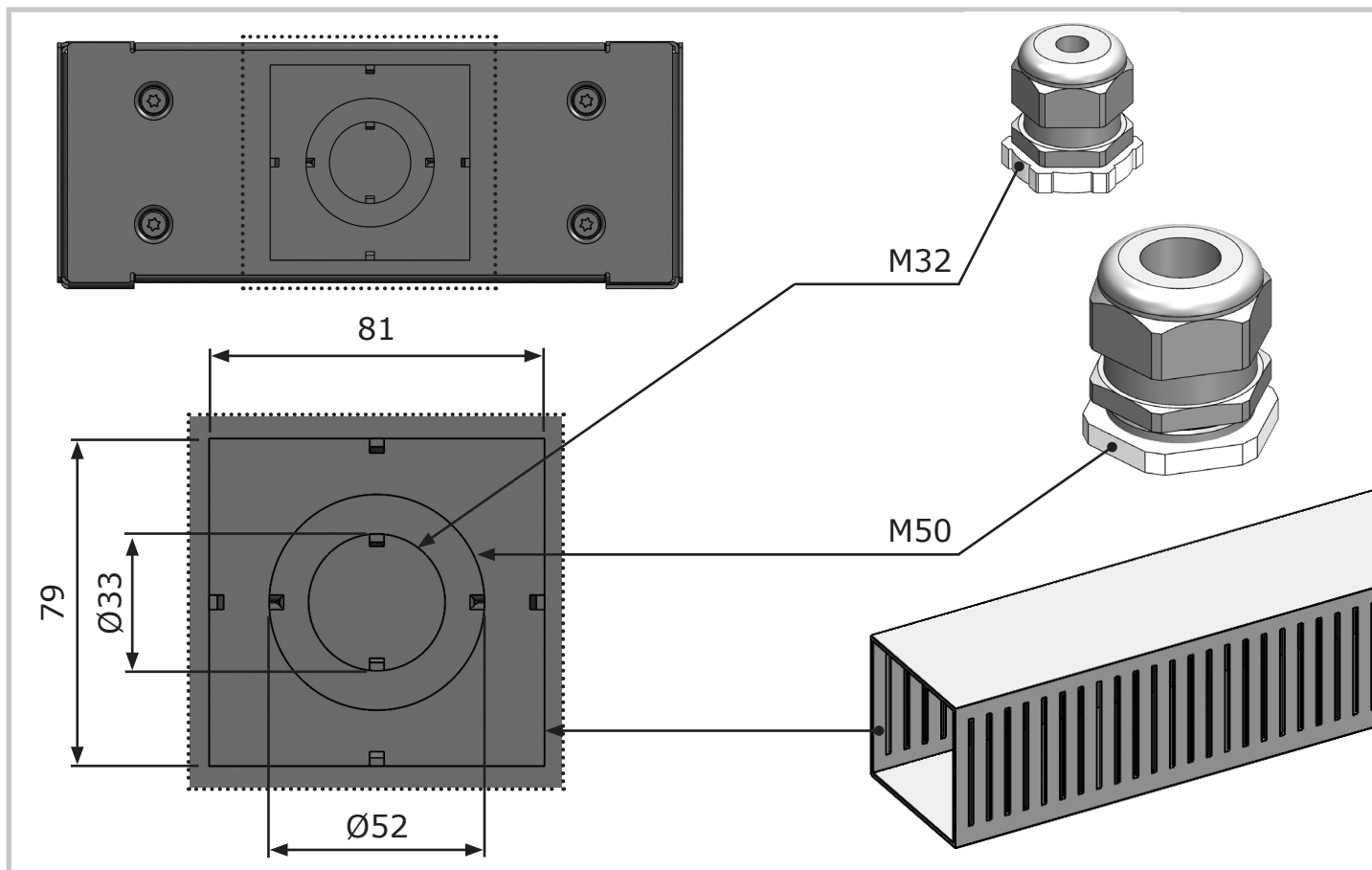

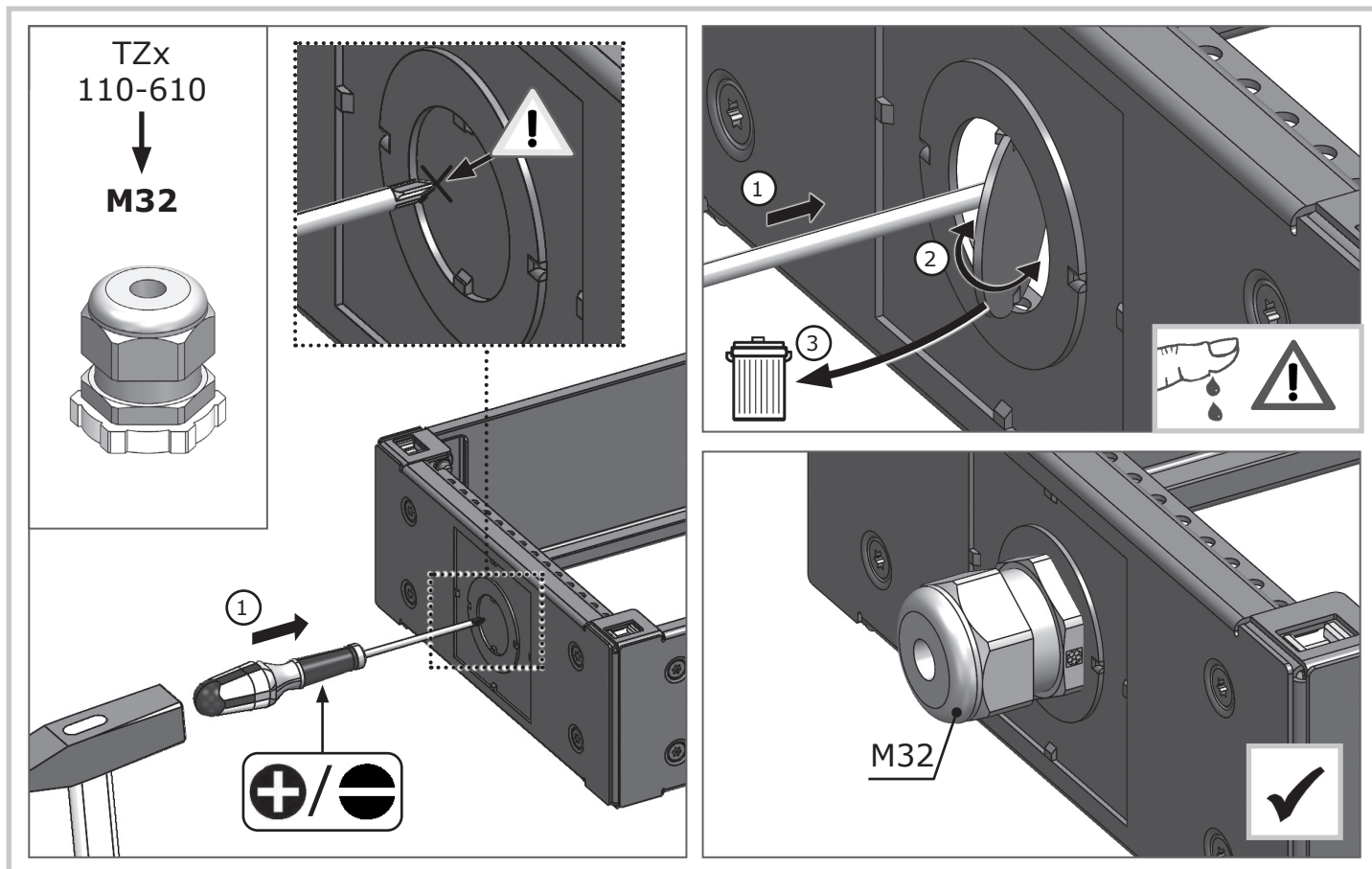

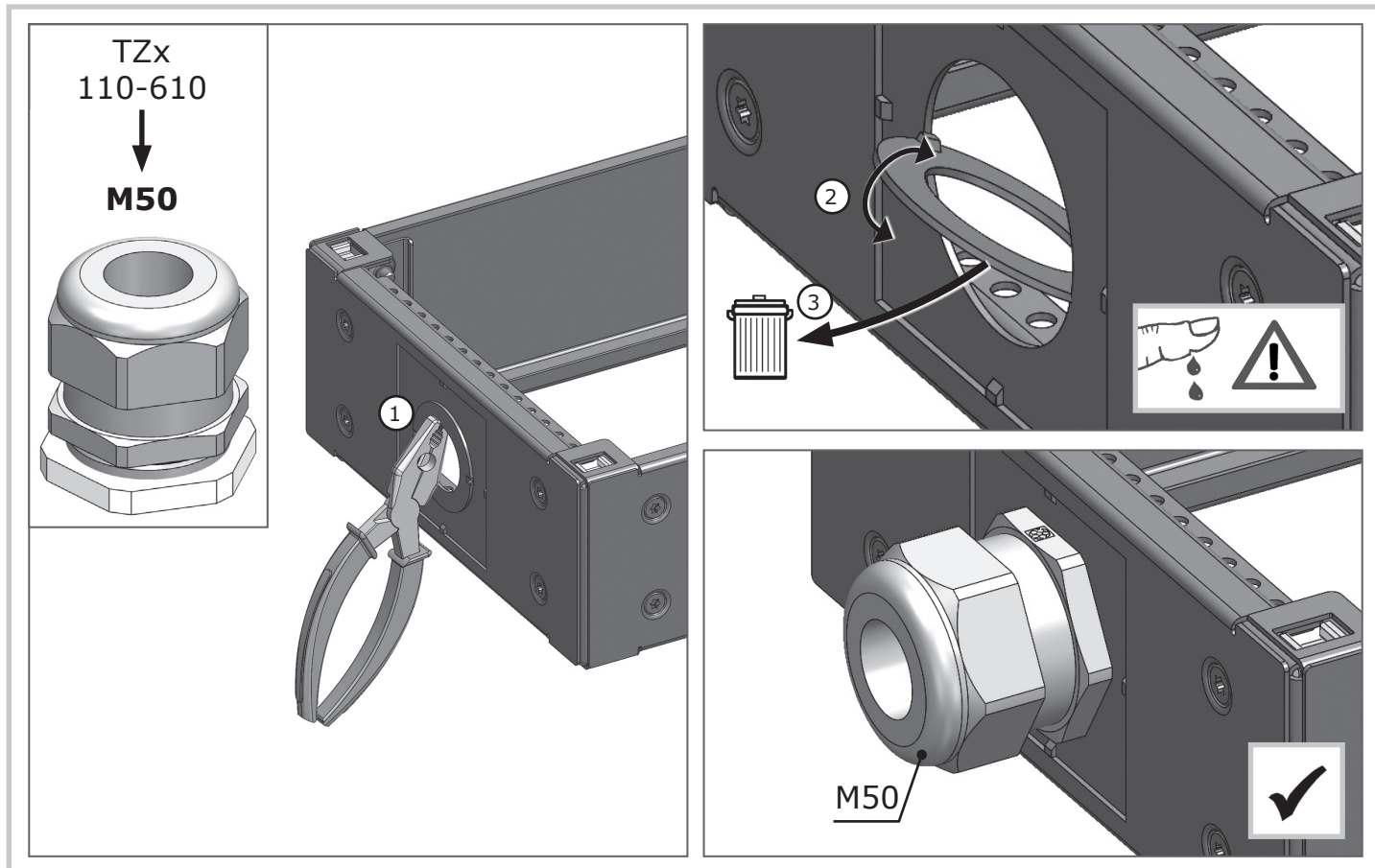

TZx
110-610

