



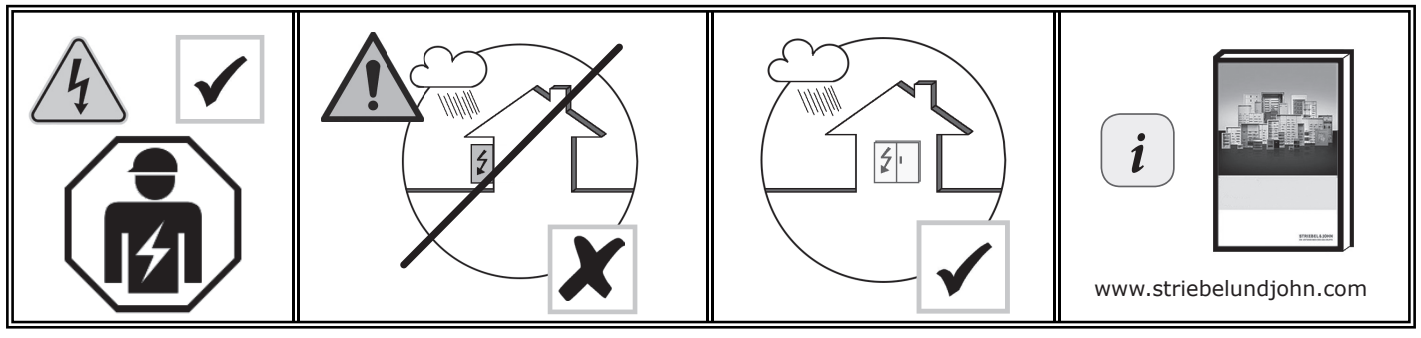




TZM..12





TZM..04 - 09



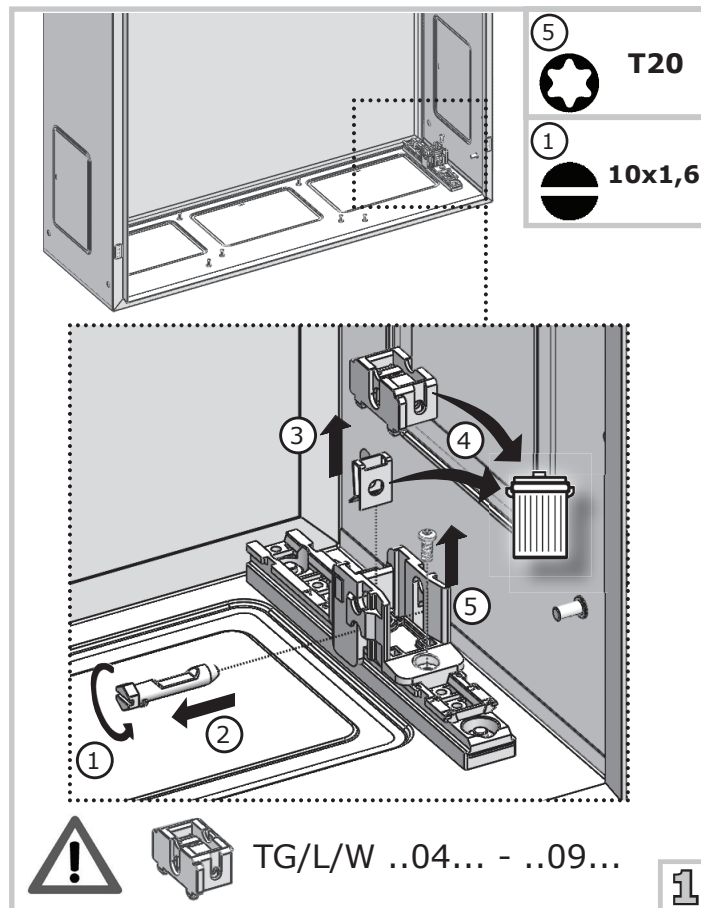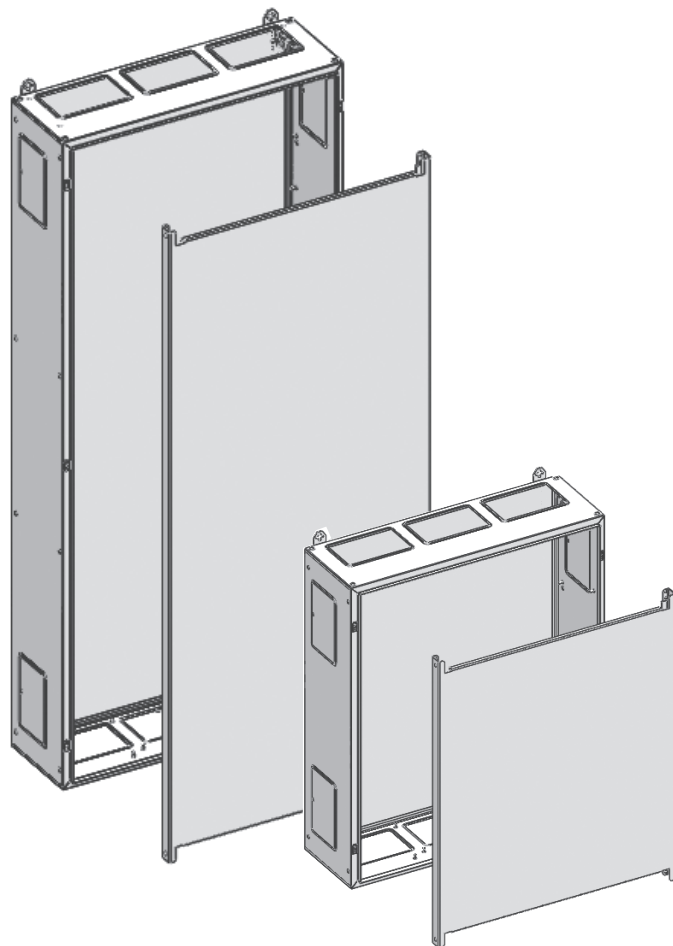

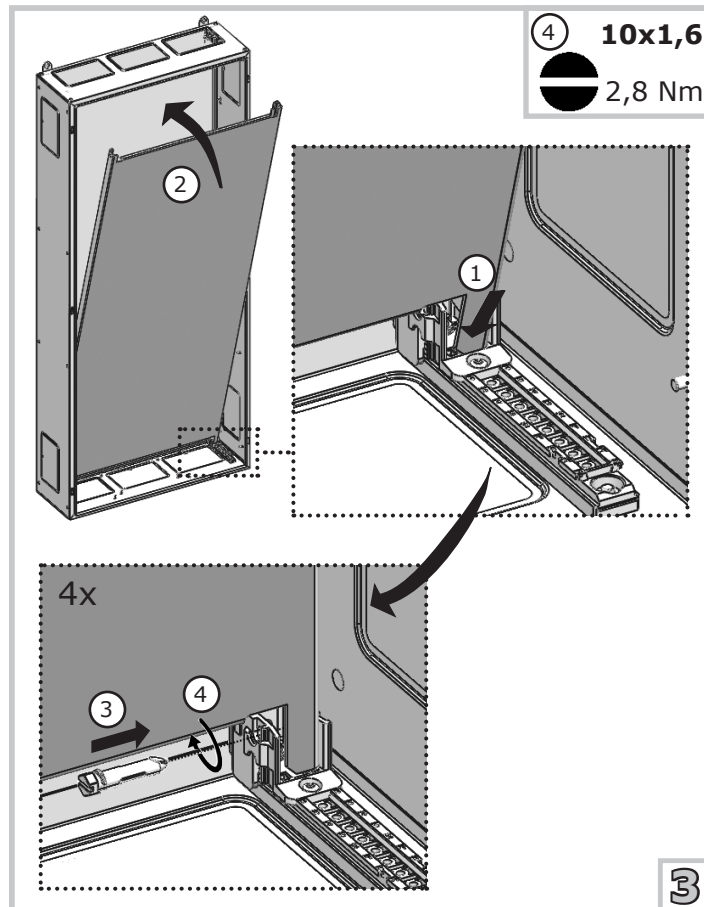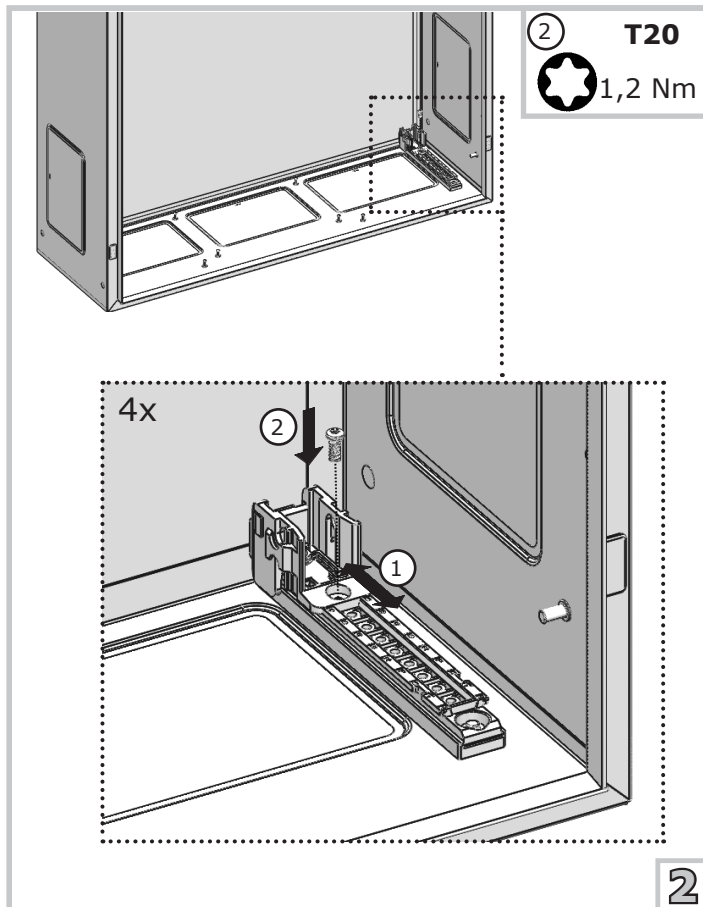

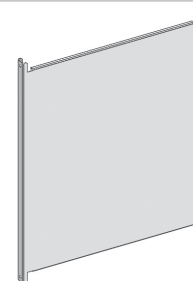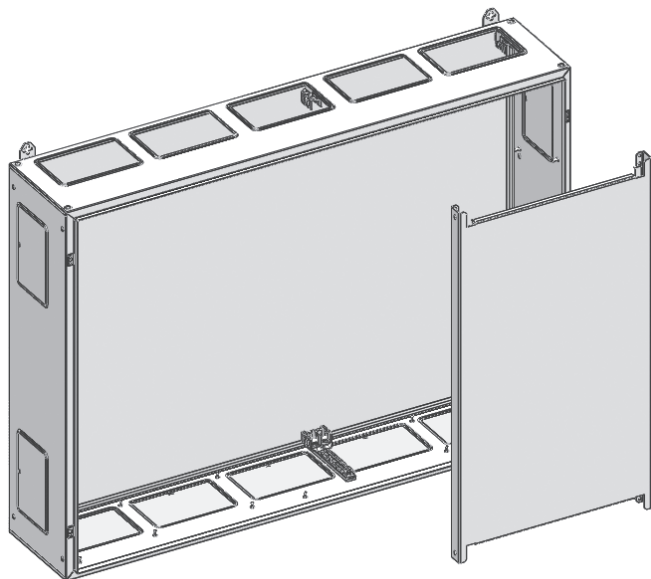


TG/L/W4..-6..

TZ601
(TG..)

2x



TZ602
(TL..)

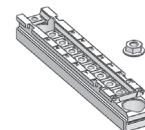






TZ603
(TW..)



2x

 
 

TZ604




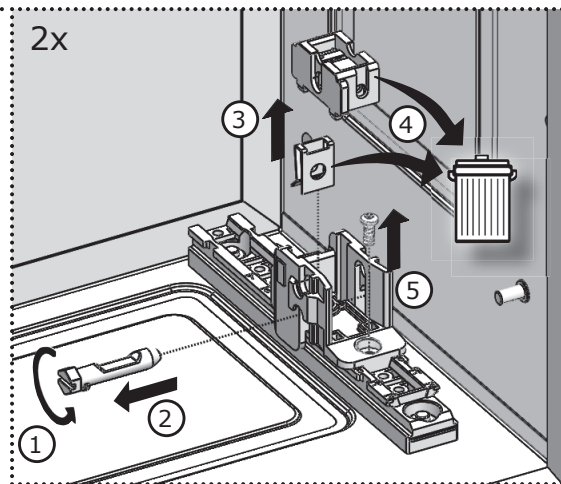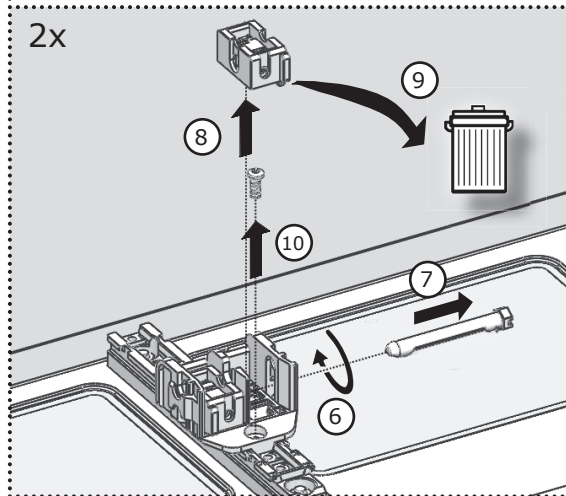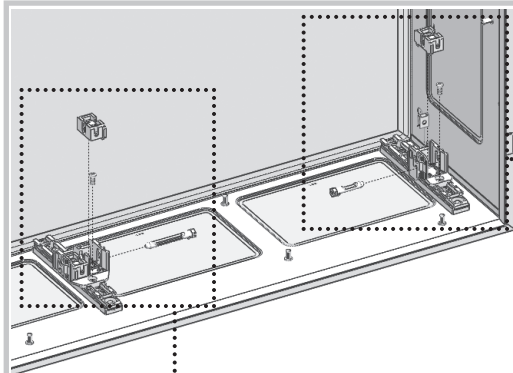

TG/L/W ..04 - ..09

2 4 **T20**
 1,2 Nm

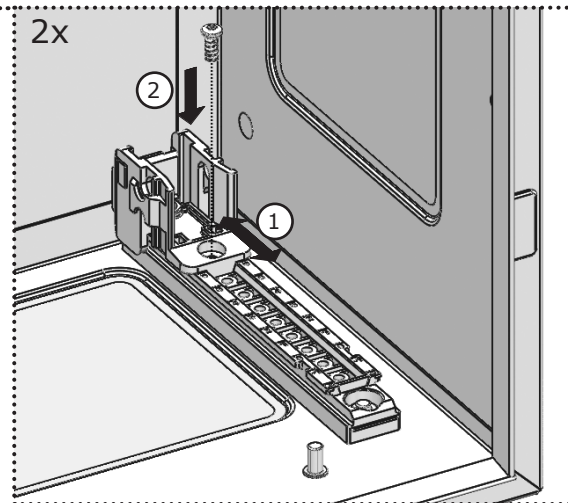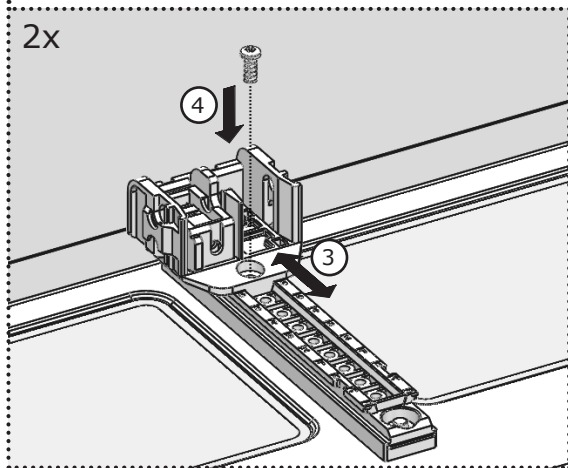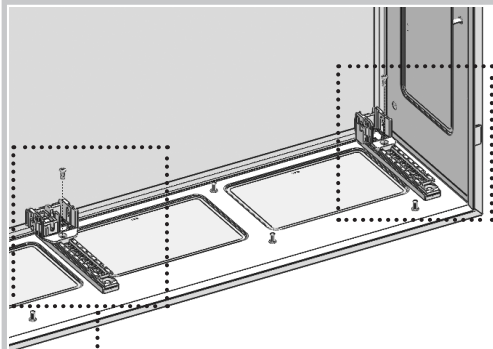

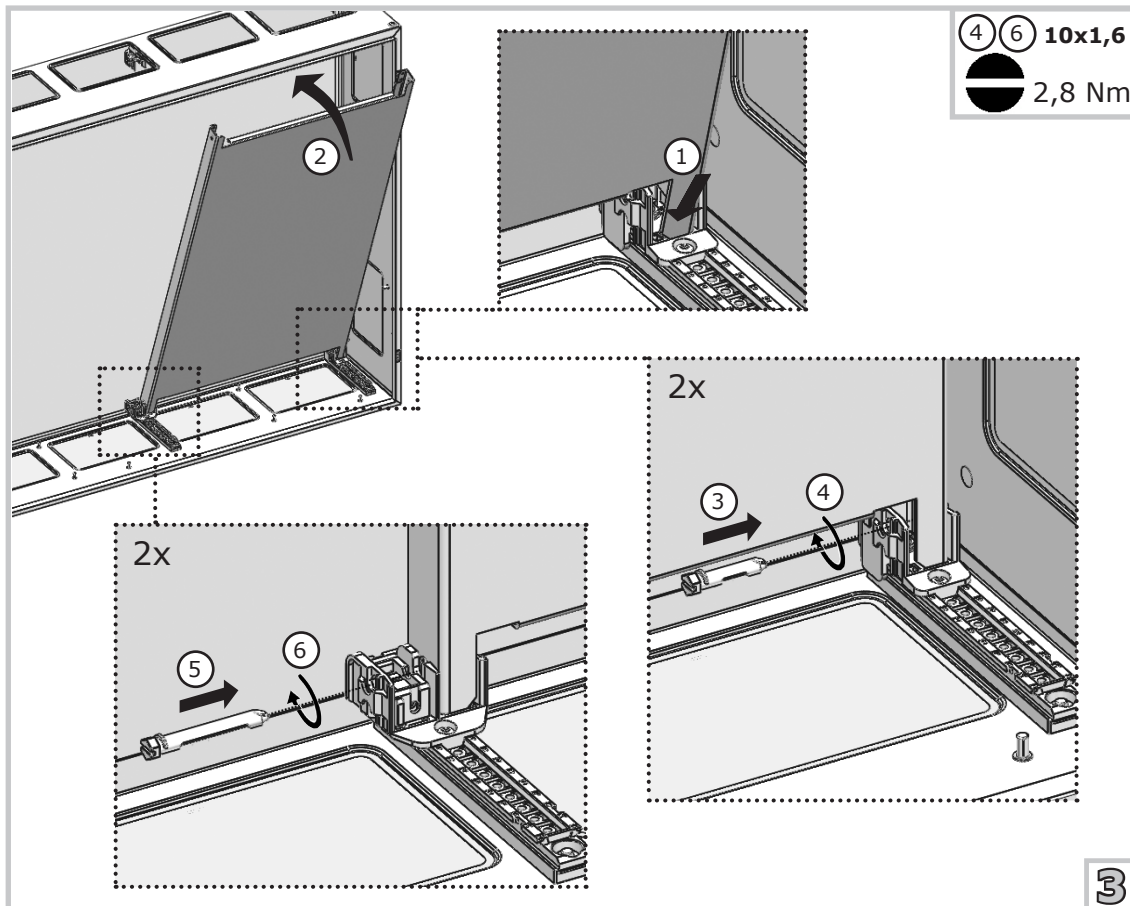

IEC61439-2