
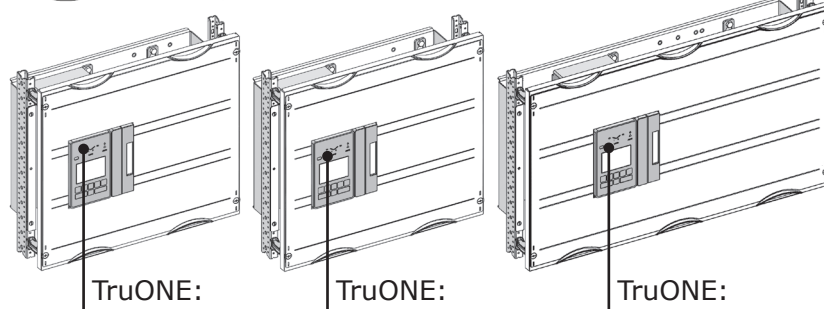


MBA250ALT

MBA400ALT

MBA401ALT

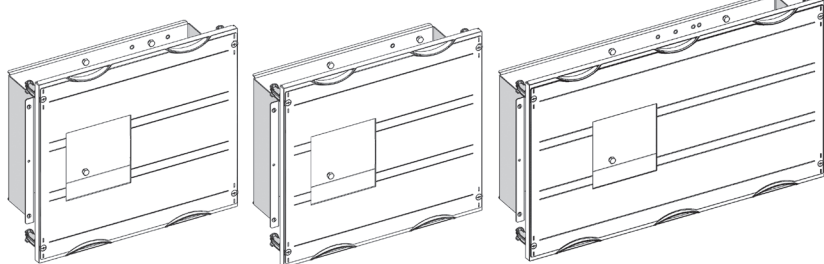


OX200-250A-2/3/4p


OX315-400A-2/3p

OX200-250A-2/3p
OX200-250A-4p
OX315-400A-3/4p


		MBA250ALT	MBA250ALT	MBA250ALT
1		4x	4x	4x
2		1x	1x	1x
3		4x	4x	4x
4		4x	4x	4x
5		1x	1x	1x

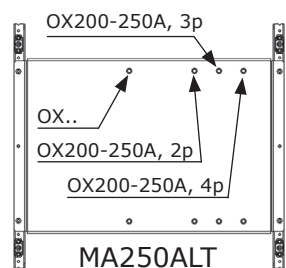




MA250ALT

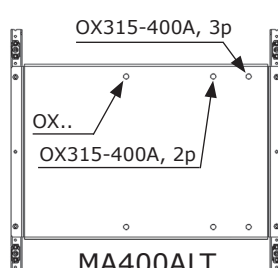

MA400ALT

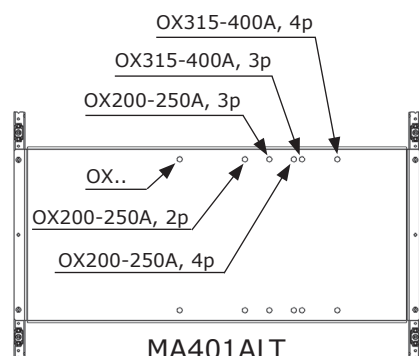

MA401ALT

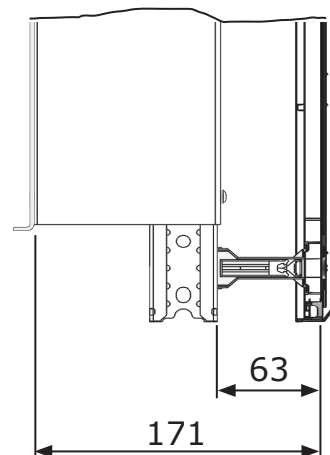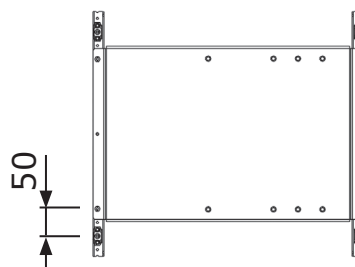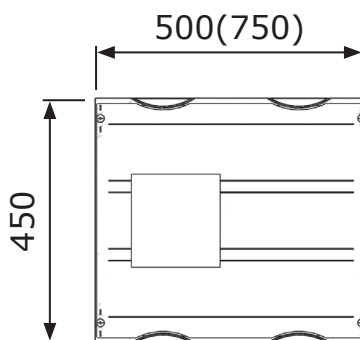

i

www.striebelundjohn.com



T25



PH2





WR




ED


1

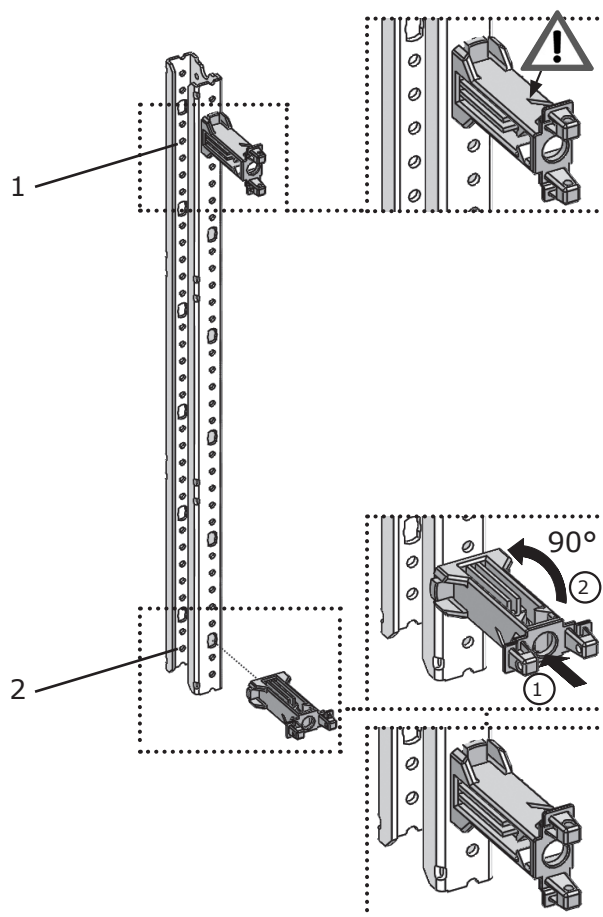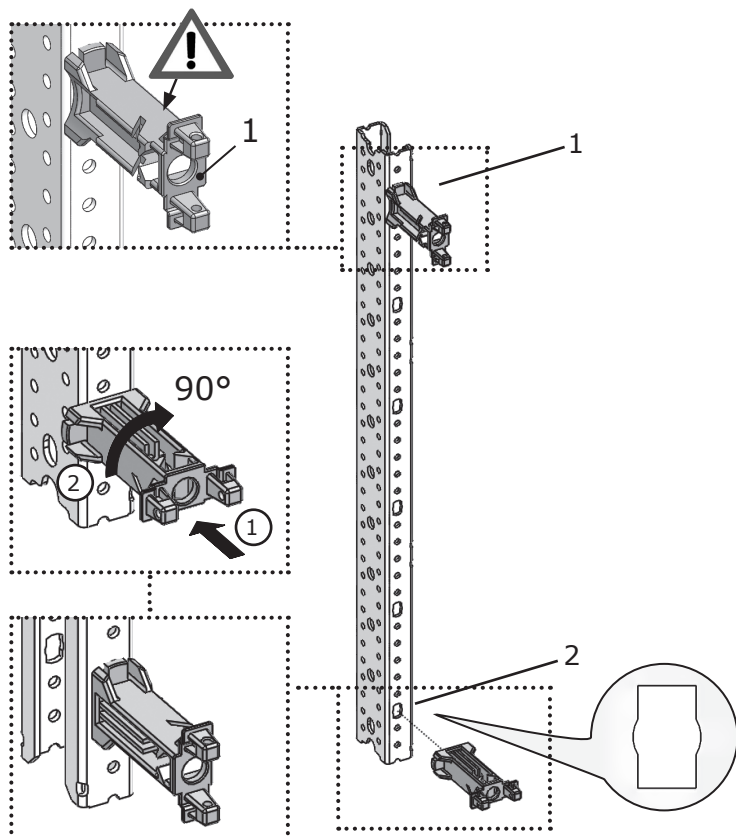


2

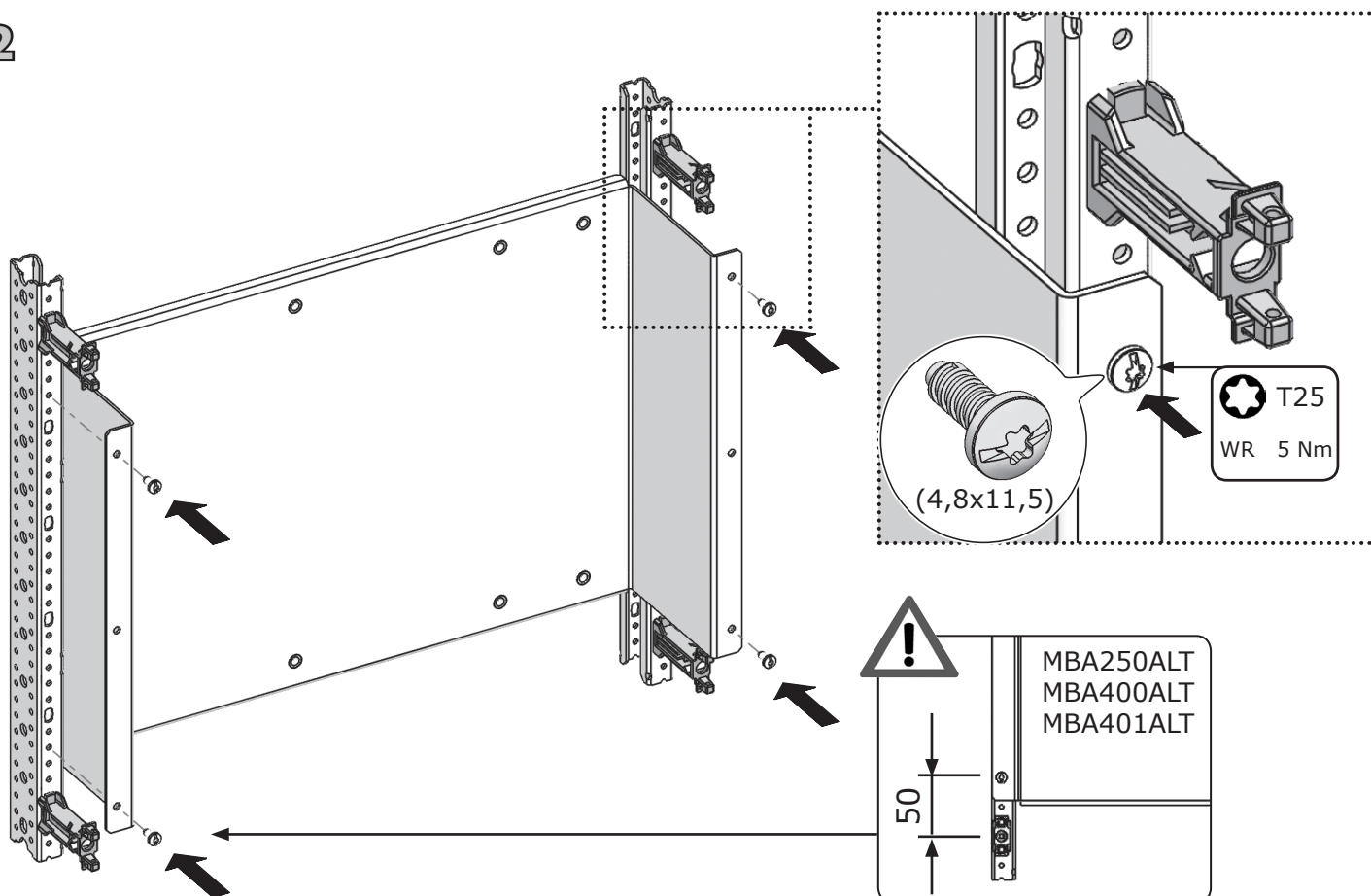

3

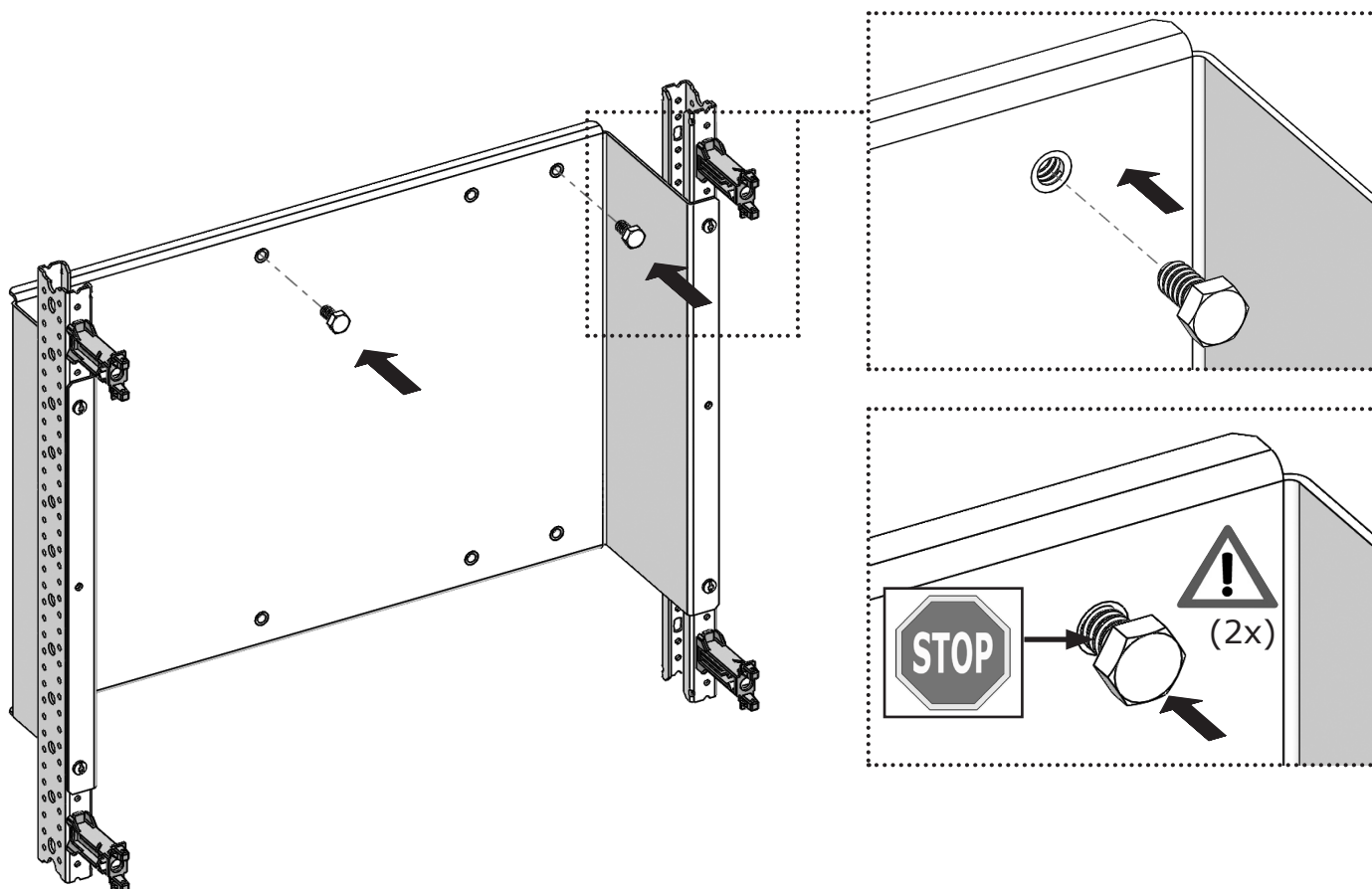

4

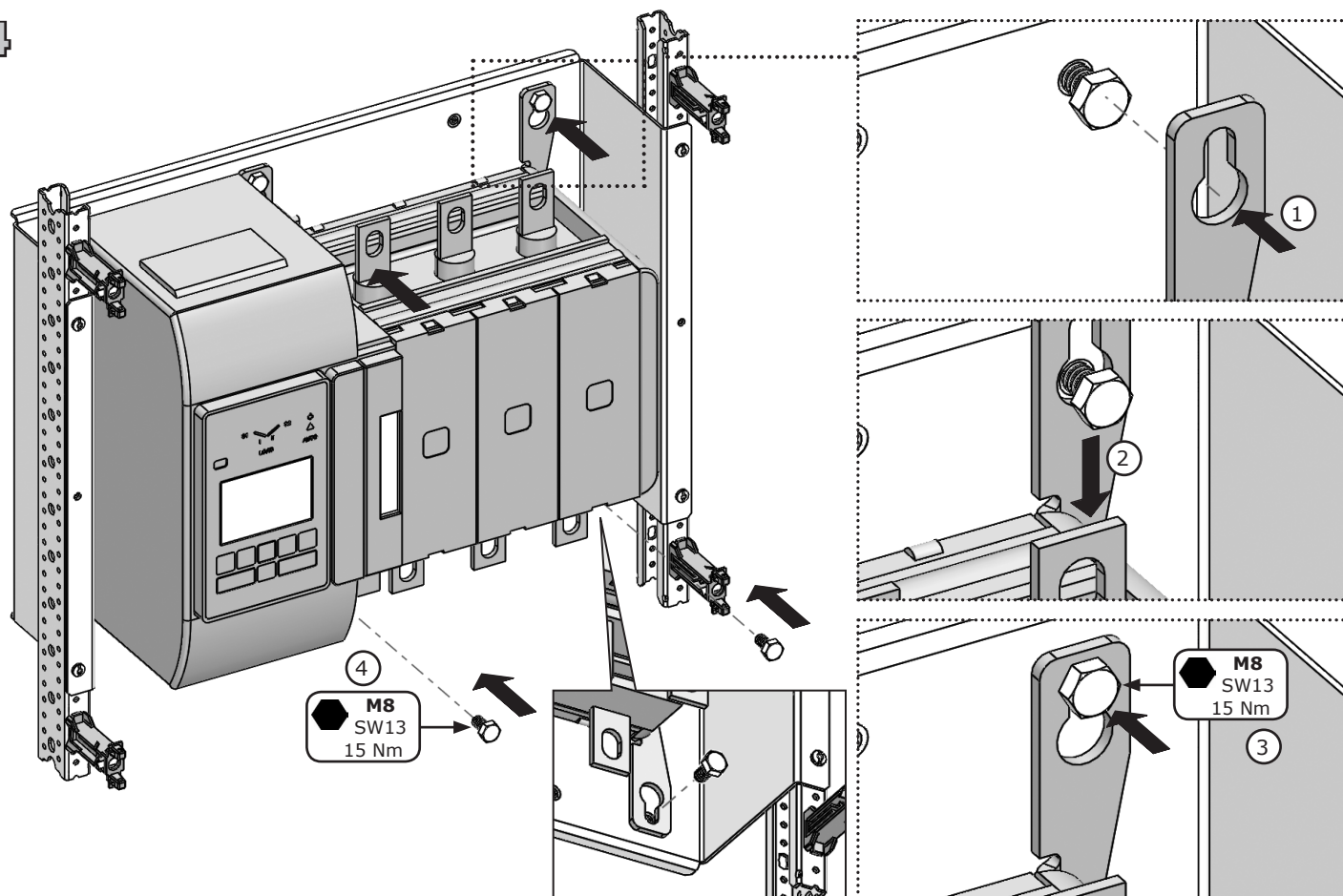

5

