





MX208LX

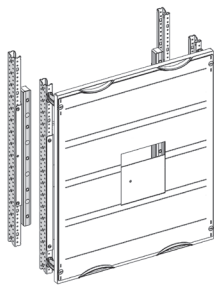

MX208LXB

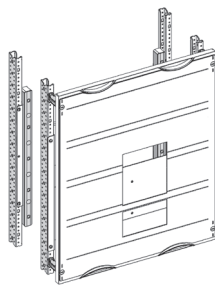


MX210LX

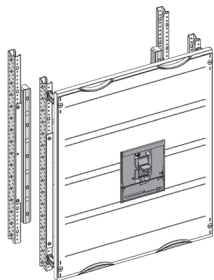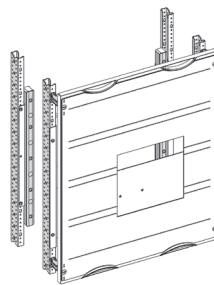


XT5

○ 4p

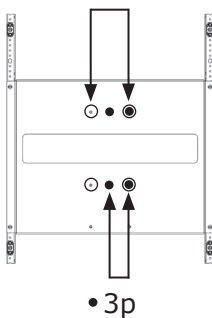


• 3p

MX208LX

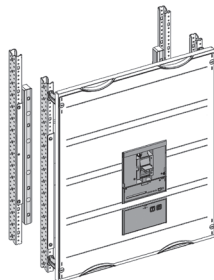


XT5

○ RC unten

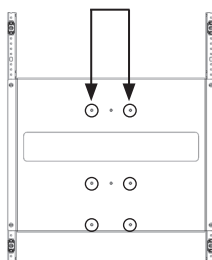


MX208LXB

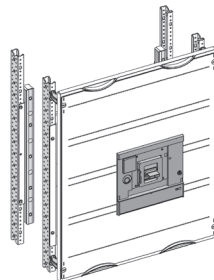


XT6/7

○ 4p

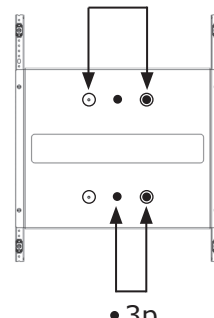


• 3p

MX210/212LX

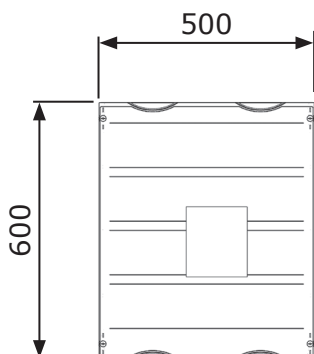

1

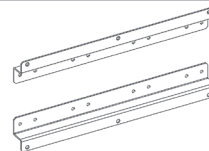


2x

2



10x

 3



2x

4



 
8x

5




8x

6




8x

7

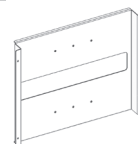


1x

 8



4x

 
9



1x



 [www.striebelundjohn.com](http://www.striebelundjohn.com)



T25/30



SW16



PH2











WR








ED




1

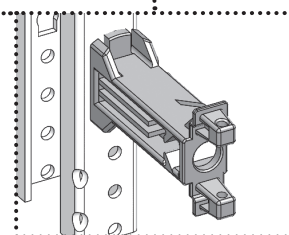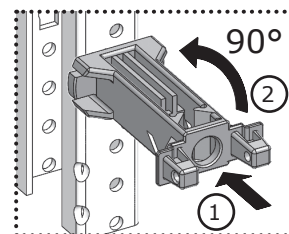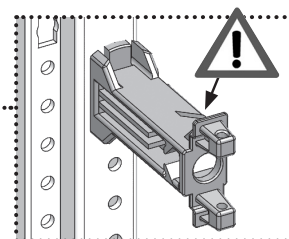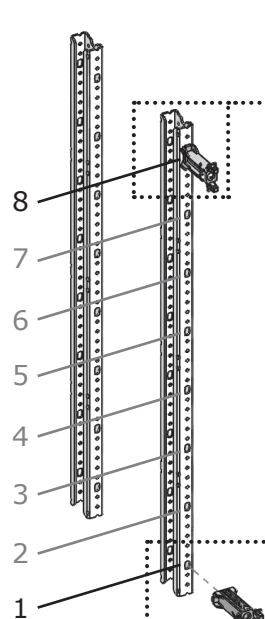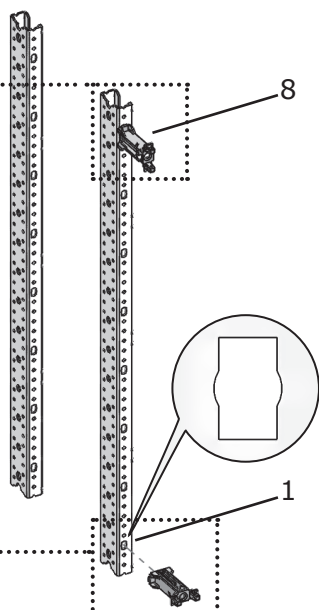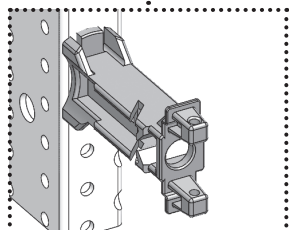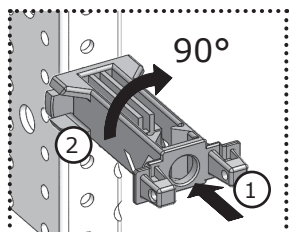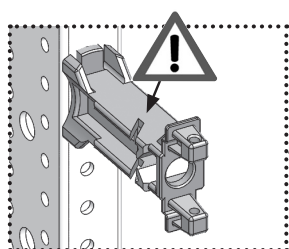



2

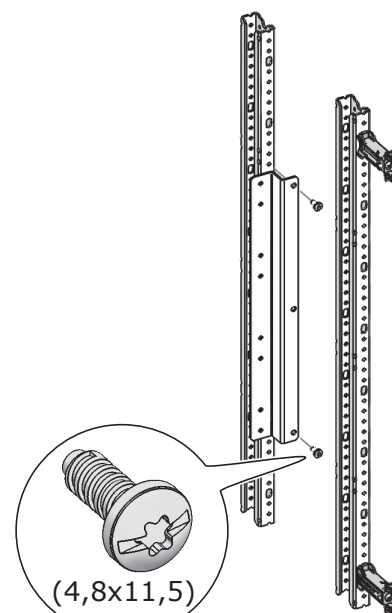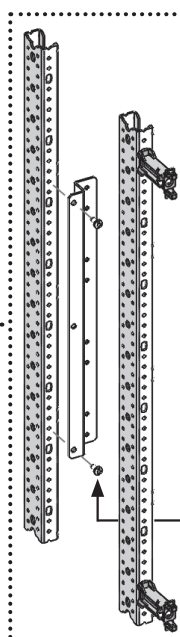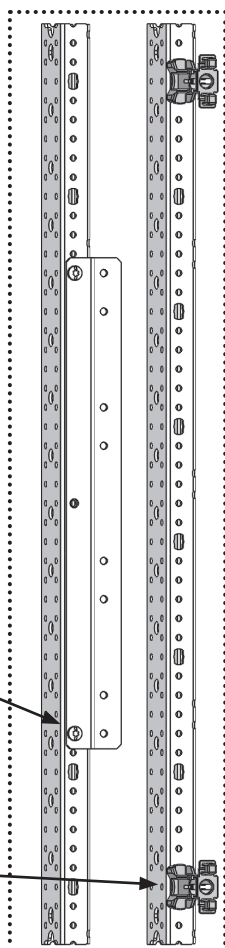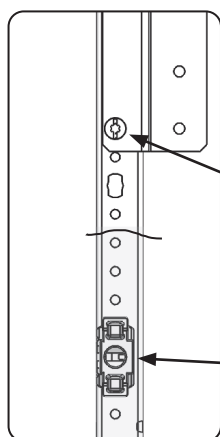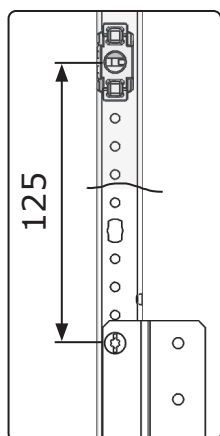



3

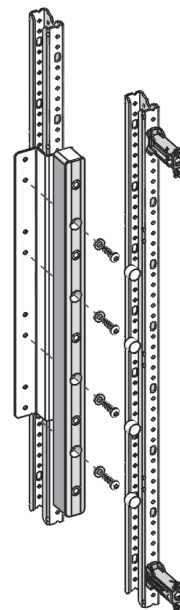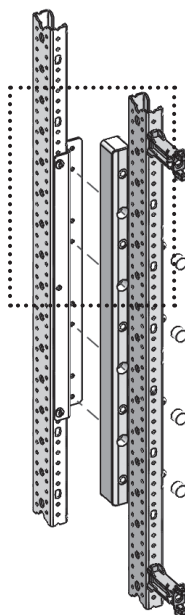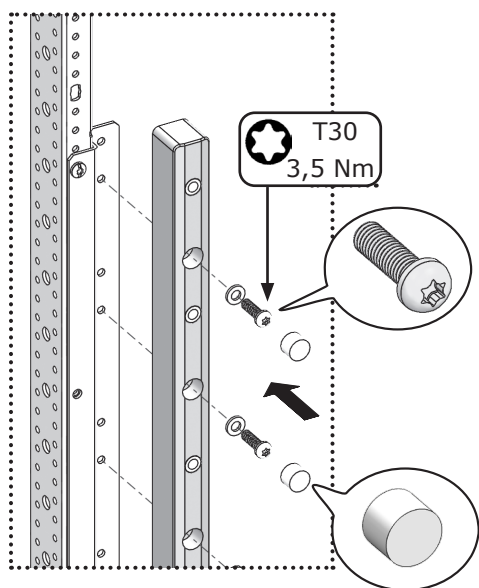


4

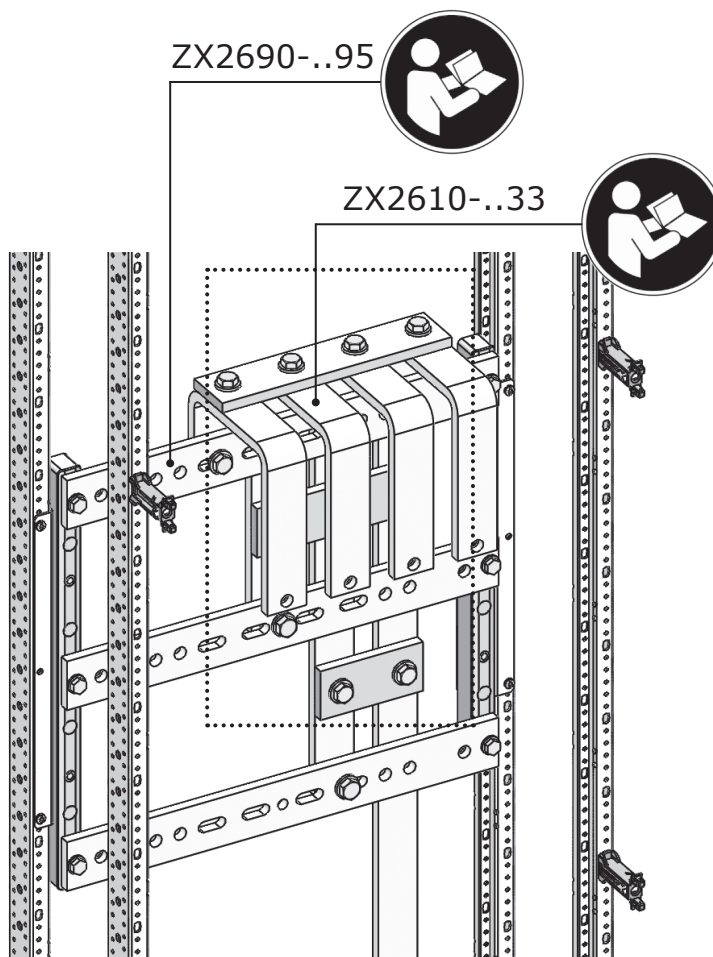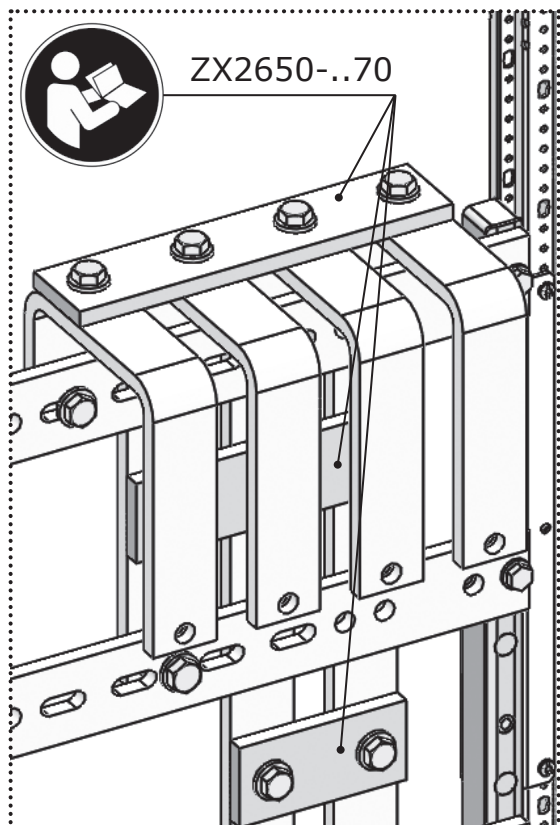

**5**

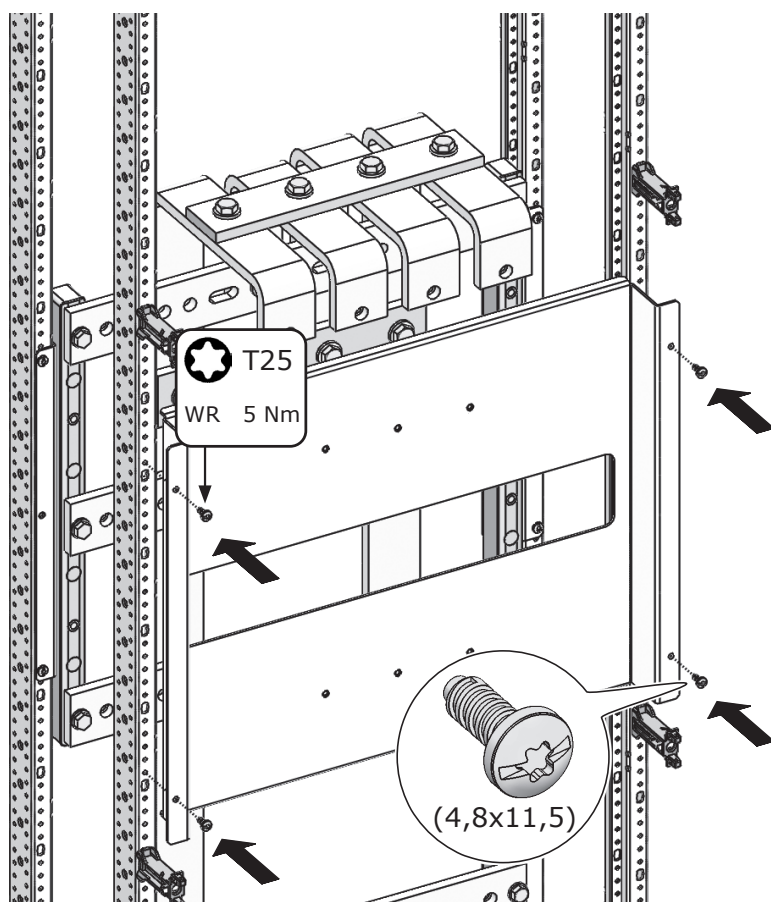
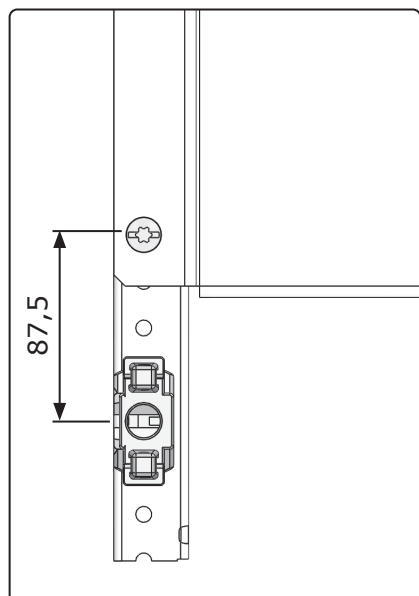


**6**



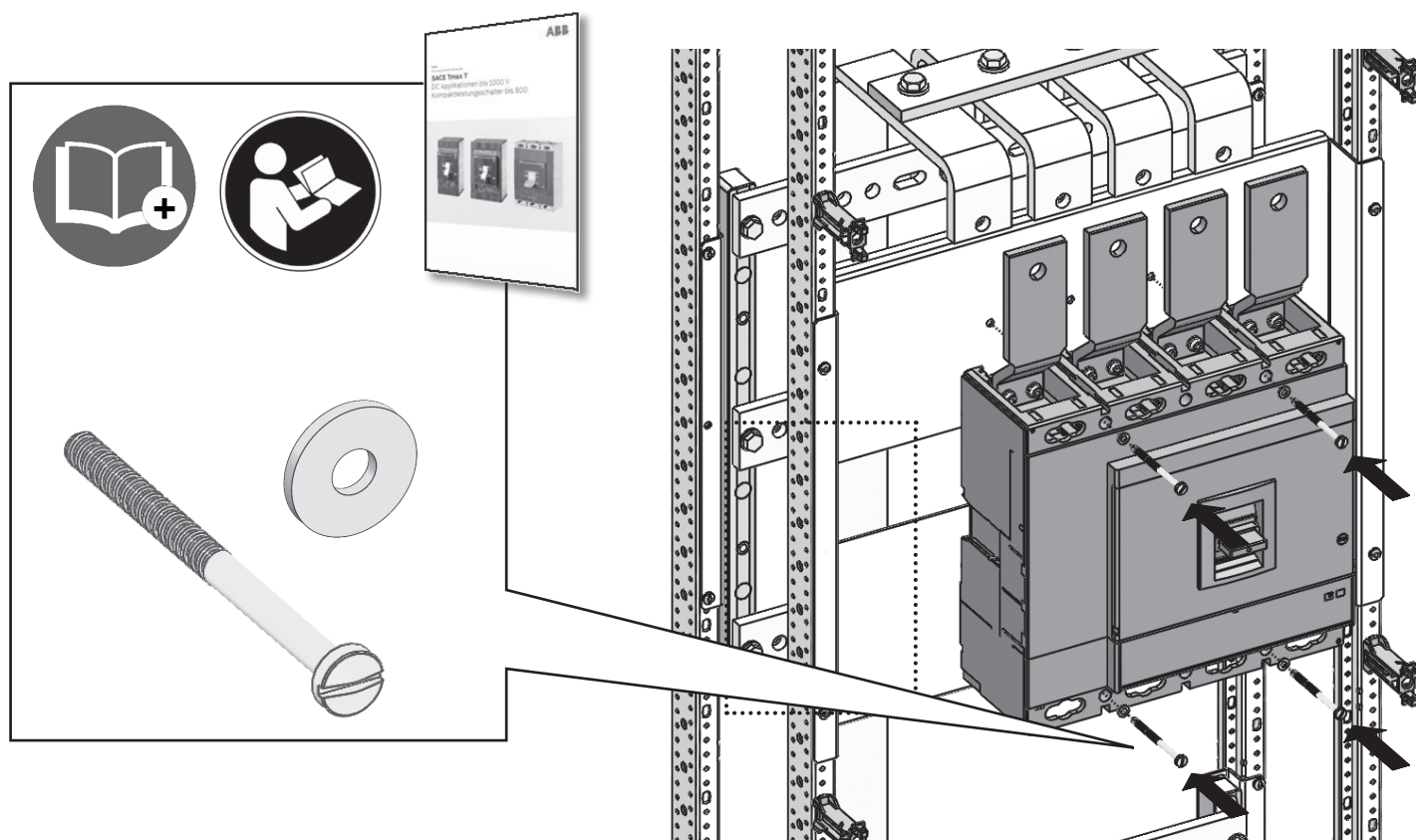




7

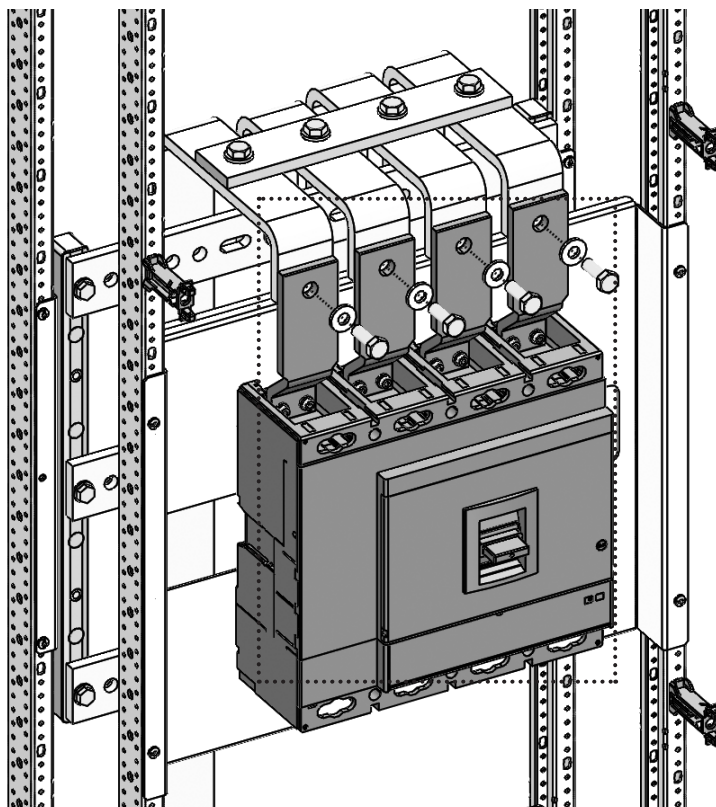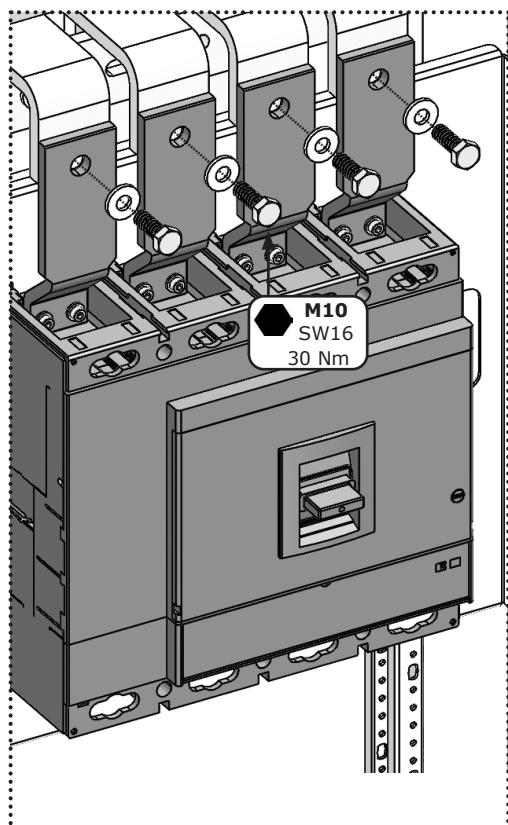

8

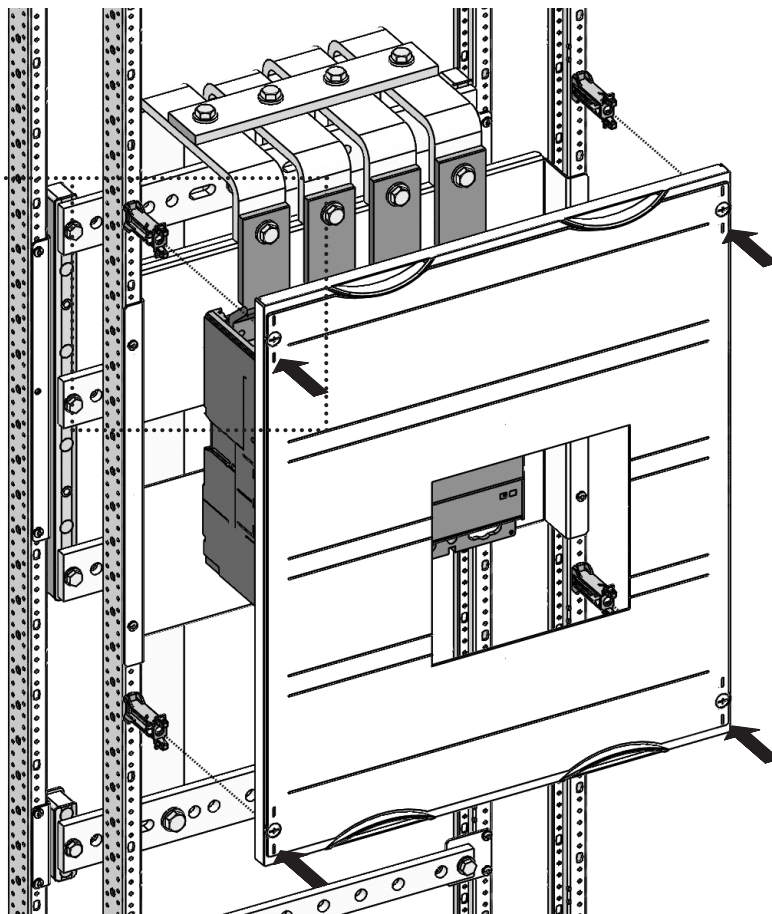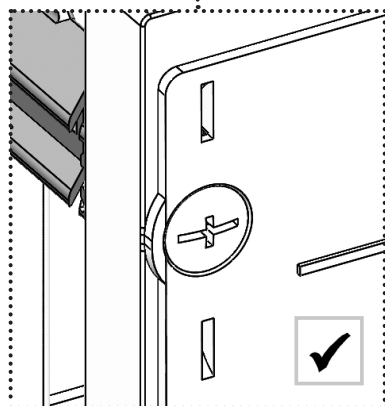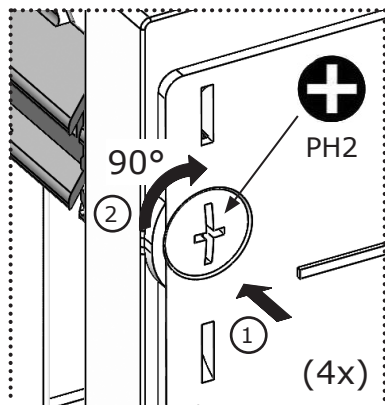

9

