


Accessories

GF4300


- » Gateway
- » Support two outdoor stations when needed

System diagram

Scenario 1-basic: one outdoor station and one indoor station

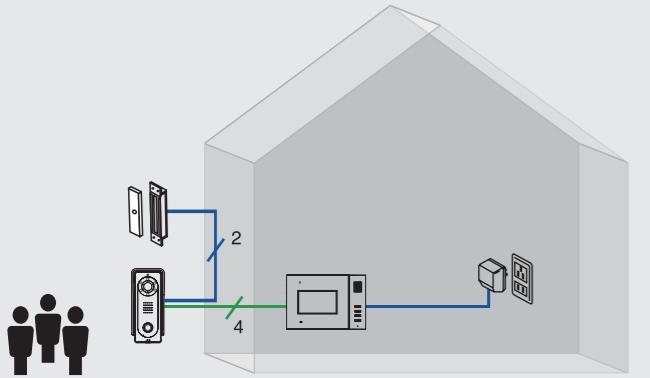

Scenario 2-maximum: two outdoor stations and four indoor stations

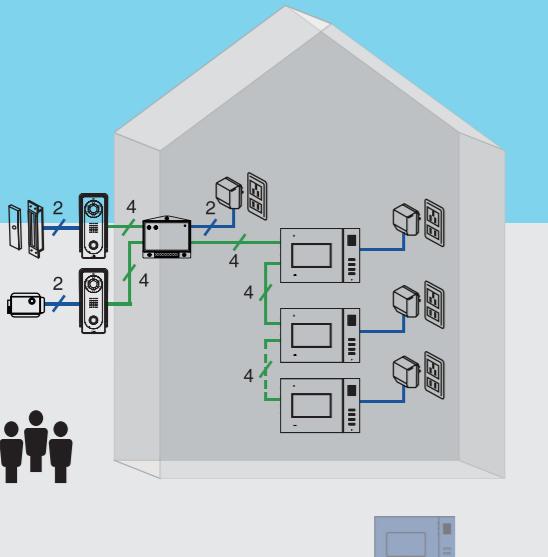

Remark:

- » GF4300 is needed when there are two outdoor stations
- » FG5G91-C needs an extra power supply

Contact us

ABB (United Arab Emirates)
Industries(L.L.C)
P.O.Box 11070 Dubai-UAE
T : +971-4-3147 586
F : +971-4-3401 541

www.abb.com

2TMC104023L0202


08-2015 XM-WMX 2000



G kit
G Range Door Entry System



The ABB G kit is the 4-wire system used in the villa segment, it is DIY design which is convenient for installation. Intercom is available between indoor stations. The system's maximum capacity is two outdoor stations and four indoor stations. The user can monitor two entries by turns, which will help better understand the outside circumstance.

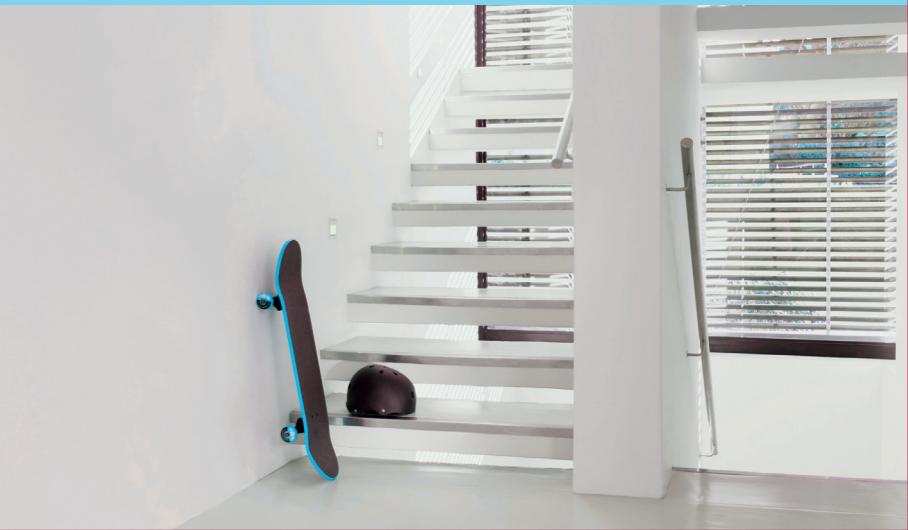



kit GFG9V1



GF5G91-C

- » 272X150X68.5cm
- » Status indication
- » Stainless steel
- » Camera can be adjustable
- » Flush-mounted
- » Nameplate replacement
- » With ID card reader
- » Anti-fog
- » Friendly voice



GF3010

- » 220X150X25cm
- » 5" TFT
- » Resolution: 320X234
- » Surface-mounted
- » Intercom between indoor stations
- » Adjustment of brightness, contrast, chroma, ring volume and voice volume



Power supply

- » Adapter, transformer for optional
- » Input: AC 100V~240V
- » Output: 14VDC



GF3010

- » 220X150X25cm
- » 5" TFT
- » Resolution: 320X234
- » Surface-mounted
- » Intercom between indoor stations
- » Adjustment of brightness, contrast, chroma, ring volume and voice volume



Power supply


- » Adapter, transformer for optional
- » Input: AC 100V~240V
- » Output: 14VDC



kit GFS7V1

GF5S70-C

- » 135X58X48cm
- » Zinc alloy
- » Surface-mounted
- » Small and exquisite
- » Comfortable and simple operation

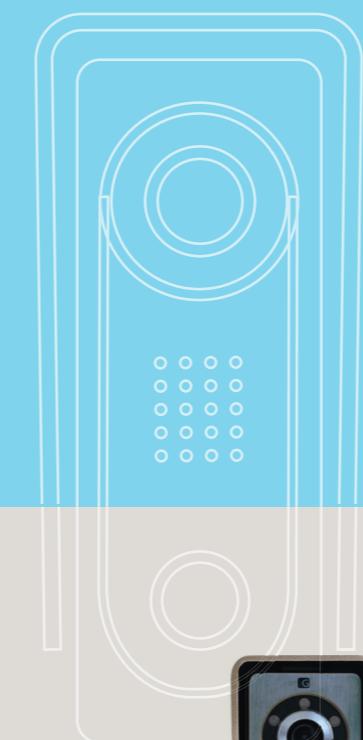

kit GFS7V11



GF5S70-C

- » 135X58X48cm
- » Zinc alloy
- » Surface-mounted
- » Small and exquisite
- » Comfortable and simple operation



GF3110

- » 308X150X25 cm
- » 7" TFT
- » Resolution: 320X234
- » Surface-mounted
- » Intercom between indoor stations
- » Adjustment of brightness, contrast, chroma, ring volume and voice volume



Power supply

- » Adapter, transformer for optional
- » Input: AC 100V~240V
- » Output: 14VDC



kit GFS7V3

GF5S70-C

- » 135X58X48cm
- » Zinc alloy
- » Surface-mounted
- » Small and exquisite
- » Comfortable and simple operation



GF3030

- » 185X120X31cm
- » 3.5" TFT
- » Resolution: 320X234
- » Surface-mounted
- » Intercom between indoor stations
- » Adjustment of brightness, contrast, chroma, ring volume and voice volume



Power supply

- » Adapter, transformer for optional
- » Input: AC 100V~240V
- » Output: 14VDC