

RED•DOT®

Outdoor weatherproof products




01

01 Dimensions
Frame: 24 in. W x 54 in. H x 24 in. D
Header: 24 in. W x 7 in. H



1. Innovative outdoor weatherproof solutions
2. Exterior protection

Plan-O-Gram Display unit

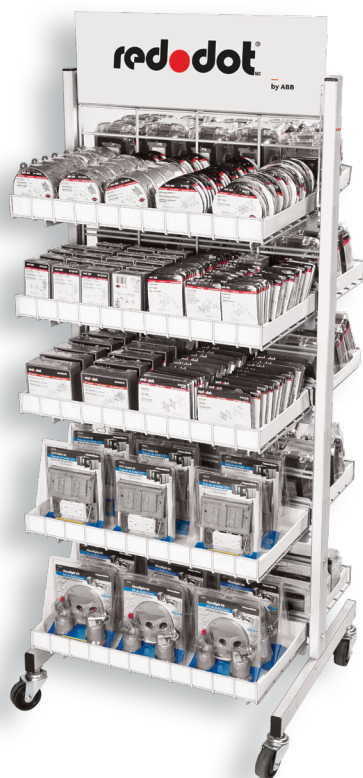

A1	A1	A1	A2	A2	A3
A4	A4	A4	A5	A6	A7
A8	A8	A9	A10		
A11	A11	A11			
A12	A12	A12			



Side A

Refer to Quick-Pop brochure
Template, ELIP Merchandising
for display accessories and shelves.

	Cat. No.	Description	Qty/ Pkg	Order Qty
	S110CN	Outdoor round box, ½ in. NPT, silver	16	32
A1	S110WHCN	Outdoor round box ½ in. NPT, white	16	option
	S110BRCN	Outdoor round box ½ in. NPT, bronze	16	option
A2	S341E	Outdoor round cover Blank, silver	40	40
A3	S-1-RD	Outdoor round cover ½ in. NPT, silver	50	50
	S100CN	Outdoor rectangular box ½ in. NPT, silver	20	20
A4	S100BRCN	Outdoor rectangular box ½ in. NPT, bronze	20	Option
	S100WHCN	Outdoor rectangular box ½ in. NPT, white	20	Option
	S340E	Outdoor rectangular cover blank, silver	42	43
A5	S340BRE	Outdoor rectangular cover blank, bronze	42	Option
	S340WHE	Outdoor rectangular cover blank, white	42	Option
	S310E	Outdoor duplex cover horizontal, silver	36	36
A6	S310BRE	Outdoor duplex cover horizontal, bronze	36	Option
	S310WHE	Outdoor duplex cover horizontal, white	36	Option
	S309E	Outdoor duplex cover vertical, silver	24	24
A7	S309BRE	Outdoor duplex cover vertical, bronze	24	Option
	S309WHE	Outdoor duplex cover vertical, white	24	Option
A8	S400CN	Outdoor 2 gang box ½ in. NPT, silver	12	12
A9	S440E	Outdoor 2 gang cover blank, silver	42	42
A10	S413E	Outdoor 2 gang cover GFCI, silver	8	16
A11	CS315	Outdoor box kit: box, GFCI device and cover, silver	4	8
		Outdoor double lamp kit:		
A12	CS212	round box, lampholders, silver	4	8



B1	B1	B1	B1	B1
B2	B2	B2	B2	B2
B3	B3	B3	B3	
B4	B4	B4	B4	B4
B5	B5	B6	B6	B6

Side B

	Cat. No.	Description	Qty/ Pkg	Order Qty
	CKPS	While-in-use nonmetallic cover One gang, 2-½ in. D, clear	7	21
B1	CKPS-BR	While-in-use nonmetallic cover One gang, 2-½ in. D, bronze	7	Option
	CKPS-G	While-in-use nonmetallic cover One gang, 2-½ in. D, grey	7	Option
	CKPS-W	While-in-use nonmetallic cover One gang, 2-½ in. D, white	7	Option
	CKPM	While-in-use nonmetallic cover One gang, 2-¾ in. D, clear	8	24
B2	CKPM-BR	While-in-use nonmetallic cover One gang, 2-¾ in. D, bronze	8	Option
	CKPM-G	While-in-use nonmetallic cover One gang, 2-¾ in. D, grey	8	Option
	CKPM-W	While-in-use nonmetallic cover One gang, 2-¾ in. D, white	8	Option
	2CKPM	While-in-use nonmetallic cover Two gang, 2-¾ in. D, clear	4	12
B3	2CKPMBR	While-in-use nonmetallic cover Two gang, 2-¾ in. D, bronze	4	Option
	2CKPMG	While-in-use nonmetallic cover Two gang, 2-¾ in. D, grey	4	Option
	2CKPMW	While-in-use nonmetallic cover Two gang, 2-¾ in. D, white	4	Option
B4	CKPL	While-in-use nonmetallic cover One gang, 4-½ in. D, clear	4	12
B5	CKMU	While-in-use metallic cover One Gang, 3-1/4 in. D, Horizontal, grey	4	4
B6	CKMUV	While-in-use metallic cover One gang, 3-¼ in. D, vertical, grey	8	8