

Colours of inspiration.
basic55®

Power and productivity
for a better world™

ABB



Setting the tone.
Enjoying aesthetics.



Living space takes on the personal touch only with individual details. Furniture, floors, accessories and colours as well as matching wall design play an important role here. The very expressive basic55® light switch range offers here a comprehensive colour concept for the design of living spaces. When viewed from the current language of colour expressed by international architects and designers it convinces with classic colours which reflect the zeitgeist of modern living style.

One concept Numerous possibilities.

basic55® Trendline



01



02

Those who design their living space wish to do it according to their own personal design concept. Which means that the colours must match the concept. And here basic55® convinces with two distinctive colour ranges. The numerous available combinations of frames, rockers and colour rings make it possible to adapt them harmoniously to all surroundings and individual style.

basic55® Baseline



03



04

01 basic55®, entrée-grey / chalet-white

02 basic55®, château-black / chalet-white

03 basic55®, alpine white / blue

04 basic55®, alpine white / orange

Contents

01



Trendline.

basic55®, chalet-white	12
basic55®, maison-beige	14
basic55®, entrée-grey	18
basic55®, château-black	20
basic55®, foyer-red	24
basic55®, bistro-blue	26
basic55®, champagne	30
Light switch colour overview	32

02



Baseline.

basic55®, alpine white / orange	36
Decorative styling frames	38
basic55®, luminous	40
basic55®, white / white	42
Light switch colour overview	44

03



Function overview.

basic55® Function overview	46
Switch range	48
Overview of product range	50

04

Overview for ordering.

Rocker switches	53
Cover plates	54
SCHUKO® socket outlets	55
Busch-Comfort switch	58
Cover frames	59



01

basic55® Trendline.
Freedom for individuality.

Colours are emotions. They influence how we feel. They shape, connect, provide contrasts. They display flair and creativity. The colours of basic55® give your room design a new dimension. They are warm, harmonious, comfortable, elegant. They lend concepts for living an individual flair and turn light switches into high-quality design objects.

Living style.

Perfection in every detail.





Timeless elegance.
Pure and without frills.



01 basic55®, chalet-white / château-black

02 basic55®, chalet-white / chalet-white

01

The modern light switch is more than just a functional element. It is a design object. It reflects the personality of the residents. It is an eye-catcher on the wall. With its colours of chalet-white or chalet-white / château-black basic55® convinces with its timeless elegance and puristic appearance.



02

Clear design. Stylish and elegant.



01 basic55®, maison-beige / château-black

02 basic55®, maison-beige / chalet-white


01

A light switch is a small object but has a huge effect. Together with the personal concept of a harmonious living style it lends support to the creative design of individual living spaces. With its colour range of maison-beige / chalet-white or maison-beige / château-black, basic55® captivates with its subtleties of style and clear design.



02



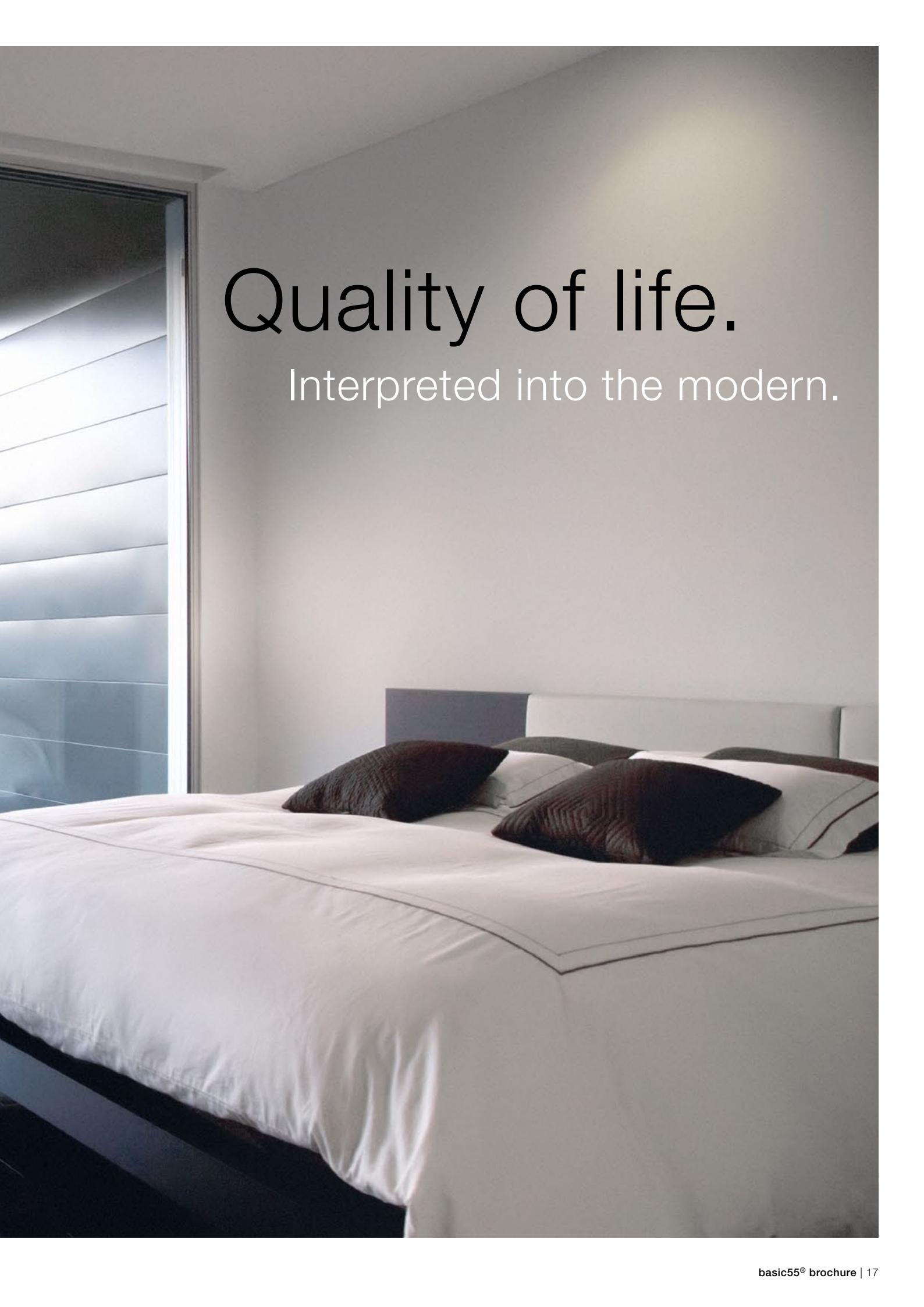

Quality of life.

Interpreted into the modern.

Harmonious composition. Subdued and timeless.



01 basic55®, entrée-grey / château-black

02 basic55®, entrée-grey / chalet-white

01

Harmony exists when everything in the room is perfect. Because each detail fits in with the overall concept. Whether furniture, accessories or light switches – it has never been better and more ideal to turn one's personal style into reality. With its colour range of entrée-grey/chalet-white or entrée-grey / château-black, basic55® impresses with its consistent design and timeless aesthetics.



Classic combination. Modern and enduring.



01 basic55®, château-black/ château-black

02 basic55®, château-black / chalet-white

01

A classic which sets new standards. This equally applies to colours. Black and white have been the epitome of purism, aesthetics and extravagant style from time immemorial. In the colour range of château-black/chalet-white or château-black/ château-black, basic55® impresses with its timeless modern style and clear optics.



02

Contrasts.

Exclusively set into the scene.





Modern interpretation. Extravagant and different.



01 basic55®, foyer-red/ château-black

02 basic55®, foyer-red/ chalet-white

01

Sometimes it is the contrasts which the observer finds exciting. They exceed normal expectations and magically attract the attention. Rooms take on a unique character. In the colour versions of foyer-red/chalet-white or foyer-red/ château-black, basic55® exudes extravagance and a creative lifestyle.



02

Expressive optics. Individualistic and creative.



01 basic55®, bistro-blue / château-black

02 basic55®, bistro-blue / chalet-white

01

Modern living is defined by the creative use of up-to-date colour trends. To turn the personal style into reality with these high-quality, visually attractive light switches is a special pleasure. In colour versions bistro-blue / chalet-white or bistro-blue / château-black, basic55® impresses with its expressiveness and individual class.



02

Living space.

Of personal design.





Individualistic style. Tasteful and luxurious.

If you value the highest of standards and aesthetic requirements in every detail then you make also no compromises when it comes to light switches. With these objects the highest requirements are first-class quality, high-grade equipment and luxurious optics. basic55® meets these requirements, and with the extravagant and stylish champagne colour version offers an exclusive solution.



01

basic55® Trendline. Creativity without limits.



01



03



05



07



02



04



06



08

The basic55® Trendline range has many facets. And it fulfils every wish for creative design. Six frame colours can be perfectly combined with two rocker colours to meet individual expectations. Plus the luxurious champagne version as alternative. Thirteen exclusive options for combining puristic design with modern, pleasant colours.



09



11



13



10



12

01 basic55®, chalet-white / chalet-white

02 basic55®, chalet-white / château-black

03 basic55®, maison-beige / chalet-white

04 basic55®, maison-beige / château-black

05 basic55®, bistro-blue / chalet-white

06 basic55®, bistro-blue / château-black

07 basic55®, entrée-grey / chalet-white

08 basic55®, entrée-grey / château-black

09 basic55®, foyer-red / chalet-white

10 basic55®, foyer-red / château-black

11 basic55®, château-black / chalet-white

12 basic55®, château-black / château-black

13 basic55®, champagne



02

basic55® Baseline.
The focal point, but discreetly.

basic55® Baseline is an innovative colour concept which inspires the imagination and projects the desire for individual styling elements into a new dimension. Being colourful and yet discreet, it is inspiration at its best. And it offers a variety of options for the creative design of living space.

Personal taste. Consistently visualized.

Individual requirements interpreted into the minutest detail lend living space character. With the harmonious combination of white frames and rockers as well as eight subtle colour rings the basic55® Baseline blends perfectly with the optics and superior quality of international concepts of living. From elegant to creative the most varied design concepts can be turned into reality.



basic55® Baseline. Scope for ideas.



01



03 luminous



02



04

01 basic55®, alpine white / alpine white

02 basic55®, alpine white / yellow

03 basic55®, alpine white / luminous

04 basic55®, alpine white / orange



05



07



06



08

05 basic55®, alpine white / apricot

06 basic55®, alpine white / silver


07 basic55®, alpine white / blue

08 basic55®, alpine white / light green

A shining example for functional design.



Pure and elegant during the day and a pure delight in the evening. The illuminated colour frame lends this interesting basic55® version an especially practical note. It turns it into a safe signpost in the dark. An intelligent as well as pleasant effect which combines perfect aesthetics with practical value.

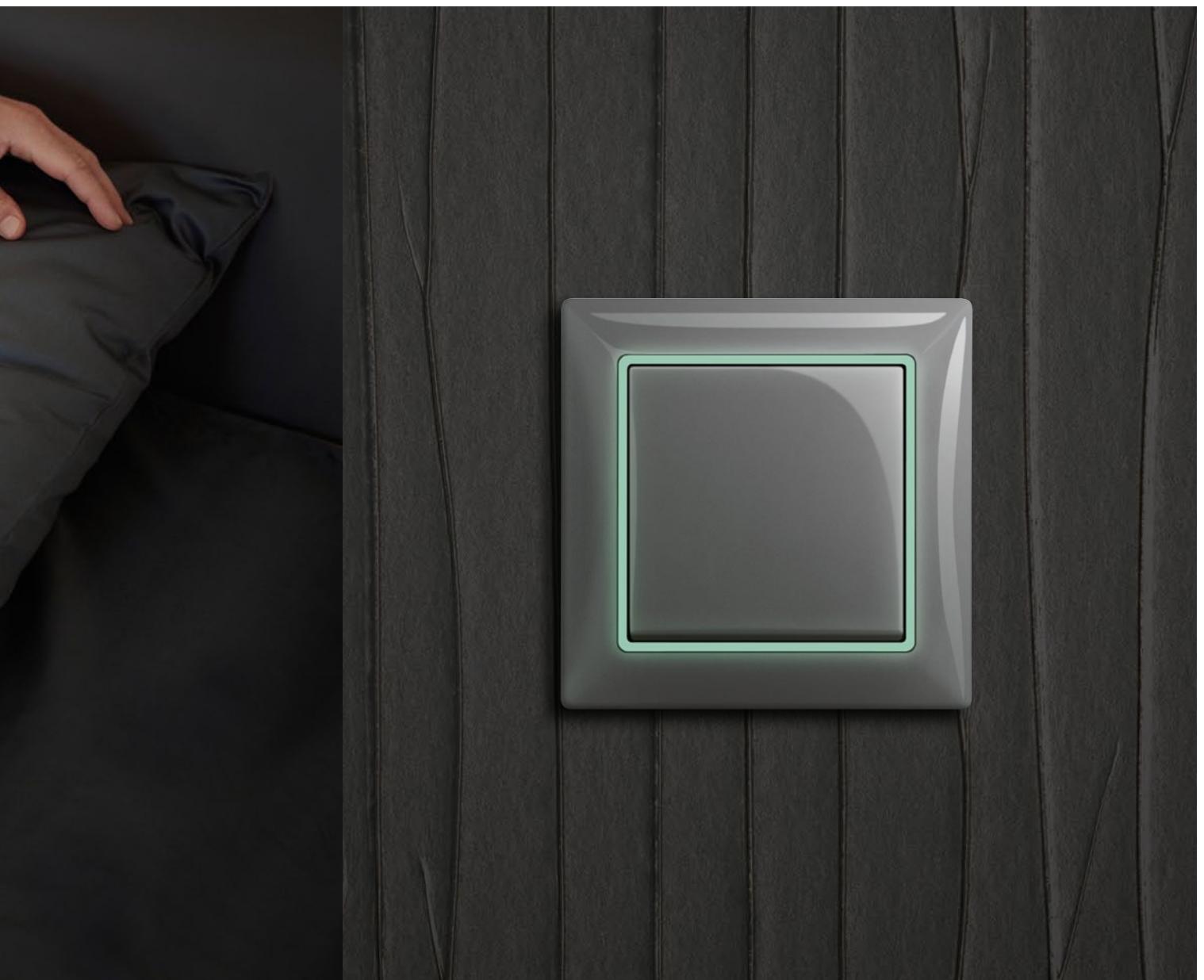

In bright rooms basic55® alpine white/luminous convinces with its puristic optics. In the dark the illuminated colour frame creates an amazing effect.

Subdued optics. Timeless and clear.

The charm of a style of living is the result of the sum total of well-matched details. The interpretation of the walls here is a deciding factor in the selection of the colour of the light switch. The subtle, harmonious tone-in-tone design of the basic55® white / white version adapts to any style of living and displays a sense of timeless, puristic aesthetics.



01

basic55® Baseline. Individuality for every room.



01



03 luminous



05



07



02



04



06



08

There are no more limits to the demands made on the creative design of living space. basic55® Baseline convinces with its clear, white frames and rockers as well as discreet colour rings, adding exciting accents. They consist of nine versions suitable for integrating into any living style. This gives each room its own individual colour concept in which even the light switches become a feast for the eyes.



09

01 basic55®, alpine white / alpine white

02 basic55®, alpine white / yellow

03 basic55®, alpine white / luminous

04 basic55®, alpine white / orange

05 basic55®, alpine white / apricot

06 basic55®, alpine white / silver

07 basic55®, alpine white / blue

08 basic55®, alpine white / light green

09 basic55®, white / white



03

Function overview.
Design with comfort.

basic55[®] Trendline and basic55[®] Baseline. Together with many technical functions the new generation of switches guarantees comfort, safety and efficiency. Whatever the desired power – the selection does justice to every requirement for modern design of living space.

Versatile comfort. To meet the highest standards.

Switches and push switches



01 02 03 04 05



06 07 08 09

Socket outlets



10 11 12 13 14

Blind switches



15 16 17 18 19

Communication systems



20 21 22 23 24




25 26 27 28 29

01	Switch/button with rocker	10	SCHUKO® socket outlet, shuttered	20	Antenna socket
02	2gang switch	11	SCHUKO® socket outlet and "DATA" marking	21	Antenna socket for TV
03	2gang switch with neon lamp	12	Socket outlet, shuttered with earthing pin	22	Antenna socket for Radio/TV/SAT
04	3gang 1way switch	13	SCHUKO® socket outlet with hinged lid	23	Light signal
05	Push switch with doorbell symbol and labeling field	14	SCHUKO® double socket outlet	24	Busch-iDock
06	Rotary dimmer	15	Blind switches/push-buttons	25	Loudspeaker outlet
07	Push switch with illumination	16	Blind switches/push-buttons with rotary knob	26	Telephone Single Outlet (TAE)
08	20 A DP switch with red neon indicator	17	Comfort timer	27	Universal data connecting unit
09	Busch-Comfort switch®	18	Card switch	28	Universal data connecting unit, 2gang
		19	Room temperature controller	29	Loudspeaker

Cover plates for vertical or horizontal installation, available in 1gang to 5gang

01	basic55®, 1gang
02	basic55®, 2gang
03	basic55®, 3gang
04	basic55®, 4gang
05	basic55®, 5gang

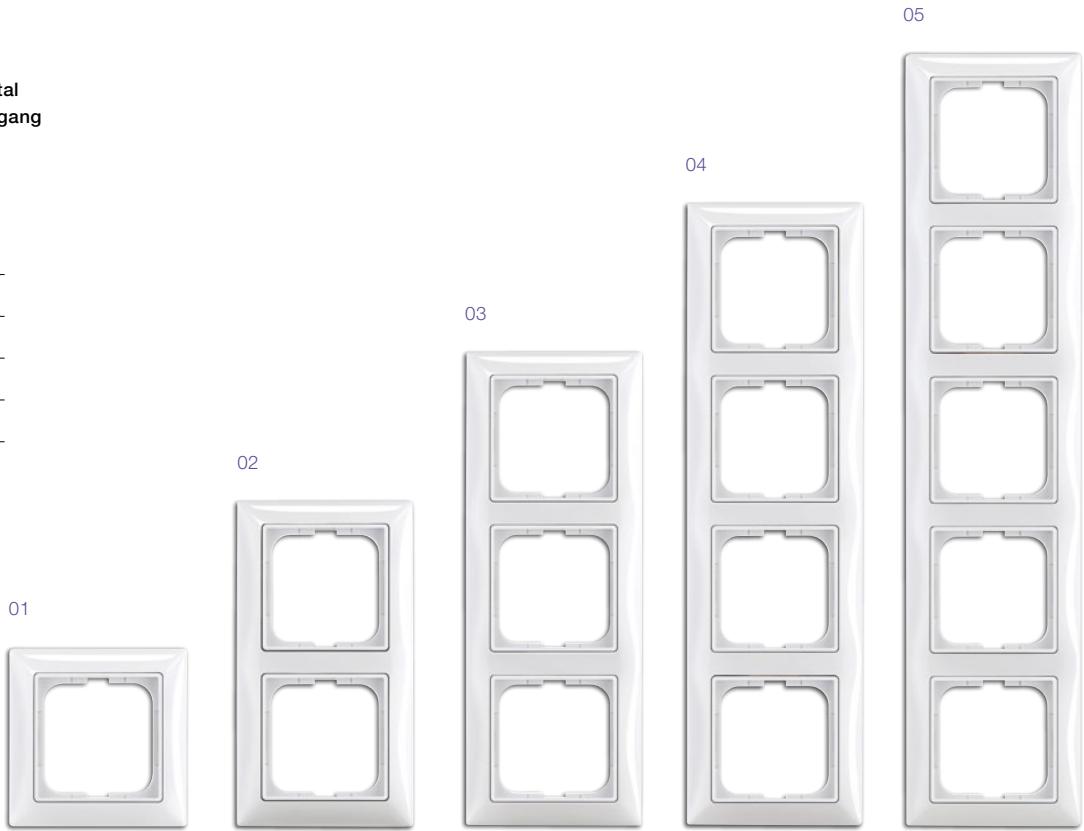

basic55®.

Expression of individual style.

basic55® Trendline



01



02



07



08



03



04



09



10



05



06



11



12



13

01 basic55®, chalet-white / chalet-white

02 basic55®, chalet-white / château-black

03 basic55®, maison-beige / chalet-white

04 basic55®, maison-beige / château-black

05 basic55®, bistro-blue / chalet-white

06 basic55®, bistro-blue / château-black

07 basic55®, entrée-grey / chalet-white

08 basic55®, entrée-grey / château-black

09 basic55®, foyer-red / chalet-white

10 basic55®, foyer-red / château-black

11 basic55®, château-black / chalet-white

12 basic55®, château-black / château-black

13 basic55®, champagne

basic55® Baseline



+



+



01



03 luminous



05



07



02



04



06



08



09

01 basic55®, alpine white / alpine white

02 basic55®, alpine white / yellow

03 basic55®, alpine white / luminous

04 basic55®, alpine white / orange

05 basic55®, alpine white / apricot

06 basic55®, alpine white / silver

07 basic55®, alpine white / blue


08 basic55®, alpine white / light green

09 basic55®, white / white

04

Overview for ordering.
The perfect solution for every
requirement.

The basic55® program offers over 225 creative versions for the individualistic design of living space. With innovative products which guarantee greater efficiency, safety and comfort. basic55® is suitable for use in new buildings as well as for later modernization. And it lends a high-quality living style character and distinctness.

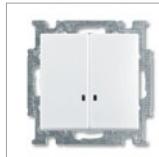Product	Article-No.	Order-No.	Pack/Qty	Product	Article-No.	Order-No.	Pack/Qty
	Switch with rocker 1gang 1way, SP With neon lamp. Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1				Switch with rocker With neon lamp. Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1		
92 white	2006/1 UC-92-507 NEW	1012-0-2146	10/100	92 white	2006/5 UCGL-92-507 NEW	1012-0-2157	10/100
93 champagne	2006/1 UC-93-507	1012-0-2164	10/100	93 champagne	2006/5 UCGL-93-507	1012-0-2168	10
94 alpine white	2006/1 UC-94-507 NEW	1012-0-2139	10/100	94 alpine white	2006/5 UCGL-94-507 NEW	1012-0-2154	10/100
95 château-black	2006/1 UC-95-507 NEW	1012-0-2174	10	95 château-black	2006/5 UCGL-95-507 NEW	1012-0-2178	10
96 chalet-white	2006/1 UC-96-507	1012-0-2184	10/100	96 chalet-white	2006/5 UCGL-96-507	1012-0-2188	10
	Switch with rocker 1gang 1way, SP With neon lamp. Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1				Switch with rocker 2gang 2way Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1		
92 white	2006/1 UCGL-92-507 NEW	1012-0-2156	10/100	92 white	2006/6/6 UC-92-507 NEW	1012-0-2151	10
93 champagne	2006/1 UCGL-93-507	1012-0-2165	10	93 champagne	2006/6/6 UC-93-507	1012-0-2171	10
94 alpine white	2006/1 UCGL-94-507	1012-0-2153	10/100	94 alpine white	2006/6/6 UC-94-507 NEW	1012-0-2144	10/100
95 château-black	2006/1 UCGL-95-507	1012-0-2175	10	95 château-black	2006/6/6 UC-95-507 NEW	1012-0-2181	10
96 chalet-white	2006/1 UCGL-96-507	1012-0-2185	10	96 chalet-white	2006/6/6 UC-96-507	1012-0-2191	10
	Switch with rocker Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1				Switch with rocker 3 gang 1way, SP Rated voltage: 250 V~ Rated current: 16 AX IEC 60669-1		
92 white	2006/6 UC-92-507 NEW	1012-0-2149	10/100	92 white	106/3/1 UC-92-507 NEW	1012-0-2158	10/100
93 champagne	2006/6 UC-93-507	1012-0-2169	10/100	93 champagne	106/3/1 UC-93-507	1012-0-2163	10
94 alpine white	2006/6 UC-94-507 NEW	1012-0-2142	10/100	94 alpine white	106/3/1 UC-94-507	1012-0-2155	10/100
95 château-black	2006/6 UC-95-507 NEW	1012-0-2179	10/100	95 château-black	106/3/1 UC-95-507	1012-0-2173	10
96 chalet-white	2006/6 UC-96-507	1012-0-2189	10/100	96 chalet-white	106/3/1 UC-96-507	1012-0-2183	10
	Switch with rocker Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1				Switch with rocker 1gang. Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1		
92 white	2006/5 UC-92-507 NEW	1012-0-2148	10/100	92 white	2006/7 UC-92-507 NEW	1012-0-2152	10
93 champagne	2006/5 UC-93-507	1012-0-2167	10/100	93 champagne	2006/7 UC-93-507	1012-0-2172	10
94 alpine white	2006/5 UC-94-507 NEW	1012-0-2141	10/100	94 alpine white	2006/7 UC-94-507 NEW	1012-0-2145	10
95 château-black	2006/5 UC-95-507 NEW	1012-0-2177	10/100	95 château-black	2006/7 UC-95-507 NEW	1012-0-2182	10
96 chalet-white	2006/5 UC-96-507	1012-0-2187	10/100	96 chalet-white	2006/7 UC-96-507	1012-0-2192	10

Product	Article-No.	Order-No.	Pack/Qty	Product	Article-No.	Order-No.	Pack/Qty
	Switch with rocker 1gang DP With neon lamp. Rated voltage: 250 V~ Rated current: 20 AX IEC 60669-1				Push switch with rocker and neutral symbol SP, with normally open contact (operating current). With N terminal. Rated voltage: 250 V~ Rated current: 10 A IEC 60669-1		
92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	NEW 1020/2 UCK-92-507 1020/2 UCK-93-507 1020/2 UCK-94-507 1020/2 UCK-95-507 1020/2 UCK-96-507	1020-0-0090 1020-0-0091 1020-0-0089 1020-0-0092 1020-0-0093	10 10 10 10 10	92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	2026 UCN-92-507 NEW 2026 UCN-93-507 2026 UCN-94-507 2026 UCN-95-507 NEW 2026 UCN-96-507	1413-0-1084 1413-0-1092 1413-0-1081 1413-0-1096 1413-0-1100	10/100 10/100 10 10 10
	Switch with rocker 1)²⁾ 1gang 2way with N-terminal With neon lamp. Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1				Blind switch with cover 1) SP, switch With interlock. Rated voltage: 250 V~ Rated current: 10 AX IEC60669-1		
92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	2006/6 UCK-92-507 NEW 2006/6 UCK-93-507 2006/6 UCK-94-507 2006/6 UCK-95-507 NEW 2006/6 UCK-96-507	1012-0-2150 1012-0-2170 1012-0-2143 1012-0-2180 1012-0-2190	10 10 10 10 10	92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	2006/4 UC-92-507 NEW 2006/4 UC-93-507 2006/4 UC-94-507 2006/4 UC-95-507 NEW 2006/4 UC-96-507	1012-0-2147 1012-0-2166 1012-0-2140 1012-0-2176 1012-0-2186	10 10 10 10 10
1) With 1 mA neon lamp. 2) Illuminable using lamps 8360, 8362, 8363, 8365, 8366, and 8367 and LED inserts.							
	Push switch with rocker SP, with normally open contact (operating current). With N terminal. Rated voltage: 250 V~ Rated current: 10 A IEC 60669-1				Blind switch with cover 1) SP, push switch. With interlock. Rated voltage: 250 V~ Rated current: 10 A IEC60669-1		
92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	2026 UC-92-507 NEW 2026 UC-93-507 2026 UC-94-507 2026 UC-95-507 NEW 2026 UC-96-507	1413-0-1083 1413-0-1091 1413-0-1080 1413-0-1095 1413-0-1099	10/100 10/100 10/100 10 10	92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	2026/4 UC-92-507 NEW 2026/4 UC-93-507 2026/4 UC-94-507 2026/4 UC-95-507 NEW 2026/4 UC-96-507	1413-0-1085 1413-0-1094 1413-0-1082 1413-0-1098 1413-0-1102	10 10 10 10 10
	Push switch with rocker with doorbell symbol and labeling field SP (operating current), With N terminal. Secondary: 250 V~ Rated current: 10 A IEC 60669-1				Blind switch with cover 1) SP, N, E With rotary knob/switch and push switch. Rated voltage: 250 V~ Rated current: 10 AX IEC 60669-1		
92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	NEW 2026 UCN/KL-92-507 2026 UCN/KL-93-507 2026 UCN/KL-94-507 2026 UCN/KL-95-507 2026 UCN/KL-96-507	1413-0-1087 1413-0-1093 1413-0-1086 1413-0-1097 1413-0-1101	10/100 10 10/100 10 10	92 white 93 champagne 94 alpine white 95 château-black 96 chalet-white	2713 UCDR-92-507 NEW 2713 UCDR-93-507 2713 UCDR-94-507 2713 UCDR-95-507 NEW 2713 UCDR-96-507	1101-0-0922 1101-0-0926 1101-0-0920 1101-0-0928 1101-0-0930	10 10 10 10 10
1) These blind switches/push buttons safely prevent a switch-over of the running direction being carried out too quickly.							
1) Blind switches/push switches prevents fast change over between operating directions. 2) Also suitable for DC drives.							

Product	Article-No.	Order-No.	Pack/Qty
	Blind switch with cover¹⁾ ²⁾ SP, N, E With rotary knob/push button. Rated voltage: 250 V~ Rated current: 10 A IEC60669-1		
92 white	2723 UCDR-92-507 NEW	1101-0-0923	10
93 champagne	2723 UCDR-93-507	1101-0-0927	10
94 alpine white	2723 UCDR-94-507 NEW	1101-0-0921	10
95 château-black	2723 UCDR-95-507 NEW	1101-0-0929	10
96 chalet-white	2723 UCDR-96-507	1101-0-0931	10

1) Blind switches/push switches prevents fast change over between operating directions.

2) Also suitable for DC drives.

Product	Article-No.	Order-No.	Pack/Qty
	SCHUKO® socket outlet¹⁾ ²⁾ With marking "DATA" With screwless terminals. 2 P + E Rated voltage: 250 V~ Rated current: 16 A		
92 white	20 EUC/DV-92-507 NEW	2011-0-3856	10
93 champagne	20 EUC/DV-93-507	2011-0-6141	10
94 alpine white	20 EUC/DV-94-507 NEW	2011-0-3854	10
95 château-black	20 EUC/DV-95-507 NEW	2011-0-6143	10
96 chalet-white	20 EUC/DV-96-507	2011-0-6145	10

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.

2) Can only be used in SI frames with adapter 1746-....

	Cover plate¹⁾ For card switch. For insert 2025 U. Suitable for cards sized 54 x 86 mm. The inner part of the cover plate is made of light-conducting plastic, so that the card slot is illuminated.		
92 white	1792-92-507 NEW	1710-0-3865	10
93 champagne	1792-93-507	1710-0-3929	10
94 alpine white	1792-94-507 NEW	1710-0-3864	10
95 château-black	1792-95-507 NEW	1710-0-3933	10
96 chalet-white	1792-96-507	1710-0-3937	10

1) Due to dimensions cover is suitable in cover frames without decorative styling frame only.

	SCHUKO® socket outlet¹⁾ With screwless terminals. 2 P + E Rated voltage: 250 V~ Rated current: 16 A		
92 white	20 EUC-92-507 NEW	2011-0-3857	10/100
93 champagne ²⁾	20 EUC-93-507	2011-0-6140	10/100
94 alpine white	20 EUC-94-507 NEW	2011-0-3855	10/100
95 château-black	20 EUC-95-507 NEW	2011-0-6142	10/100
96 chalet-white	20 EUC-96-507	2011-0-6144	10/100

1) Terminals suitable for loop through connection.

2) Surface painted.

	SCHUKO® socket outlet¹⁾ ²⁾ Shuttered. With screwless terminals. 2 P + E Rated voltage: 250 V~ Rated current: 16 A		
92 white	20 EUCKS-92-507 NEW	2013-0-5279	10/100
93 champagne	20 EUCKS-93-507	2013-0-5337	10
94 alpine white	20 EUCKS-94-507 NEW	2013-0-5278	10/100
95 château-black	20 EUCKS-95-507 NEW	2013-0-5338	10
96 chalet-white	20 EUCKS-96-507	2013-0-5339	10

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.

2) Increased shock protection.

	SCHUKO® socket outlet¹⁾ With hinged lid. With screwless terminals. 2 P + E Hinged lid notches when opened. Rated voltage: 250 V~ Rated current: 16 A		
92 white	20 EUK-92-507 NEW	2018-0-0351	10/100
93 champagne	20 EUK-93-507	2018-0-1498	10
94 alpine white	20 EUK-94-507 NEW	2018-0-0350	10/100
95 château-black	20 EUK-95-507 NEW	2018-0-1499	10
96 chalet-white	20 EUK-96-507	2018-0-1500	10

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.

	SCHUKO® socket outlet¹⁾ with marking With screwless terminals. 2 P + E With continuous coloured marking of cover plate and base. Rated voltage: 250 V~ Rated current: 16 A		
12 red	20 EUC-12-92-507	2011-0-6151	
13 green	20 EUC-13-92-507	2011-0-6152	
14 orange	20 EUC-14-92-507	2011-0-6153	

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.

	SCHUKO® socket outlet¹⁾ With hinged lid. Delivered with special frame for IP44 protection level. The IP44 protection level will be achieved only if the device is mounted on a flat and gapless wall. With screwless terminals. 2 P + E Rated voltage: 250 V~ Rated current: 16 A		
92 white	20 EUCKD-92-507 NEW	2018-0-1504	10/100
93 champagne	20 EUCKD-93-507	2018-0-1501	10/100
94 alpine white	20 EUCKD-94-507	2018-0-1505	10/100
95 château-black	20 EUCKD-95-507	2018-0-1502	10/100
96 chalet-white	20 EUCKD-96-507	2018-0-1503	10/100

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.

Product	Article-No.	Order-No.	Pack/Qty
	Cover Plate Shuttered. For socket outlet insert 20 M-500.		
92 white	2399 UCKS-92-507 NEW	2099-0-0251	10
93 champagne	2399 UCKS-93-507	2099-0-0259	10
94 alpine white	2399 UCKS-94-507 NEW	2099-0-0250	10
95 château-black	2399 UCKS-95-507 NEW	2099-0-0260	10
96 chalet-white	2399 UCKS-96-507	2099-0-0261	10

	Double SCHUKO® socket outlet 1) With screwless terminals. 2 P + E Suitable for 1gang flush-mounted boxes. Rated voltage: 250 V~ Rated current: 16 A		
92 white	20-02 EUJ-92-507 NEW	2014-0-1463	10/80
93 champagne	20-02 EUJ-93-507	2014-0-1476	10
94 alpine white	20-02 EUJ-94-507 NEW	2014-0-1462	10/80
95 château-black	20-02 EUJ-95-507 NEW	2014-0-1477	10
96 chalet-white	20-02 EUJ-96-507	2014-0-1478	10

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.

	Double SCHUKO® socket outlet 1) 2) Shuttered. With screwless terminals. 2 P + E Suitable for 1gang flush-mounted boxes. Rated voltage: 250 V~ Rated current: 16 A		
92 white	20-02 EUJKS-92-507 NEW	2021-0-0379	10
93 champagne	20-02 EUJKS-93-507	2021-0-0380	10
94 alpine white	20-02 EUJKS-94-507 NEW	2021-0-0378	10
95 château-black	20-02 EUJKS-95-507 NEW	2021-0-0381	10
96 chalet-white	20-02 EUJKS-96-507	2021-0-0382	10

1) Connecting terminals approved in accordance with VDE 0620-1 as connectors.
2) Increased shock protection .

	SCHUKO® socket outlet 1) With screw-type terminals. 2 P + E Rated voltage: 250 V~ Rated current: 16 A		
92 ivory	23 EUC-92-507 NEW	2011-0-6154	
93 champagne	23 EUC-93-507 NEW	2011-0-6146	
94 alpine white	23 EUC-94-507 NEW	2011-0-6155	
95 château-black	23 EUC-95-507 NEW	2011-0-6147	
96 chalet-white	23 EUC-96-507	2011-0-6150	

1) Terminals suitable for loop through connection.

Product	Article-No.	Order-No.	Pack/Qty
	Cover plate 1gang As cover for universal data connection boxes. Art.-No. 0213 (Cat 3), 0216 (Cat 5), 0220-507 (Cat. 5e.), 0221-507 (Cat. 6), data technology and comparable types from the company Rutenbeck. Brand-Rex (WAEGV 8 EKR/EK). BTR (universal data connecting unit design and IAE design). Telegärtner (AMJ 45, UMJ 45). With down-leading outlet.		
92 white	1803-92-507 NEW	1753-0-0098	10/100
93 champagne	1803-93-507	1753-0-0204	10/100
94 alpine white	1803-94-507 NEW	1753-0-0096	10/100
95 château-black	1803-95-507 NEW	1753-0-0207	10
96 chalet-white	1803-96-507	1753-0-0210	10

Product	Article-No.	Order-No.	Pack/Qty
	Cover plate 2gang As cover for universal data connection boxes. Art. No. 0214, 0215 (Cat 3), 0220/12-507, 0221/12-507, 0218, 0217 (Cat 5e/6 data technology) and comparable types of the company Rutenbeck. Brand-Rex (WAEGV 8/8 EKR/EK). AMP (NETCONNECT 5E). BTR (E-DAT C6, E-DAT design, Universal data connecting unit design and IAE design). cti (cti-wire 2.8 Cat.6). Telegärtner (AMJ 45, UMJ 45). With down-leading outlet.		
92 white	1803-02-92-507 NEW	1753-0-0097	10/100
93 champagne	1803-02-93-507	1753-0-0203	10/100
94 alpine white	1803-02-94-507 NEW	1753-0-0095	10/100
95 château-black	1803-02-95-507 NEW	1753-0-0206	10
96 chalet-white	1803-02-96-507	1753-0-0209	10

Product	Article-No.	Order-No.	Pack/Qty
	Cover plate For telephone connection unit. Für USB-, VGA-, HDMI-Anschlussdosen und Kommunikationsadapter. For loudspeaker connection box. Suitable for part number 0248/0x-101. For data modules. Suitable for Art. No. 0219/12 and 0219/13. For modular outlets with 90° RJ45 outlet from Telegärtner (type MJ and WE).		
92 white	2539-92-507 NEW	1724-0-4279	10
93 champagne	2539-93-507	1724-0-4312	10
94 alpine white	2539-94-507 NEW	1724-0-4275	10/100
95 château-black	2539-95-507 NEW	1724-0-4315	10
96 chalet-white	2539-96-507	1724-0-4318	10

Product	Article-No.	Order-No.	Pack/Qty
	Cover plate Adapter ring For telecommunication. With cover plate 50 x 50 mm, AMP, Brand-Rex, Rutenbeck, BTR, Telegärtner, etc.		
92 white	1746-92-507 NEW	1726-0-0221	10
93 champagne	1746-93-507	1726-0-0229	10
94 alpine white	1746-94-507 NEW	1726-0-0219	10
95 château-black	1746-95-507 NEW	1726-0-0231	10
96 chalet-white	1746-96-507	1726-0-0233	10

Product	Article-No.	Order-No.	Pack/Qty
	TV outlet For connection to a TV or FM co-axial aerial lead. Rated frequency: 5000 Hz/860000 Hz IEC 60169-2		
92 white	1743-01-92-507 NEW	1724-0-4280	10/100
93 champagne	1743-01-93-507	1724-0-4310	10/100
94 alpine white	1743-01-94-507 NEW	1724-0-4276	10/100
95 château-black	1743-01-95-507 NEW	1724-0-4313	10
96 chalet-white	1743-01-96-507	1724-0-4317	10

Product	Article-No.	Order-No.	Pack/Qty
	Cover plate As cover for flush-mounted light signal. For insert 2061/2661 U.		
92 white	1756-92-507 NEW	1753-0-0099	10
93 champagne	1756-93-507	1753-0-0202	10
94 alpine white	1756-94-507 NEW	1753-0-0100	10
95 château-black	1756-95-507 NEW	1753-0-0205	10
96 chalet-white	1756-96-507	1753-0-0208	10

	Cover plate As cover for standard Radio/TV/SAT socket outlets. With 3 connectors. Radio/TV/SAT. With M3 fixing screw.		
92 white	1743-92-507 NEW	1724-0-4284	10/100
93 champagne	1743-93-507	1724-0-4311	10/100
94 alpine white	1743-94-507 NEW	1724-0-4283	10/100
95 château-black	1743-95-507 NEW	1724-0-4314	10
96 chalet-white	1743-96-507	1724-0-4316	10

	Busch Dimmer® with cover plate With rotary control, 2way On-Off switching and soft-catch. Leading Edge control. Rated voltage: 230 V~, +10 % / -10 % Rated frequency: 50 Hz Rated power: 60 - 400 W IEC 60669-2-1		
92 white	2251 UCGL-92-507 NEW	6515-0-0843	1/10
93 champagne	2251 UCGL-93-507	6515-0-0845	1/10
94 alpine white	2251 UCGL-94-507 NEW	6515-0-0842	1/10
95 château-black	2251 UCGL-95-507 NEW	6515-0-0846	1/10
96 chalet-white	2251 UCGL-96-507	6515-0-0847	1/10

	Cover plate 1) With metal mounting plate. As cover for flex outlet, for cords up to 10.3 mm diameter. With strain relief (without terminal block).		
92 white	2527-92-507	1710-0-3773	10
93 champagne	2527-93-507	1710-0-3932	10
94 alpine white	2527-94-507 NEW	1710-0-3772	10
95 château-black	2527-95-507 NEW	1710-0-3936	10
96 chalet-white	2527-96-507	1710-0-3940	10

	Cover plate 1) With rotary knob, with indication lamp. For Busch-Dimmer®. For inserts 2112 U-101/2117 U/2117/11 U/2247 U/ 2250 U/6513 U-102/6517 U-101/6519 U/6520 U/6523 U/ 6591 U-101 and 6592 U.		
92 white	2115-92-507 NEW	6599-0-2929	10
93 champagne	2115-93-507	6599-0-2990	10
94 alpine white	2115-94-507 NEW	6599-0-2928	10
95 château-black	2115-95-507 NEW	6599-0-2991	10
96 chalet-white	2115-96-507	6599-0-2992	10

1) Replacement neon lamp, Art. No. 3855.

	Blank plate With metal mounting plate.		
92 white	2538-92-507 NEW	1715-0-0313	10
93 champagne	2538-93-507	1715-0-0314	10
94 alpine white	2538-94-507 NEW	1715-0-0312	10
95 château-black	2538-95-507 NEW	1715-0-0315	10
96 chalet-white	2538-96-507	1715-0-0316	10

	Control element 1) 2) 3) With neon lamp.		
92 white	6543-92-507 NEW	6599-0-2996	
93 champagne	6543-93-507	6599-0-2993	
94 alpine white	6543-94-507 NEW	6599-0-2997	
95 château-black	6543-95-507 NEW	6599-0-2994	
96 chalet-white	6543-96-507	6599-0-2995	

1) Compatible with previous type 6543-xxx.

2) Touch-type Controller 6550 U-xxx non-illuminable.

3) Replacement neon lamp 3857.

Product	Article-No.	Order-No.	Pack/Qty
Cover plate For Comfort timer control element 6455. For Standard timer control element 6456. For room temperature controller 1098 U-101 and 1098 UF-101.			
NEW			
92 white	6435-92-507	6430-0-0353	10
93 champagne	6435-93-507	6430-0-0392	10
94 alpine white	6435-94-507	6430-0-0352	10
95 château-black	6435-95-507	6430-0-0393	10
96 chalet-white	6435-96-507	6430-0-0394	10

Cover plate For room thermostat. for room thermostat 1094 U, 1097 U			
92 white	1794-92-507	1710-0-3868	10
93 champagne	1794-93-507	1710-0-3930	10
94 alpine white	1794-94-507	1710-0-3866	10
95 château-black	1794-95-507	1710-0-3934	10
96 chalet-white	1794-96-507	1710-0-3938	10

Cover plate For room thermostat. With sliding switch for nightly room temperature reduction. to activate nighttime mode and reduction of room temperature by 4K,for thermostat 1095 U, 1096 U and 1095 UF.			
92 white	1795-92-507	1710-0-3869	10
93 champagne	1795-93-507	1710-0-3931	10
94 alpine white	1795-94-507	1710-0-3867	10
95 château-black	1795-95-507	1710-0-3935	10
96 chalet-white	1795-96-507	1710-0-3939	10

Busch-Comfort switch control element 1) With neon lamp. For 2-wire insert 6815 U. For relay insert 6816 U. Adjustable operating mode: semiautomatic mode, automatic switch-on, manual switch-off. Adjustable operating mode: automatic timer, manual switch-on, automatic (timer and motion-controlled) switch-off. Adjustable operating mode: automatic mode, automatic (motion-controlled) switch-on and switch-off. Push switch function possible at all times. Switch-off delay: 1 to 10 min., adjustable. Surveillance density: 9 sectors with 28 switching segments. Detection range: frontal: 5 m, lateral: 3 m Detection angle: 170 ° Brightness limit value: 0.5 Lux - 300 Lux , Daytime operation Mounting height: 0.8 m - 1.2 m Protection class (Sensor): IP 20 Temperature range (Device): 0 °C to 35 °C			
92 white	6815-92-507	6800-0-2487	1/10
93 champagne	6815-93-507	6800-0-2596	1/10
94 alpine white	6815-94-507	6800-0-2486	1/10
95 château-black	6815-95-507	6800-0-2597	1/10
96 chalet-white	6815-96-507	6800-0-2598	1/10

1) Please order the respective flush mounted insert separately.

Product	Article-No.	Order-No.	Pack/Qty
Cover plate 1) With labelling field. For modular jack with slide entrance. To fit only Art. No. 1810, 1812, 1814, 1816, 1818, 1819 and 1820. Size of labelling field: 60.2 x 9.2 mm.			
92 white			
NEW			
92 white	1800-92-507	1710-0-3944	
93 champagne	1800-93-507	1710-0-3941	
94 alpine white	1800-94-507	1710-0-3945	
95 château-black	1800-95-507	1710-0-3942	
96 chalet-white	1800-96-507	1710-0-3943	

1) Labelling sheets 1799 18 and labelling software.

Product	Article-No.	Order-No.	Pack/Qty
Cover plate With metal mounting plate. For 1 modular jack. Suitable for Art. Nos. 0210, 0211, and 0219. Without claws.			
92 white			
NEW			
92 white	2561-92-507	1753-0-0211	
93 champagne	2561-93-507	1753-0-0212	
94 alpine white	2561-94-507	1753-0-0213	
95 château-black	2561-95-507	1753-0-0214	
96 chalet-white	2561-96-507	1753-0-0215	

Product	Article-No.	Order-No.	Pack/Qty
Cover plate For FT DigitalRadio 8215 U.			
92 white			
NEW			
92 white	8252-92-507	8200-0-0166	10
93 champagne	8252-93-507	8200-0-0157	10
94 alpine white	8252-94-507	8200-0-0169	10
95 château-black	8252-95-507	8200-0-0160	10
96 chalet-white	8252-96-507	8200-0-0163	10

Product	Article-No.	Order-No.	Pack/Qty
Cover plate For loudspeaker insert 8223 U.			
92 white			
NEW			
92 white	8253-92-507	8200-0-0167	1/10
93 champagne	8253-93-507	8200-0-0158	1/10
94 alpine white	8253-94-507	8200-0-0170	1/10
95 château-black	8253-95-507	8200-0-0161	1/10
96 chalet-white	8253-96-507	8200-0-0164	1/10

Product	Article-No.	Order-No.	Pack/Qty
Cover plate For Busch-iDock 8218 U.			
92 white	8254-92-507 NEW	8200-0-0168	10
93 champagne	8254-93-507	8200-0-0159	10
94 alpine white	8254-94-507 NEW	8200-0-0171	10
95 château-black	8254-95-507 NEW	8200-0-0162	10
96 chalet-white	8254-96-507	8200-0-0165	10
Modular-Jack insert Cat. 5e ungeschirmt, 8 (8)-polig For cover plate 2561- and insert 1812, 1866 built-in, 1867 built-in. For conductor cross-sections of 0.12 mm ² (AWG 26) to 0.35 mm ² (AWG 22).			
NEW 0211/11			0225-0-0153
			10

Product	Article-No.	Order-No.	Pack/Qty
Cover frame with decorative styling frame 1gang frame			
91 entrée-grey	2511-91-507	1725-0-1531	10/100
92 white	2511-92-507 NEW	1725-0-1484	10/100
93 champagne	2511-93-507	1725-0-1501	10/100
94 alpine white	2511-94-507 NEW	1725-0-1479	10/100
95 château-black	2511-95-507 NEW	1725-0-1506	10/100
96 chalet-white	2511-96-507 NEW	1725-0-1511	10/100
97 foyer-red	2511-97-507 NEW	1725-0-1516	10/100
98 bistro-blue	2511-98-507 NEW	1725-0-1521	10/100
99 maison-beige	2511-99-507	1725-0-1526	10/100

Product	Article-No.	Order-No.	Pack/Qty
Cover frame with decorative styling frame 2gang frame For vertical or horizontal installation.			
91 entrée-grey	2512-91-507	1725-0-1532	10/100
92 white	2512-92-507 NEW	1725-0-1485	10/100
93 champagne	2512-93-507	1725-0-1502	10/100
94 alpine white	2512-94-507 NEW	1725-0-1480	10/100
95 château-black	2512-95-507 NEW	1725-0-1507	10/100
96 chalet-white	2512-96-507 NEW	1725-0-1512	10/100
97 foyer-red	2512-97-507 NEW	1725-0-1517	10/100
98 bistro-blue	2512-98-507 NEW	1725-0-1522	10/100
99 maison-beige	2512-99-507	1725-0-1527	10/100

Product	Article-No.	Order-No.	Pack/Qty
Cover frame with decorative styling frame 3gang frame For vertical or horizontal installation.			
91 entrée-grey	2513-91-507	1725-0-1533	10/100
92 white	2513-92-507 NEW	1725-0-1486	10/100
93 champagne	2513-93-507	1725-0-1503	10
94 alpine white	2513-94-507 NEW	1725-0-1481	10/100
95 château-black	2513-95-507 NEW	1725-0-1508	10/100
96 chalet-white	2513-96-507 NEW	1725-0-1513	10
97 foyer-red	2513-97-507 NEW	1725-0-1518	10
98 bistro-blue	2513-98-507 NEW	1725-0-1523	10
99 maison-beige	2513-99-507	1725-0-1528	10/100

Product	Article-No.	Order-No.	Pack/Qty
Cover frame with decorative styling frame 4gang frame			
For vertical or horizontal installation.			
91 entrée-grey	NEW 2514-91-507	1725-0-1534	10
92 white	NEW 2514-92-507	1725-0-1487	10
93 champagne	NEW 2514-93-507	1725-0-1504	10
94 alpine white	NEW 2514-94-507	1725-0-1482	10
95 château-black	NEW 2514-95-507	1725-0-1509	10
96 chalet-white	NEW 2514-96-507	1725-0-1514	10
97 foyer-red	NEW 2514-97-507	1725-0-1519	10
98 bistro-blue	NEW 2514-98-507	1725-0-1524	10
99 maison-beige	NEW 2514-99-507	1725-0-1529	10

Cover frame with decorative styling frame 5gang frame			
For vertical or horizontal installation.			
91 entrée-grey	NEW 2515-91-507	1725-0-1535	10
92 white	NEW 2515-92-507	1725-0-1488	10
93 champagne	NEW 2515-93-507	1725-0-1505	10
94 alpine white	NEW 2515-94-507	1725-0-1483	10
95 château-black	NEW 2515-95-507	1725-0-1510	10
96 chalet-white	NEW 2515-96-507	1725-0-1515	10
97 foyer-red	NEW 2515-97-507	1725-0-1520	10
98 bistro-blue	NEW 2515-98-507	1725-0-1525	10
99 maison-beige	NEW 2515-99-507	1725-0-1530	10

Decorative styling frame			
For styling frames 2511-9x-507, 2512-9x-507, 2513-9x-507, 2514-9x-507, 2515-9x-507			
92 white	NEW 2516-92-507	1726-0-0220	10/100
93 champagne	NEW 2516-93-507	1726-0-0230	10/100
94 alpine white	NEW 2516-94-507	1726-0-0218	10/100
95 château-black	NEW 2516-95-507	1726-0-0232	10/100
96 chalet-white	NEW 2516-96-507	1726-0-0234	10/100
901 attica/pigeon blue	2516-901-507	1726-0-0222	10/100
902 silver metallic	2516-902-507	1726-0-0223	10/100
903 light green	2516-903-507	1726-0-0224	10/100
904 orange	2516-904-507	1726-0-0225	10/100
905 yellow	2516-905-507	1726-0-0226	10/100
906 apricot	2516-906-507	1726-0-0227	10/100
907 luminous	2516-907-507	1726-0-0228	10/100

Product	Article-No.	Order-No.	Pack/Qty
Surface mounting box 1gang box			
Box for inserts and cover plates with cover frame.			
92 white	NEW 1701-92-507	1799-0-0971	
93 champagne	1701-93-507	1799-0-0962	
94 alpine white	1701-94-507	1799-0-0974	
95 château-black	1701-95-507	1799-0-0965	
96 chalet-white	1701-96-507	1799-0-0968	


Product	Article-No.	Order-No.	Pack/Qty
Surface mounting box 2gang box			
Box for inserts and cover plates with cover frame.			
92 white	NEW 1702-92-507	1799-0-0972	
93 champagne	1702-93-507	1799-0-0963	
94 alpine white	1702-94-507	1799-0-0975	
95 château-black	1702-95-507	1799-0-0966	
96 chalet-white	1702-96-507	1799-0-0969	


Product	Article-No.	Order-No.	Pack/Qty
Surface mounting box 3gang box			
92 white	NEW 1703-92-507	1799-0-0973	
93 champagne	1703-93-507	1799-0-0964	
94 alpine white	1703-94-507	1799-0-0976	
95 château-black	1703-95-507	1799-0-0967	
96 chalet-white	1703-96-507	1799-0-0970	



92 white	NEW 2516-92-507	1726-0-0220	10/100
93 champagne	NEW 2516-93-507	1726-0-0230	10/100
94 alpine white	NEW 2516-94-507	1726-0-0218	10/100
95 château-black	NEW 2516-95-507	1726-0-0232	10/100
96 chalet-white	NEW 2516-96-507	1726-0-0234	10/100
901 attica/pigeon blue	2516-901-507	1726-0-0222	10/100
902 silver metallic	2516-902-507	1726-0-0223	10/100
903 light green	2516-903-507	1726-0-0224	10/100
904 orange	2516-904-507	1726-0-0225	10/100
905 yellow	2516-905-507	1726-0-0226	10/100
906 apricot	2516-906-507	1726-0-0227	10/100
907 luminous	2516-907-507	1726-0-0228	10/100

  Notes.





The wallpaper shown on pages
13, 19, 25, 29, 31 and 41 are
part of the current range of the

MARBURGER TAPETENFABRIK
(Marburger wallpaper factory)

J. B. Schaefer GmbH & Co. KG
Bertram-Schaefer-Str. 11
35274 Kirchhain
Telephone: +49 (0) 6422 81-0
www.marburg.com

Contact

A member
of the ABB Group

Busch-Jaeger Elektro GmbH
P.O. Box
58505 Lüdenscheid
Germany

Freisenbergstraße 2
58513 Lüdenscheid
Germany

www.BUSCH-JAEGER.com
info.bje@de.abb.com

Central sales service:

Phone +49 180 5 669900
Fax +49 180 5 669909
(0.14 €/min. from the German landline but different costs from abroad, please check it locally)