

TECHNICAL DATA SHEET

Stanilite®

Platinum exit LED edgelit Quickfit® Nexus®



Catalogue no.	Description
Nexus products	
SGPLQNRFLDP	Platinum exit LED edgelit Quickfit Nexus RF pictograph
Spare parts	
03-01308P	Battery LiFePO4 3.2V 1.5Ah

Range

Platinum range


Product group

Exit LED edgelit



Features

- High emergency classification
- LED technology 100,000 hours plus lamp life
- Low power consumption and LED light source for reduced operation and maintenance costs
- Advanced charging technology combined with Lithium iron phosphate battery for long life and low maintenance
- Nexus monitored, wireless
- RF frequency range 920 - 925 MHz
- Architecturally pleasing slim line design
- Quickfit unique steel slide connect bracket for quick installation and easy maintenance
- Includes all pictograph diffuser options
- Universal wall/ceiling mounting, can also be rod or wire suspended
- Retrofit capability; fits into any existing Quickfit mounting bracket

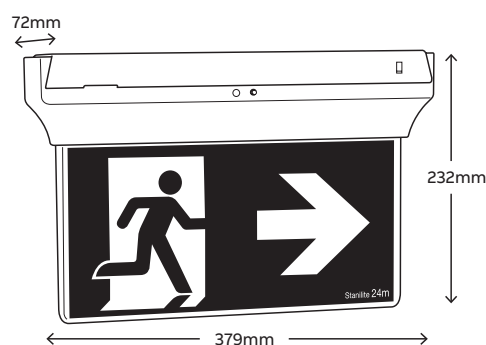

Dimensions			
	Length	Width	Height (incl. bracket)
	379mm	72mm	232mm
Weight			
	Model	Weight	
	Nexus RF	1.8kg	
Construction			
	Part	Construction	
	Body and diffuser	Polycarbonate	
	Bracket	White powder coated zinc steel	

Light source			
	Model	Light source	
	Nexus RF	Multiple LED 0.7W	
Power consumption			
	Model	Power consumption	
	Nexus RF	2.4W	
Note: Preliminary results			
Photometrics			
	Model	Class	Classification
	Nexus RF	C0	D3.2
		C90	E2
Note: Preliminary results			

Note:

- Complies to IEC60598.2.22 and AS2293