

Stanilite®

Economy batten LED - 4 foot



Range

Economy range

Product group


Batten LED



Features

- Typically 3,800 lumens on mains AC operation, 635 lumens in emergency operation
- IP40
- IK06 impact rating
- Long LED life 50,000 hours
- Colour temperature 4,000K
- High colour rendering index CRI>80
- High temperature rated Lithium iron phosphate battery
- Large terminal block for quick and easy installation
- Lanyard attached to the lamp and base body makes installation easier
- Frosted diffuser for even light distribution
- Insect proof sealed LED module
- Can be surface mounted or suspended
- AC efficacy typically 100 lumens/watt
- Ambient operating temperature; AC 0°C to +40°C and EM +10°C to +40°C

Catalogue no.	Description
AC/EM products	
ECOBAT4AC	Economy batten LED AC 3800 lumens
ECOBAT4EM	Economy batten LED EM 3800 lumens maintained
Spare parts	
03-01227	Battery LiFePO4 6.4V 3.0Ah

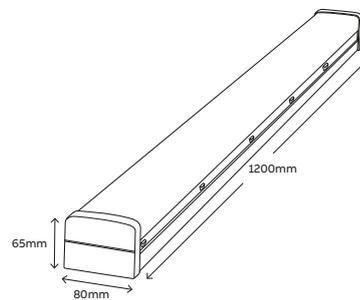

Dimensions			
	Length	Width	Height
	1200mm	80mm	65mm

Weight	
Model	Weight
AC	2.1kg
EM	2.8kg

Construction	
Part	Construction
Base body	Powder coated steel
Lamp body, end cap and diffuser	Polycarbonate and aluminium

Light source				
	Model	Light source		
	AC/EM	LED strips		
Power consumption				
	Model	Normal	S/A off	Standby
	AC	40W	0W	N/A
	EM	45W	5W	N/A
Note: Preliminary results				
Photometrics				
	Model	Class	Classification	
	EM	C0	D80	
		C90	D50	
Note: Preliminary results				

Note:

- AC designed to comply with AS/NZS60598.2.1 and meet relevant Australian EMC standards
- EM designed to comply with AS2293.3 and meet relevant Australian EMC standards