

# Stanilite®

## Economy Spitfire® LED recessed non-maintained



### Range

Economy range

### Product group


Spitfire LED



### Features

- Superior photometric classification
- LED technology 100,000 hours plus lamp life
- Low power consumption and LED light source for reduced operation and maintenance costs
- High temperature rated Lithium iron phosphate battery
- Spring fixing design allows for different ceiling thickness (1mm-20mm)
- White adaptors included to convert standard 94mm lamp head to 145mm diameter
- Non-maintained operation
- Ingress protection IP20
- Insulation class II
- SAA tested and approved

Catalogue no.	Description
<b>EM products</b>	
ECOSPITFIRE	Economy Spitfire LED recessed
<b>Spare parts</b>	
03-01226	Battery LiFePO4 6.4V 1.5Ah

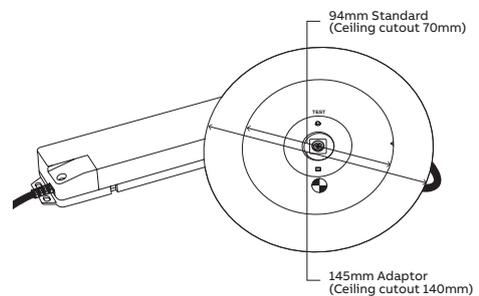

Dimensions	
Lamp head	Ceiling cutout
94mm standard	70mm
145mm adaptor	140mm
Weight	
Model	Weight
EM	1.0kg
Construction	
Part	Construction
Lamp head	White polycarbonate

<b>Light source</b>			
	<b>Model</b>	<b>Light source</b>	
	EM	3W	

<b>Power consumption</b>			
	<b>Model</b>	<b>Power consumption</b>	
	EM	1.0W average	

Note: Preliminary results

<b>Photometrics</b>			
	<b>Model</b>	<b>Class</b>	<b>Classification</b>
	EM	C0	D40
		C90	D40

Note:

- Designed to comply with AS2293 and meet relevant Australian EMC standards