



Inora

Simplicity for timeless design



- Simple and elegant design: curved rocker combined with chamfer frame on the top and the bottom
- Backlight with blue illumination
- Safe and faster installation due to ergonomic design
- Durability thanks to high-quality materials
- Socket outlets designed with safety shutter to protect children from power hazards

Inora

Simplicity for timeless design

Inora's simple and elegant design perfectly complements the interior of any residential or commercial building. With its functional simplicity it creates a timeless aesthetic.

simplicity

Less is more. With clean lines, gently curved rockers, and stylish chamfer frames on the top and bottom the Inora range is infinitely sophisticated. The unobtrusive design coordinates effortlessly with any interior design scheme. Or if you would like to turn your light switch into a striking design element, you can opt for a back-light with blue illumination.

Form follows function. The Inora range of light switches and wiring accessories has been


designed with quality, functionality, and simplicity in mind. Many functions such as USB charging ports have been combined into one product, saving space, and optimizing installation and use. As a result, fewer wiring accessories are needed throughout the building, which also contributes to a clean interior design.

The Inora range of light switches and wiring accessories has been designed with quality, functionality and simplicity in mind.



timeless

Available in four colors – white, classic grey, starry black and royal gold – the simplicity of the Inora switches and socket outlets sets new standards for timeless design.

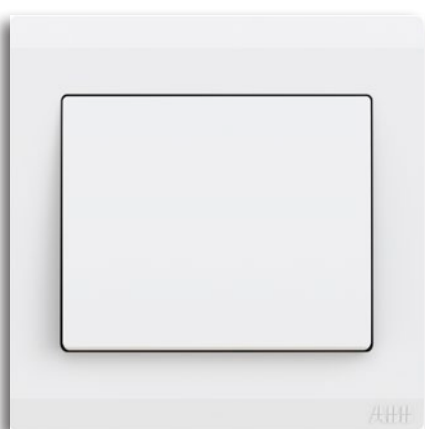

01



02



03



04



ess

-
- 01 White
 - 02 Classic grey - G
 - 03 Starry black - 885
 - 04 Royal gold - PG


Inora

Your first choice, simple and elegant

Whether it's in a kitchen, a living room or a child's room, with a total above-wall switch height of 8.5 mm, Inora is your first choice, simple and elegant.

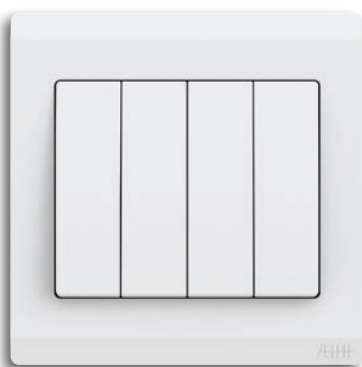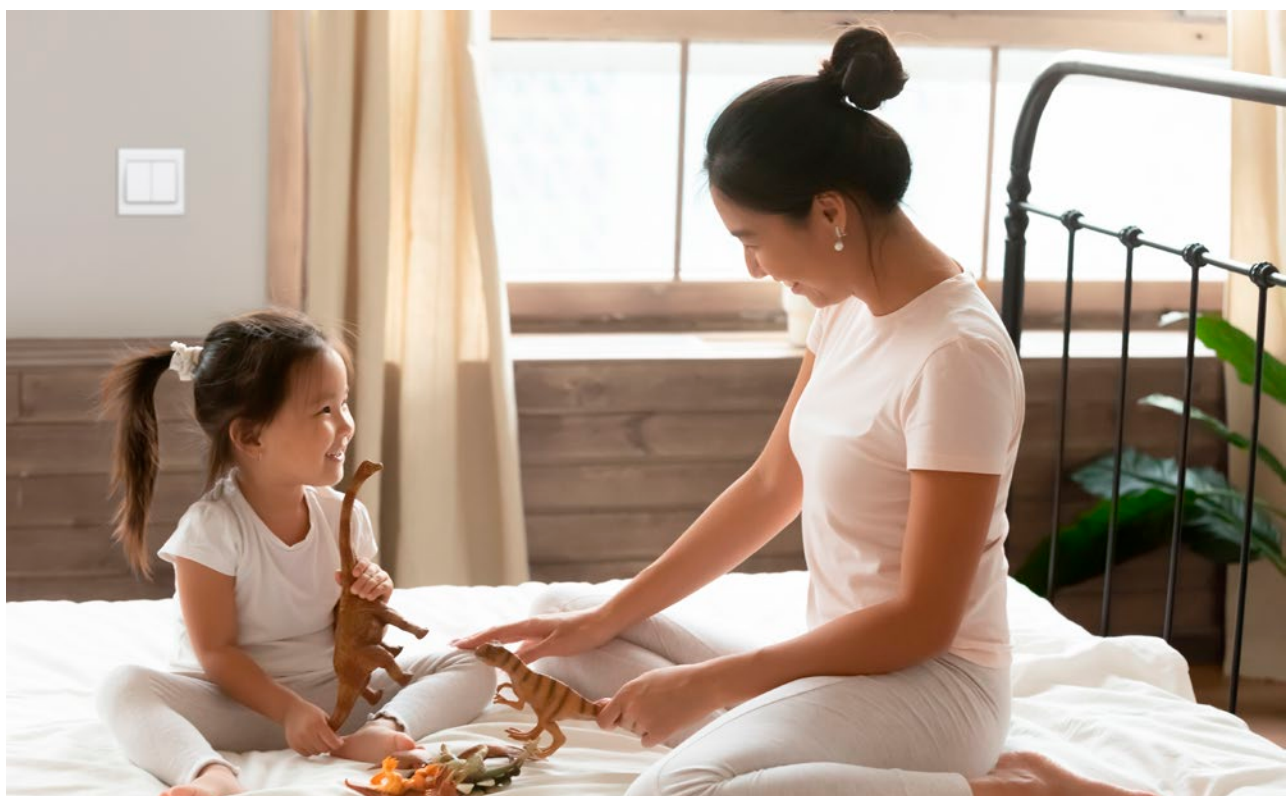


01

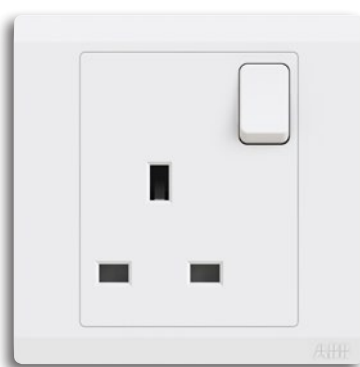

02

- 01 White switch
- 02 White socket

Features & benefits

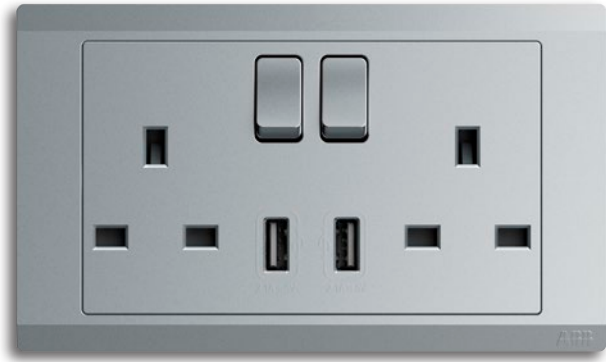


—
Inora socket outlets
with integrated
USB charging

benefits

Wide range

The Inora range covers the main needs of modern electrical installation.

 - From standard switches, socket outlets, dimmers, cooker control units to sockets with integrated USB charging ports
- Wide variety of data communication outlets



Safety

ABB attaches great importance to safety. The Inora range has been certified according to British Standard installations.

- Socket outlets have been designed with safety shutters to protect children from power hazards
- Subtle blue illumination for simple location at night



Durability

Inora is designed to be timeless, not only in terms of its design but also in terms of quality.

- High-quality polycarbonate materials for both surface and installation parts
- High-quality red copper and silver alloy materials for metals parts to optimize performance



Easy installation

Space optimization and installation efficiency.

- Safe and faster installation due to ergonomic design
- Up to four rockers in 1gang frame, providing a cost-effective and space-saving solution





—
Designed to provide reliability, durability and safety, Inora is the affordable range of light switches and wiring accessories – the perfect fit for any type of residential or commercial buildings.

elegant



Room Temperature Control



Black



White


The BR series thermostats feature a large display with touch control buttons for easy operation. The frameless design, along with its large display ensures easy viewing and adds an elegant touch to complement its surroundings.

intuitive



Product overview

Switches

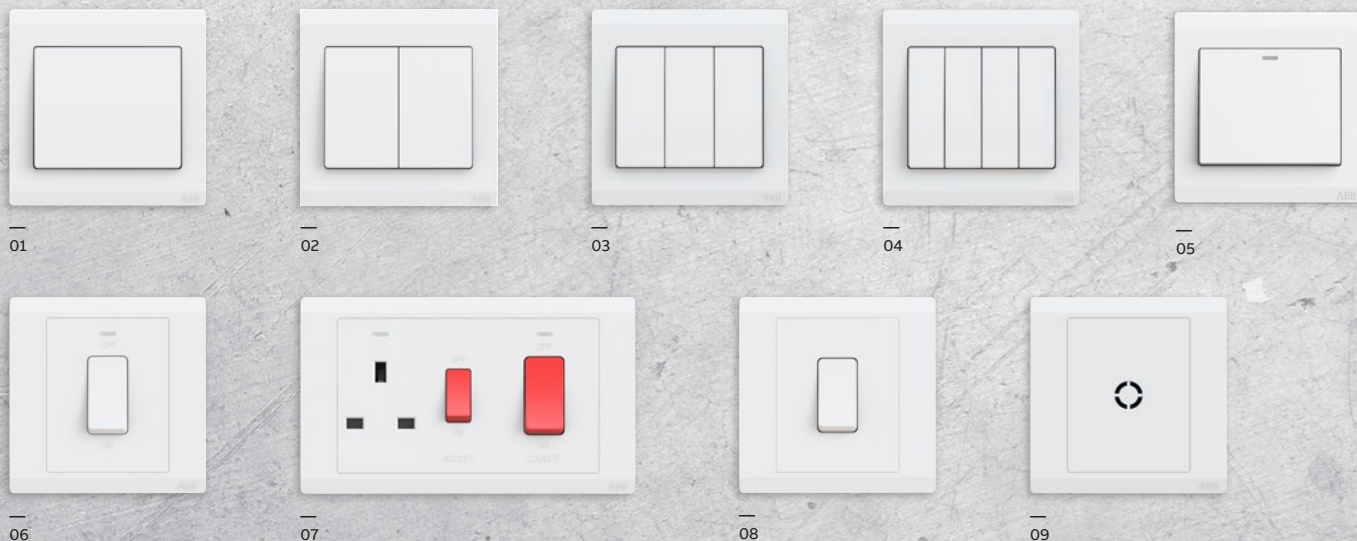


See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Switches					
01	2TCZ171001R0030	BL101	1 Gang 1 Way 10AX SWITCH	10AX	35mm
02	2TCZ171003R0030	BL102	2 Gang 1 Way 10AX SWITCH	10AX	35mm
03	2TCZ171005R0030	BL103	3 Gang 1 Way 10AX SWITCH	10AX	35mm
04	2TCZ171007R0030	BL104	4 Gang 1 Way 10AX SWITCH	10AX	35mm
01	2TCZ171002R0030	BL105	1 Gang 2 Way 10AX SWITCH	10AX	35mm
02	2TCZ171004R0030	BL106	2 Gang 2 Way 10AX SWITCH	10AX	35mm
03	2TCZ171006R0030	BL107	3 Gang 2 Way 10AX SWITCH	10AX	35mm
04	2TCZ171008R0030	BL108	4 Gang 2 Way 10AX SWITCH	10AX	35mm
01	2TCZ171095R0070	BL110	1 Gang 1 Way 20AX SWITCH	20AX	35mm
05	2TCZ171096R0070	BL111	1 Gang 1 Way 20AX DP SWITCH WITH LED	20AX	35mm
06	2TCZ171020R0070	BL111S	1 Gang 1 Way 20AX DP SWITCH WITH ILLUMINATION	20AX	35mm
01	2TCZ171097R0070	BL112	1 Gang 2 Way 20AX SWITCH	20AX	35mm
02	2TCZ171016R0070	BL114	2 Gang 1 Way 20AX SWITCH	20AX	35mm
02	2TCZ171017R0070	BL115	2 Gang 2 Way 20AX SWITCH	20AX	35mm
03	2TCZ171018R0070	BL146*	3 Gang 1 Way 20AX SWITCH	20AX	35mm
03	2TCZ171022R0070	BL147*	3 Gang 2 Way 20AX SWITCH	20AX	35mm
07	2TCZ171015R0090	BL118	2 Gang 1Way 45A DP SWITCH & 13A SWITCH SOCKET WITH ILLUMINATION	45A/13A	35mm
01	2TCZ171009R0030	BL119	1 Gang INTERMEDIATE 10AX SWITCH	10AX	35mm
08	2TCZ171021R0030	BL119S	1 Gang INTERMEDIATE 10AX SWITCH	10AX	35mm
09	2TCZ171099R0070	BL120	20A FLEX OUTLET	20A	35mm
01	2TCZ171010R0030	BL430	1 Gang 1 Way 10A PUSH SWITCH	10A	35mm
01	2TCZ171024R0030	BL456*	1 Gang 2 Way 10A PUSH SWITCH	10A	35mm
02	2TCZ171025R0030	BL438*	2 Gang 1 Way 10A PUSH SWITCH	10A	35mm

Notes: * Will be available in Jun 2024.

Product overview

Switches

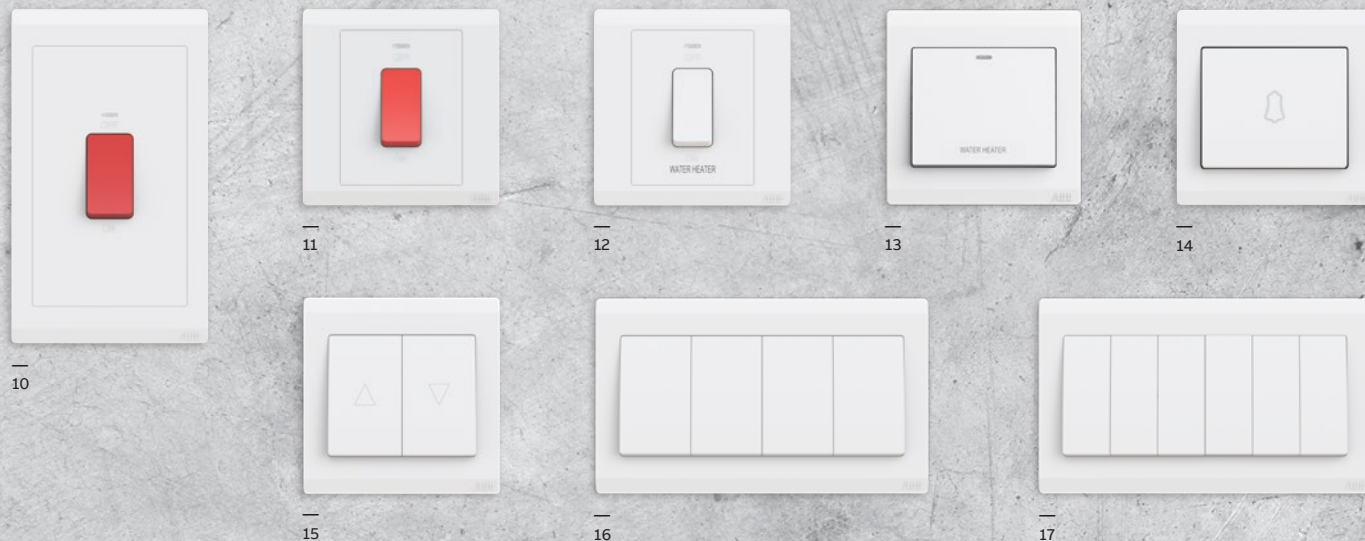


See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Switches					
10	2TCZ171019R0090	BL143	1 Gang 45A DP SWITCH WITH ILLUMINATION (6X3)	45A	35mm
12	2TCZ171012R0075	BL171WH	1 Gang 1 Way 20AX DP SW WITH ILLUMINATION- MARKED WATER HEATER	20AX	35mm
11	2TCZ171013R0090	BL176	1 Gang 1 Way 32A DP SWITCH WITH ILLUMINATION	32A	35mm
11	2TCZ171098R0090	BL179	1 Gang 1 Way 45A DP SWITCH WITH ILLUMINATION	45A	35mm
13	2TCZ171014R0070	BL180WH	1 Gang 1 Way 20AX DP SWITCH WITH LED, MARKED WATER HEATER	20AX	35mm
13	2TCZ171023R0070	BL148WH*	1 Gang 2 Way 20AX DP SWITCH WITH NEON, MARKED WATER HEATER	20AX	35mm
14	2TCZ171011R0030	BL429	1 Gang 1 Way 10A PUSH SWITCH- MARKED BELL	10A	35mm
15	2TCZ171026R0030	BL149*	BLIND CONTROL SWITCH 10A	10A	35mm
16	2TCZ171027R0030	BL191*	4 Gang 2 Way 10AX SWITCH (6X3)	10AX	35mm
17	2TCZ171028R0030	BL198*	6 Gang 2 Way 10AX SWITCH (6X3)	10AX	35mm

Notes: * Will be available in Jun 2024.

Product overview

Socket outlets

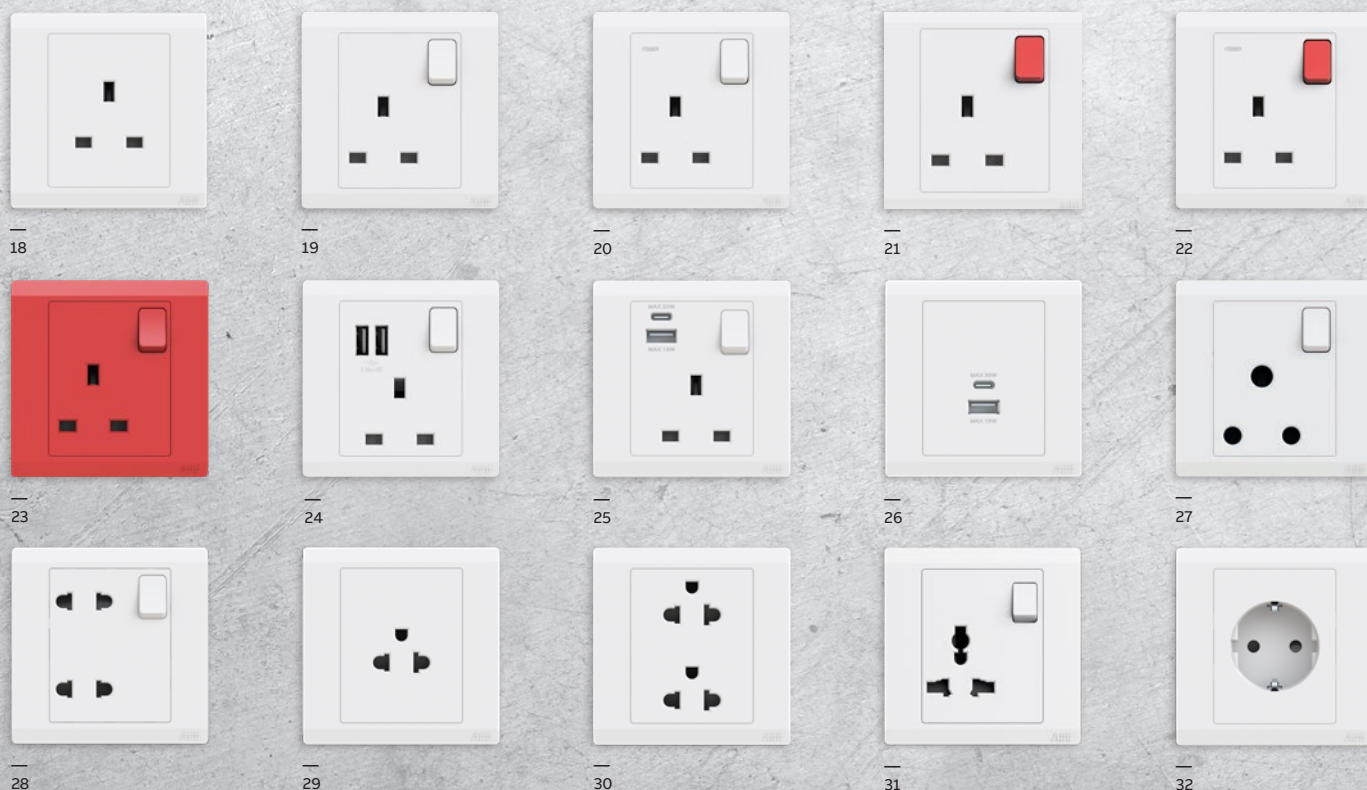


See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Socket					
18	2TCZ172005R0040	BL208	1 Gang 13A SOCKET	13A	35mm
27	2TCZ172012R0050	BL209	1 Gang 15A SWITCHED SOCKET SP	15A	35mm
22	2TCZ172020R0040	BL213	1 Gang 13A SWITCHED SOCKET SP WITH RED ROCKER & ILLUMINATION	13A	35mm
21	2TCZ172019R0040	BL214	1 Gang 13A SWITCHED SOCKET SP WITH RED ROCKER	13A	35mm
28	2TCZ172004R0030	BL222	2 Gang 10A EURO-AMERICAN SWITCHED SOCKET	10A	35mm
19	2TCZ172001R0040	BL224	1 Gang 13A SWITCHED SOCKET SP	13A	35mm
23	2TCZ172001R6240	BL224-R*	1 Gang 13A SWITCHED SOCKET SP	13A	35mm
20	2TCZ172002R0040	BL229	1 Gang 13A SWITCHED SOCKET SP WITH ILLUMINATION	13A	35mm
19	2TCZ172095R0040	BL237	1 Gang 13A SWITCHED SOCKET DP	13A	35mm
20	2TCZ172096R0040	BL238	1 Gang 13A SWITCHED SOCKET DP WITH ILLUMINATION	13A	35mm
29	2TCZ172007R0060	BL244	1 Gang 16A EURO-AMERICAN SWITCHED SOCKET WITH EARTH	16A	35mm
30	2TCZ172008R0060	BL245	2 Gang 16A EURO-AMERICAN SWITCHED SOCKET WITH EARTH	16A	35mm
25	2TCZ172013R0040	BL247*	1 Gang 13A SWITCHED SOCKET DP WITH USB,TYPE A+C	13A	35mm
26	2TCZ172015R0010	BL249*	2 Gang USB CHARGER,TYPE A+C	TYPE A: MAX 18W TYPE C: MAX 30W TYPE A+C: MAX 15W	35mm
24	2TCZ172016R0040	BL261	1 Gang BS SWITCHED SOCKET DP WITH USB,TYPEA*2	13A	47mm
31	2TCZ172003R0040	BL294	1 Gang 13A SWITCHED MULTI-SOCKET OUTLET	13A	35mm
32	2TCZ172009R0060	BL296*	1 Gang 16A SCHUKO SOCKET	16A	35mm

Notes: * Will be available in Jun 2024.

Product overview

Socket outlets

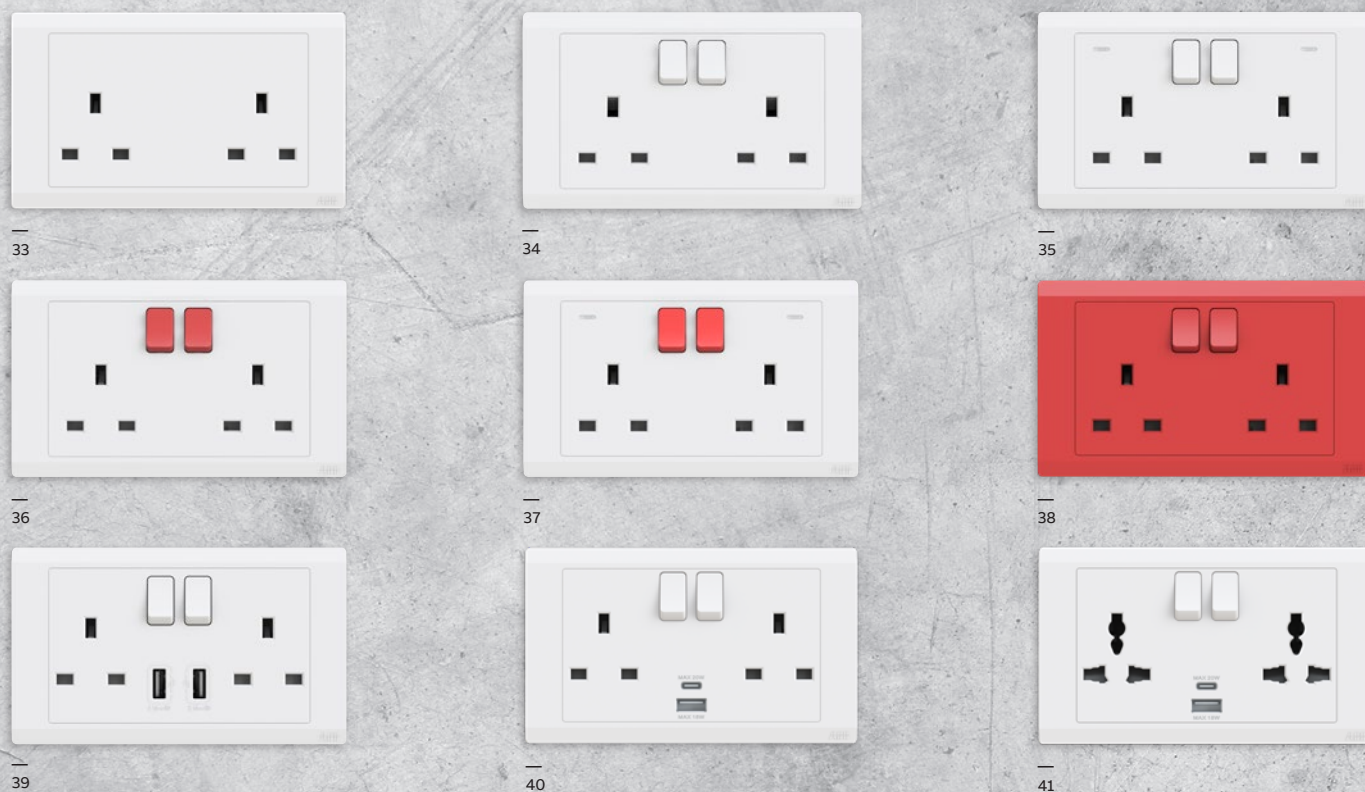


See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Socket					
36	2TCZ172021R0040	BL215	2 Gang 13A SWITCHED SOCKET SP WITH RED ROCKER	13A	35mm
34	2TCZ172010R0040	BL227	2 Gang 13A SWITCHED SOCKET SP	13A	35mm
38	2TCZ172010R6240	BL227-R*	2 Gang 13A SWITCHED SOCKET SP	13A	35mm
35	2TCZ172011R0040	BL230	2 Gang 13A SWITCHED SOCKET SP WITH ILLUMINATION	13A	35mm
37	2TCZ172094R0040	BL236	2 Gang 13A SWITCHED SOCKET SP WITH RED ROCKER & ILLUMINATION	13A	35mm
34	2TCZ172097R0040	BL239	2 Gang 13A SWITCHED SOCKET DP	13A	35mm
35	2TCZ172098R0040	BL240	2 Gang 13A SWITCHED SOCKET DP WITH ILLUMINATION	13A	35mm
40	2TCZ172014R0040	BL248*	2 Gang 13A SWITCHED SOCKET DP WITH USB,TYPE A+C	13A	35mm
41	2TCZ172018R0040	BL250*	2 Gang 13A SWITCHED MULTI-SOCKET SP WITH USB,TYPE A+C	13A	35mm
33	2TCZ172006R0040	BL260	2 Gang 13A SOCKET	13A	35mm
39	2TCZ172017R0040	BL262	2 Gang BS SWITCHED SOCKET DP WITH USB,TYPEA*2	13A	47mm

Notes: * Will be available in Jun 2024.

Product overview

Data outlets

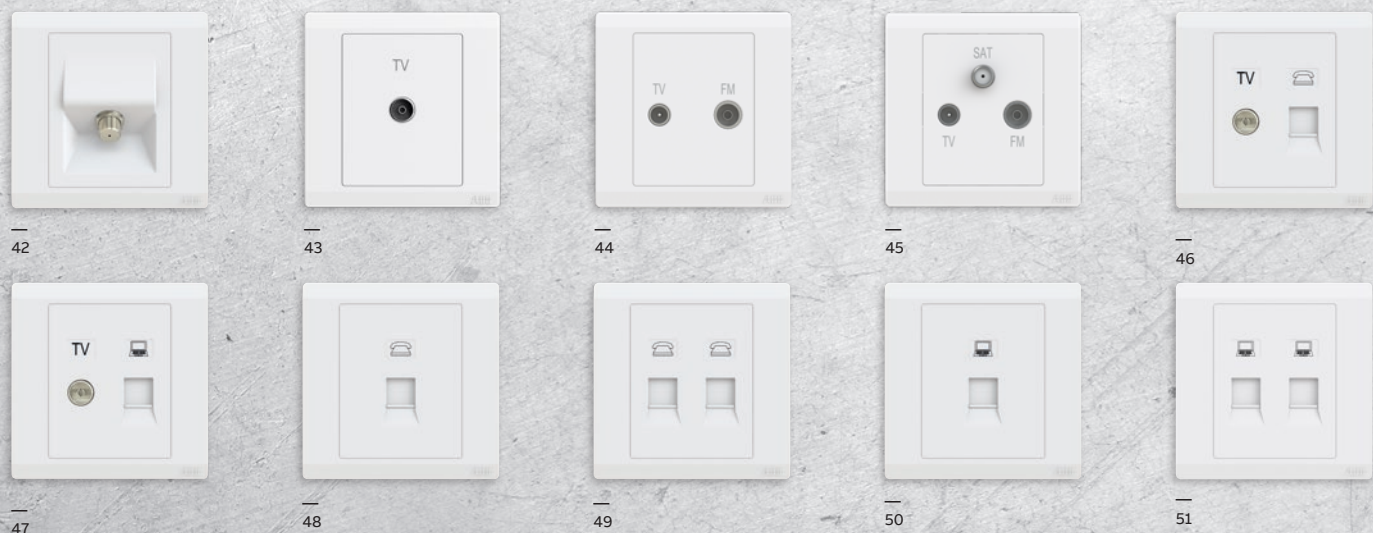

See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Data outlets					
43	2TCZ173001R0010	BL301	1 Gang TV OUTLET, DEAD-END LINE	5-1000MHz	35mm
42	2TCZ173099R0010	BL308	1 Gang SAT OUTLET- 45 DEGREE , F TYPE	5-1000MHz	35mm
44	2TCZ173003R0010	BL312	2 Gang TV & FM OUTLET, DEAD-END LINE	5-1000MHz	35mm
45	2TCZ173002R0010	BL313	3 Gang TV, SAT & FM OUTLET, DEAD-END LINE, F TYPE	5-1000MHz	35mm
51	2TCZ173019R0010	BL317	2 Gang DATA OUTLET RJ45 CAT.6a	RJ45 Cat.6a	35mm
50	2TCZ173020R0010	BL318	1 Gang DATA OUTLET RJ45 CAT.6a	RJ45 Cat.6a	35mm
48	2TCZ173006R0010	BL321	1 Gang TELEPHONE OUTLET RJ11	RJ11	35mm
49	2TCZ173012R0010	BL322	2 Gang TELEPHONE OUTLET RJ11	RJ11	35mm
46	2TCZ173010R0010	BL324	2 Gang TV/TELEPHONE OUTLET	5-1000MHz RJ11	35mm
47	2TCZ173016R0010	BL325	2 Gang TV/DATA OUTLET RJ45 CAT.5e	5-1000MHz RJ45 Cat.5e	35mm
51	2TCZ173014R0010	BL329	2 Gang DATA OUTLET RJ45 CAT.6	RJ45 Cat.6	35mm
50	2TCZ173007R0010	BL331	1 Gang DATA OUTLET RJ45 CAT.5e	RJ45 Cat.5e	35mm
50	2TCZ173017R0010	BL331-H	1 Gang DATA OUTLET HOUSING	-	35mm
51	2TCZ173013R0010	BL332	2 Gang DATA OUTLET RJ45 CAT.5e	RJ45 Cat.5e	35mm
51	2TCZ173018R0010	BL332-H	2 Gang DATA OUTLET HOUSING	-	35mm
50	2TCZ173008R0010	BL333	1 Gang DATA OUTLET RJ45 CAT.6	RJ45 Cat.6	35mm

Product overview

Function control/FCU & Flex outlets/ Accessories



See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Function control					
58	2TCZ174002R0010	BL401	SHAVER SOCKET	Input: 230V, 50 Hz/60 Hz Outlet: 115 V/230 V, 20 VA	47mm
52	2TCZ174004R0060	BL402*	ELECTRONIC CARD SWITCH 16A	16A	41mm
53	2TCZ174005R0030	BL403*	PUSH BUTTON, DND/MUR WITH BELL SYMBOL 10A	10A	35mm
54	2TCZ174006R0030	BL493*	2 Gang SWITCH DND/MUR WITH NEON 10AX	10AX	35mm
56	2TCZ174003R0010	BL405	LED DIMMER	4-150W	35mm
55	2TCZ174001R0010	BL412	ROTARY DIMMER	25-500VA	35mm
57	2TCZ174009R0010	BL422	FAN REGULATOR	25-500VA	35mm
FCU & Flex outlets					
59	2TCZ175003R0040	BL506	1 Gang 13A UNSWITCHED FUSED CONNECTION UNIT	13A250V~	35mm
61	2TCZ175004R0040	BL507	1 Gang 13A SWITCHED FUSED CONNECTION UNIT WITH ILLUMINATION	13A250V~	35mm
60	2TCZ175099R0040	BL508	1 Gang 13A SWITCHED FUSED CONNECTION UNIT	13A250V~	35mm
62	2TCZ175006R0090	BL590	FLEX OUTLET 45A	45A250V~	35mm
Accessories					
63	2TCZ175001R0010	BL504	1 Gang BLANK PLATE	-	35mm
64	2TCZ175002R0010	BL505	2 Gang BLANK PLATE	-	35mm

Notes: * Will be available in Jun 2024.

Product overview

Thermostat




See product picture	Order Code	Type	Description	Technical Data	Flush-mounted Box Dimension
Switches					
65	2TCZ204001R0010	BR417	Thermostat, ON/OFF (2/3 wires)	85VAC-250VAC	47mm
	2TCZ204002R0010	BR483	Thermostat, 0-10Vdc output	24VAC	47mm
	2TCZ204003R0010	BR432	Thermostat, ON/OFF (2/3 wires)-RS485 Modbus	85VAC-250VAC	47mm
	2TCZ204004R0010	BR484	Thermostat, 0-10Vdc output-RS485 Modbus	24VAC	47mm
66	2TCZ204001R4410	BR417-885	Thermostat, ON/OFF (2/3 wires)	85VAC-250VAC	47mm
	2TCZ204002R4410	BR483-885	Thermostat, 0-10Vdc output	24VAC	47mm
	2TCZ204003R4410	BR432-885	Thermostat, ON/OFF (2/3 wires)-RS485 Modbus	85VAC-250VAC	47mm
	2TCZ204004R4410	BR484-885	Thermostat, 0-10Vdc output-RS485	24VAC	47mm
Technical Data					
Operating Voltages	85VAC-250VAC /24VAC, 50-60Hz				
Load Capacity	Resistive: 4A; Inductive: 2A				
Wind Speed	Auto/High/Middle/Low				
Mode selection	Cooling/Fan only/Energy saving/Sleeping				
Temperature Setting Range	5-35°C (0.5°C sensitivity)				
Temperature Display Range	0-45°C				
Temperature Accuracy	+/- 1°C				
Installation box	86 x 86 x 47 mm (BS type) *For 35 mm boxes AMD508 adapter is required.				
Protection Rating	IP20				


Product Technical Information

Dimensions


Dimensions for 1gang frames

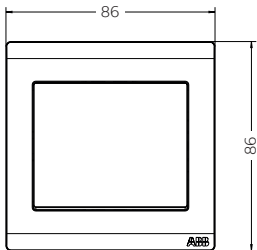


Distance between fixing screws for 1gang frames

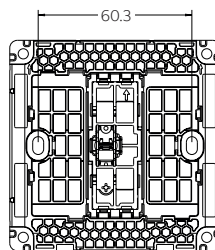


Dimensions for 2gang frames

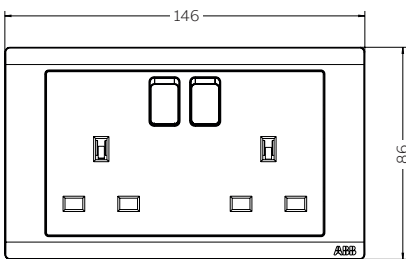


Distance between fixing screws for 2gang frames

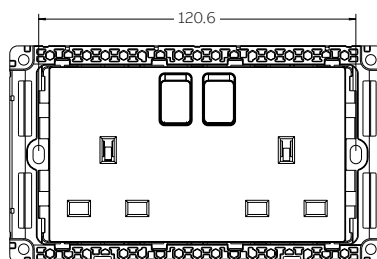


Dimensions for 1gang 45A DP switch (6x3)

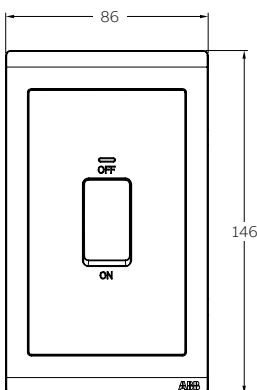


Distance between fixing screws for 45A DP switch (6x3)

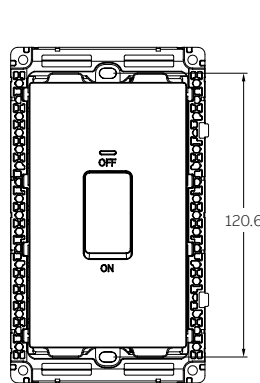

Dimensions for shaver socket

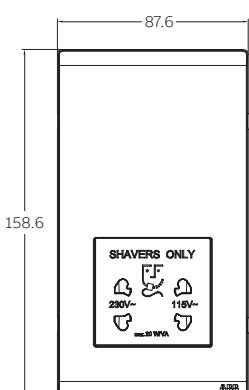


Distance between fixing screws for Shaver socket

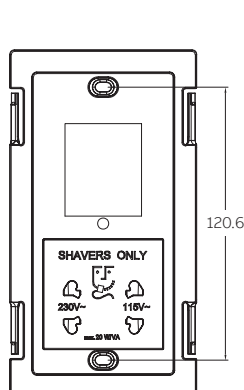


Product Technical Information


Wiring Diagrams

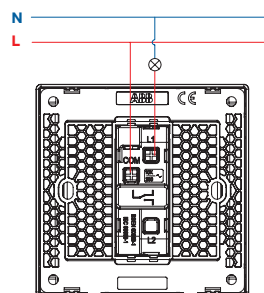


1G 1W switch

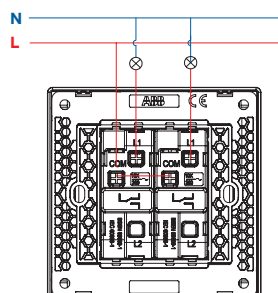


2G 1W switch

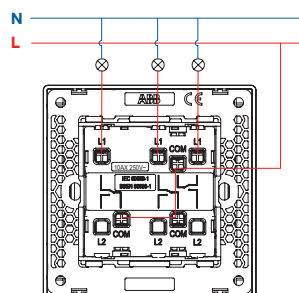


3G 1W switch

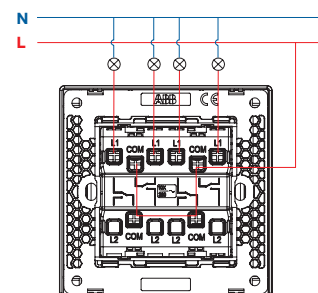


4G 1W switch

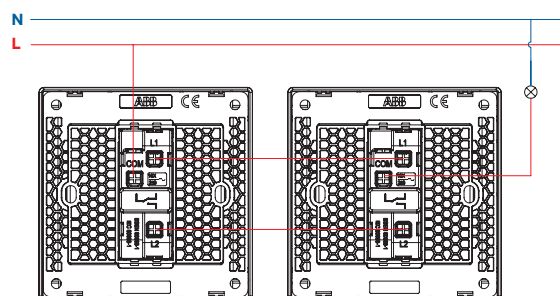


1G 2W switch

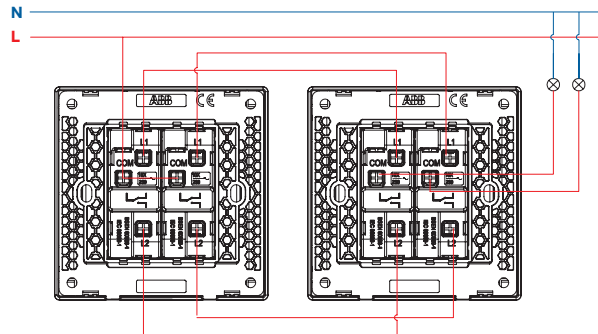

2G 2W switch

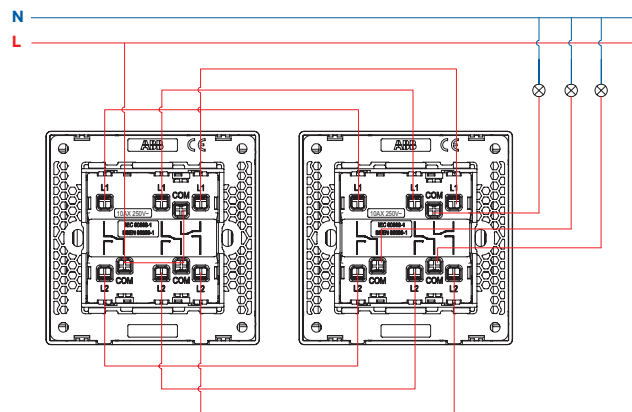


3G 2W switch

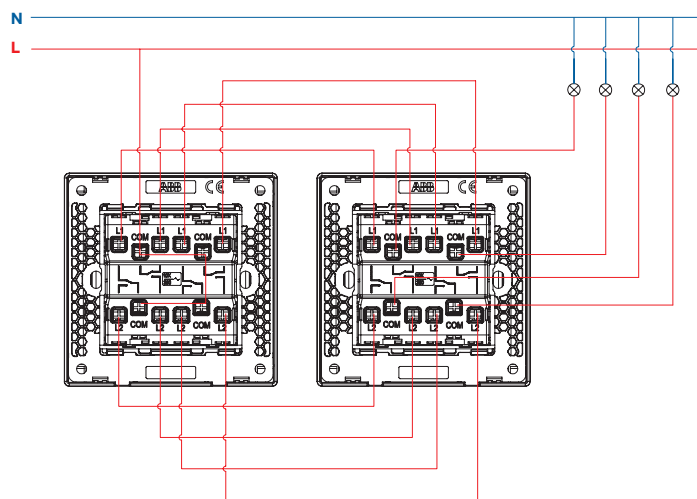


4G 2W switch

Product Technical Information


Wiring Diagrams

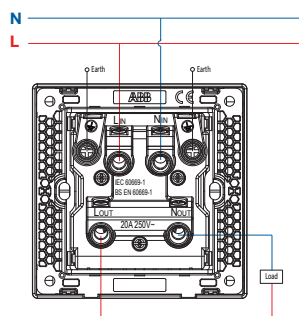


1G 1W switch 20 A DP

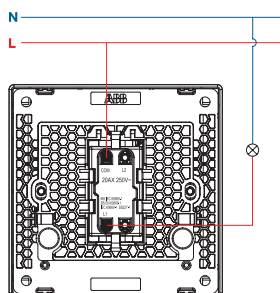


1G 1W switch 20AX DP

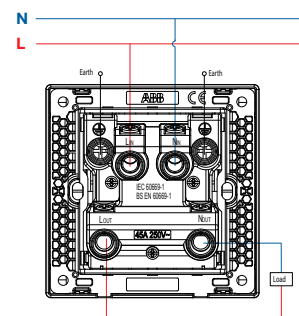


1G 1W 32/45 A switch DP

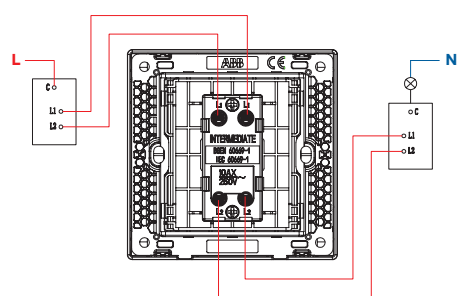


1G intermediate switch

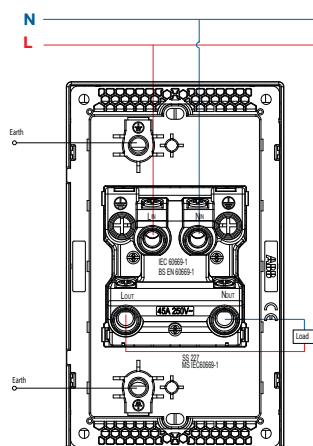


1G 1W 45A switch DP

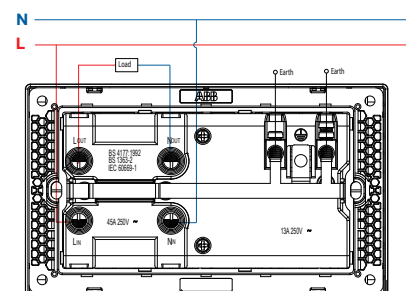


Cooker control unit

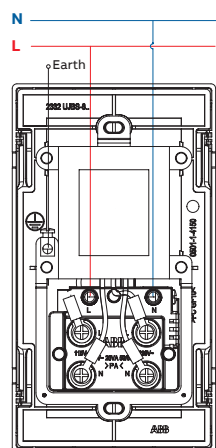

Shaver socket

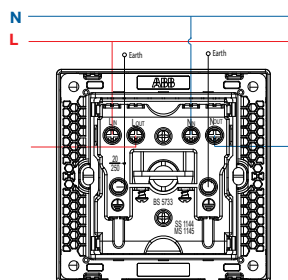


Flex outlet 20 A

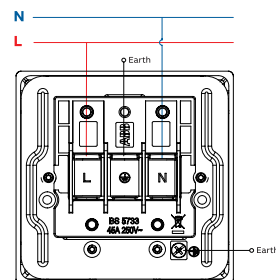


Flex outlet 45 A

Product Technical Information


Wiring Diagrams

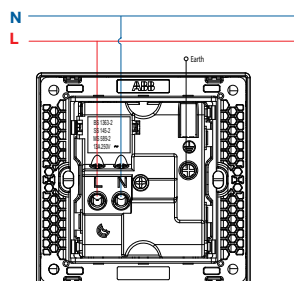


1G 13 A switched socket outlet

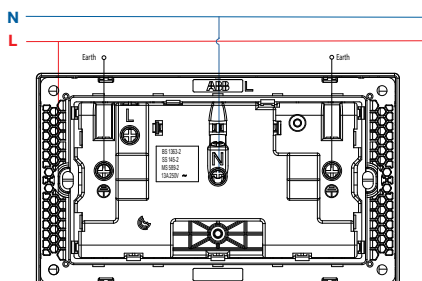


2G 13 A switched socket outlet

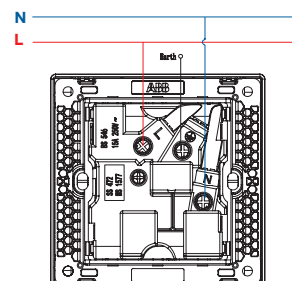


1G 15 A switched socket outlet

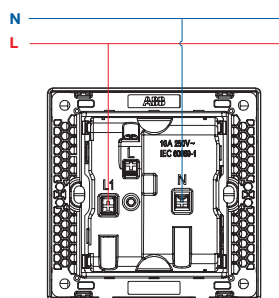


2G 10A Euro-American Switch Socket

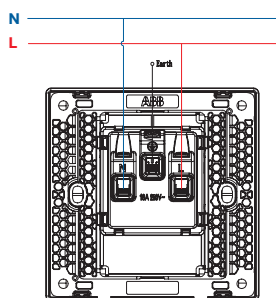


1G/2G 16A Euro-American Socket with Earth

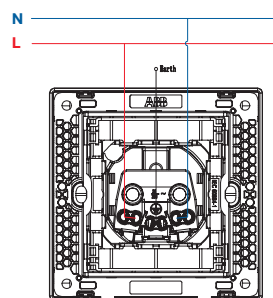


1G 16A SCHUKO Socket

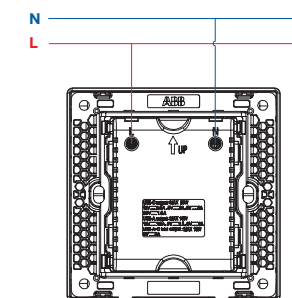


2G USB Charger, Type A+C

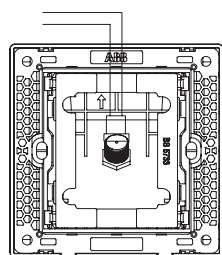

1G TV outlet


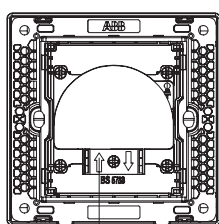


2G TV&FM / 3G TV,SAT&FM Outlet

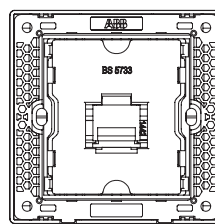


1G telephone outlet

WIRING DIAGRAM

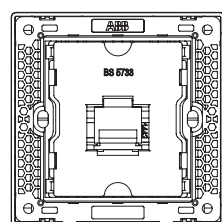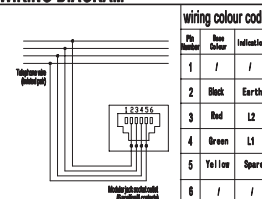


1G/2G data outlet

WIRING DIAGRAM

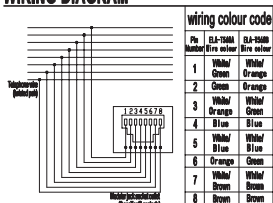


Product Technical Information


Wiring Diagrams

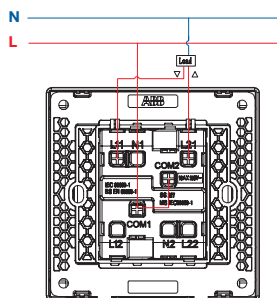

Blind Control Switch

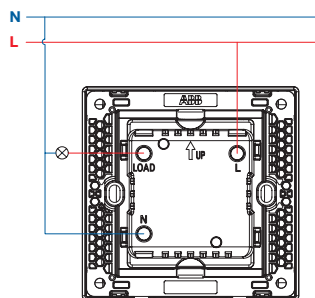


Electronic Card Switch

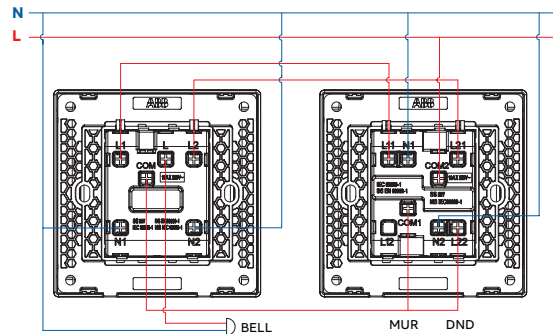


DND/MUR BELL Switch (OUTDOOR)


DND/MUR Switch (INDOOR)

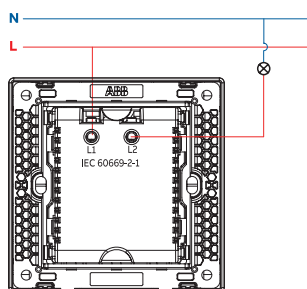


Rotary dimmer

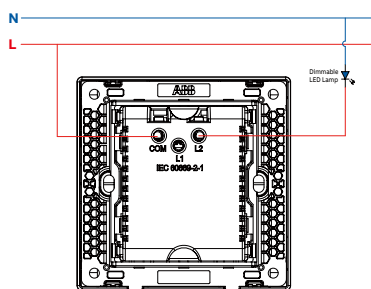


LED dimmer - 1 Way operation

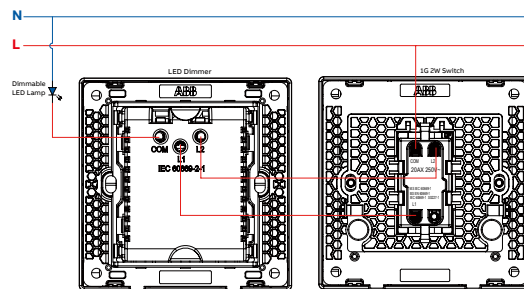


LED dimmer - 2 Way operation

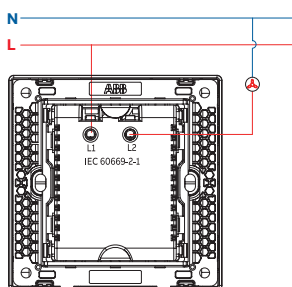

Fan regulator

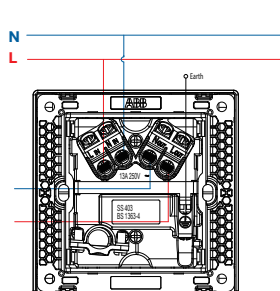

Fused connection unit

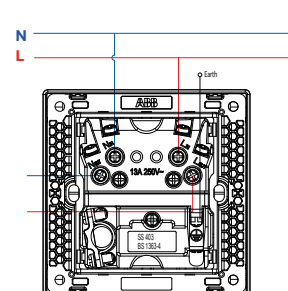

Fused switched connection unit

Product Standards

Product description	Standard	Description
Switches	IEC60669-1 / BSEN60669-1 / SS 227 / MSIEC60669-1	Switches for household and similar fixed electrical installations
Cooker control unit	BS4177 IEC60669-1 BS1363-2 SASO 2203	Specification for Cooker control units Switches for household and similar fixed electrical installations Specification for 13 A switched and unswitched socket outlets Standard for Cooker control units
13 A sockets	BS1363-2 / SS 145-2 / SASO 2203 / MS 589-2	Specification for 13 A switched and unswitched socket outlets
15 A sockets	BS546 / SS472 / MS1577	Two-pole and earthing - pin plugs, socket outlets and socket outlet adaptors
16A SCHUKO socket	IEC60884-1	Plugs and socket - outlets for household and similar purposes – Part 1: General requirements
Shaver socket	IEC60558-1 IEC60558-2-5	Safety of power transformers, power supply units and similar - Part 2-5: particular requirement for shaver transformers and shaver supply units
Dimmer / Fan regulator / Electronic card switch	IEC60669-2-1	Switches for household and similar fixed electrical installations - Part 2-1: Particular requirements - Electronic switches
Telecommunication	BS5733	General requirements for electrical accessories
Fused Connection Unit	BS 1363-4 / SS403	Specification for 13 A fused connection units switched and unswitched
Flex outlet 20 A / 45 A	BS 5733 / MS1144 / MS1145	General requirements for electrical accessories
Plates	BS5733	General requirements for electrical accessories
Thermostat	IEC 60730-1 / EN 60730-1	Automatic electrical controls - Part 1: General requirements
	IEC 60730-2-9 / EN 60730-2-9	Automatic electrical controls - Part 2-9: Particular requirements for temperature sensing control



Notes

Lined area for notes, consisting of multiple horizontal lines.

Contacts

UAE

ABB Industries LLC

Al Quoz Industrial Area 3
4th Interchange, St. No: 4 Dubai
Phone: 0097 1 (4) 3147500

Saudi Arabia

ABB Electrical Industries Co. Ltd.

Al Ahsa Street, Malaz 11371, Riyadh
Phone: 00966 11 4845600

Qatar

ABB LLC

Al Asmakh Tower, 15th floor
864 Hazm Zraig St., Bldg No. 49
Zone 63, Onaiza District, West Bay
PO BOX 8688
Phone: +974 4425 3888

Kuwait

ABB Engineering Technologies Co. (KSCC)

Alghunaim Commercial Twr, 2nd Flr, Al-Qibla Area
P.O.Box 4275, Safat-13043,
Abu Baker Al-Sadique Street
Phone: +965 2428626

Bahrain

ABB Technologies W.L.L.

Gulf Executive Offices, 12/Flr. Office 1023
Entrance 15, Road 3801, AlGudaibiya 338
Phone : +973 17810659

Oman

ABB LLC

218, Hatat House, P. O. Box 778,
131 Al Hamriya Muscat
Phone: 00968 24 567 410

Jordan

ABB Ltd.

Wasfi Altal Street - Building 356 - Khalda
P.O Box 926098 Amman 11190
Phone: +962 (6) 5507733

Pakistan

ABB Power & Automation (Pvt) Ltd.

P.E.C. Building, 97-A/D-1,
Liberty Market, Gulberg-III,
P.O. 2353, Lahore-54660, Pakistan
Phone: +92-42-32560740

Nigeria

ABBNG Limited

Plot 8C Metalbox road, off Acme
road Ogba, Ikeja, Lagos, Nigeria
Phone: +234907 000 0176

Sri Lanka

ABB India Limited

Level 35, West Tower, World Trade Center
Colombo 00100, Sri Lanka
Phone: +94 77 789 6445

Bangladesh

ABB Limited, The Glass House,
38 Gulshan Avenue (12th Floor)
Dhaka -1212
Phone: +88 02 98 56468 / 53412

Singapore

ABB Pte. Ltd.

2, Ayer Rajah Crescent
SGP - 139935
Phone: +65 6 776 5711

Malaysia

ABB Malaysia Sdn Bhd

Lot 608, Jalan Lagoon Selatan,
47500 Subang Jaya, Selangor.
Phone: +603 5628 4888

Vietnam

ABB Automation and Electrification (Vietnam) Company Ltd

12th Floor, REE tower, 9 Doan Van Bo street,
12th ward, 4 District, Ho Chi Minh City
Phone: +8428 3943 1488

Hong Kong

ABB (Hong Kong) Limited

Offices E&F, 5/F YHC Tower,
No. 1 Sheung Yuet Road, Kowloon Bay,
Kowloon, Hong Kong
Phone: +852 2929-3912



—
[new.abb.com/low-voltage/products/
residential-products](https://new.abb.com/low-voltage/products/residential-products)