

# City of Chicago Approved Chicago Prestige™ Edge-Lit Series

Premium white LED exit signs



## Construction

- Housing: Die-cast aluminum back box, trim ring, trim plate and canopy. Standard finish is brushed aluminum with other finishes available as an option
- Faceplate: Virgin acrylic face plate is thin, silk-screened to provide a flawless legend. Face plates are available with red letters on a white background
- White LED light source, 10-year life expectancy

## Mounting

- Modular design allows for surface or recessed mount
- Canopy included for surface wall, end or ceiling mount applications
- Trim ring included for recessed wall or ceiling mount applications.
- Housing provided with conduit knock-out 1/2", top, back and end
- (C) circular or (A) angular trim plate used for surface or recessed wall or ceiling mount applications
- Hanger bars included for lay-in installation in T-bar grid

## Special wording panels

- Available. Contact your sales representative with your design requirements

## Electronics

- Optional Advanced Diagnostics
- 120-277 60HZ

## Approvals




- UL 924 listed
- City of Chicago Approved

## Warranty

- Unit has a five-year limited warranty  
Detailed warranty terms located online at:  
[www.emergi-lite.com/usa/files/EL\\_Warranty.pdf](http://www.emergi-lite.com/usa/files/EL_Warranty.pdf)

## Dimensions

Dimensions are approximate and subject to change.

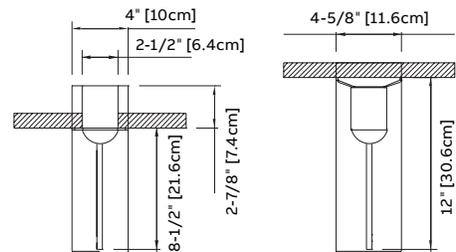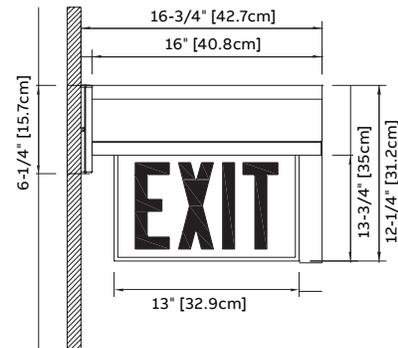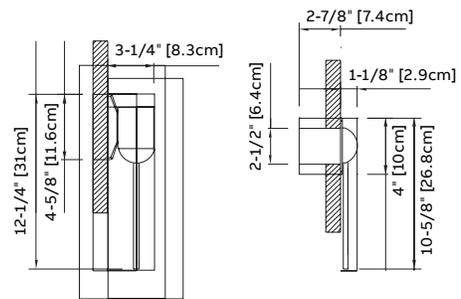

Add 1-1/2" to height of unit when ordering panel with arrow




Modular design accommodates surface or recessed mount with included canopy and trim ring.

**Arrow (chevron) designation**



Wording and chevrons not to scale. For illustration purposes only.

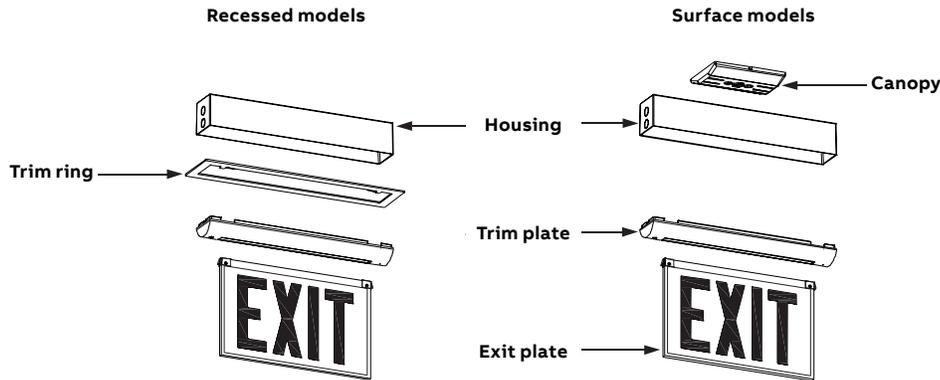

**Power consumption**

Model		AC specs		DC specs
AC-only	120 to 277VAC	Less than 2.5W	-	-
AC/DC-remote	120 to 277VAC	Less than 2.5W	6 to 24VDC	Less than 2.5W
Self-powered	120 to 277VAC	Less than 3.5W	Ni-Cd battery	2 hours
Self-powered diagnostic	120 to 277VAC	Less than 3.5W	Ni-Cd battery	2 hours

**Backbox** (order as a separate item)

Description	Suffix
Backbox kit white	BBKTS-WT-E
Backbox kit black	BBKTS-BK-E
Backbox kit brushed aluminum	BBKTS-BA-E
Backbox kit chrome	BBKTS-CH-E
Backbox kit dark bronze	BBKTS-BR-E
Backbox kit polished brass	BBKTS-PB-E

**Accessories** (order as a separate item)

Description	Suffix <sup>1</sup>
White pendant	P*-WT
Black pendant	P*-BK
Gray pendant	P*-GY

<sup>1</sup>Custom pendant lengths and colors available, specify (12", 24", 36", etc.)

**How to order**

Housing color	Custom specification	Model	Legend and panel	Trim plate	Options
<b>Blank</b> = Brushed aluminum	<b>CC</b> = City of Chicago	<b>PLX</b> = AC only	<b>#2A</b> = Single face, STAIRS, no arrow	<b>A</b> = Angular	<b>-DL</b> = Damp locations
<b>W</b> = White		<b>PLXDC</b> = AC/DC-remote 6-24V	<b>#17A</b> = Double face, STAIRS, no arrow	<b>C</b> = Circular	<b>-X</b> = Less backbox <sup>1</sup>
<b>B</b> = Black		<b>PLX2CKT</b> = AC-dual circuit	<b>#5A</b> = Single face, STAIRS, arrow right		
<b>BR</b> = Dark bronze (painted)		<b>PLXN</b> = Self-powered	<b>#8A</b> = Single face, STAIRS, arrow left		
<b>PB</b> = Polished brass		<b>PLXND</b> = Self-powered diagnostic	<b>#11A</b> = Single face, STAIRS, double arrow		
<b>CH</b> = Polished Chrome			<b>#23A</b> = Double face, STAIRS, double arrow		
			<b>#20A</b> = Double face, (1) STAIRS, (2) STAIRS, single arrow		
			<b>#3</b> = Single face, EXIT, no arrow		
			<b>#18</b> = Double face, EXIT, no arrow		
			<b>#6</b> = Single face, EXIT, arrow right		
			<b>#9</b> = Single face, EXIT, arrow left		
			<b>#12</b> = Single face, EXIT, double arrow		
			<b>#24</b> = Double face, EXIT, double arrow		
			<b>#21</b> = Double face, (1) EXIT, (2) EXIT, single arrow		
			<b>LP</b> = Panel shipped separately		

Example: WCCPLX#2AA

<sup>1</sup>Order backbox as a separate item