

Prestige™ DX Series

Die-cast exit sign



Construction

- Faceplate, backplate and canopy are made of die-cast aluminum
- 6 inch EXIT lettering legend, available in red or green
- 8 inch EXIT lettering legend, available in red
- Choice of finishes: white, black, brushed aluminum or dark bronze

Mounting

- Surface mount
- Canopy included for end or ceiling mount applications
- Universal J-box mounting

Special wording panel

- Available. Contact your sales representative with your design requirements

Electronics

- Standard Advanced Diagnostics on DXN
- 120-277 50/60Hz
- Compatible with Emergi-lite Mini Inverters (contact your sales representative for more information)

Approvals

- CSA-US (To UL 924 standards)
- Damp location optional (50°F to 104°F)
- Meets NFPA101 (Life Safety Code), NFPA 70 NEC, OSHA illumination standards
- E-California Energy Commission Title 20

Warranty

- Unit has a five-year limited warranty
Detailed warranty terms located on page 202 or online at:
www.emergi-lite.com/usa/files/EL_Warranty.pdf

Power consumption

Model 6"	AC specs	DC specs
AC/DC-remote	120 to 277VAC, 50/60Hz	6 to 48VDC Less than 1.5W
Self-powered	120 to 277VAC, 50/60Hz	Nickel-cadmium battery Min. 90 minutes
Model 8"	AC specs	DC specs
AC/DC	120 to 277VAC, 50/60Hz	6 to 24VDC 1.6W
Self-powered	120 to 277VAC, 50/60Hz	Nickel-cadmium battery Min. 90 minutes

Color frame/faceplate colors



Black



White




Brushed aluminum



Dark bronze
(painted)

Dimensions

Dimensions are approximate and subject to change.

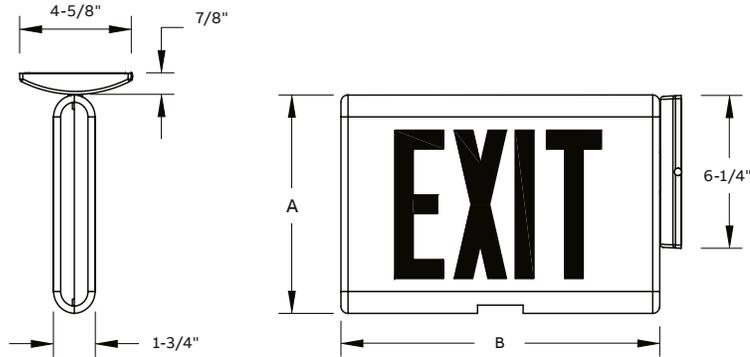

Cabinet information

Letters	Dimensions	
	A	B
6"	8-7/8"	13-1/16"
8"	10-1/2"	15-1/4"

Accessories (order as a separate item)

Description	Suffix
White pendant	PDW ¹
Black pendant	PDB ¹
Pendant mount gray	PDGY ¹
Wire guard (wall mount) (6 in.)	WG12-E
Wire guard (ceiling mount) (6 in.)	WG5-E
Wire guard (end mount) (6 in.)	WG5-E

¹Specify pendant length (12", 24", 36", etc.)

How to order

Color frame/faceplate	Series	# of faces	Legend color	Letters
Blank = Black/brushed aluminum	DXN = Self-powered unit	1 = Single face	R = Red	Blank = 6" letters
WW = White/white	DX = AC/DC	2 = Double face	G = Green	8 = 8" letters
WA = White/brushed aluminum			Open face ¹	
BZ = Bronze/bronze			RW = Red on white	
BB = Black/black			GW = Green on white	
AA = All brushed aluminum				

Diagnostic options	Options	Version
Blank = Standard	Blank = Standard	-N = New design ²
	DL = Damp location	
	VR = Vandal resistant screws	
	VR1 = Polycarbonate shield with tamper proof screws	
	2CKT = 2 Circuit (120/120 or 277/277, AC only) ²	

Example: DXN1R-N

¹Open face required for special wording, only available on 6" models

²Not required for 8" letters