

New product

CM-SS Series

Steel pictogram sign




Features

- Steel housing and polycarbonate panel illuminated by high efficiency LEDs
- Universal side, wall and ceiling mount
- Universal single and double face
- 3 pictogram panels included: 1 with no arrow and 2 with arrows
- 120-347VAC 50/60HZ, 6-24VDC input
- Nickel-cadmium battery offering 120 minutes of emergency lighting
- Red LED charger monitor and momentary test switch (self-powered model)
- CSA C22.2 no.141-15 certified
- **Warranty details at: www.emergi-lite.ca**



Dimensions

Dimensions are approximate and subject to change.

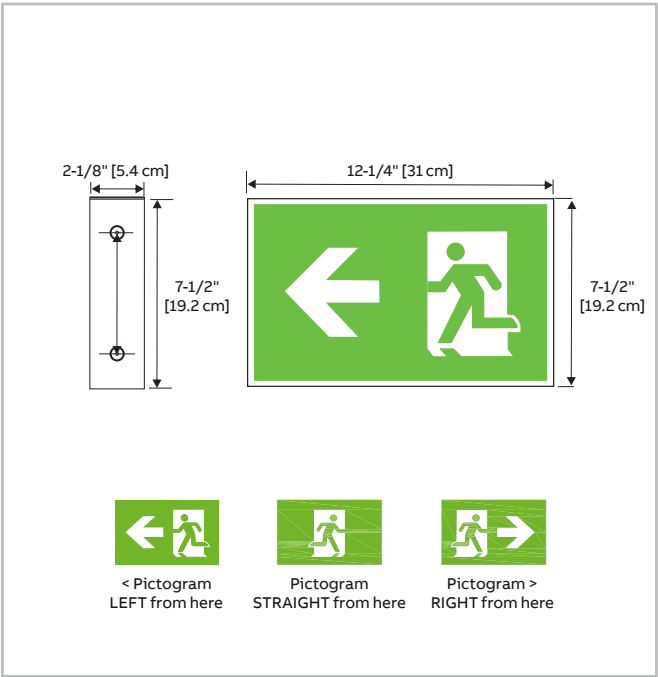

Power consumption and unit rating

Model	Input wattage (AC/SP)	Current (AC/SP)	AC specs	DC specs
			Efficiency (AC/SP)	
CM-SS-E	120V, 50/60Hz	2W/3W	0.01A/0.02A	0.96P/0.98PF
	277V, 50/60Hz	2.1W/3.2W	0.009A/0.013A	0.88PF/0.9PF
	347V, 50/60Hz	3W/4W	0.01A/0.017A	0.91P/0.92PF

Ordering information

Series	Voltage	Brand
CM-SS	-ACDC= 120VAC-347VAC, 6-24VDC	-E= Emergi-Lite®
	-SP=120VAC-347VAC, self-powered (120 minutes)	

Example: CM-SS-ACDC-E