



中国国家强制性产品认证证书

证书编号: 2012010302579872

委托人名称、地址

ABB Oy, Breakers and Switches
Muottitie 2A FI-65320 VAASA, Finland

生产者(制造商)名称、地址

ABB Oy, Breakers and Switches
Muottitie 2A FI-65320 VAASA, Finland

生产企业名称、地址

Plastone OU
Tule 23A, EE-76505 Saue, Estonia

产品名称和系列、规格、型号

隔离开关

OTDC16F_, OTDC25F_,
OTDC32F_, OTDC16U_, OTDC16US_, OTDC25U_, OTDC25US_, OTDC32U_, OTDC32US_ (型号解释
详见附件);

产品标准和技术要求

GB 14048.3-2008

上述产品符合强制性产品认证实施规则
CNCA-C03-02:2014的要求, 特发此证。

发证日期: 2015年05月20日

有效期至: 2017年11月09日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

本证书为变更证书, 证书首次颁发日期: 2012年11月09日

本证书的相关信息可通过国家认监委网站www.cnca.gov.cn查询



主任:

中国质量认证中心

中国·北京·南四环西路188号9区 100070

<http://www.cqc.com.cn>



Q 1145149



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

No. : 2012010302579872

NAME AND ADDRESS OF THE APPLICANT

ABB Oy, Breakers and Switches
Muottitie 2A FI-65320 VAASA, Finland

NAME AND ADDRESS OF THE MANUFACTURER

ABB Oy, Breakers and Switches
Muottitie 2A FI-65320 VAASA, Finland

NAME AND ADDRESS OF THE FACTORY

Plastone OU
Tule 23A, EE-76505 Saue, Estonia

NAME, MODEL AND SPECIFICATION

Switch-disconnector

OTDC16F_, OTDC25F_,
OTDC32F_, OTDC16U_, OTDC16US_, OTDC25U_, OTDC25US_, OTDC32U_, OTDC32US

THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB 14048.3-2008

This is to certify that the above mentioned products have met the requirements of implementation rules for compulsory certification(REF NO. CNCA-C03-02:2014).

Date of issue: May.20,2015 Date of expiry: Nov.09,2017

Validity of this certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

Date of original certification: Nov.09,2012

This certificate can be verified through CNCA's website: www.cnca.gov.cn



President:

Wang Kejiao



CHINA QUALITY CERTIFICATION CENTRE

Section 9, No.188, Nansihuan Xilu, Beijing 100070 P.R.China

<http://www.cqc.com.cn>

Q 1145149



中国国家强制性产品认证证书

附录:

第 1 页 共 6 页

证书编号: 2012010302579872

纸号: 1145149

OTDC16F,OTDC16U,OTDC16US,OTDC25F,OTDC25U,OTDC25US,OTDC32F,OTDC32U,
OTDC32US

额定绝缘电压(Ui): 1000V,1250V;

约定发热电流(Ith): OTDC16F:25A,OTDC25F:32A,OTDC32F:45A,OTDC16U,OTDC16US:40A,
OTDC25U,OTDC25US:50A,OTDC32U, OTDC32US:63A;

额定工作电压(Ue): 见下表一;

额定工作电流(Ie): 见下表一;

额定短时耐受电流(Icw):800A/1s(OTDC16F,OTDC25F, OTDC32F),
1000A/1s(OTDC16U,OTDC16US,OTDC25U,OTDC25US,OTDC32U,OTDC32US);

额定短路接通能力(Icm): 800A(OTDC16F,OTDC25F,OTDC32F),

1000A(OTDC16U,OTDC16US,OTDC25U,OTDC25US,OTDC32U,OTDC32US);

使用类别: DC-21B;

	2-pole (OTDC_F2)	3-pole (OTDC_F3)	4-pole (OTDC_F4)
OTDC16F	DC-21B 16 A 660 V (2-poles in series)	DC-21B 16 A 1000 V (3-poles in series)	DC-21B 16 A 660 V (2-poles in series)
OTDC25F	DC-21B 25 A 660 V (2-poles in series)	DC-21B 25 A 1000 V (3-poles in series)	DC-21B 25 A 660 V (2-poles in series)
OTDC32F	DC-21B 32 A 660 V (2-poles in series)	DC-21B 32 A 1000 V (3-poles in series)	DC-21B 32 A 660 V (2-poles in series)

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>





中国国家强制性产品认证证书

附录:

第 2 页 共 6 页

证书编号: 2012010302579872

纸号: 1145149

Utilization category DC-21B	2-pole 1 circuit	4-pole 2 circuit	6-pole 3 circuit
OTDC16U_ , OTDC16UT_	16A 660V 10A 1000V	16A 660V 10A 1000V	16A 660V 10A 1000V
OTDC25U_ , OTDC25UT_	25A 660V 16A 1000V	25A 660V 16A 1000V	25A 660V 16A 1000V
OTDC32U_ , OTDC32UT_	32A 660V 20A 1000V	32A 660V 20A 1000V	32A 660V 20A 1000V
OTDC16US_ , OTDC16UST_	16A 660V	16A 660V	16A 660V
OTDC25US_ , OTDC25UST_	25A 660V	25A 660V	25A 660V
OTDC32US_ , OTDC32UST_	32A 660V	32A 660V	32A 660V

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>





中国国家强制性产品认证证书


附录:

第 3 页 共 6 页

证书编号: 2012010302579872

纸号: 1145149

型号的解释:

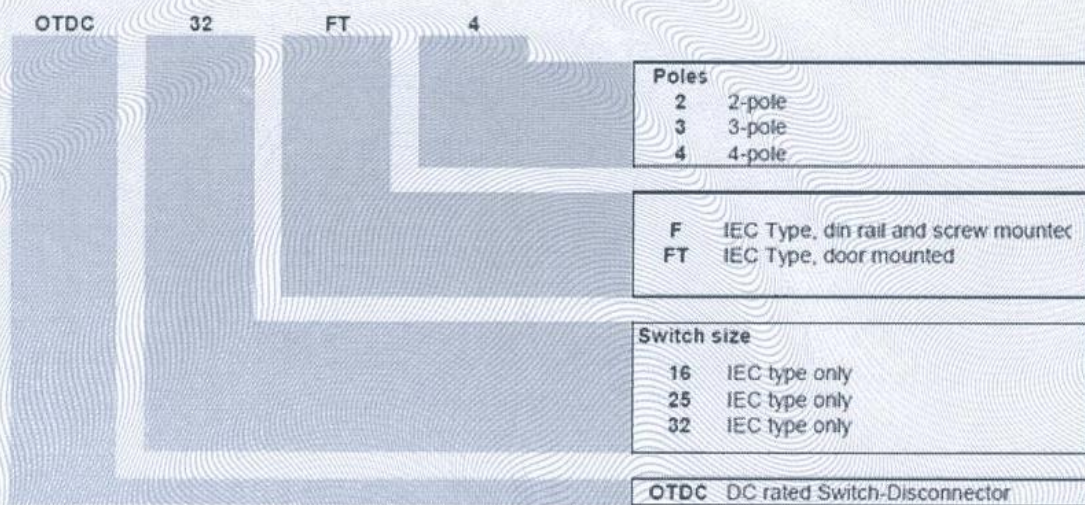

OTDC16F2	OTDC25F2	OTDC32F2
OTDC16F3	OTDC25F3	OTDC32F3
OTDC16F4	OTDC25F4	OTDC32F4

OTDC16FT2	OTDC25FT2	OTDC32FT2
OTDC16FT3	OTDC25FT3	OTDC32FT3
OTDC16FT4	OTDC25FT4	OTDC32FT4

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国·北京·南四环西路188号9区 100070

<http://www.cqc.com.cn>





中国国家强制性产品认证证书

附录:

第 4 页 共 6 页

证书编号: 2012010302579872

纸号: 1145149

OTDC	32	US	T	6	
					Poles
					2 2-pole
					4 4-pole
					6 6-pole
					- Din rail and base mounted
					T Door mounted
					U UL/IEC type, without connection bar
					US UL/IEC type, with connection bar
					Switch size
					16
					25
					32
					OTDC DC rated Switch-Disconnecter

OTDC16U2	OTDC25U2	OTDC32U2
OTDC16U4	OTDC25U4	OTDC32U4
OTDC16U6	OTDC25U6	OTDC32U6
OTDC16UT2	OTDC25UT2	OTDC32UT2
OTDC16UT4	OTDC25UT4	OTDC32UT4
OTDC16UT6	OTDC25UT6	OTDC32UT6
OTDC16US2	OTDC25US2	OTDC32US2
OTDC16US4	OTDC25US4	OTDC32US4
OTDC16US6	OTDC25US6	OTDC32US6
OTDC16UST2	OTDC25UST2	OTDC32UST2
OTDC16UST4	OTDC25UST4	OTDC32UST4
OTDC16UST6	OTDC25UST6	OTDC32UST6

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>





中国国家强制性产品认证证书


附录:

第 5 页 共 6 页

证书编号: 2012010302579872

纸号: 1145149

直流产品接线方式

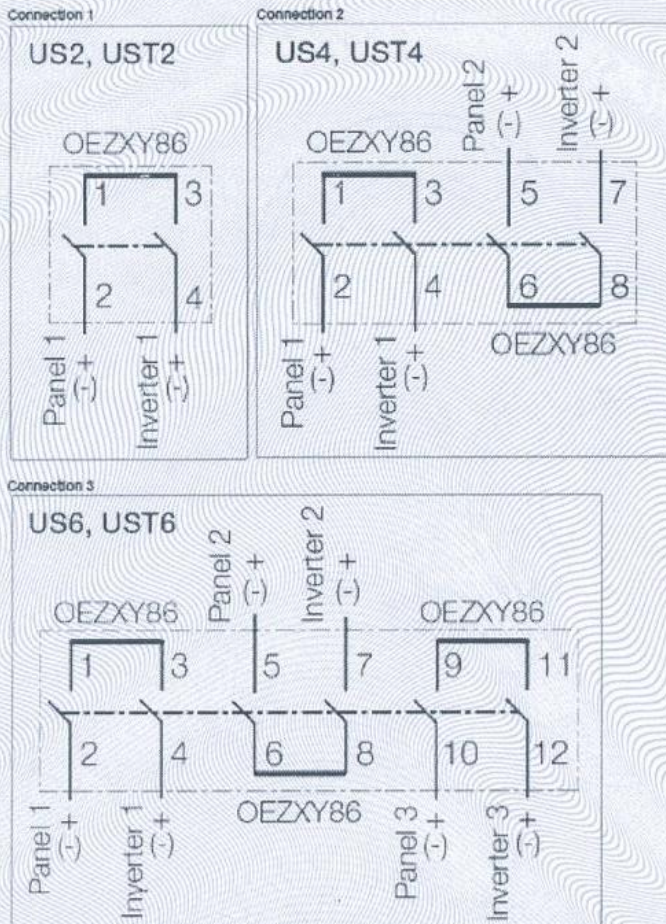

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>






中国国家强制性产品认证证书

附录:

第 6 页 共 6 页

证书编号: 2012010302579872

纸号: 1145149

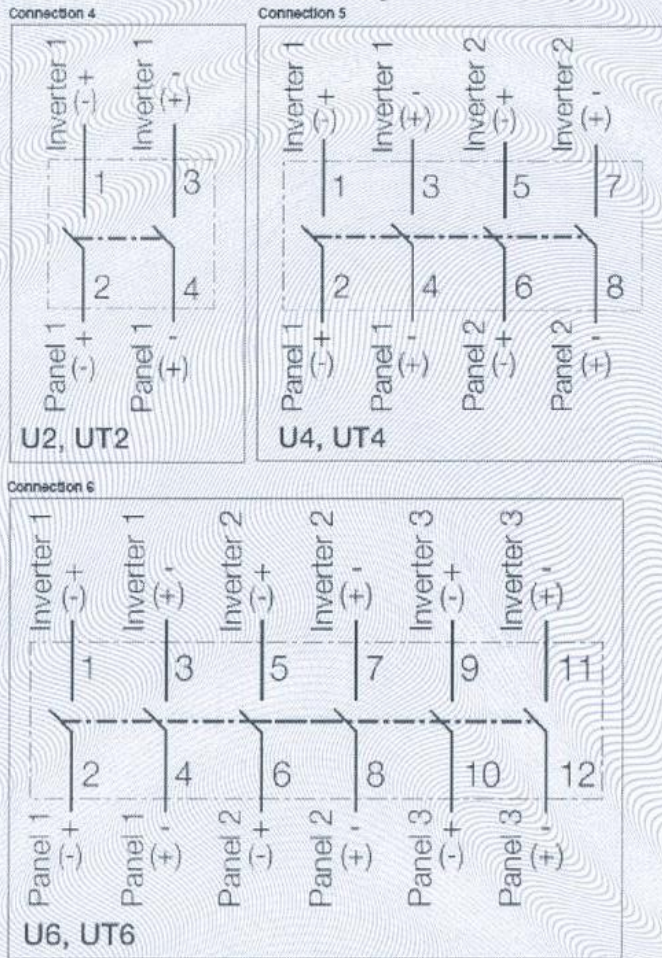

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>

