

产品认证证书

II型自愿认证

证书编号: CQC2003010305054693

发证日期: 2021年04月16日

有效期至: 2024年11月14日

委托人名称及注册地址 ABB 新会低压开关有限公司
广东省江门市新会区今古洲工业开发区

制造商名称及注册地址 ABB 新会低压开关有限公司
广东省江门市新会区今古洲工业开发区

生产企业名称及生产地址 ABB 新会低压开关有限公司
广东省江门市新会区今古洲工业开发区

产品名称和系列、规格、型号 指示装置
TYPE C(CP、C2SS、C3SS、CL、CE、CB、CEP) 型号解释见附件

产品标准和技术要求 GB/T 14048.5-2017

认证模式 产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC12-000001-2020 认证规则的要求, 特发此证。

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站 (www.cnca.gov.cn) 查验证书信息



授权签字人:

主任:

刘江

陆楠

中国质量认证中心



<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C(2) 0031457

PRODUCT CERTIFICATION

TYPE II CQC CERTIFICATION

CERTIFICATE NO.: CQC2003010305054693

Valid from: Apr.16,2021

Valid until: Nov.14,2024

NAME AND REGISTERED ADDRESS OF THE APPLICANT	ABB Xinhui Low Voltage Switchgear Co.,Ltd. Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China
NAME AND REGISTERED ADDRESS OF THE MANUFACTURER	ABB Xinhui Low Voltage Switchgear Co.,Ltd. Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China
NAME AND LOCATION OF THE FACTORY	ABB Xinhui Low Voltage Switchgear Co.,Ltd. Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China
PRODUCT NAME, MODEL AND SPECIFICATION	Pilot devices TYPE C(CP、C2SS、C3SS、CL、CE、CB、CEP) See the Appendix
THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS	GB/T 14048.5-2017
TYPE OF CERTIFICATION SCHEMES	Type Testing of Product + Initial Factory Inspection + Follow up Factory Inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC12-000001-2020.
The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

The certificate information is available through the QR code below or CNCA's website: www.cnca.gov.cn



SIGNED BY:

PRESIDENT:

CHINA QUALITY CERTIFICATION CENTRE



<http://www.cqc.com.cn>

Section 9, No.188, Nansihuan Xilu, Beijing 100070 P.R.China

Tel: +86 10 83886666

C(2) 0031457

产品认证证书

II型自愿认证

证书编号: CQC2003010305054693

第 1 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

TYPE C(CP、C2SS、C3SS、CL、CE、CB、CEP)

Ui:300V (按钮、选择开关和急停开关, 蜂鸣器和带灯按钮), 415V (指示灯);

Uimp:6kV (按钮、选择开关和急停开关和带灯按钮), 4kV (蜂鸣器);

Ith:5A(按钮、选择开关、急停按钮和带灯按钮);

按钮、选择开关、急停按钮、带灯按钮、塑料按钮盒(套装)

AC-15: 120V/3A, 240V/2A (触头 Ag), 120V/1.5A, 240V/1A (触头 Cu/Ep.Ag); DC-13: 24V/0.3A, 125V/0.2A;

LED 指示灯: Ue=110-130VAC, 230VAC, Ie=15mA;

Ue=48VAC/DC, Ie=12mA; Ue=110-130VDC, Ie=7mA; Ue=220VDC, Ie=5mA;

Ue=380VAC, Ie=16mA; Ue=60VAC/DC, 415VAC, Ie=17mA;

LED II 指示灯: Ue=48-60VAC/DC, Ie=13-17mA;

Ue=110-130VAC, Ie=15-17mA; Ue=110-130VDC, Ie=8-9mA; Ue=230VAC, Ie=17mA;

Ue=220VDC, Ie=6mA; Ie=2mA(CL2-720), Ue=380-415VAC, Ie=15-17mA;

白织灯指示灯: Uemax=240VAC;

蜂鸣器(红,黄色带灯):

Ue=110-130VAC, 230VAC, Ie=70mA; Ue=110-130VDC, Ie=15mA;

(绿色带灯): Ue=110-130VAC, 230VAC, Ie=55mA; Ue=110-130VDC, Ie=15mA;

外壳防护等级: 安装在特定面板后头部外壳防护等级可达到 IP66, 尾部端面可达到 IP20, 基于标准产品的特殊印刷 LED 指示灯 CL9 安装在特定面板后头部外壳防护等级可达到 IP66 和尾部端面可达到 IP20, 没有安装平垫圈的 LED 指示灯 CL9 安装在特定面板后头部外壳防护等级可达到 IP40 和尾部端面可达到 IP20。塑料按钮盒(套装) CEP 没有安装保护罩或标牌时外壳防护等级可达到 IP66, 安装保护罩或标牌时外壳防护等级为 IP40

附件



中国质量认证中心

产品认证证书

II型自愿认证

证书编号: CQC2003010305054693



第 2 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

型号解释:

按钮

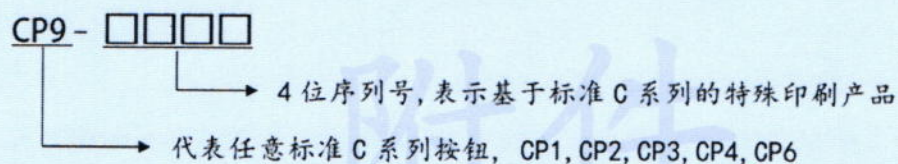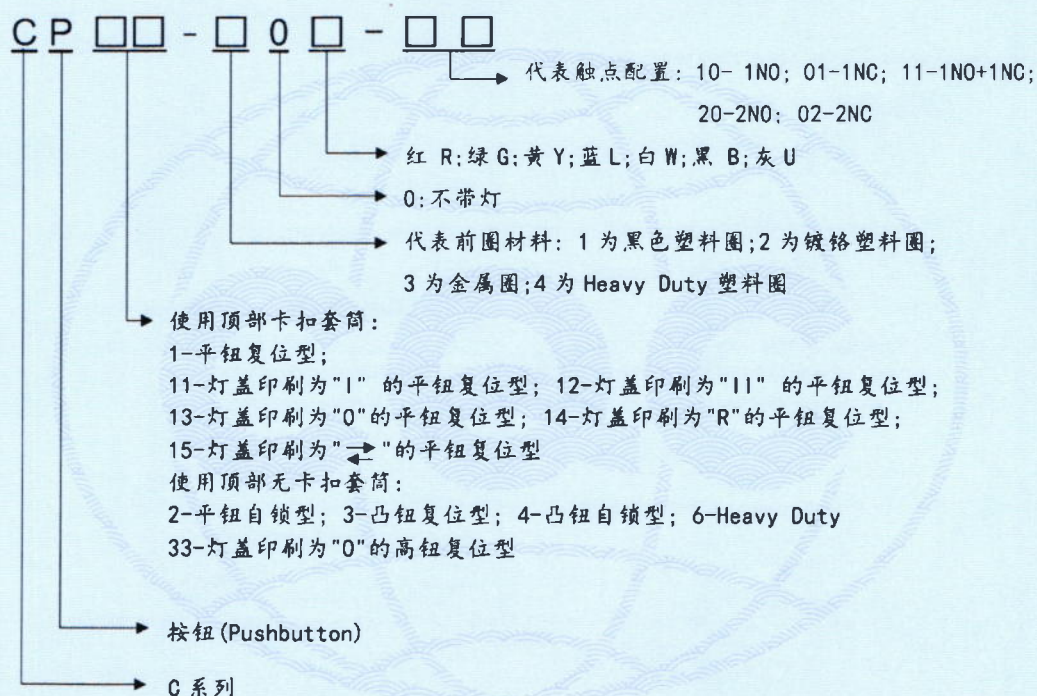

带灯按钮



中国质量认证中心

<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

代表触点配置: 10- 1NO; 01-1NC

红 R; 绿 G; 黄 Y; 蓝 L; 透明 C

指示灯额定电压: 1-24V AC/DC; 2-110-130V AC/DC; 3-230V AC/DC

产品认证证书

II型自愿认证


证书编号: CQC2003010305054693

第 3 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

2 位选择开关

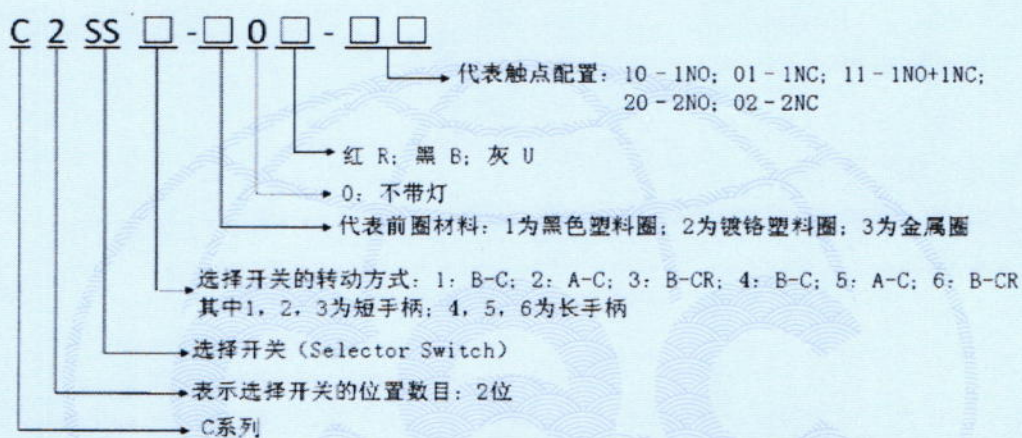

C 2 SS 9 - □ □ □ □

- 4 位序列号, 表示基于标准 C 系列的特殊印刷产品
- 代表任意标准 C 系列 2 位选择开关: C2SS1, C2SS2, C2SS3, C2SS4, C2SS5, C2SS6

附件



3 位选择开关

中国质量认证中心

<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C 3 SS □ - □ 0 □ - □ □

代表触点配置: 10 - 1NO; 01 - 1NC; 11 - 1NO+1NC;
20 - 2NO; 02 - 2NC

红 R; 黑 B; 灰 U

产品认证证书

II型自愿认证

证书编号: CQC2003010305054693

第 4 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

指示灯

CL □ - □ □ □ □

红:R; 绿:G; 黄:Y; 白:W; 透明:C; 蓝:L

- 00: 指示灯 (无灯泡), 最大电压等级 240VAC;
- 01: LED/LED II 指示灯, 12VDC; 02: LED/LED II 指示灯, 24VAC/DC
- 04: LED 指示灯, 48VAC/DC; 05: LED 指示灯, 60VAC/DC
- 06: LED/LED II 指示灯, 6.3VDC; 07: LED II 指示灯, 48-60VAC/DC
- 13: LED/LED II 指示灯, 110-130VAC; 15: LED/LED II 指示灯, 110-130VDC
- 20: LED/LED II 指示灯, 220VDC; 23: LED/LED II 指示灯, 230VAC
- 30: LED 指示灯, 380VAC; 41: LED 指示灯, 415VAC
- 42: LED/LED II 指示灯, 380-415VAC;
- -1: 指示灯 (无灯泡); -5: LED 指示灯;
- 2-5: LED II 指示灯;
- 2-6: LED II 指示灯 (具有较高抗感应电压的客户化产品)
- 指示灯 (Light)
- C 系列

CL9- □ □ □ □

→ 4 位序列号, 表示基于标准 C 系列的特殊产品

→ 代表任意标准 C 系列指示灯

附件



中国质量认证中心

产品认证证书

II型自愿认证

证书编号: CQC2003010305054693

第 5 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

急停开关

C E □ □ □ - 1 0 □ - □ □

- 代表触点配置: 10-1NO; 01-1NC; 11-1NO+1NC; 20-2NO; 02-2NC
- 红:R; 绿:G; 黄:Y; 蓝:L; 白:W; 黑:B
- 0: 不带灯
- 塑料前圈
- 头部是用钥匙释放时钥匙的种类, 1: Key code 455; 2, 3. 按客户要求
头部无需用钥匙释放: (空白)
- T: 头部是转动释放; P: 头部是拉动释放; K: 头部是用钥匙释放
- 3-头部直径是 30mm, 4-头部直径是 40mm
- 急停按钮 (Emergency Stop)
- C 系列

CE9- □ □ □ □

- 4 位序列号, 表示基于标准 C 系列的特殊产品
- 代表任意标准 C 系列急停按钮

附件



中国质量认证中心

^{蜂鸣器}
<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C B 1 - 6 □ □ □

红:R; 绿:G; 黄:Y; 蓝:L; 白:W; 黑:B; 灰:U; 透明:C

产品认证证书

II型自愿认证

证书编号: CQC2003010305054693


第 6 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

塑料按钮盒(套装)

CEP □ 1 - □□□□

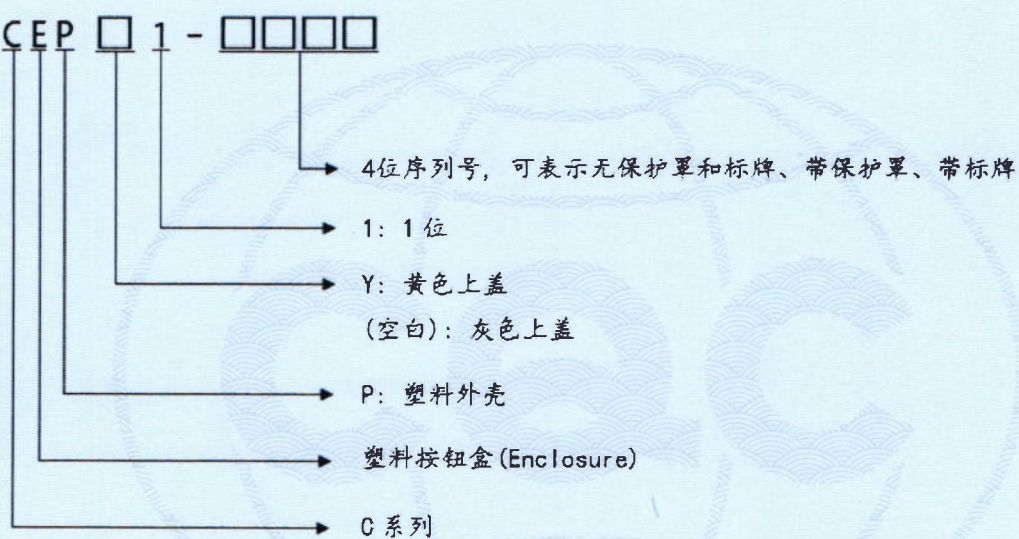

附件



中国质量认证中心

产品认证证书


II型自愿认证

证书编号: CQC2003010305054693

第 7 页 共 7 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 31457

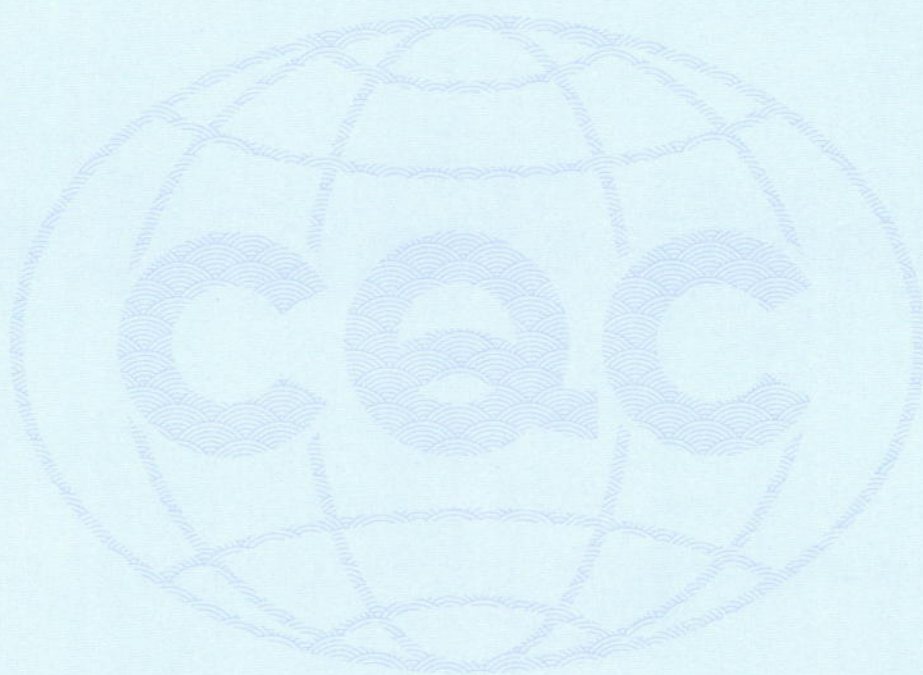

附件



中国质量认证中心