

# 产品认证证书

## II型自愿认证

证书编号: CQC2009010307370092

发证日期: 2022年03月24日

有效期至: 2032年03月23日

**委托人名称及注册地址** 厦门 ABB 低压电器设备有限公司  
厦门火炬高新区(翔安)产业区舩山西二路 881 号一层

**制造商名称及注册地址** 厦门 ABB 低压电器设备有限公司  
厦门火炬高新区(翔安)产业区舩山西二路 881 号一层

**生产企业名称及生产地址** 厦门 ABB 低压电器设备有限公司  
福建省厦门市火炬高新区(翔安)产业区舩山西二路 881 号

**产品名称和系列、规格、型号** 万能式断路器  
E4S,E4H,E4V,E4H/f;详见附件

**产品标准和技术要求** GB/T 14048.2-2020

**认证模式** 产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC12-000001-2020 认证规则的要求, 特发此证。

本证书为变更证书, 证书首次颁发日期: 2020 年 09 月 01 日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站(www.cnca.gov.cn)查验证书信息



授权签字人

签发

罗妍

谢肇煦



中国质量认证中心



<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C(2) 0147467



# CERTIFICATE OF PRODUCT CERTIFICATION

## TYPE II CQC CERTIFICATION

CERTIFICATE NO.: CQC2009010307370092

Valid from: Mar.24,2022

Valid until: Mar.23,2032

|                                                                  |                                                                                                                                                                                       |
|------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>NAME AND REGISTERED ADDRESS OF THE APPLICANT</b>              | ABB Xiamen Low Voltage Equipment Co., Ltd.<br>1st Floor, No. 881, FangShanXiEr Road, Xiang' An Industrial Area, Torch Hi-Tech Industrial Development Zone, Xiamen, Fujian, P.R. China |
| <b>NAME AND REGISTERED ADDRESS OF THE MANUFACTURER</b>           | ABB Xiamen Low Voltage Equipment Co., Ltd.<br>1st Floor, No. 881, FangShanXiEr Road, Xiang' An Industrial Area, Torch Hi-Tech Industrial Development Zone, Xiamen, Fujian, P.R. China |
| <b>NAME AND LOCATION OF THE FACTORY</b>                          | ABB Xiamen Low Voltage Equipment Co., Ltd.<br>No. 881, FangShanXiEr Road, Xiang' An Industrial Area, Torch Hi-Tech Industrial Development Zone, Xiamen, Fujian, P.R.China             |
| <b>PRODUCT NAME, MODEL AND SPECIFICATION</b>                     | Air Circuit-breaker<br>E4S,E4H,E4V,E4H/f;see the Appendix                                                                                                                             |
| <b>THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS</b> | GB/T 14048.2-2020                                                                                                                                                                     |
| <b>TYPE OF CERTIFICATION SCHEMES</b>                             | Type Testing of Product + Initial Factory Inspection + Follow up Factory Inspection                                                                                                   |

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC12-000001-2020.

Date of original issued: Sep.01,2020

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

The certificate information is available through the QR code below or CNCA's website: [www.cnca.gov.cn](http://www.cnca.gov.cn)



SIGN BY

罗妍

SIGNATURE

谢肇熙

CHINA QUALITY CERTIFICATION CENTRE



<http://www.cqc.com.cn>

Section 9, No. 188, Nansihuan Xilu, Beijing 100070 P.R. China

Tel: +86 10 83886666

C(2) 0147467



# 产品认证证书

## II型自愿认证

证书编号: CQC2009010307370092

第1页 共2页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 147467

上报参数:

E4S、E4H、E4V、E4H/f

Uimp: 12kV;

Ui: 1000V;

Ue: AC230V, AC415V, AC440V, AC525V, AC690V;

Ie: E4S, E4H, E4H/f: 800A, 1000A, 1250A, 1600A, 2000A, 2500A, 3200A, 4000A;

E4V: 1250A, 1600A, 2000A, 2500A, 3200A, 4000A;

过电流脱扣器类型: 电子式;

E4S: Icu=Ics=75kA, Icw: 75kA/1s;

E4H: Icu=Ics=100kA(AC230V, AC415V, AC440V, AC525V);

Icu=Ics=85kA(AC690V);

Icw: 100kA/1s;

E4V: Icu=Ics=150kA(AC230V, AC415V, AC440V);

Icu=Ics=130kA(AC525V);

Icu=Ics=100kA(AC690V);

Icw: 100kA/1s;

E4H/f: Icu=Ics=100kA, Icw: 85kA/1s;

选择性类别: B;

极数: 3P, 4P;

适用于隔离;

适用频率: 50/60Hz;

配用的辅助报警触头 (本体):

2NO2NC, 5NO5NC, 15NO15NC;

Ith: 15A;

AC-12: Ue/Ie: AC250V/15A, AC400V/3A;

DC-12: Ue/Ie: DC125V/0.3A, DC250V/0.15A;

符合附录 N 的电子附件:

欠压 YU:

Us: 24V DC, 30/48/110-120/120-127/220-240V AC/DC, 380-400V AC 50/60Hz

分励/闭合线圈 YO/YC:

Us: 24V DC, 30/48/110-120/120-127/220-240V AC/DC, 380-400V AC 50/60Hz



中国质量认证中心





# 产品认证证书

## II型自愿认证

证书编号: CQC2009010307370092


第 2 页 共 2 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 147467

型号解释:

Emax 系列万能式断路器

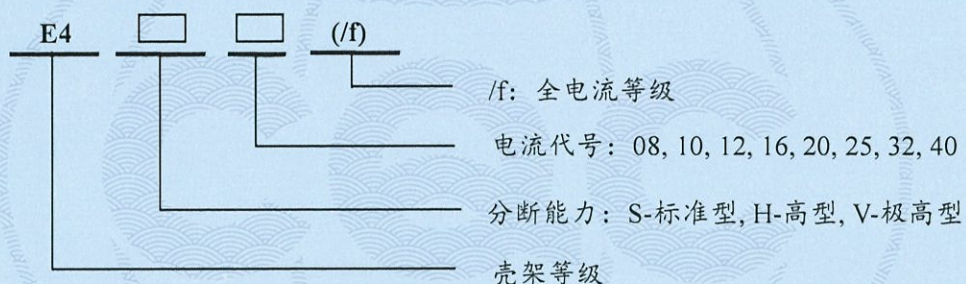

中国质量认证中心

