

产品认证证书

II型自愿认证

证书编号: CQC2010010307423576

发证日期: 2022年03月24日

有效期至: 2032年03月23日

委托人名称	厦门 ABB 低压电器设备有限公司
及注册地址	厦门火炬高新区(翔安)产业区舩山西二路 881 号一层
制造商名称	厦门 ABB 低压电器设备有限公司
及注册地址	厦门火炬高新区(翔安)产业区舩山西二路 881 号一层
生产企业名称	厦门 ABB 低压电器设备有限公司
及生产地址	福建省厦门市火炬高新区(翔安)产业区舩山西二路 881 号
产品名称和系列、 规格、型号	塑料外壳式断路器 T7S,T7H,T7L; 详见参数附件
产品标准和技术要求	GB/T 14048.2-2020
认证模式	产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC12-000001-2020 认证规则的要求, 特发此证。

本证书为变更证书, 证书首次颁发日期: 2020 年 09 月 01 日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站(www.cnca.gov.cn)查验证书信息



授权签字人

签发

罗妍

谢肇煦



中国质量认证中心



<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C(2) 0147468

CERTIFICATE OF PRODUCT CERTIFICATION

TYPE II CQC CERTIFICATION

CERTIFICATE NO.: CQC2010010307423576

Valid from: Mar.24,2022

Valid until: Mar.23,2032

NAME AND REGISTERED ADDRESS OF THE APPLICANT	ABB Xiamen Low Voltage Equipment Co., Ltd. 1st Floor, No. 881, FangShanXiEr Road, Xiang' An Industrial Area, Torch Hi-Tech Industrial Development Zone, Xiamen, Fujian, P.R. China
NAME AND REGISTERED ADDRESS OF THE MANUFACTURER	ABB Xiamen Low Voltage Equipment Co., Ltd. 1st Floor, No. 881, FangShanXiEr Road, Xiang' An Industrial Area, Torch Hi-Tech Industrial Development Zone, Xiamen, Fujian, P.R. China
NAME AND LOCATION OF THE FACTORY	ABB Xiamen Low Voltage Equipment Co., Ltd. No. 881, FangShanXiEr Road, Xiang' An Industrial Area, Torch Hi-Tech Industrial Development Zone, Xiamen, Fujian, P.R.China
PRODUCT NAME, MODEL AND SPECIFICATION	Moulded Case Circuit-breaker T7S,T7H,T7L; See the Appendix
THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS	GB/T 14048.2-2020
TYPE OF CERTIFICATION SCHEMES	Type Testing of Product + Initial Factory Inspection + Follow up Factory Inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC12-000001-2020.

Date of original issued: Sep.01,2020

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

The certificate information is available through the QR code below or CNCA's website: www.cnca.gov.cn



SIGN BY

罗妍

SIGNATURE

谢肇熙



CHINA QUALITY CERTIFICATION CENTRE



<http://www.cqc.com.cn>

Section 9, No.188, Nansihuan Xilu, Beijing 100070 P.R.China

Tel: +86 10 83886666

C(2) 0147468

产品认证证书

II型自愿认证

证书编号: CQC2010010307423576

第 1 页 共 2 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 147468

上报参数:

T7S, T7H, T7L

Uimp:8kV;

Ui:1000V

Ue:AC220V, AC230V, AC380V, AC415V, AC440V, AC500V, AC690V;

Ie:400A, 630A, 800A, 1000A, 1250A, 1600A;

过电流脱扣器类型:电子式;

T7S:

Ue:220/230V: Icu:85kA, Ics:85kA, Icw:20kA/1s;

Ue:380/415V/440V: Icu:50kA, Ics:50kA, Icw:20kA/1s;

Ue:500V: Icu:40kA, Ics:40kA, Icw:20kA/1s;

Ue:690V: Icu:30kA, Ics:30kA, Icw:20kA/1s;

T7H:

Ue:220/230V: Icu:100kA, Ics:100kA, Icw:20kA/1s;

Ue:380/415V: Icu:70kA, Ics:70kA, Icw:20kA/1s;

Ue:440V: Icu:65kA, Ics:65kA, Icw:20kA/1s;

Ue:500V: Icu:50kA, Ics:50kA, Icw:20kA/1s;

Ue:690V: Icu:42kA, Ics:32kA, Icw:20kA/1s;

T7L:

Ue:220/230V: Icu:200kA, Ics:200kA, Icw:20kA/1s;

Ue:380/415V: Icu:120kA, Ics:120kA, Icw:20kA/1s;

Ue: 440V: Icu:100kA, Ics:100kA, Icw:20kA/1s;

Ue:500V: Icu:85kA, Ics:64kA, Icw:20kA/1s;

Ue:690V: Icu:50kA, Ics:38kA, Icw:20kA/1s;

适用频率: 50/60Hz;

适用于隔离;

选择性类别: B;

极数:3P,4P;

配用的辅助报警触头 (本体):



中国质量认证中心



产品认证证书

II型自愿认证

证书编号: CQC2010010307423576

第 2 页 共 2 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 147468

4NO4NC;

Ith:5A;

AC-12: Ue/Ie: AC250V/5A, AC400V/3A;

DC-12: Ue/Ie: DC125V/0.5A, DC250V/0.3A;

符合附录 N 的电子附件:


欠压脱扣器: UVR, Us: AC/DC24V, AC/DC110-120V, AC/DC 220-240V;

分励脱扣器: SOR, Us: AC/DC24V, AC/DC110-120V, AC/DC 220-240V;

闭合线圈: Us: AC/DC24V, AC/DC110-120V, AC/DC 220-240V;

型号解释:

Tmax 系列塑料外壳式断路器:

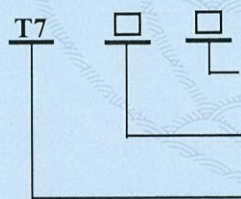

电流值(A): 400,630,800,1000,1250,1600

分断能力: S-标准型,H-高型,L-大型

壳架等级



中国质量认证中心

