



# 产品认证证书

证书编号: CQC2015010302771588

## 申请人名称及地址

ABB S.P.A. - ABB SACE Division  
Via Pescaria 5, 24123 Bergamo ITALY

## 制造商名称及地址

ABB S.P.A. - ABB SACE Division  
Via Pescaria 5, 24123 Bergamo ITALY

## 生产企业名称及地址

ABB S.P.A. - ABB SACE Division (V054909)  
Via Enrico Fermi 14, IT-03100 Frosinone Italy

## 产品名称和系列、规格、型号

### 隔离开关

E2.2B/MS, E2.2N/MS, E2.2H/MS, E2.2H/E9/MS, E2.2H/E/MS; 详细参数见附件

## 产品标准和技术要求

GB/T14048.3-2017

## 认证模式

型式试验+初始工厂检查+获证后监督

上述产品符合 CQC11-462141-2019 认证规则的要求, 特发此证。

发证日期: 2020 年 09 月 02 日      有效期至: 2024 年 07 月 08 日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

主任: \_\_\_\_\_

陆楠



## 中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>

C 0356178





# PRODUCT CERTIFICATE

**CERTIFICATE NO.: CQC2015010302771588**

**NAME AND ADDRESS OF THE APPLICANT**

ABB S.P.A. - ABB SACE Division  
Via Pescaria 5, 24123 Bergamo ITALY

**NAME AND ADDRESS OF THE MANUFACTURER**

ABB S.P.A. - ABB SACE Division  
Via Pescaria 5, 24123 Bergamo ITALY

**NAME AND ADDRESS OF THE FACTORY**

ABB S.P.A. - ABB SACE Division (V054909)  
Via Enrico Fermi 14, IT-03100 Frosinone Italy

**PRODUCT NAME, MODEL AND SPECIFICATION**

Switch-disconnectors  
E2.2B/MS, E2.2N/MS, E2.2H/MS, E2.2H/E9/MS, E2.2H/E/MS; See the appendix

**THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS**

GB/T14048.3-2017

**TYPE OF CERTIFICATION SCHEMES**

Type testing of product + initial factory inspection + follow up factory inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC11-462141-2019 .

**Valid from:** Sep.02,2020

**Valid until:** Jul.08,2024

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

**President:**

Lu Mei



## CHINA QUALITY CERTIFICATION CENTRE

Section 9, No.188, Nansihuan Xilu, Beijing 100070 P.R.China  
<http://www.cqc.com.cn>

C 0356178



# 产品认证证书

附录

第 1 页 共 2 页

证书编号: CQC2015010302771588

纸号: 356178

E2. 2B/MS, E2. 2N/MS, E2. 2H/MS, E2. 2H/E9/MS, E2. 2H/E/MS

Uimp: 12kV;

Ui: 1000V (E2. 2B/MS, E2. 2N/MS, E2. 2H/MS), 1250V (E2. 2H/E9/MS, E2. 2H/E/MS);

Ith: 2000A (E2. 2B/MS), 2500A (E2. 2N/MS, E2. 2H/MS, E2. 2H/E9/MS, E2. 2H/E/MS);

Ue: AC440V, AC690V (E2. 2B/MS, E2. 2N/MS, E2. 2H/MS);

AC900V (E2. 2H/E9/MS, E2. 2H/E/MS); AC1000/1140V (E2. 2H/E/MS);

Ie: 1600A, 2000A (E2. 2B/MS);

800A, 1000A, 1250A, 1600A, 2000A, 2500A (E2. 2N/MS, E2. 2H/MS, E2. 2H/E/MS);

1250A, 1600A, 2000A, 2500A (E2. 2H/E9/MS);

Icw 和 Icm 见下表:

| Ue             |                | E2.2B/MS | E2.2N/MS | E2.2H/MS | E2.2H/E9 MS | E2.2H/E MS |
|----------------|----------------|----------|----------|----------|-------------|------------|
| 440 - 690Vac   | Icw 1s<br>[kA] | 42       | 66       | 85       | -           | -          |
| 900Vac         |                | -        | -        | -        | 65          | 65         |
| 1000 - 1140Vac |                | -        | -        | -        | -           | 50         |
| 440 - 690Vac   | Icm [kA]       | 88       | 145      | 187      | -           | -          |
| 900Vac         |                | -        | -        | -        | 143         | 143        |
| 1000 - 1140Vac |                | -        | -        | -        | -           | 105        |

使用类别: AC-23A;

适用频率: 50/60Hz;

极数: 3P, 4P

注: 此附录与证书同时使用时有效。

主任:

陆梅

中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>







# 产品认证证书


附录

第 2 页 共 2 页

证书编号: CQC2015010302771588

纸 号: 356178

型号解释:

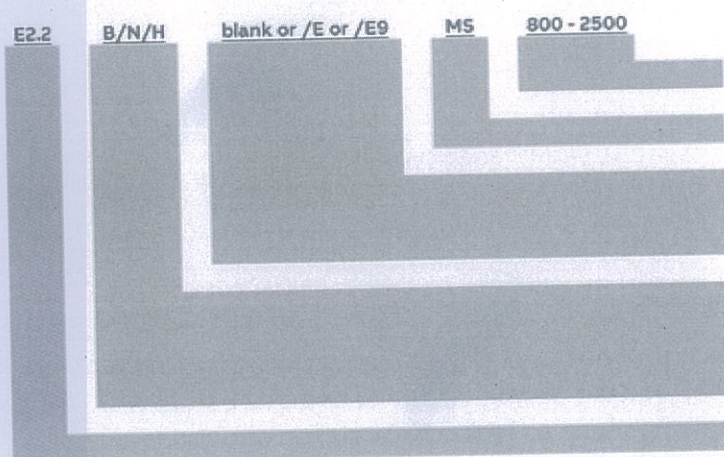

额定电流

MS = 隔离开关

空白 = 690Vac 版本  
/E = 1000-1140Vac 版本  
/E9 = 900Vac 版本

短时耐受等级

H = 高型  
N = 普通型  
B = 基本型

E2.2 = Emax2系列隔离开关型号 E2.2

注: 此附录与证书同时使用时有效。

主任: \_\_\_\_\_

陆梅



## 中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>